




AMP D-Subminiature Connectors


A

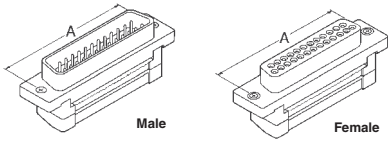

Material and Finish: • Plastic Shell: Housing, Cover and Cable Stabilizer - 94V-0 rated thermoplastic, black • Metal Shell: Front Shell - Steel, tin plated Housing, Cover & Cable Stabilizer - 94V-0 rated thermoplastic, black • Contacts: Phosphor bronze, duplex plated 30µ" gold on mating end, tin-lead on termination end, with entire contact nickel underplated • Threaded Inserts: Brass, unplated • Mounting Holes: Standard - .120" (3.05mm) Diameter

Recognized under the Component Program of Underwriters Laboratories Inc., File No. E28476 Certified by Canadian Standards Association., File No. LR 46568

Table with columns: No. of Contacts, Conn. Finish, Dimension A Inch (mm), Digi-Key Part No., Pricing 1 10, AMP Part No. Includes sections for Male Plastic Shell, Male Plastic Shell With Threaded Inserts, Male Metal Shell, Male Metal Shell With Threaded Inserts, Female Plastic Shell, Female Plastic Shell With Threaded Inserts, Female Metal Shell, Female Metal Shell With Threaded Inserts, and Cable Strain Relief/Stabilizer.

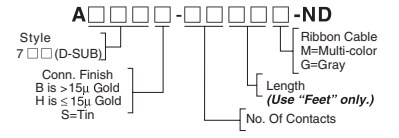

AMP D-Subminiature Cable Assemblies



Single Ended - Male * MC = Multi-Color, GR = Gray Plastic shell with strain relief shown

Table with columns: No. of Contacts, Conn. Finish, Length Feet (Meters), Rib-bon* Cable, Digi-Key Part No., Pricing 1 10

Also available in the following configuration: A7PX-...-ND - With Metal Shell Connector and Strain Relief. Note: Also available with 50 contacts. A7VXB-...-ND - Metal Shell with Threaded Insert and Strain Relief. A7NXB-...-ND - Plastic Shell with Threaded Insert and Strain Relief. Note: Available with 9, 15 and 25 contacts. Call for complete part number and pricing!

Single Ended - Female * MC = Multi-Color, GR = Gray Plastic shell with strain relief shown

Table with columns: No. of Contacts, Conn. Finish, Length Feet (Meters), Rib-bon* Cable, Digi-Key Part No., Pricing 1 10

Also available in the following configuration: A7SX-...-ND - With Metal Shell Connector and Strain Relief. Note: Also available with 50 contacts. A7WXB-...-ND - Metal Shell with Threaded Insert and Strain Relief. A7OXB-...-ND - Plastic Shell with Threaded Insert and Strain Relief. Call for complete part number and pricing!

Male to Male * MC = Multi-Color, GR = Gray Plastic shell with strain relief shown

Table with columns: No. of Contacts, Conn. Finish, Length Feet (Meters), Rib-bon* Cable, Digi-Key Part No., Pricing 1 10

Table with columns: No. of Contacts, Conn. Finish, Length Feet (Meters), Rib-bon* Cable, Digi-Key Part No., Pricing 1 10

Also available in the following configuration: A7PP-...-ND - With Metal Shell Connector and Strain Relief. Note: Also available with 50 contacts. A7VVB-...-ND - Metal Shell with Threaded Insert and Strain Relief. A7NNB-...-ND - Plastic Shell with Threaded Insert and Strain Relief. Call for complete part number and pricing!

Female to Female * MC = Multi-Color, GR = Gray Plastic shell with strain relief shown

Table with columns: No. of Contacts, Conn. Finish, Length Feet (Meters), Rib-bon* Cable, Digi-Key Part No., Pricing 1 10

Also available in the following configuration: A7SS-...-ND - With Metal Shell Connector and Strain Relief. Note: Also available with 50 contacts. A7WWB-...-ND - Metal Shell with Threaded Insert and Strain Relief. A7O0B-...-ND - Plastic Shell with Threaded Insert and Strain Relief. Call for complete part number and pricing!

Male to Female * MC = Multi-Color, GR = Gray Plastic shell with strain relief shown

Table with columns: No. of Contacts, Conn. Finish, Length Feet (Meters), Rib-bon* Cable, Digi-Key Part No., Pricing 1 10

Also available in the following configuration: A7PS-...-ND - With Metal Shell Connector and Strain Relief. Note: Also available with 50 contacts. A7VWB-...-ND - Metal Shell with Threaded Insert and Strain Relief. A7NOB-...-ND - Plastic Shell with Threaded Insert and Strain Relief. Call for complete part number and pricing!

Free shipping on orders over \$200 CAD! All prices in Canadian dollars and include duty and brokerage fees. 30 (CA2011) 1-800-344-4539 • www.digikey.ca • 218-681-6674 • Fax: 218-681-3380