

A

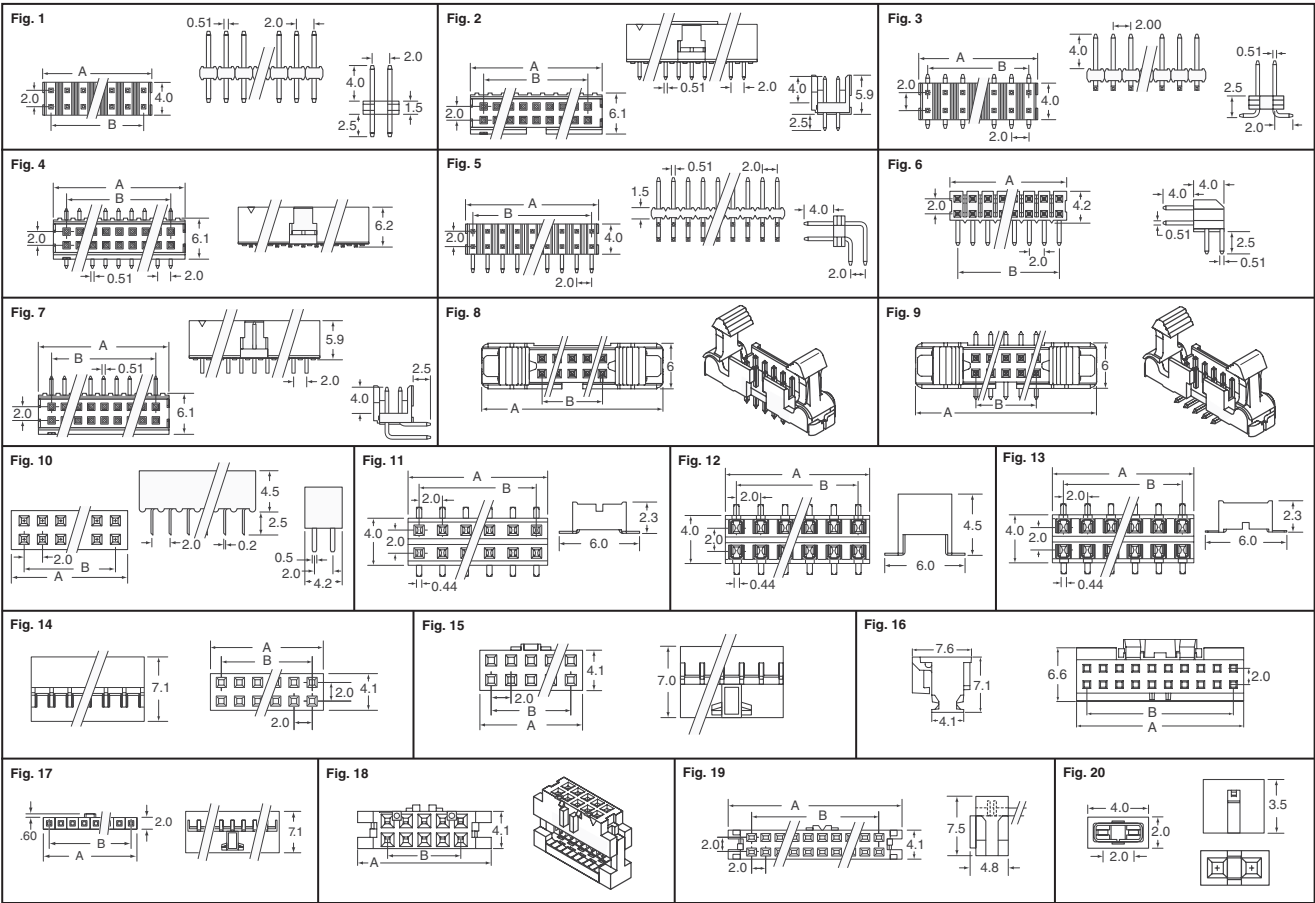


Fig.	No. of Pos.	Dim. (mm)		Digi-Key Part No.	Pricing			FCI Part No.	
		A	B		1	25	100		
Dual Row Unshrouded Vertical Headers, Through Hole									
1	4	4.00	2.00	609-2591-ND	1.18	15.01	50.70	57102-G06-02LF	
	6	6.00	4.00	609-2583-ND	1.08	13.78	46.72	57102-G06-03LF	
	8	8.00	6.00	609-2602-ND	1.28	17.56	59.08	57102-G06-04LF	
	10	10.00	8.00	609-2590-ND	1.93	26.72	91.60	57102-G06-05LF	
	12	12.00	10.00	609-2595-ND	2.32	32.06	109.90	57102-G06-06LF	
	14	14.00	12.00	609-2596-ND	2.61	36.09	123.74	57102-G06-07LF	
	16	16.00	14.00	609-2597-ND	2.76	37.32	130.61	57102-G06-08LF	
	20	20.00	18.00	609-2593-ND	1.77	24.01	84.05	57102-G06-10LF	
	22	22.00	20.00	609-2594-ND	3.55	48.97	167.91	57102-G06-11LF	
	26	26.00	24.00	609-2599-ND	3.64	53.75	190.73	57102-G06-13LF	
1	30	30.00	28.00	609-2603-ND	3.82	58.83	207.36	57102-G06-15LF	
	32	32.00	30.00	609-2604-ND	4.34	64.46	230.67	57102-G06-16LF	
	34	34.00	32.00	609-2605-ND	4.47	68.47	245.08	57102-G06-17LF	
	36	36.00	34.00	609-2600-ND	4.74	72.51	251.89	57102-G06-18LF	
	40	40.00	38.00	609-2589-ND	4.58	70.61	248.84	57102-G06-20LF	
	44	44.00	42.00	609-2608-ND	4.68	72.61	263.02	57102-G06-22LF	
	50	50.00	48.00	609-2624-ND	3.14	46.59	166.73	57102-G06-25LF	
	Dual Row Unshrouded Vertical Headers, Through Hole, Pin-in-Paste								
	1	8	8.00	6.00	609-2888-ND	2.00	27.02	94.55	10075024-G01-04ULF
		10	10.00	8.00	609-2889-ND	1.35	18.72	65.51	10075024-G01-05ULF
12		12.00	10.00	609-2890-ND	1.72	24.15	79.02	10075024-G01-06ULF	
20		20.00	18.00	609-2894-ND	2.98	44.06	156.35	10075024-G01-10ULF	
22		22.00	20.00	609-2895-ND	3.28	49.09	171.20	10075024-G01-11ULF	
26		26.00	24.00	609-2897-ND	3.73	57.04	198.12	10075024-G01-13ULF	
32		32.00	30.00	609-2900-ND	4.26	65.68	231.49	10075024-G01-16ULF	
34		34.00	32.00	609-2901-ND	4.41	68.07	239.91	10075024-G01-17ULF	
36		36.00	34.00	609-2902-ND	4.42	68.55	248.32	10075024-G01-18ULF	
40		40.00	38.00	609-2904-ND	4.79	74.37	269.35	10075024-G01-20ULF	
1	42	42.00	40.00	609-2905-ND	5.05	78.43	284.10	10075024-G01-21ULF	
	44	44.00	42.00	609-2906-ND	5.27	81.92	296.72	10075024-G01-22ULF	
	46	46.00	44.00	609-2907-ND	5.35	85.99	305.73	10075024-G01-23ULF	
	48	48.00	46.00	609-2908-ND	5.57	89.47	318.12	10075024-G01-24ULF	
	50	50.00	48.00	609-2909-ND	5.93	92.63	338.77	10075024-G01-25ULF	
	Dual Row Shrouded Vertical Headers, Through Hole								
	2	6	8.00	4.00	609-3628-ND	1.13	14.45	48.83	98414-G06-06LF
		6	8.00	4.00	609-3103-ND	1.63	22.47	77.01	98414-G06-06ULF
		8	10.00	6.00	609-3104-ND	1.31	18.12	60.97	98414-G06-08ULF
		10	12.00	8.00	609-2580-ND	1.95	27.10	94.86	98414-G06-10LF
10		12.00	8.00	609-3105-ND	1.53	20.59	70.62	98414-G06-10ULF	

Fig.	No. of Pos.	Dim. (mm)		Digi-Key Part No.	Pricing			FCI Part No.	
		A	B		1	25	100		
2	12	14.00	10.00	609-2581-ND	2.35	32.52	113.82	98414-G06-12LF	
	12	14.00	10.00	609-3106-ND	1.83	24.72	86.51	98414-G06-12ULF	
	14	16.00	12.00	609-2576-ND	2.50	34.79	121.73	98414-G06-14LF	
	16	18.00	14.00	609-2577-ND	1.98	26.76	93.66	98414-G06-16LF	
	16	18.00	14.00	609-3107-ND	2.31	32.96	114.01	98414-G06-16ULF	
	20	22.00	18.00	609-2582-ND	2.35	33.45	115.73	98414-G06-20LF	
	20	22.00	18.00	609-3108-ND	2.72	40.16	142.51	98414-G06-20ULF	
	22	24.00	20.00	609-2585-ND	3.23	48.44	168.93	98414-G06-22LF	
	26	28.00	24.00	609-2607-ND	3.64	55.78	199.65	98414-G06-26LF	
	34	36.00	32.00	609-2588-ND	4.61	71.02	250.32	98414-G06-34LF	
2	44	46.00	42.00	609-2606-ND	5.00	80.49	286.20	98414-G06-44LF	
	50	52.00	48.00	609-2584-ND	5.69	88.93	325.22	98414-G06-50LF	
Dual Row Shrouded Vertical Headers, Through Hole, Pin-in-Paste									
2	6	14.00	10.00	609-2935-ND	2.19	30.34	106.20	10075025-G01-06LF	
	10	22.00	18.00	609-2937-ND	1.45	20.04	70.12	10075025-G01-10ULF	
	12	26.00	22.00	609-2938-ND	1.83	24.67	84.55	10075025-G01-12ULF	
	14	30.00	26.00	609-2939-ND	2.08	29.01	99.46	10075025-G01-14ULF	
	16	34.00	30.00	609-2940-ND	2.78	38.68	135.39	10075025-G01-16ULF	
	20	42.00	38.00	609-2942-ND	3.14	47.14	164.41	10075025-G01-20ULF	
3	26	54.00	50.00	609-2945-ND	3.98	61.12	211.99	10075025-G01-26ULF	
	40	82.00	78.00	609-2952-ND	5.13	79.57	288.24	10075025-G01-40ULF	
	50	102.00	98.00	609-2957-ND	6.23	99.12	362.50	10075025-G01-50ULF	
	Dual Row Unshrouded Vertical Headers, SMD								
	3	4	4.00	2.00	609-2614-ND	1.16	14.77	49.89	57202-G52-02LF
		6	6.00	4.00	609-2615-ND	2.29	31.56	106.12	57202-G52-03LF
		8	8.00	6.00	609-2623-ND	.89	11.05	35.93	57202-G52-04LF
		10	10.00	8.00	609-2610-ND	1.03	12.94	43.88	57202-G52-05LF
		12	12.00	10.00	609-2618-ND	1.17	15.19	51.32	57202-G52-06LF
		14	14.00	12.00	609-2619-ND	1.26	17.33	58.30	57202-G52-07LF
16		16.00	14.00	609-2620-ND	1.44	19.62	66.65	57202-G52-08LF	
20		20.00	18.00	609-2622-ND	1.71	23.63	81.04	57202-G52-10LF	
22		22.00	20.00	609-2616-ND	3.64	54.61	190.12	57202-G52-11LF	
30		30.00	28.00	609-2628-ND	4.72	70.86	247.10	57202-G52-15LF	
3	32	32.00	30.00	609-2633-ND	2.45	36.02	124.62	57202-G52-16LF	
	36	36.00	34.00	609-2630-ND	5.12	78.85	277.90	57202-G52-18LF	
	40	40.00	38.00	609-2632-ND	5.16	82.92	294.79	57202-G52-20LF	
	44	44.00	42.00	609-2627-ND	5.13	82.48	293.27	57202-G52-22LF	
	50	50.00	48.00	609-2638-ND	5.84	91.09	333.12	57202-G52-25LF	

Δ Cut Tape ★ Tape & Reel § Pin Length is 2.0mm

(Continued)

Digi-Reel® Most SMT cutdown parts are available on a Digi-Reel®. For Digi-Reel part number, change 1-ND to 6-ND or CT-ND to DKR-ND. See Digi-Key® Services on page 2 for additional information.

Free shipping on orders over \$200 CAD! All prices in Canadian dollars and include duty and brokerage fees.