



BergStik™ .100" (2.54mm) Headers



A

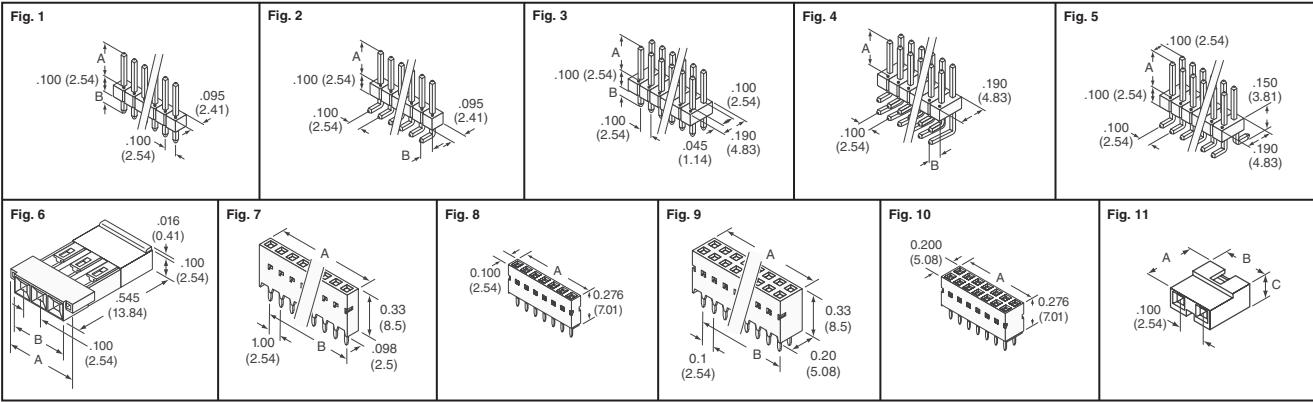


Fig.	No. of Positions	Plating	Dimensions - Inches (mm)		Digi-Key Part No.	Pricing		FCI Part No.
			A	B		1	25	
Straight Single Row								
1	1	30µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3460-ND	.22	2.58	68000-101HLF
	2	30µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3500-ND	1.23	16.90	68000-102HLF
	3	30µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3461-ND	.24	2.66	68000-103HLF
	4	30µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3248-ND	.27	4.03	68000-104HLF
	5	30µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3462-ND	.53	6.27	68000-105HLF
	6	30µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3249-ND	.61	7.26	68000-106HLF
	8	30µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3400-ND	2.98	44.82	68000-108HLF
	9	30µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3463-ND	.85	10.38	68000-109HLF
	10	30µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3250-ND	.58	6.93	68000-110HLF
	12	30µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3251-ND	.95	12.05	68000-112HLF
	16	30µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3252-ND	1.25	17.17	68000-116HLF
	20	30µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3253-ND	1.31	18.10	68000-120HLF
	26	30µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3254-ND	1.66	22.95	68000-126HLF
	32	30µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3501-ND	1.99	27.52	68000-136HLF
	2	15µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3502-ND	.38	4.47	68000-202HLF
	3	15µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3464-ND	.25	2.68	68000-203HLF
	4	15µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3255-ND	.38	4.42	68000-204HLF
	6	15µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3256-ND	.52	6.26	68000-206HLF
	8	15µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3257-ND	.62	7.53	68000-208HLF
	10	15µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3258-ND	.77	9.72	68000-210HLF
	12	15µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3259-ND	.86	10.83	68000-212HLF
	16	15µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3260-ND	1.09	13.66	68000-216HLF
	26	15µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3261-ND	1.54	20.72	68000-226HLF
	36	15µ" Gold	0.230 (5.84)	0.095 (2.41)	609-3465-ND	1.21	15.91	68000-236HLF
	1	100µ" Tin	0.230 (5.84)	0.095 (2.41)	609-3466-ND	.15	1.86	68000-401HLF
	2	100µ" Tin	0.230 (5.84)	0.095 (2.41)	609-3503-ND	2.49	35.64	68000-402HLF
	3	100µ" Tin	0.230 (5.84)	0.095 (2.41)	609-3504-ND	2.66	39.37	68000-403HLF
	4	100µ" Tin	0.230 (5.84)	0.095 (2.41)	609-3262-ND	.39	4.56	68000-404HLF
	6	100µ" Tin	0.230 (5.84)	0.095 (2.41)	609-3263-ND	.39	4.54	68000-406HLF
	8	100µ" Tin	0.230 (5.84)	0.095 (2.41)	609-3264-ND	.46	5.33	68000-408HLF
	10	100µ" Tin	0.230 (5.84)	0.095 (2.41)	609-3265-ND	.64	7.84	68000-410HLF
	12	100µ" Tin	0.230 (5.84)	0.095 (2.41)	609-3266-ND	.75	9.41	68000-412HLF
	16	100µ" Tin	0.230 (5.84)	0.095 (2.41)	609-3267-ND	.97	11.63	68000-416HLF
	18	100µ" Tin	0.230 (5.84)	0.095 (2.41)	609-3268-ND	1.04	13.08	68000-418HLF
	20	100µ" Tin	0.230 (5.84)	0.095 (2.41)	609-3269-ND	1.13	14.12	68000-420HLF
	26	100µ" Tin	0.230 (5.84)	0.095 (2.41)	609-3270-ND	1.30	17.94	68000-426HLF
	36	100µ" Tin	0.230 (5.84)	0.095 (2.41)	609-3505-ND	1.16	14.76	68000-436HLF
	1	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3467-ND	.21	2.49	68001-101HLF
	2	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3506-ND	1.63	21.84	68001-102HLF
	3	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3468-ND	.40	4.75	68001-103HLF
4	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3271-ND	.48	5.79	68001-104HLF	
6	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3272-ND	.53	6.23	68001-106HLF	
8	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3273-ND	.85	10.49	68001-108HLF	
10	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3274-ND	.97	11.59	68001-110HLF	
12	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3275-ND	.64	7.82	68001-112HLF	
16	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3276-ND	1.30	17.94	68001-116HLF	
20	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3401-ND	1.22	16.75	68001-120HLF	
26	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3277-ND	1.58	21.26	68001-126HLF	
36	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-2222-ND	1.82	25.99	68001-136HLF	
2	15µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3469-ND	.29	3.15	68001-202HLF	
3	15µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3470-ND	.35	3.80	68001-203HLF	
4	15µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3402-ND	.58	6.74	68001-204HLF	
6	15µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3403-ND	.72	8.74	68001-206HLF	
8	15µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3278-ND	1.03	12.70	68001-208HLF	

Fig.	No. of Positions	Plating	Dimensions - Inches (mm)		Digi-Key Part No.	Pricing		FCI Part No.
			A	B		1	25	
1	10	15µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3279-ND	.72	9.03	68001-210HLF
	12	15µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3280-ND	.86	10.83	68001-212HLF
	16	15µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3281-ND	1.09	13.54	68001-216HLF
	20	15µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3282-ND	1.20	16.56	68001-220HLF
	26	15µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3283-ND	1.36	18.59	68001-226HLF
	36	15µ" Gold	0.230 (5.84)	0.120 (3.05)	609-2223-ND	1.75	24.45	68001-236HLF
	2	100µ" Tin	0.230 (5.84)	0.120 (3.05)	609-3507-ND	1.41	19.88	68001-402HLF
	3	100µ" Tin	0.230 (5.84)	0.120 (3.05)	609-3471-ND	.34	3.77	68001-403HLF
	4	100µ" Tin	0.230 (5.84)	0.120 (3.05)	609-3404-ND	2.32	34.12	68001-404HLF
	6	100µ" Tin	0.230 (5.84)	0.120 (3.05)	609-3284-ND	.56	6.51	68001-406HLF
	8	100µ" Tin	0.230 (5.84)	0.120 (3.05)	609-3405-ND	3.00	44.95	68001-408HLF
	10	100µ" Tin	0.230 (5.84)	0.120 (3.05)	609-3285-ND	.64	7.84	68001-410HLF
	12	100µ" Tin	0.230 (5.84)	0.120 (3.05)	609-3286-ND	.71	8.80	68001-412HLF
	16	100µ" Tin	0.230 (5.84)	0.120 (3.05)	609-3287-ND	.95	12.04	68001-416HLF
	20	100µ" Tin	0.230 (5.84)	0.120 (3.05)	609-3288-ND	1.13	14.12	68001-420HLF
	26	100µ" Tin	0.230 (5.84)	0.120 (3.05)	609-3289-ND	1.36	18.59	68001-426HLF
	36	100µ" Tin	0.230 (5.84)	0.120 (3.05)	609-2224-ND	1.36	18.74	68001-436HLF
	4	30µ" Gold	0.230 (5.84)	0.150 (3.81)	609-3290-ND	.43	5.12	68002-104HLF
	6	30µ" Gold	0.230 (5.84)	0.150 (3.81)	609-3291-ND	.59	6.85	68002-106HLF
	8	30µ" Gold	0.230 (5.84)	0.150 (3.81)	609-3292-ND	.83	10.14	68002-108HLF
	10	30µ" Gold	0.230 (5.84)	0.150 (3.81)	609-3293-ND	.99	12.04	68002-110HLF
	12	30µ" Gold	0.230 (5.84)	0.150 (3.81)	609-3294-ND	.90	11.28	68002-112HLF
	16	30µ" Gold	0.230 (5.84)	0.150 (3.81)	609-3295-ND	1.16	14.83	68002-116HLF
	20	30µ" Gold	0.230 (5.84)	0.150 (3.81)	609-3296-ND	1.26	17.23	68002-120HLF
	26	30µ" Gold	0.230 (5.84)	0.150 (3.81)	609-3297-ND	1.58	21.37	68002-126HLF
	4	15µ" Gold	0.230 (5.84)	0.150 (3.81)	609-3298-ND	.38	4.51	68002-204HLF
	6	15µ" Gold	0.230 (5.84)	0.150 (3.81)	609-3299-ND	.54	6.37	68002-206HLF
	8	15µ" Gold	0.230 (5.84)	0.150 (3.81)	609-3300-ND	.61	7.33	68002-208HLF
	10	15µ" Gold	0.230 (5.84)	0.150 (3.81)	609-3301-ND	.72	8.82	68002-210HLF
	12	15µ" Gold	0.230 (5.84)	0.150 (3.81)	609-3302-ND	.88	10.78	68002-212HLF
	16	15µ" Gold	0.230 (5.84)	0.150 (3.81)	609-3303-ND	1.09	13.54	68002-216HLF
	26	15µ" Gold	0.230 (5.84)	0.150 (3.81)	609-3304-ND	1.51	20.43	68002-226HLF
	36	15µ" Gold	0.230 (5.84)	0.150 (3.81)	609-3508-ND	2.14	30.56	68002-236HLF
	4	100µ" Tin	0.230 (5.84)	0.150 (3.81)	609-3305-ND	.34	3.76	68002-404HLF
	6	100µ" Tin	0.230 (5.84)	0.150 (3.81)	609-3306-ND	.52	6.17	68002-406HLF
	8	100µ" Tin	0.230 (5.84)	0.150 (3.81)	609-3406-ND	.47	5.58	68002-408HLF
	10	100µ" Tin	0.230 (5.84)	0.150 (3.81)	609-3307-ND	.64	7.84	68002-410HLF
	12	100µ" Tin	0.230 (5.84)	0.150 (3.81)	609-3308-ND	.75	9.41	68002-412HLF
	16	100µ" Tin	0.230 (5.84)	0.150 (3.81)	609-3309-ND	1.03	12.96	68002-416HLF
	20	100µ" Tin	0.230 (5.84)	0.150 (3.81)	609-3310-ND	1.13	14.12	68002-420HLF
26	100µ" Tin	0.230 (5.84)	0.150 (3.81)	609-3311-ND	1.51	20.43	68002-426HLF	
36	100µ" Tin	0.500 (12.70)	0.120 (3.05)	609-3490-ND	2.13	30.40	69152-436HLF	
36	100µ" Tin	0.318 (8.08)	0.120 (3.05)	609-3510-ND	1.71	23.96	78511-436HLF	
Right Angle Single Row								
2	36	30µ" Gold	0.230 (5.84)	0.090 (2.29)	609-3497-ND	2.39	35.11	68015-136HLF
	36	100µ" Tin	0.230 (5.84)	0.090 (2.29)	609-3498-ND	2.24	33.03	68015-436HLF
	4	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3312-ND	.62	7.23	68016-104HLF
	6	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3313-ND	.47	5.44	68016-106HLF
	8	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3314-ND	1.20	15.82	68016-108HLF
	10	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3315-ND	.99	12.22	68016-110HLF
	12	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3316-ND	1.54	20.68	68016-112HLF
	16	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3317-ND	1.01	12.41	680