



AMPLIMITE®

D-Sub Connectors (Cont.)

A

Table with columns: Fig., No. of Pos., Sex, Digi-Key Part No., Price Each 1 25, AMP Part No. Includes rows for 25 and 37 pin female connectors.

Zinc Plated Shell, .545" (13.84mm) Mount — RoHS Compliant

Table with columns: Fig., No. of Pos., Sex, Digi-Key Part No., Price Each 1 25, AMP Part No. Includes rows for 9, 15, 25, 37 pin male and female connectors.

Steel, Tin Plated Shell, .545" (13.84mm) Mount, with Standard Mounting Screws — RoHS Compliant

Table with columns: Fig., No. of Pos., Sex, Digi-Key Part No., Price Each 1 25, AMP Part No. Includes rows for 9, 15, 25, 37, 50 pin male and female connectors.

Steel, Tin Plated Shell, .545" (13.84mm) Mount, with Female Screwlocks

Table with columns: Fig., No. of Pos., Sex, Digi-Key Part No., Price Each 1 25, AMP Part No. Includes rows for 9, 15, 25, 37, 50 pin male and female connectors.

◆ RoHS Compliant § 30µ Gold ▲ 15µ Gold ◊ 10µ Gold † Tin shell ‡ Gold flash on mating end ▲ With Grounding Indents and Straps * With Grounding straps

HDJ-20 All Plastic Jacketed Cable Connector

Use with HDP-20 Crimp Snap-In Contacts (sold separately)

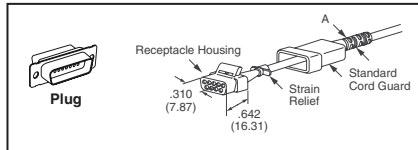


Table with columns: No. of Pos., Description, Digi-Key Part No., Price Each 1 25, AMP Part No. Includes rows for Receptacle Plug, Steel Strain Relief, and Steel Strain Relief.

Table with columns: No. of Pos., Dim. Inch (mm), Digi-Key Part No., Price Each 1 25, AMP Part No. Includes rows for HDJ-20 Standard Cord Guards and HDJ-20 Squeeze-to-Release Cord Guards.

† 94V-0 rated thermoplastic black ‡ Cut Tape § Tape and Reel

HD-20 All-Plastic Straight Posted with ACTION PIN


 


Table with columns: No. of Pos., Sex, Profile, Digi-Key Part No., Price Each 1 25, AMP Part No. Includes rows for HD-20 All-Plastic Straight Posted with ACTION PIN.

Plug Assemblies

 HDJ-20 All-Plastic Plug Assemblies with Right-Angle Posted Contacts



Material and Finish: Housing and Post Spacer: Black thermoplastic, 94V-2 rated Pin Contacts (Posted): Brass, plated Gold flash on mating end, tin-lead on solder posts, entire contact nickel underplated

Table with columns: No. of Positions, Digi-Key Part No., Price Each 1 25, AMP Part No. Includes rows for HDJ-20 All-Plastic Plug Assemblies.

◆ RoHS Compliant

HDP-20 Front Metal-Shell Straight Posted with Solder Pins



Material and Finish: Front Shell: Steel, tin plated Housing: 94V-0 rated, black glass filled polyester Threaded Inserts: Tin plated steel, 4-40 inner thread Female Screwlocks: Tin plated steel, 4-40 inner thread Boardlocks: Tin plated Phosphor bronze Contacts: Phosphor bronze Plating: Gold over nickel, tin plating on solder part

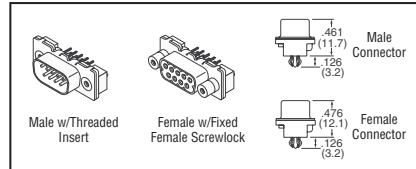


Table with columns: No. of Pos., Sex, Digi-Key Part No., Price Each 1 25, AMP Part No. Includes rows for HDP-20 Front Metal-Shell Straight Posted with Solder Pins.

HD-20 Front Metal-Shell Straight Posted with ACTION PIN



Material and Finish: Front Shell: Steel, tin plated Housing: 94V-0 rated thermoplastic, black Threaded Inserts: Brass, unplated Female Screwlocks: Zinc Action Pin Contacts: Copper alloy duplex plated Plating: 30µ gold on mating end, tin-lead on Action Pin post surface, with entire contact 50µ (minimum) nickel underplated

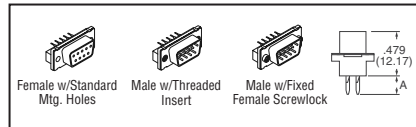


Table with columns: No. of Pos., Sex, Dim A In. (mm), Digi-Key Part No., Price Each 1 25, AMP Part No. Includes rows for HD-20 Front Metal-Shell Straight Posted with ACTION PIN.


Table with columns: No. of Pos., Sex, Dim A In. (mm), Digi-Key Part No., Price Each 1 25, AMP Part No. Includes rows for HD-20 All-Plastic Straight Posted with ACTION PIN.

Table with columns: No. of Pos., Sex, Dim A In. (mm), Digi-Key Part No., Price Each 1 25, AMP Part No. Includes rows for HD-20 All-Plastic Straight Posted with ACTION PIN.

Table with columns: No. of Pos., Sex, Dim A In. (mm), Digi-Key Part No., Price Each 1 25, AMP Part No. Includes rows for HD-20 All-Plastic Straight Posted with ACTION PIN.

† Brass Screwlocks

 HD-20 All-Plastic Straight Posted



Material and Finish: Housing: 94V-0 rated thermoplastic, black Threaded Inserts: Brass, unplated Female Screwlocks: Brass, nickel plated Pin Contacts: Brass or phosphor bronze plated, tin-lead on termination end, with entire contact 50µ (minimum) nickel underplated

Table with columns: No. of Pos., Sex, Dim. A In. (mm), Digi-Key Part No., Price Each 1 25, AMP Part No. Includes rows for HD-20 All-Plastic Straight Posted.

Table with columns: No. of Pos., Sex, Dim. A In. (mm), Digi-Key Part No., Price Each 1 25, AMP Part No. Includes rows for HD-20 All-Plastic Straight Posted.

Table with columns: No. of Pos., Sex, Dim. A In. (mm), Digi-Key Part No., Price Each 1 25, AMP Part No. Includes rows for HD-20 All-Plastic Straight Posted.

† 30µ gold on mating end ‡ Gold flash on mating end (Continued)

Free shipping on orders over \$200 CAD! All prices in Canadian dollars and include duty and brokerage fees.

280 (CA2011)

1-800-344-4539 • www.digikey.ca • 218-681-6674 • Fax: 218-681-3380