



Thru Panel USB Socket Inserts A and B Types


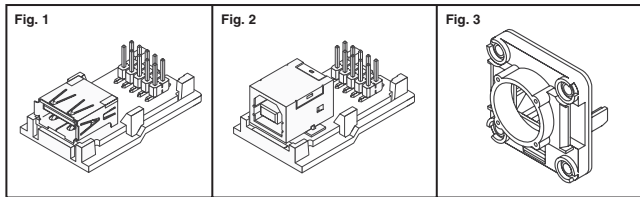


Fig.	Description	Digi-Key Part No.	Price Each			Phoenix Contact Part No.
A-Type						
1	4 Positions	277-2024-ND	23.39	21.52	18.95	1653854
B-Type						
2	4 Positions	277-2025-ND	23.39	21.52	18.95	1653867
Panel Mounting Frame						
3	Gray in Color	277-2063-ND	4.97	4.28	3.77	1653744

Pluscon Circular Connectors

M12 flush type connectors and panel feed-throughs has been developed from the various requirements of sensor/actuator device connection technology in the industrial sector.
Rating: IP67, D-Coded.

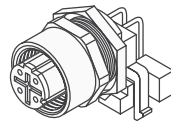

Unshielded Shown

Description	Digi-Key Part No.	Price Each			Phoenix Contact Part No.
Shielded					
4 Positions, Straight Solder	277-2018-ND	12.33	11.35	9.99	1542619
4 Positions, Right Angle Solder	277-2019-ND	24.05	22.13	19.48	1534630
Unshielded					
4 Positions, Straight Screw Mount	277-2020-ND	13.38	12.31	10.84	1551503
4 Positions, Straight Screw Mount	277-2021-ND	18.20	16.75	14.75	1552272
Adapters from M12 to RJ45					
Right Angle	277-2022-ND	38.60	35.52	31.27	1657261
Straight	277-2023-ND	38.60	35.52	31.27	1657494

Paladin Tools® Tools



SureStrip® 4.0:


High quality wire stripping and cutting tool for 20 - 12AWG (0.5mm - 4.0mm²) • Strips stranded and solid conductors with PVC insulation • Strips multiple conductors and thin, ribbon-cable conductors simultaneously • Built-in wire cutter • Precision self-adjusting blades prevent wire damage • Strips double-insulated cable in two work cycles • User-replaceable stripping blades • Adjustable wire stop to set strip lengths • Value stripper to prepare wire for wire and ferrule termination

Mini-Stripax® Plus:

Universal wire stripper and cutter that uses changeable blades to strip PVC and Teflon® insulation. Strips PVC-insulated wire in the range of 28 - 18AWG (0.80mm - 1.0mm²) and Teflon-insulated wire in the range of 32 - 18AWG (.032mm - 1.00mm²) • Strips flexible and solid conductors with PVC, Teflon, silicone and other special insulations • Strips multiple conductors and thin ribbon-cable conductors simultaneously • Adjustable wire stop and built-in wire cutter • 28 - 18AWG (0.80mm - 1.00mm²) PVC blade included


Stripax® Pro 6 Strippers:

The new stripax performs powerful stripping of standard and industrial insulations including PVC, THHN, THHW, silicone and polyethylene. Stripping blades are composed of 68 individual spring-compression blades to adjust precisely to the insulation. Not for Teflon or Kapton hard insulations.

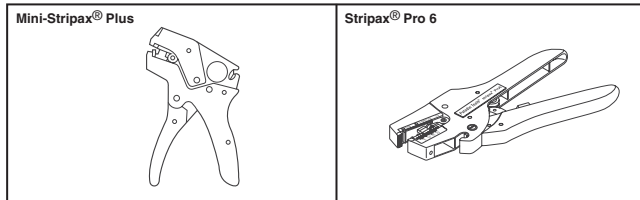

Description	Digi-Key Part No.	Price Each	Paladin Tools Part No.
Sure Strip 4.0 (AWG 20 - 12)	PA904893-ND	86.84	904893
Mini-Stripax Plus (AWG 28 - 18)	PA1115P-ND	115.39	1115P
Replacement Blade for PAL1115-ND	PA2108-ND	35.84	2108
Stripax Pro 6 (AWG 28 - 10)	PA1113-ND	107.07	1113

Modular Jacks and Panel Mount Frames

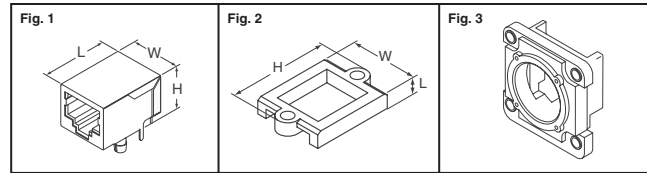


A

Fig.	Description	Dimensions L x W x H (mm)	Digi-Key Part No.	Price Each			Phoenix Contact Part No.
Modular Jacks							
1	8x1 Port R/A	21.6 x 16.1 x 14	277-1675-ND	5.46	4.70	4.14	1688586
	8x2 Ports R/A	22 x 31.85 x 14	277-1676-ND	17.71	16.30	14.35	1688599
	8x4 Ports R/A	22 x 59.79 x 14	277-1677-ND	35.53	32.69	28.78	1688609
	8x6 Ports R/A	22 x 87.73 x 14	277-1678-ND	52.64	48.43	42.64	1688612
	8x8 Ports R/A	22 x 115.67 x 14	277-1679-ND	69.71	64.14	56.47	1688625
Panel Mount Frames							
2	1 Position	4 x 18 x 26.37	277-1680-ND	2.88	2.49	2.19	1688641
	2 Positions	4 x 31.97 x 26.37	277-1681-ND	3.56	3.06	2.70	1688654
	4 Positions	4 x 59.91 x 26.37	277-1682-ND	6.65	5.72	5.03	1688667
	6 Positions	4 x 87.85 x 26.37	277-1683-ND	7.15	6.58	5.80	1688670
	8 Positions	4 x 115.79 x 26.37	277-1684-ND	8.90	8.19	7.21	1688683
	Panel Cutout Mounting Frames						
3	Gray in Color	—	277-2016-ND	4.74	4.08	3.59	1689446
	Black in Color	—	277-2017-ND	4.74	4.08	3.59	1658655

Ethernet Switches

The FL SWITCH SFN range of factory line switches with standard functions in numerous versions can be used for quick and cost effective Ethernet network expansion.

 Specifications: • Transmission speed: 10/100 Mbit/s (RJ45) • Basic functionality: Unmanaged switch autonegotiation, complies with IEEE 802.3, store and forward switching mode • Supply voltage: 24VDC




Description	Dimensions D x W x H (mm)	Digi-Key Part No.	Price Each	Phoenix Contact Part No.
5 Ports	70 x 30 x 120	277-2014-ND	131.61	2891152
8 Ports	70 x 50 x 120	277-2015-ND	211.38	2891929

Crimp Tools



- Fully ratcheting cycle
- Adjustable crimp tension
- Hardened dies for long life
- Crimp 4, 6, and 8 positions
- Cuts and strips cable
- RJ45, RJ11

 PA1530R-ND




PA1530R-ND	Modular Crimp Tool.....	\$154.66
PA2530-ND	Replacement Blade Set (for 1530R).....	\$11.21

Cable Tester



Features:

- Tests over 20 types of patch cables up to 1,000 feet in length (600 feet for 75Ω coax)
- LAN and telephone
- Serial
- Coax 50Ω and 75Ω
- USB
- VGA
- Mini- SB
- S-video
- FireWire
- PS/2 keyboard
- Parallel printer
- 9V battery included

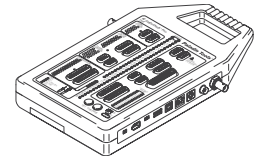


PA1577-ND	Tool PC Cable Tester.....	\$213.20
-----------	---------------------------	----------

Data and Telephone Tool



Features:

- Crimping cavities for RJ45, RJ11/RJ12 and RJ22 handset modular plugs
- Cuts and strips round UTP/STP phone and data cable along with flat satin phone cable
- 22 - 28AWG (.08mm - .34mm²) flat or round; solid or stranded telephone and data cables

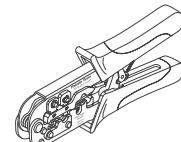

PA1556-ND	All-in-One Data and Telephone Tool.....	\$55.91
-----------	---	---------

Free shipping on orders over \$200 CAD! All prices in Canadian dollars and include duty and brokerage fees.

1-800-344-4539 • www.digikey.ca • 218-681-6674 • Fax: 218-681-3380

(CA2011) 317