

Accessories



A


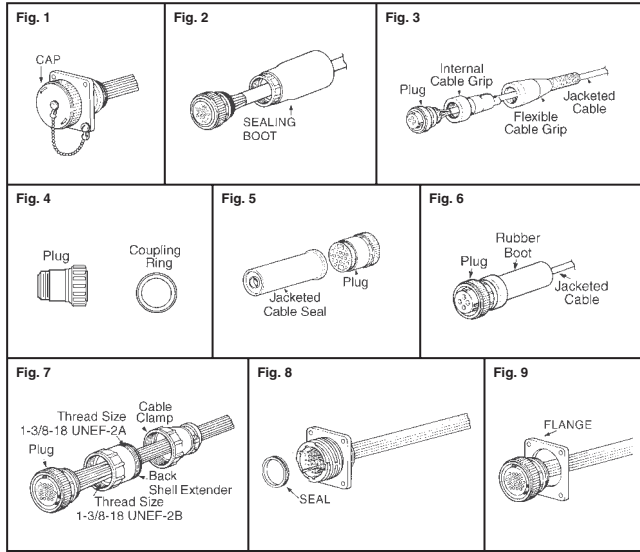


Fig.	Description	Shell Size	Digi-Key Part No.	Price Each 1	Price Each 25	AMP Part No.
1	Sealing Cap for Receptacles, Plastic Strap	23	A16041-ND	5.50	5.10	207446-1
	Sealing Cap for Receptacles, Metal Bead Chain	11	A16042-ND	7.25	6.72	208800-1
	Sealing Cap for Receptacles, Metal Bead Chain	13	A16043-ND	8.28	7.68	213485-1
	Sealing Cap for Receptacles, Metal Bead Chain	17	A16044-ND	7.47	6.93	208652-1
	Sealing Cap for Receptacles, Metal Bead Chain	23	A16045-ND	7.84	7.28	208680-1
	Sealing Cap for Receptacles, Metal Bead Chain	23	A20537-ND†	10.32	9.58	208680-2
2	Heat Shrinkable Sealing Boot, .260" - .600"	11	A16046-ND	10.97	10.18	54010-1
	Heat Shrinkable Sealing Boot, .300" - .725"	13	A16047-ND	11.41	10.58	54123-1
	Heat Shrinkable Sealing Boot, .400" - .875"	17	A16048-ND	11.20	10.39	54011-1
	Heat Shrinkable Sealing Boot, .400" - .875"	17	A99560-ND	11.68	10.84	54011-3
	Heat Shrinkable Sealing Boot, .250" - .500"	17	A16060-ND‡	6.77	6.27	213933-1
	Heat Shrinkable Sealing Boot, .500" - 1.25"	23	A16049-ND	12.95	12.01	54012-1
3	Flexible Cable Boot, Black Thermoplastic	11	A16050-ND	3.36	3.12	207489-1
	Flexible Cable Boot, Black Thermoplastic	17	A16052-ND	5.20	4.82	207241-1
	Internal Cable Grip, Black Thermoplastic	11	A16051-ND	3.77	3.50	207490-1
	Internal Cable Grip, Black Thermoplastic 8.25mm	17	A16053-ND	4.84	4.48	207387-1
	Internal Cable Grip, Black Thermoplastic 9.78mm	17	A16054-ND	4.65	4.31	207387-2
	4	Replacement Coupling Ring	11	A16055-ND	1.18	1.10
Replacement Coupling Ring		13	A16056-ND	1.73	1.60	213813-1
Replacement Coupling Ring		17	A16057-ND	1.37	1.27	213810-1
Replacement Coupling Ring		23	A16058-ND	2.21	2.05	213812-1
5	Jacketed Cable Seal, Cable Diameter 7.62mm	23	A16063-ND	13.16	12.20	207052-1
	Jacketed Cable Seal, Cable Diameter 11.43mm	23	A16064-ND	26.86	24.91	207052-2
	Jacketed Cable Seal, Cable Diameter 15.24mm	23	A16065-ND	14.96	13.86	207052-3
6	Rubber Boots	11	A16059-ND§	6.49	6.02	206304-1
7	Back Shell Extender	23	A16062-ND	5.22	4.84	207055-1
8	Peripheral Seals for Receptacles Only	11	A1335-ND	.79	.73	206403-1
	Peripheral Seals for Receptacles Only	13	A1336-ND	1.08	1.01	206403-4
	Peripheral Seals for Receptacles Only	17	A1337-ND	.82	.76	206403-2
	Peripheral Seals for Receptacles Only	23	A1338-ND	1.50	1.40	206403-3
9	Panel Mount Flanges for Plugs Only	11	A25003-ND	6.24	5.78	207299-1
	Panel Mount Flanges for Plugs Only	13	A25004-ND	5.17	4.80	207299-2
	Panel Mount Flanges for Plugs Only	17	A25019-ND	5.41	5.02	207299-3
	Panel Mount Flanges for Plugs Only	23	A25020-ND	3.42	3.18	207299-4
—	Flange Gasket	11	A30707-ND	.74	.69	81665-3
	Flange Gasket	13	A30705-ND	.75	.70	81665-4
	Flange Gasket	17	A25784-ND	.75	.71	81665-2
	Flange Gasket	23	A30706-ND	.81	.75	81665-5
—	Keying Plug, Series 1 and 4	11	A16066-ND	.22	.22	200821-1
	Keying Plug, Series 2	—	A16067-ND	.45	.42	206509-1
	Keying Plug, Series 3 and 4 (Socket Cavities)	—	A16068-ND	.90	.83	206508-1
	Keying Plug, Series 3 and 4 (Pin Cavities)	—	A16069-ND	2.48	2.31	207597-1

§ Rubber boots are used with jacketed cable to provide splashproof connections for Series 1 and 3 connectors (black neoprene). † For use with series 2 only ‡ Thin Wall Boot

 Wire Entry Seal Kits




Includes one Gang Seal and one pressure plate marked for cavity identification.

Material and Finish:

Seal - Elastomer, red iron oxide. Pressure Plate - Nylon, black

Arrangement	Insulation Diameter Inch (mm)	Seal Diameter Inch (mm)	Digi-Key Part No.	Price Each			AMP Part No.
				1	25	50	
Kit for Pins							
13-9	.075 - .125 (1.91 - 3.18)	.681 (17.30)	A25059-ND	7.01	6.51	5.69	213926-1
17-3	.178 - .265 (4.52 - 6.73)	.790 (20.07)	A25060-ND	8.19	7.60	6.64	213899-1
17-10	.150 - .265 (3.81 - 6.73)	.790 (20.07)	A25788-ND	5.91	5.48	4.79	213900-1
17-14	.075 - .125 (1.91 - 3.18)	.790 (20.07)	A25061-ND	7.16	6.64	5.80	213919-2
17-16	.075 - .125 (1.91 - 3.18)	.790 (20.07)	A25062-ND	7.16	6.64	5.80	213920-2
Kit for Sockets							
13-9	.075 - .125 (1.91 - 3.18)	.681 (17.30)	A25063-ND	7.01	6.51	5.69	213925-1
17-3	.178 - .265 (4.52 - 6.73)	.790 (20.07)	A25060-ND	8.19	7.60	6.64	213899-1
17-10	.150 - .265 (3.81 - 6.73)	.790 (20.07)	A25788-ND	5.91	5.48	4.79	213900-1
17-14	.075 - .125 (1.91 - 3.18)	.790 (20.07)	A25064-ND	5.32	4.93	4.31	213919-2
17-16	.075 - .125 (1.91 - 3.18)	.790 (20.07)	A25065-ND	12.51	11.60	10.14	213920-2

Cable Clamps – Plastic Shell

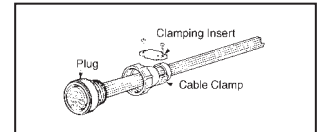

Cable clamps are used to prevent excessive strain on cable or wire from being transmitted to the contacts inside the connector housings.


These may be used on all receptacles and plugs. Two screws included.

Shell Size	Cable Outer Diameter Inch (mm)	Screw Length Inch (mm)	Digi-Key Part No.	Price Each			AMP Part No.
				1	25	AMP Part No.	
11	.329 (8.36)	.375 (9.53)	A1330-ND	4.78	4.44	206062-1	
	.329 (8.36)	.375 (9.53)	A32514-ND◆	4.78	4.44	1-206062-6	
	.329 (8.36)	.380 (9.65)	A99541-ND◆	7.98	7.40	182658-1	
	.329 (8.36)	.500 (12.7)	A25021-ND	4.78	4.44	206062-3	
	.329 (8.36)	.500 (12.7)	A32515-ND◆	4.78	4.44	1-206062-4	
	.453 (11.51)	.500 (12.7)	A1687-ND	4.78	4.44	206358-1	
	.453 (11.51)	.500 (12.7)	A32518-ND◆	4.78	4.44	206358-5	
	.453 (11.51)	.500 (12.7)	A99553-ND◆	5.94	5.51	182928-1	
	.453 (11.51)	.500 (12.7)	A1331-ND	4.86	4.50	206966-1	
	.453 (11.51)	.500 (12.7)	A32519-ND◆	4.86	4.50	206966-7	
13	.453 (11.51)	.500 (12.7)	A99543-ND◆	9.12	8.46	182663-1	
	.703 (17.86)	.625 (15.88)	A1688-ND	5.04	4.67	207008-1	
	.703 (17.86)	.625 (15.88)	A33751-ND◆	5.04	4.67	207008-5	
	.453 (11.51)	.500 (12.7)	A1332-ND	4.86	4.50	206070-1	
	.453 (11.51)	.500 (12.7)	A32516-ND◆	4.86	4.50	206070-8	
	.453 (11.51)	.500 (12.7)	A99540-ND◆	8.28	7.69	182655-1	
17	.703 (17.86)	.625 (15.88)	A1689-ND	5.32	4.93	206322-1	
	.703 (17.86)	.625 (15.88)	A99542-ND◆	9.93	9.21	182661-1	
	.703 (17.86)	.625 (15.88)	A1334-ND	4.99	4.63	206138-1	
	.703 (17.86)	.625 (15.88)	A32517-ND◆	4.99	4.63	206138-8	
	.703 (17.86)	.625 (15.88)	A99539-ND◆	9.36	8.68	182652-1	
	.703 (17.86)	.625 (15.88)	A99554-ND◆	9.12	7.22	182930-1	
23	1.125 (28.58)	.625 (15.88)	A1690-ND	6.31	5.85	206512-1	
	1.125 (28.58)	.625 (15.88)	A32502-ND◆	6.31	5.85	206512-5	
	1.125 (28.58)	1.00 (25.4)	A16061-ND†	7.27	6.74	207774-1	
	1.125 (28.58)	1.00 (25.4)	A33752-ND†	7.50	6.96	207774-3	
	1.125 (28.58)	.625 (15.88)	A1688-ND	5.04	4.67	207008-1	
	1.125 (28.58)	.625 (15.88)	A33751-ND◆	5.04	4.67	207008-5	

◆ RoHS Compliant † Self-Centering

Right Angle Cable Clamps

Cable clamps are used to prevent excessive strain on cable or wire from being transmitted to the contacts inside the connector housings. These may be used on all receptacles and plugs. Two screws included.

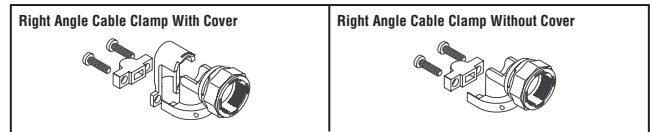

Shell Size	Cable Outer Diameter Inch (mm)	Digi-Key Part No.	Price Each			AMP Part No.
			1	25	AMP Part No.	
Cable Clamp with Cover						
11	.329 (8.36)	A31208-ND	8.24	7.64	1546347-1	
	.329 (8.36)	A32501-ND◆	8.24	7.64	1546347-2	
13	.453 (11.51)	A31209-ND	7.23	6.70	1546348-1	
	.453 (11.51)	A33753-ND◆	8.02	7.45	1546348-2	
17	.453 (11.51)	A31210-ND	7.23	6.70	1546349-1	
	.453 (11.51)	A33754-ND◆	8.37	7.77	1546349-2	
23	.703 (17.86)	A31211-ND	7.64	7.08	1546350-1	
	.703 (17.86)	A33755-ND◆	7.64	7.08	1546350-2	
Cable Clamp without Cover						
11	.329 (8.36)	A31212-ND	6.24	5.78	796379-1	
	.329 (8.36)	A33756-ND◆	7.38	6.85	796379-2	
13	.453 (11.51)	A31213-ND	6.31	5.85	796380-1	
	.453 (11.51)	A33757-ND◆	6.31	5.85	796380-2	
17	.453 (11.51)	A31214-ND	6.31	5.85	796381-1	
	.453 (11.51)	A33758-ND◆	6.31	5.85	796381-2	
23	.703 (17.86)	A31215-ND	6.81	6.32	796382-1	
	.703 (17.86)	A33759-ND◆	6.81	6.32	796382-2	

◆ RoHS Compliant

Free shipping on orders over \$200 CAD! All prices in Canadian dollars and include duty and brokerage fees.