

A

Fig.	Description	Digi-Key Part No.	Price Each	10	Pomona Part No.
1	SMA Plug Straight Crimp, RG58	501-1250-ND	5.17	4.68	72943
2	SMA Plug Straight Crimp, RG141	501-1251-ND	5.59	5.05	72944
3	SMA Jack Straight Crimp, RG141	501-1252-ND	5.85	5.29	72952
4	SMA Plug (Male) - Plug (Male)	501-1253-ND	7.54	6.82	72964
5	SMA "T" Type Jack (Female) - Jack (Female) - Jack (Female)	501-1254-ND	14.33	12.95	72968
6	SMA "T" Type Jack (Female) - Plug (Male) - Jack (Female)	501-1255-ND	13.94	12.60	72969
7	SMA Jack (Female) - Jack (Female), Panel	501-1256-ND	14.42	13.03	72973
8	SMA Plug, 50ohm Termination	501-1257-ND	21.70	19.61	72975
9	SMA (Male) - SMB (Male)	501-1258-ND	8.70	7.87	72976
10	SMA (Male) - SMB (Female)	501-1259-ND	8.55	7.73	72977
11	SMA (Female) - SMB (Male)	501-1260-ND	11.46	10.36	72978
12	SMA (Female) - SMB (Female)	501-1261-ND	11.31	10.22	72979
13	SMB Straight Plug Crimp, RG174/188/316	501-1262-ND	6.54	5.91	72981
14	SMB Jack Straight Crimp, RG174/188/316	501-1263-ND	8.21	7.43	72984
15	SMB Jack Straight Crimp, RG179/187	501-1264-ND	8.21	7.43	72985


Fig.	Description	Digi-Key Part No.	Price Each	10	Pomona Part No.
16	SMB Jack Right Angle Crimp, RG178/196	501-1265-ND	7.19	6.50	72991
16	SMB Jack Right Angle Crimp, RG174/188/316	501-1266-ND	8.49	7.68	72992
17	SMB Jack Right Angle Crimp, RG179/187	501-1267-ND	8.49	7.68	72993
18	SMB Plug Right Angle PCB Receptacle	501-1268-ND	7.00	6.33	72997
19	SMB Bulkhead Plug, RG174/188/316	501-1269-ND	5.81	5.26	73000
20	SMB Bulkhead Plug, RG179/187	501-1270-ND	5.81	5.26	73001
21	MCX Plug Straight Crimp, RG179	501-1271-ND	6.30	5.69	73004
22	MCX Jack Straight Crimp, RG174/316	501-1272-ND	5.16	4.67	73010
23	MCX Jack Straight Crimp, RG178	501-1272-ND	5.22	4.72	73011
24	MCX Jack Straight Crimp, RG179	501-1274-ND	6.15	5.56	73012
25	MCX Plug Straight Semi-Rigid, RG402	501-1275-ND	4.96	4.48	73014
26	MCX Plug Right Angle Semi-Rigid, RG402	501-1276-ND	5.76	5.21	73016
27	MMCX Plug Right Angle Semi-Rigid, RG402	501-1277-ND	7.54	6.82	73032
28	MMCX Plug Straight Semi-Rigid, RG402	501-1278-ND	7.06	6.38	73034
29	MMCX Jack Straight Semi-Rigid, RG405	501-1279-ND	7.40	6.69	73037
30	MMCX Jack Straight Edgcard	501-1280-ND	7.06	6.38	73039

F Connectors



Dimensions in Inches (mm)

Fig.	Description	Digi-Key Part No.	Price Each	1	10	Pomona Part No.
1	F Type Female-Female Bulkhead to Panel Feed Through	501-1143-ND	1.73	1.57	6706	
2	F Type Female-Male Push-On Adapter	501-1144-ND	2.74	2.48	6713	
3	F (Male-Female) Right Angle, 75Ω	501-1159-ND	3.95	3.57	6800	
4	F (Male-Female) In-Line, 75Ω	501-1160-ND	1.49	1.35	6801	

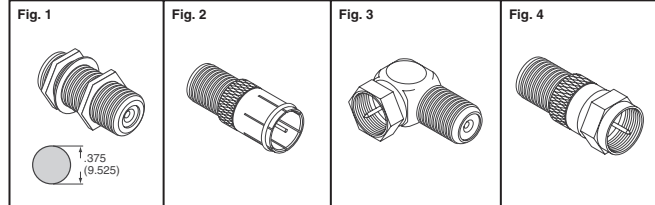

CUI INC F Connectors

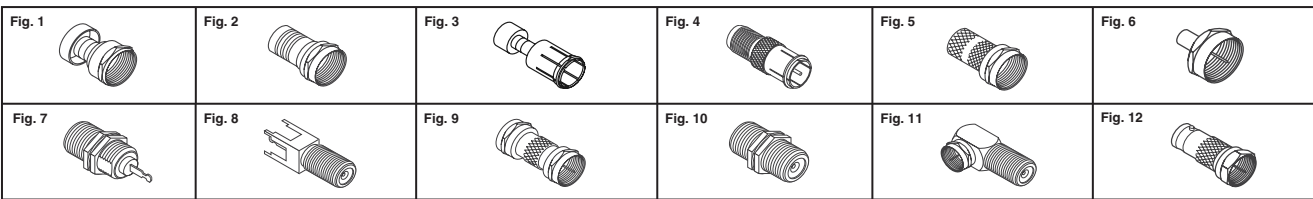


Fig.	Description	Digi-Key Part No.	Pricing			
			1	10	100	1,000
1	Separated Crimp Ring, for RG-59 Cable	CP-0010-ND◆	.74	6.42	49.38	370.31
	Separated Crimp Ring, for RG-6 Cable	CP-0060-ND	.74	6.42	49.38	370.31
2	Long Type Built-On Crimp Ring, for RG-59 Cable	CP-0210-ND	1.14	9.92	76.31	572.30
	Long Type Built-On Crimp Ring, for RG-6 Cable	CP-0260-ND	1.14	9.92	76.31	572.30
3	Push-On, Crimp Type, for RG-59 Cable	CP-0310-ND	1.95	16.92	130.17	976.28
4	Adapter, Screw-On/Push-On	CP-2000-ND◆	1.28	11.09	85.28	639.63
5	Twist-On Type, for RG-59 Cable	CP-0410-ND	1.31	11.38	87.53	656.46

Fig.	Description	Digi-Key Part No.	Pricing			
			1	10	100	1,000
6	Male Terminator, with Built-In 75 Ohm Resistor	CP-0610-ND	.84	7.29	56.11	420.81
7	Female Bulkhead Receptacle, with Washer and Nut	CP-1010-ND◆	.88	7.59	58.35	437.64
8	PCB Type, Full Length 26mm	CP-1210-ND◆	1.55	13.42	103.24	774.29
9	Adapter, Universal Male F to F Coupler	CP-2010-ND	2.93	25.38	195.26	1464.42
10	Adapter, Female F to F Coupler, with Washer and Nut	CP-2110-ND◆	1.04	9.04	69.57	521.80
11	Adapter, Right Angle F Male to F Female	CP-2510-ND	2.96	25.68	197.50	1481.25
12	Adapter, F Male to BNC Female	CP-0130-ND◆	3.30	28.59	219.94	1649.58

◆ RoHS Compliant

Free shipping on orders over \$200 CAD! All prices in Canadian dollars and include duty and brokerage fees.

1-800-344-4539 • www.digikey.ca • 218-681-6674 • Fax: 218-681-3380

(CA2011) 483