

A

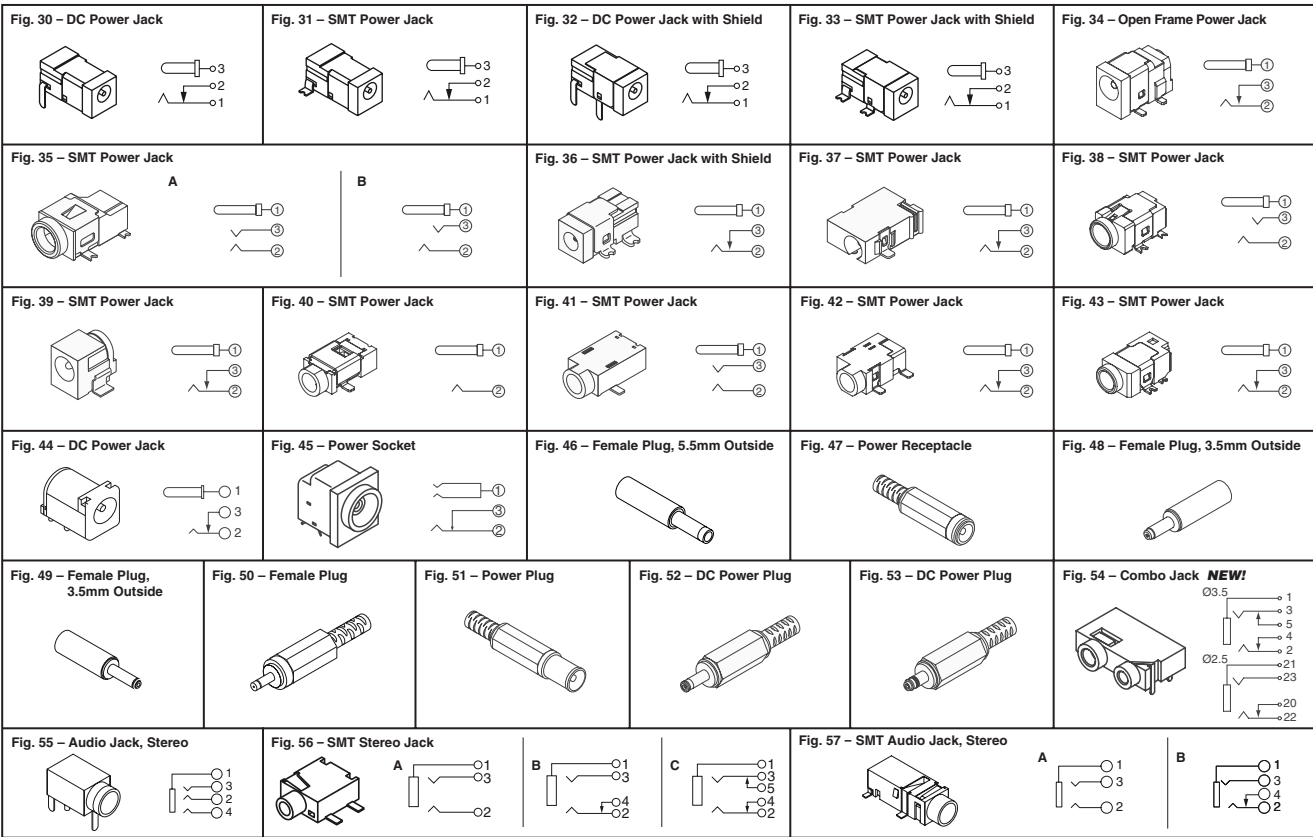


Fig.	Mates With	Dia. (mm)	Digi-Key Part No.	Price Each			CUI Part No.
				1	10	100	
39	PP3-002A	2.0	CP-037APJTR-ND	104.36	200		PJ-037A-SMT
	PP3-002A	2.0	CP-037AHJCT-ND	1.11	1.08	.97	PJ-037AH-SMT
	PP3-002A	2.0	CP-037AHJTR-ND	111.09	200		PJ-037AH-SMT
	PP3-002B	2.5	CP-037BPJCT-ND	1.04	1.01	.91	PJ-037B-SMT
	PP3-002B	2.5	CP-037BPJTR-ND	104.36	200		PJ-037B-SMT
40	PP3-002B	2.5	CP-037BHPJCT-ND	1.11	1.08	.97	PJ-037BH-SMT
	PP3-002B	2.5	CP-037BHPJTR-ND	111.09	200		PJ-037BH-SMT
	PP-012	0.65	CP-038JCT-ND	1.01	.98	.88	PJ-038-SMT
	PP-012	0.65	CP-038JTR-ND	605.97	1,200		PJ-038-SMT
	PP-012	0.65	CP-039JCT-ND	1.01	.98	.88	PJ-039-SMT
41	PP-012	0.65	CP-039JTR-ND	605.97	1,200		PJ-039-SMT
	PP-012	0.65	CP-040PJCT-ND	.94	.92	.82	PJ-040-SMT
	PP-012	0.65	CP-040PJTR-ND	565.57	1,200		PJ-040-SMT
	PP-012	0.65	CP-041PJCT-ND	.94	.92	.82	PJ-041-SMT
	PP-012	0.65	CP-041PJTR-ND	565.57	1,200		PJ-041-SMT
42	PP-012	0.65	CP-042PJCT-ND	.98	.95	.85	PJ-042-SMT
	PP-012	0.65	CP-042PJTR-ND	732.21	1,500		PJ-042-SMT
43	PP-019	1.0	CP-043PJCT-ND	.98	.95	.85	PJ-043-SMT
	PP-019	1.0	CP-043PJTR-ND	439.33	900		PJ-043-SMT
44	PP3-002A	2.1	CP-102A-ND	.43	.37	.29	PJ-102A
	PP3-002B	2.5	CP-102B-ND	.43	.37	.29	PJ-102B
	PP3-002A	2.1	CP-102AH-ND	.47	.41	.32	PJ-102AH
	PP3-002B	2.5	CP-102BH-ND	.47	.41	.32	PJ-102BH
	PP3-002A	2.1	CP-202A-ND	.43	.37	.29	PJ-202A
45	PP3-002B	2.5	CP-202B-ND	.43	.37	.29	PJ-202B
	PP3-002A	2.1	CP-202AH-ND	.47	.41	.32	PJ-202AH
	PP3-002B	2.5	CP-202BH-ND	.47	.41	.32	PJ-202BH
	PP-015	1.1	CP-019-ND	.74	.65	.50	PJ-019
	PP-016	1.45	CP-025-ND	.74	.65	.50	PJ-025
46	—	2.1	CP3-1000-ND	1.04	.91	.70	PP3-002A
	—	2.5	CP3-1001-ND	1.04	.91	.70	PP3-002B
	PJ-063AH	2.1	CP3-002AH-ND	1.62	1.40	1.08	PP3-002AH
	PJ-063BH	2.5	CP3-002BH-ND	1.62	1.40	1.08	PP3-002BH
	—	2.1	CP-024A-ND	2.56	2.22	1.71	PR-002A
47	—	2.5	CP-024B-ND	2.56	2.22	1.71	PR-002B
	—	1.0	CP3-1002-ND	1.04	.91	.70	PP3-002C
48	—	1.3	CP3-1003-ND	1.04	.91	.70	PP3-002D
	—	0.7x2.35	CP-012-ND	1.01	.88	.68	PP-012
	—	1.7x4.0	CP-013-ND	.94	.82	.63	PP-013
49	—	1.7x4.75	CP-014-ND	.94	.82	.63	PP-014
	—	1.0x5.5	CP-015-ND	1.35	1.17	.90	PP-015
50	—	1.4	CP-026-ND	1.21	1.05	.81	PP-016
	—	0.9	CP-017-ND	1.21	1.05	.81	PP-017
	—	1.1	CP-119-ND	1.21	1.05	.81	PP-019
51	—	1.1	CP-018-ND	1.35	1.17	.90	PP-018
	—	1.1	CP-119-ND	1.21	1.05	.81	PP-019
52	—	0.9	CP-017-ND	1.21	1.05	.81	PP-017
	—	1.1	CP-119-ND	1.21	1.05	.81	PP-019
53	PJ-035-SMT	1.1	CP-018-ND	1.35	1.17	.90	PP-018
	SP-3501, SP-2501	3.5/2.5	CP1-320154-ND	.92	.80	.62	SJ1-3201-54
54	SP-2501	2.5	CP1-2503A-ND	.45	.40	.31	SJ1-2503A
	SP-2501	2.5	CP1-2513SJCT-ND	.76	.66	.51	SJ1-2513-SMT
55	SP-2501	2.5	CP1-2513SJTR-ND	.76	.66	.51	SJ1-2513-SMT
	SP-2501	2.5	CP1-2513SJTR-ND	378.73	1,000		SJ1-2513-SMT

Fig.	Mates With	Dia. (mm)	Digi-Key Part No.	Price Each			CUI Part No.
				1	10	100	
56B	SP-2501	2.5	CP-2514TR-ND	1178.27	1,000		SJ-2513-SMT
	SP-2501	2.5	CP1-2514SJCT-ND	.77	.68	.52	SJ1-2514-SMT
	SP-2501	2.5	CP1-2514SJTR-ND	387.15	1,000		SJ1-2514-SMT
56C	SP-2501	2.5	CP1-2515SJCT-ND	.80	.69	.53	SJ1-2515-SMT
	SP-2501	2.5	CP1-2515SJTR-ND	395.56	1,000		SJ1-2515-SMT
57A	SP-2501	2.5	CP-2523SJCT-ND	.97	.84	.65	SJ-2523-SMT
	SP-2501	2.5	CP-2523SJTR-ND	481.41	1,000		SJ-2523-SMT
57B	SP-2501	2.5	CP-2524SJCT-ND	1.01	.88	.68	SJ-2524-SMT
	SP-2501	2.5	CP-2524SJTR-ND	503.29	1,000		SJ-2524-SMT
58	SP-2501	2.5	CP1-2533SJCT-ND	.77	.68	.52	SJ1-2533-SMT
	SP-2501	2.5	CP1-2533SJTR-ND	388.83	1,000		SJ1-2533-SMT
59	SP-2501	2.5	CP1-2534SJCT-ND	.83	.72	.55	SJ1-2534-SMT
	SP-2501	2.5	CP1-2534SJTR-ND	412.39	1,000		SJ1-2534-SMT
60A	SP-3501	3.5	CP-3504-ND	2.31	2.01	1.55	SJ1-3504
	SP-3501	3.5	CP-3505-ND	2.36	2.05	1.58	SJ1-3505
60B	SP-3501	3.5	CP1-3513-ND	.83	.72	.56	SJ1-3513
	SP-3501	3.5	CP1-3513-ND	.59	.52	.40	SJ1-3513N
61A	SP-3501	3.5	CP1-3514-ND	.84	.73	.57	SJ1-3514
	SP-3501	3.5	CP1-3514-ND	.59	.52	.40	SJ1-3514N
61B	SP-3501	3.5	CP1-3515-ND	.85	.75	.58	SJ1-3515
	SP-3501	3.5	CP1-3515-ND	.62	.54	.42	SJ1-3515N
61C	SP-3501	3.5	CP1-3516-ND	.71	.62	.48	SJ1-3516-SMT
	SP-3501	3.5	CP1-3516-ND	282.78	800		SJ1-3516-SMT
62A	SP-3501	3.5	CP1-3513SJCT-ND	.73	.63	.49	SJ1-3514-SMT
	SP-3501	3.5	CP1-3514SJCT-ND	289.52	800		SJ1-3514-SMT
62B	SP-3501	3.5	CP1-3513SJTR-ND	.74	.65	.50	SJ1-3515-SMT
	SP-3501	3.5	CP1-3514SJTR-ND	296.25	800		SJ1-3515-SMT
62C	SP-3501	3.5	CP1-3515SJBCT-ND	1.02	.99	.89	SJ1-3515-SMT-BE
	SP-3501	3.5	CP1-3515SJBTR-ND	408.02	800		SJ1-3515-SMT-BE
	SP-3501	3.5	CP1-3515SJBCT-ND	1.02	.99	.89	SJ1-3515-SMT-GR
	SP-3501	3.5	CP1-3515SJBTR-ND	408.02	800		SJ1-3515-SMT-GR
	SP-3501	3.5	CP1-3515SJPTR-ND	408.02	800		SJ1-3515-SMT-PI
63A	SP-2501	2.5	CP-S2504N-ND	.50	.45	.34	SJ-2504N
	SP-2501	2.5	CP-S2509N-ND	.48	.42	.32	SJ-2509N
64A	SP-3501	3.5	CP1-3523NG-ND	.49	.43	.33	SJ1-3523N
	SP-3501	3.5	CP1-3523NG-ND	.49	.43	.33	SJ1-3523NG
64B	SP-3501	3.5	CP1-3524NG-ND	.49	.44	.34	SJ1-3524NG
	SP-3501	3.5	CP1-3524NG-ND	.49	.44	.34	SJ1-3524N
64C	SP-3501	3.5	CP1-3525NG-ND	.50	.44	.34	SJ1-3525N
	SP-3501	3.5	CP1-3525NG-ND	.50	.44	.34	SJ1-3525NG
	SP-3501	3.5	CP1-3525NG-GR-ND	.68	.60	.46	SJ1-3525NG-GR
	SP-3501	3.5	CP1-3525NG-PI-ND	.68	.60	.46	SJ1-3525NG-PI
	SP-3501	3.5	CP-3523SJCT-ND	.98	.85	.65	SJ1-3523-SMT
65A	SP-3501	3.5	CP-3523SJTR-ND	486.46	1,000		SJ1-3523-SMT
	SP-3501	3.5	CP-3523SJTR-ND				

▲ Threaded with nut ★ Non-threaded ▼ Shielded version ↗ Cut Tape ☆ Tape and Reel ◆ RoHS Compliant

(Continued)

Digi-Reel® Most SMT cutdown parts are available on a Digi-Reel®. For Digi-Reel part number, change 1-ND to 6-ND or CT-ND to DKR-ND. See Digi-Key® Services on page 2 for additional information.

Free shipping on orders over \$200 CAD! All prices in Canadian dollars and include duty and brokerage fees.

500 (CA2011) 1-800-344-4539 • www.digikey.ca • 218-681-6674 • Fax: 218-681-3380