


Application	Inductance	Digi-Key Part No.	Cut Tape Price Each			Digi-Key Part No.	Tape and Reel		Würth Part No.
			1	25	100		Qty.	Pricing	
Transformer for LT3805 SMD	36.3µH	732-2264-1-ND	16.83	14.03	11.93	732-2264-2-ND	200	1739.35	750310435
Transformer for NXP SSL1750 Through-hole	550µH	732-2234-ND†	23.57	19.64	17.40	—	—	—	750340477
Transformer for NXP SSL2101/SSL2102 Through-hole	1.08mH	732-2231-ND†	16.50	13.75	12.18	—	—	—	750340505
Transformer for NXP SSL2101/SSL2102 Through-hole	1.48mH	732-2232-ND†	14.14	11.79	10.44	—	—	—	750311402
Transformer for NXP STARPLUG Through-hole	1.8mH	732-2238-ND†	14.14	11.79	10.44	—	—	—	750871013
Transformer for NXP STARPLUG Through-hole	2.0mH	732-2239-ND†	13.67	11.39	10.09	—	—	—	750871035
Transformer for NXP STARPLUG Through-hole	500µH	732-2237-ND†	15.08	12.57	11.14	—	—	—	750871630
Transformer for NXP STARPLUG Through-hole	900µH	732-2240-ND†	20.27	16.89	14.96	—	—	—	750871830
Transformer for NXP STARPLUG Through-hole	900µH	732-2241-ND†	16.50	13.75	12.18	—	—	—	750871831
Transformer for NXP TEA1733 Through-hole	2.2mH	732-2242-ND†	16.50	13.75	12.18	—	—	—	760871631
Transformer for NXP TEA1733 Through-hole	4.0mH	732-2243-ND†	16.50	13.75	12.18	—	—	—	760871632
Transformer for NXP UM10369 Through-hole	1.6mH	732-2236-ND†	15.08	12.57	11.14	—	—	—	750841630
Transformer for NXP UM10377 Through-hole	1.6mH	732-2235-ND†	14.14	11.79	10.44	—	—	—	750871530
Transformer for ON Semi NCP1014 Through-hole	1.8mH	732-2261-ND†	18.85	15.72	13.92	—	—	—	750811042
Transformer for ON Semi NCP1652 Through-hole	625µH	732-2260-ND†	18.85	15.72	13.92	—	—	—	750311267
Transformer for PI LNK362 Through-hole	2.64mH	732-2248-ND†	14.61	12.18	10.79	—	—	—	7508110100
Transformer for PI LNK564 Through-hole	2.70mH	732-2249-ND†	14.61	12.18	10.79	—	—	—	750811019
Transformer for PI LNK603 Through-hole	2.28mH	732-2245-ND†	14.14	11.79	10.44	—	—	—	750811023
Transformer for PI LNK605 Through-hole	1.55mH	732-2244-ND†	14.14	11.79	10.44	—	—	—	750871032
Transformer for PI LNK613 Through-hole	2.58mH	732-2246-ND†	14.61	12.18	10.79	—	—	—	7508110102
Transformer for PI LNK616 Through-hole	1.07mH	732-2247-ND†	14.61	12.18	10.79	—	—	—	7508110101
Transformer for PI TNY278 Through-hole	900µH	732-2250-ND†	16.50	13.75	12.18	—	—	—	750310849
Transformer for PI TOP258 Through-hole	1.04mH	732-2251-ND†	13.20	11.00	9.75	—	—	—	750811630
Transformer for PoE SMD	35µH	732-2436-1-ND	13.47	11.23	9.54	732-2436-2-ND	200	1391.48	7491199332
Transformer for PoE SMD	40µH	732-2437-1-ND	13.47	11.23	9.54	732-2437-2-ND	200	1391.48	7491199312
Transformer for PoE SMD	127µH	732-2430-1-ND	13.47	11.23	9.54	732-2430-2-ND	200	1391.48	749119933
Transformer for PoE SMD	127µH	732-2431-1-ND	13.47	11.23	9.54	732-2431-2-ND	200	1391.48	7491199331
Transformer for PoE SMD	127µH	732-2432-1-ND	13.47	11.23	9.54	732-2432-2-ND	200	1391.48	749119950
Transformer for PoE SMD	127µH	732-2433-1-ND	13.47	11.23	9.54	732-2433-2-ND	200	1391.48	7491199501
Transformer for PoE SMD	127µH	732-2434-1-ND	13.47	11.23	9.54	732-2434-2-ND	200	1391.48	7491199112
Transformer for PoE SMD	127µH	732-2435-1-ND	13.47	11.23	9.54	732-2435-2-ND	200	1391.48	7491199212
Transformer for PoE+ SMD	38µH	732-2438-1-ND	13.47	11.23	9.54	732-2438-2-ND	200	1391.48	750310742
Transformer for PoE+ SMD	38µH	732-2439-1-ND	13.47	11.23	9.54	732-2439-2-ND	200	1391.48	750310743
Transformer for PoE+ SMD	38µH	732-2440-1-ND	13.47	11.23	9.54	732-2440-2-ND	200	1391.48	750310744
Transformer for PoE+ SMD	42µH	732-2441-1-ND	14.81	12.35	—	732-2441-2-ND	125	956.64	749119433
Transformer for PoE+ SMD	42µH	732-2442-1-ND	14.81	12.35	—	732-2442-2-ND	125	956.64	7491194501
Transformer for PoE+ SMD	42µH	732-2443-1-ND	14.81	12.35	—	732-2443-2-ND	125	956.64	7491194912
Transformer for PoE+ SMD	65µH	732-2444-1-ND	14.81	12.35	—	732-2444-2-ND	125	956.64	749119450
Transformer for SI3210/SI3211 SMD	11.3µH	732-2465-1-ND	9.43	7.86	6.68	732-2465-2-ND	200	974.03	750031353
Transformer for ST VIPER15L Through-hole	3.90mH	732-2257-ND†	14.14	11.79	10.44	—	—	—	750370026
Transformer for ST VIPER15L Through-hole	4.00mH	732-2256-ND†	15.08	12.57	11.14	—	—	—	750871011
Transformer for ST VIPER17H Through-hole	1.20mH	732-2253-ND†	13.20	11.00	9.75	—	—	—	750310660
Transformer for ST VIPER17H Through-hole	1.60mH	732-2252-ND†	10.37	8.65	7.66	—	—	—	750370024
Transformer for ST VIPER17L Through-hole	2.38mH	732-2255-ND†	12.73	10.61	9.40	—	—	—	750871030
Transformer for ST VIPER17L Through-hole	3.30mH	732-2254-ND†	12.73	10.61	9.40	—	—	—	750871010
Transformer for ST VIPER27L Through-hole	1.7mH	732-2259-ND†	15.08	12.57	11.14	—	—	—	750871111
Transformer for ST VIPER28 Through-hole	1.6mH	732-2258-ND†	15.08	12.57	11.14	—	—	—	750871110
Transformer SMD	3.4µH	732-2450-1-ND	18.85	15.72	—	732-2450-2-ND	120	1168.84	749196540
Transformer SMD	4.3µH	732-2451-1-ND	18.85	15.72	—	732-2451-2-ND	120	1168.84	749196530
Transformer SMD	5.3µH	732-2452-1-ND	18.85	15.72	—	732-2452-2-ND	120	1168.84	749196520
Transformer SMD	7.6µH	732-2453-1-ND	18.85	15.72	—	732-2453-2-ND	120	1168.84	749196541
Transformer SMD	7.9µH	732-2454-1-ND	12.79	10.67	9.07	732-2454-2-ND	300	1758.99	749196341
Transformer SMD	9.3µH	732-2455-1-ND	12.79	10.67	9.07	732-2455-2-ND	300	1758.99	749196331
Transformer SMD	9.7µH	732-2456-1-ND	18.85	15.72	—	732-2456-2-ND	120	1168.84	749196531
Transformer SMD	9.9µH	732-2457-1-ND	18.85	15.72	—	732-2457-2-ND	120	1168.84	749196510
Transformer SMD	12µH	732-2445-1-ND	18.85	15.72	—	732-2445-2-ND	120	1168.84	749196521
Transformer SMD	14.2µH	732-2446-1-ND	12.79	10.67	9.07	732-2446-2-ND	300	1758.99	749196321
Transformer SMD	22.3µH	732-2448-1-ND	18.85	15.72	—	732-2448-2-ND	120	1168.84	749196511
Transformer SMD	23.3µH	732-2449-1-ND	12.79	10.67	9.07	732-2449-2-ND	300	1758.99	749196311
Transformer SMD	153.8µH	732-2447-1-ND	12.79	10.67	9.07	732-2447-2-ND	300	1758.99	749196301

† Tray

**NEW! PFC Choke**



Dimensions in mm

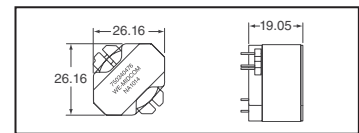


Application	Inductance (µH)	Digi-Key Part No.	Price Each			Würth Part No.
			1	25	100	
NXP SL1750	250	732-2233-ND	16.50	13.75	12.18	750340476

**NEW! Analog Modem Transformers**



Dimensions in mm

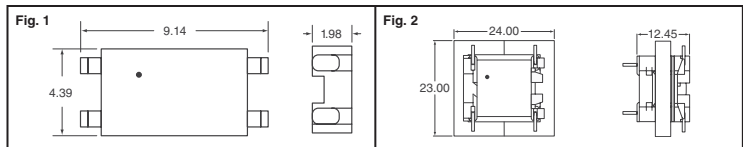

- Features:**
- SMD and THT
  - Small size
  - Flat profile
- Applications:**
- Analog modems

Fig.	Application	Inductance (µH)	Turn Ratio	Digi-Key Part No.	Cut Tape Price Each			Digi-Key Part No.	Tape & Reel Pricing 3,000	Würth Part No.
					1	25	100			
1	SmartDAA™ V.90	30	1.67:1	732-2228-1-ND	1.62	1.35	1.15	732-2228-2-ND	471.31/M	750082154
	SmartDAA SMD	30	1.67:1	732-2428-1-ND	2.69	2.25	1.91	732-2428-2-ND	785.52/M	750110007
2	PCB	—	1:1	732-2429-ND†	6.13	5.11	4.53	—	—	750082111

† Tray

Digi-Reel® Most SMT cutdown parts are available on a Digi-Reel®. For Digi-Reel part number, change 1-ND to 6-ND or CT-ND to DKR-ND. See Digi-Key® Services on page 2 for additional information.

Free shipping on orders over \$200 CAD! All prices in Canadian dollars and include duty and brokerage fees.

1-800-344-4539 • www.digikey.ca • 218-681-6674 • Fax: 218-681-3380

(CA2011) 1587