




Expertise Applied | Answers Delivered

SMD Nano²⁰ Fuses with Clip Assembly — 0157(T) Series



Specifications:
 • Operating Temperature: -55°C - 125°C
 • Construction Materials: Body: Ceramic; Cap: 157 Series: (0.125A) Gold Plated Brass; 157T Series: (0.375A - 5A) Silver Plated Brass
 Clip Plating: Matte Tin • Interrupting Rating: (0.125A - 8A) 50A @ 125VAC/VDC, 300A @ 32VDC (10A) 35A @ 125VAC, 50A @ 125VDC, 300A @ 32VDC

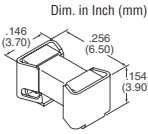


Note: See data sheet for detailed Amperage Safety Approvals.

Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each	Digi-Key Part No.	T&R Pricing
			1 10		1,500
0157 Series — Very Fast Acting					
0.125	125	F2958CT-ND	3.75 3.45	F2958TR-ND	1448.15/M
0.250	125	F2959CT-ND	3.57 3.28	F2959TR-ND	1378.19/M
0.500	125	F2960CT-ND	3.57 3.28	F2960TR-ND	1378.19/M
1.00	125	F2962CT-ND	3.03 2.79	F2962TR-ND	1169.92/M
1.50	125	F2963CT-ND	3.03 2.79	F2963TR-ND	1169.92/M
2.00	125	F2964CT-ND	3.03 2.79	F2964TR-ND	1169.92/M
2.50	125	F2965CT-ND	3.03 2.79	F2965TR-ND	1169.92/M
3.00	125	F2966CT-ND	3.03 2.79	F2966TR-ND	1169.92/M
3.50	125	F2967CT-ND	3.03 2.79	F2967TR-ND	1169.92/M
4.00	125	F2968CT-ND	3.03 2.79	F2968TR-ND	1169.92/M
5.00	125	F2969CT-ND	3.03 2.79	F2969TR-ND	1169.92/M
6.30	125	F2970CT-ND	3.03 2.79	F2970TR-ND	1169.92/M
7.00	125	F2971CT-ND	3.03 2.79	F2971TR-ND	1169.92/M
8.00	125	F2972CT-ND	3.03 2.79	F2972TR-ND	1169.92/M
10.00	125	F2973CT-ND	3.23 2.98	F2973TR-ND	1251.27/M
0157T Series — Sio-Bio®					
0.375	125	F2974CT-ND	4.44 4.10	F2974TR-ND	1719.88/M
0.500	125	F2975CT-ND	4.44 4.10	F2975TR-ND	1719.88/M
1.00	125	F2977CT-ND	3.92 3.61	F2977TR-ND	1513.24/M
1.50	125	F2978CT-ND	3.92 3.61	F2978TR-ND	1513.24/M
2.00	125	F2979CT-ND	3.92 3.61	F2979TR-ND	1513.24/M
2.50	125	F2980CT-ND	3.92 3.61	F2980TR-ND	1513.24/M
3.00	125	F2981CT-ND	3.92 3.61	F2981TR-ND	1513.24/M
3.50	125	F2982CT-ND	3.92 3.61	F2982TR-ND	1513.24/M
4.00	125	F2983CT-ND	3.92 3.61	F2983TR-ND	1513.24/M
5.00	125	F2984CT-ND	3.92 3.61	F2984TR-ND	1513.24/M

NEW! SMD Nano²⁰ 250V Fuses with Clip Assembly — 0160 Series




Specifications:
 • Operating Temperature: -55°C - 125°C • Materials: Body: Ceramic; Cap: Silver Plated Brass • Interrupting Rating: 50A @ 250VAC

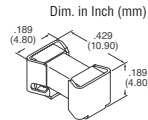

Note: See data sheet for detailed Amperage Safety Approvals.

Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each	Digi-Key Part No.	T&R Pricing
			1 10		1,000
0160 Series — Sio-Bio®					
0.500	250	F3558CT-ND	4.24 3.91	F3558TR-ND	1641.78
0.750	250	F3559CT-ND	4.24 3.91	F3559TR-ND	1641.78
1.00	250	F3560CT-ND	4.24 3.91	F3560TR-ND	1641.78
1.50	250	F3561CT-ND	4.24 3.91	F3561TR-ND	1641.78
2.00	250	F3562CT-ND	4.24 3.91	F3562TR-ND	1641.78
2.50	250	F3563CT-ND	4.24 3.91	F3563TR-ND	1641.78
3.00	250	F3564CT-ND	4.24 3.91	F3564TR-ND	1641.78
3.50	250	F3565CT-ND	4.24 3.91	F3565TR-ND	1641.78
4.00	250	F3566CT-ND	4.24 3.91	F3566TR-ND	1641.78
5.00	250	F3567CT-ND	4.24 3.91	F3567TR-ND	1641.78

 SMD Nano²⁰ 250V Fuses 0443 Series





Specifications:
 • Operating Temperature: -55°C - 125°C • Construction Materials: Body: Ceramic; Cap: Silver Plated Brass • Interrupting Rating: 50A @ 250VAC

Note: See data sheet for detailed Amperage Safety Approvals.

Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each	Digi-Key Part No.	T&R Pricing
			1 10		1,500
0443 Series — Sio-Bio®					
.500	250	F2904CT-ND	1.82 1.68	F2904TR-ND	704.56/M
.750	250	F2905CT-ND	1.82 1.68	F2905TR-ND	704.56/M

Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each	Digi-Key Part No.	T&R Pricing
			1 10		1,500
1.00	250	F2906CT-ND	1.82 1.68	F2906TR-ND	704.56/M
1.50	250	F2907CT-ND	1.82 1.68	F2907TR-ND	704.56/M
2.00	250	F2908CT-ND	1.82 1.68	F2908TR-ND	704.56/M
2.50	250	F2909CT-ND	1.82 1.68	F2909TR-ND	704.56/M
3.00	250	F2910CT-ND	1.82 1.68	F2910TR-ND	704.56/M
3.50	250	F2911CT-ND	1.82 1.68	F2911TR-ND	704.56/M
4.00	250	F2912CT-ND	1.82 1.68	F2912TR-ND	704.56/M
5.00	250	F2913CT-ND	1.77 1.63	F2913TR-ND	683.40/M

 SMD Nano²⁰ High Current Fuses 0456 Series

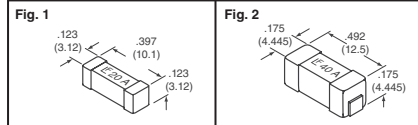

Specifications:
 • Operating Temperature: -55°C - 125°C with proper derating • Materials: Body: Ceramic; Cap: Silver Plated Brass • Interrupting Rating: (20A - 30A) 100A @ 125VAC; (40A) 600A @ 60VDC

Note: See data sheet for detailed Amperage Safety Approvals.


Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each	Digi-Key Part No.	T&R Pricing
			1 10		2,500
Fig. 1 — 0456 Series					
20	125	F3344CT-ND	5.93 5.45	F3344TR-ND	2163.07/M
30	125	F3345CT-ND	5.46 5.03	F3345TR-ND	1997.04/M

Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each	Digi-Key Part No.	T&R Pricing
			1 10		1,500
Fig. 2 — 0456 Series					
40	60	F3364CT-ND	6.77 6.23	F3364TR-ND	2614.81/M

Axial PICO® II Pico Fuses 0251 Series



Specifications:
 • Operating Temperature: -55°C - 125°C • Construction Materials: Body: UL94V-0 epoxy coating, green • Materials: Pure tin coated copper wire leads • Interrupting Rating: 300VDC, 50A VAC

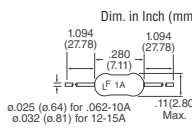

Note: See data sheet for detailed Amperage Safety Approvals.


Amp Rating	Voltage Rating	Digi-Key Part No.	Price Each
			1 100
0251 Series — Very Fast Acting (Bulk)			
.062	125	F2307-ND	1.34 1.24 .93
.125	125	F2308-ND	.84 .79 .59
.250	125	F2309-ND	.84 .79 .59
.375	125	F2310-ND	.84 .79 .59
.500	125	F2311-ND	.71 .65 .49
.630	125	F2312-ND	.71 .65 .49
.750	125	F2353-ND	.71 .65 .49
1.00	125	F2313-ND	.71 .65 .49
1.25	125	F2323-ND	.71 .65 .49
1.50	125	F2319-ND	.71 .65 .49
2.00	125	F2314-ND	.71 .65 .49
2.50	125	F2321-ND	.71 .65 .49
3.00	125	F2315-ND	.71 .65 .49
3.50	125	F2322-ND	.71 .65 .49
4.00	125	F2316-ND	.71 .65 .49
5.00	125	F2317-ND	.71 .65 .49
7.00	125	F2318-ND	.71 .65 .49
10.00	125	F2320-ND	.71 .65 .49
12.00	32	F2351-ND	.95 .88 .66
15.00	32	F2352-ND	.95 .88 .66

Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each	Digi-Key Part No.	T&R Pricing
			1 10		1,000
0251 Series — Very Fast Acting					
.250	125	F3165CT-ND	1.01 .94	F3165TR-ND	392.14
.375	125	F3166CT-ND	1.01 .94	F3166TR-ND	392.14
.500	125	F3167CT-ND	.84 .78	F3167TR-ND	325.43
.750	125	F3168CT-ND	.84 .78	F3168TR-ND	325.43
1.00	125	F3169CT-ND	.84 .78	F3169TR-ND	325.43
1.50	125	F3170CT-ND	.84 .78	F3170TR-ND	325.43
2.00	125	F3171CT-ND	.84 .78	F3171TR-ND	325.43
3.00	125	F3172CT-ND	.84 .78	F3172TR-ND	325.43
4.00	125	F3173CT-ND	.84 .78	F3173TR-ND	325.43
5.00	125	F3174CT-ND	.84 .78	F3174TR-ND	325.43

Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each	Digi-Key Part No.	T&R Pricing
			1 10		1,000
7.00	125	F3175CT-ND	.84 .78	F3175TR-ND	325.43
10.00	125	F3176CT-ND	.84 .78	F3176TR-ND	325.43
15.00	32	F3177CT-ND	1.14 1.05	F3177TR-ND	440.95

• 251L-473L-KIT-ND Digi-Key® 251 Series Fuse Very Fast Acting and 473 Series Fuse Sio-Bio® Axial Pico II™ 5 each of parts indicated, plastic storage box not included.....\$117.92

 Axial PICO® II Pico Fuses 0473L Series



Specifications:
 • Operating Temperature: -55°C - 125°C
 • Construction Materials: Body: UL94V0 epoxy coating, Gold; Leads: Solder coated Copper wire



Note: See data sheet for detailed Amperage Safety Approvals.


Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each	Digi-Key Part No.	T&R Pricing
			1 10		1,000
0473L Series — Sio-Bio®					
.375	125	F2338CT-ND	2.68 2.47	F2338TR-ND	1034.86
.500	125	F2339CT-ND	2.68 2.47	F2339TR-ND	1034.86
.750	125	F2340CT-ND	2.68 2.47	F2340TR-ND	1034.86
1.00	125	F2341CT-ND	2.68 2.47	F2341TR-ND	1034.86
1.50	125	F2347CT-ND	2.68 2.47	F2347TR-ND	1034.86
2.00	125	F2342CT-ND	2.68 2.47	F2342TR-ND	1034.86
2.50	125	F2348CT-ND	2.68 2.47	F2348TR-ND	1034.86
3.00	125	F2343CT-ND	2.68 2.47	F2343TR-ND	1034.86
3.50	125	F2349CT-ND	2.68 2.47	F2349TR-ND	1034.86
4.00	125	F2344CT-ND	2.68 2.47	F2344TR-ND	1034.86
5.00	125	F2345CT-ND	2.68 2.47	F2345TR-ND	1034.86
7.00	125	F2346CT-ND	2.68 2.47	F2346TR-ND	1034.86

• 251L-473L-KIT-ND Digi-Key® 251 Series Fuse Very Fast Acting and 473 Series Fuse Sio-Bio® Axial Pico II™ 5 each of parts indicated, plastic storage box not included.....\$117.92

Axial PICO® II 250V Pico Fuses 0263L Series



 Specifications:
 • Operating Temperature: -55°C - 125°C • Materials: Encapsulated epoxy-coated Body; Pure tin coated copper leads; Green in color • Interrupting Rating: 50A @ 250VAC



Note: See data sheet for detailed Amperage Safety Approvals.

Amp Rating	Voltage Rating	Digi-Key Part No.	Price Each
			1 10 100
0263L Series — Very Fast Acting			
.062	250	F2324-ND	2.98 2.75 2.07
.125	250	F2325-ND	2.37 2.19 1.65
.250	250	F2326-ND	2.37 2.19 1.65
.375	250	F2327-ND	2.37 2.19 1.65
.500	250	F2328-ND	2.37 2.19 1.65
.750	250	F2329-ND	1.96 1.82 1.36
1.00	250	F2330-ND	1.96 1.82 1.36
1.50	250	F2335-ND	1.96 1.82 1.36
2.00	250	F2331-ND	