




NEW! ROSE+BOPLA Boxes and Enclosures

A Phoenix Mecano Company

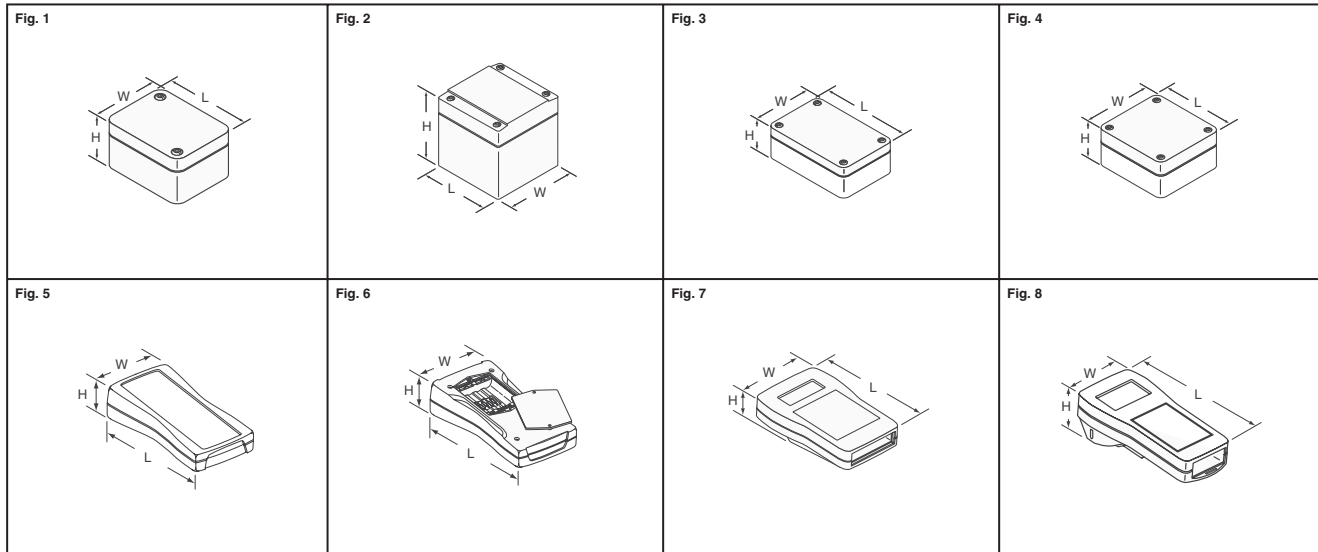

NEMA / Watertight Polycarbonate Enclosures

Color	Dimensions - Inch (mm)			Digi-Key Part No.	Price Each		Rose+Bopla Part No.
	L	W	H		1	10	
Fig. 1 — O2 Series							
Gray	2.55 (65)	1.96 (50)	1.37 (35)	902-1088-ND	13.03	11.03	2206000
Gray	3.22 (82)	3.14 (80)	2.16 (55)	902-1089-ND	19.18	16.23	2210000
Gray	4.72 (120)	3.14 (80)	2.16 (55)	902-1090-ND	20.96	17.74	2215000
Gray	4.72 (120)	3.14 (80)	3.34 (85)	902-1091-ND	24.69	20.89	2226000
Gray	4.80 (122)	4.72 (120)	3.35 (85)	902-1092-ND	30.78	26.05	2227000
Gray	6.29 (160)	4.72 (120)	3.54 (90)	902-1093-ND	35.51	30.04	2238000
Gray	7.87 (200)	4.72 (120)	2.95 (75)	902-1094-ND	38.41	32.51	2221000
Gray	7.87 (200)	4.72 (120)	3.54 (90)	902-1095-ND	40.54	34.31	2237000

Watertight Fiberglass Enclosures

Color	Dimensions - Inch (mm)			Digi-Key Part No.	Price Each		Rose+Bopla Part No.
	L	W	H		1	10	
Fig. 4 — O2 Series							
Gray	3.15 (80)	2.95 (75)	2.20 (56)	902-1014-ND	21.99	19.45	20808060
Gray	4.80 (122)	4.72 (120)	3.58 (91)	902-1015-ND	36.86	32.56	21212090
Gray	8.66 (220)	4.72 (120)	3.58 (91)	902-1016-ND	43.14	38.14	21222090
Gray	6.30 (160)	6.30 (160)	3.58 (91)	902-1017-ND	48.79	43.13	21616090
Gray	10.24 (260)	6.30 (160)	3.58 (91)	902-1018-ND	56.12	49.62	21626090
Gray	14.17 (360)	6.30 (160)	3.58 (91)	902-1019-ND	74.96	66.28	21636090

NEMA / Watertight Aluminum Enclosures

Color	Dimensions - Inch (mm)			Digi-Key Part No.	Price Each		Rose+Bopla Part No.
	L	W	H		1	10	
Fig. 2 — Aluform Series — Membrane Keypad							
Gray	3.15 (80)	3.15 (80)	3.19 (81)	902-1000-ND	24.35	21.08	40808080
Gray	4.72 (120)	3.15 (80)	3.19 (81)	902-1001-ND	27.68	24.38	40812080
Gray	3.94 (100)	3.94 (100)	2.40 (61)	902-1002-ND	27.90	24.15	41010060
Gray	3.94 (100)	6.30 (160)	2.40 (61)	902-1003-ND	39.41	34.11	41016060
Gray	3.94 (100)	7.87 (200)	2.40 (61)	902-1004-ND	43.31	37.48	41020060
Gray	4.72 (120)	4.72 (120)	3.19 (81)	902-1005-ND	38.62	33.44	41212080
Gray	4.72 (120)	6.30 (160)	3.19 (81)	902-1006-ND	48.05	41.59	41216080
Gray	5.51 (140)	5.51 (140)	2.80 (71)	902-1007-ND	42.40	36.71	41414070
Gray	7.09 (180)	5.51 (140)	2.80 (71)	902-1008-ND	51.28	44.39	41418070
Gray	8.66 (220)	5.51 (140)	2.80 (71)	902-1009-ND	54.20	46.91	41422070
Gray	6.30 (160)	6.30 (160)	3.19 (81)	902-1010-ND	47.95	41.51	41616080
Gray	9.45 (240)	6.30 (160)	3.19 (81)	902-1011-ND	59.52	51.51	41624080
Gray	7.87 (200)	7.87 (200)	2.80 (71)	902-1012-ND	60.57	52.43	42020070
Gray	11.02 (280)	7.87 (200)	2.80 (71)	902-1013-ND	66.69	57.71	42028070
Fig. 3 — Diecast O1 Series							
Gray	2.28 (58)	2.52 (64)	1.34 (34)	902-1103-ND	21.68	19.16	10610030
Gray	5.91 (150)	2.52 (64)	1.34 (34)	902-1104-ND	27.64	24.44	10615030
Gray	2.95 (75)	3.15 (80)	2.24 (57)	902-1105-ND	22.51	19.90	10808060
Gray	4.92 (125)	3.15 (80)	2.24 (57)	902-1106-ND	28.43	25.13	10813060
Gray	6.89 (175)	3.15 (80)	2.24 (57)	902-1107-ND	36.59	32.35	10818060
Gray	4.80 (122)	4.72 (120)	3.19 (81)	902-1108-ND	54.71	48.36	11212080
Gray	8.66 (220)	4.72 (120)	3.19 (81)	902-1109-ND	68.26	60.35	11222080
Gray	10.24 (260)	6.30 (160)	3.58 (91)	902-1110-ND	92.13	81.45	11626090

Handheld Enclosures

Color	Dimensions - Inch (mm)			Digi-Key Part No.	Price Each		Rose+Bopla Part No.
	L	W	H		1	10	
Fig. 5 — BOS Streamline 400 Series							
Gray	4.70 (119.3)	2.55 (64.9)	1.04 (26.5)	902-1034-ND	19.38	17.64	BS400F7024
Fig. 6 — BOS Streamline 403 Series							
Gray	4.70 (119.3)	2.55 (64.9)	1.04 (26.5)	902-1035-ND	27.03	24.60	BS403F7024
Fig. 5 — BOS Streamline 600 Series							
Gray	6.27 (159.4)	3.07 (77.9)	1.32 (33.5)	902-1036-ND	22.61	20.58	BS600F7024
Fig. 6 — BOS Streamline 603 Series							
Gray	6.27 (159.4)	3.07 (77.9)	1.32 (33.5)	902-1037-ND	32.31	29.40	BS603F7024
Fig. 5 — BOS Streamline 800 Series							
Gray	8.24 (209.3)	3.86 (98)	1.37 (34.8)	902-1038-ND	29.08	26.46	BS800F7024
Fig. 6 — BOS Streamline 803 Series							
Gray	8.24 (209.3)	3.86 (98)	1.37 (34.8)	902-1039-ND	38.76	35.28	BS803F7024
Accessories							
Gaskets for BS 400, Yellow				902-1040-ND	16.29	14.83	BS400DIRAL1003
Gaskets for BS 400, Blue				902-1041-ND	16.29	14.83	BS400DIRAL5005
Gaskets for BS 400, Dark Gray				902-1042-ND	16.29	14.83	BS400DIRAL7024
Gasket for BS 600, Yellow				902-1043-ND	17.20	15.65	BS600DIRAL1003
Gasket for BS 600, Blue				902-1044-ND	17.20	15.65	BS600DIRAL5005
Gasket for BS 600, Dark Gray				902-1045-ND	17.20	15.65	BS600DIRAL7024
Gasket for BS 800, Yellow				902-1046-ND	18.13	16.50	BS800DIRAL1003
Gasket for BS 800, Blue				902-1047-ND	18.13	16.50	BS800DIRAL5005
Gasket for BS 800, Dark Gray				902-1048-ND	18.13	16.50	BS800DIRAL7024
Screw Covers, Dark Gray				902-1049-ND	9.42	8.57	BS-SA7024

Color	Dimensions - Inch (mm)			Digi-Key Part No.	Price Each		Rose+Bopla Part No.
	L	W	H		1	10	
Fig. 7 — TG 130 Series							
Blue-Green	4.92 (125)	3.15 (80)	1.44 (37)	902-1064-ND†	12.15	10.53	270102000
Blue-Green	4.92 (125)	3.15 (80)	1.44 (37)	902-1065-ND‡	12.15	10.53	270102010

† Flat Open ‡ Flat Closed § Deep Open ▲ Deep Closed ▼ Open △ Closed
 ◊ With Display Window • Without Display Opening ★ With Keypad Area (Continued)

Free shipping on orders over \$200 CAD! All prices in Canadian dollars and include duty and brokerage fees.

2490 (CA2011)

1-800-344-4539 • www.digikey.ca • 218-681-6674 • Fax: 218-681-3380