

**NEW! HARWiN Metric Spacers**

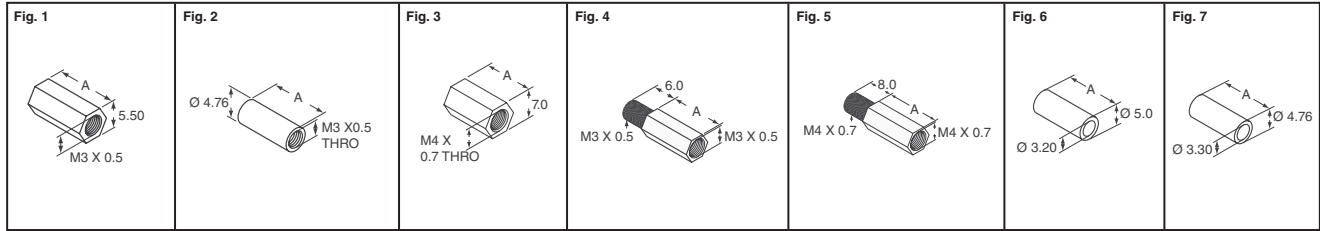


Fig.	Dim. A (mm)	Digi-Key Part No.	Price Each			Harwin Part No.
			1	50	100	
<b>Female, Brass, M3 Thread, Hexagonal</b>						
1	4	952-1481-ND	.61	.48	.41	R30-101402
	7	952-1482-ND	.66	.52	.44	R30-101702
	8	952-1483-ND	.70	.55	.47	R30-101802
	9	952-1484-ND	.70	.55	.47	R30-101902
	10	952-1485-ND	.70	.55	.47	R30-1011002
	11	952-1486-ND	.70	.55	.47	R30-1011102
	12	952-1487-ND	.70	.55	.47	R30-1011202
	13	952-1488-ND	.75	.58	.50	R30-1011302
	14	952-1489-ND	.75	.58	.49	R30-1011402
	15	952-1490-ND	.75	.58	.50	R30-1011502
	16	952-1491-ND	.78	.62	.52	R30-1011602
	18	952-1492-ND	.83	.65	.55	R30-1011802
	20	952-1493-ND	.97	.75	.64	R30-1012002
	25	952-1494-ND	1.06	.82	.70	R30-1012502
	<b>Female, Brass, M3 Thread, Circular</b>					
2	4	952-1514-ND	.52	.36	.28	R30-5000402
	6	952-1515-ND	.58	.41	.32	R30-5000602
	7	952-1516-ND	.69	.49	.38	R30-5000702
	8	952-1517-ND	.69	.49	.38	R30-5000802
	9	952-1518-ND	.69	.49	.38	R30-5000902
	10	952-1519-ND	.69	.49	.38	R30-5001002
	11	952-1520-ND	.75	.53	.41	R30-5001102
	12	952-1521-ND	.75	.53	.41	R30-5001202
	14	952-1522-ND	.61	.49	.41	R30-5001402
	16	952-1523-ND	.66	.52	.44	R30-5001602
3	18	952-1524-ND	.66	.52	.44	R30-5001802
	20	952-1525-ND	.75	.58	.50	R30-5002002
	25	952-1525-ND	.75	.58	.50	R30-5002002
<b>Female, Brass, M4 Thread, Hexagonal</b>						
3	6	952-1535-ND	.75	.53	.41	R40-1000602
	8	952-1536-ND	.61	.48	.41	R40-1000802
	10	952-1537-ND	.61	.48	.41	R40-1001002
	12	952-1538-ND	.61	.48	.41	R40-1001202
	13	952-1539-ND	.61	.48	.41	R40-1001302
	14	952-1540-ND	.66	.52	.44	R40-1001402
	16	952-1541-ND	.70	.55	.47	R40-1001602
	20	952-1542-ND	.83	.65	.55	R40-1002002
	25	952-1543-ND	.88	.68	.58	R40-1002502
	<b>Male/Female, Brass, M3 Thread, Hexagonal</b>					
4	4	952-1495-ND	.66	.52	.44	R30-3000402
	5	952-1496-ND	.70	.55	.47	R30-3000502
	6	952-1497-ND	.70	.55	.47	R30-3000602
	7	952-1498-ND	.75	.58	.50	R30-3000702
	8	952-1499-ND	.75	.58	.50	R30-3000802
	9	952-1500-ND	.78	.62	.52	R30-3000902
	10	952-1501-ND	.78	.62	.52	R30-3001002
	11	952-1502-ND	.83	.65	.55	R30-3001102
	12	952-1503-ND	.83	.65	.55	R30-3001202
	13	952-1504-ND	.88	.68	.58	R30-3001302
	14	952-1505-ND	.88	.68	.58	R30-3001402

Fig.	Dim. A (mm)	Digi-Key Part No.	Price Each			Harwin Part No.	
			1	50	100		
4	15	952-1506-ND	.92	.72	.61	R30-3001502	
	16	952-1507-ND	.92	.72	.61	R30-3001602	
	18	952-1508-ND	.97	.75	.64	R30-3001802	
	20	952-1509-ND	1.05	.82	.70	R30-3001902	
	20	952-1510-ND	1.10	.86	.73	R30-3002002	
	24	952-1511-ND	.93	.78	.65	R30-3002402	
5	25	952-1512-ND	1.01	.85	.71	R30-3002502	
	30	952-1513-ND	1.13	.94	.78	R30-3003002	
	<b>Male/Female, Brass, M4 Thread, Hexagonal</b>						
	5	6	952-1544-ND	.78	.62	.52	R40-3000602
		7	952-1545-ND	.83	.65	.55	R40-3000702
		8	952-1546-ND	.88	.68	.58	R40-3000802
		9	952-1547-ND	.92	.72	.61	R40-3000902
		10	952-1548-ND	.97	.75	.64	R40-3001002
		11	952-1549-ND	1.00	.79	.67	R40-3001102
		12	952-1550-ND	1.05	.82	.70	R40-3001202
13		952-1551-ND	1.05	.82	.70	R40-3001302	
14		952-1552-ND	.93	.78	.65	R40-3001402	
15		952-1553-ND	.98	.81	.68	R40-3001502	
6	16	952-1554-ND	1.01	.85	.71	R40-3001602	
	18	952-1555-ND	1.05	.88	.73	R40-3001802	
	20	952-1556-ND	1.16	.97	.81	R40-3002002	
	25	952-1557-ND	1.38	1.16	.97	R40-3002502	
	30	952-1558-ND	1.50	1.25	1.04	R40-3003002	
	<b>M3 Clearance, Plastic, Circular</b>						
6	3	952-1526-ND	.48	.30	.20	R30-6700394	
	4	952-1527-ND	.56	.40	.31	R30-6700494	
	5	952-1528-ND	.50	.32	.21	R30-6700594	
	6	952-1529-ND	.62	.44	.34	R30-6700694	
	8	952-1530-ND	.53	.33	.22	R30-6700894	
7	10	952-1531-ND	.43	.30	.23	R30-6701094	
	11	952-1532-ND	.73	.52	.40	R30-6701194	
	12	952-1533-ND	.55	.44	.37	R30-6701294	
	13	952-1534-ND	.55	.44	.37	R30-6701394	
	<b>M3 Clearance, Brass, Circular</b>						
7	2	952-1559-ND	.92	.72	.61	R30-6010202	
	3	952-1560-ND	.92	.72	.61	R30-6010302	
	4	952-1561-ND	.97	.75	.64	R30-6010402	
	5	952-1562-ND	.97	.75	.64	R30-6010502	
	6	952-1563-ND	.97	.75	.64	R30-6010602	
	7	952-1564-ND	1.00	.79	.67	R30-6010702	
	8	952-1565-ND	1.05	.82	.70	R30-6010802	
	9	952-1566-ND	.93	.78	.65	R30-6010902	
	10	952-1567-ND	.93	.78	.65	R30-6011002	
	11	952-1568-ND	.98	.81	.68	R30-6011102	
	12	952-1569-ND	.98	.81	.68	R30-6011202	
	13	952-1570-ND	1.01	.85	.71	R30-6011302	
	14	952-1571-ND	1.05	.88	.73	R30-6011402	
	15	952-1572-ND	1.08	.91	.76	R30-6011502	
22	952-1573-ND	1.61	1.34	1.12	R30-6012202		
30	952-1574-ND	1.01	.85	.71	R30-6013002		



**K**

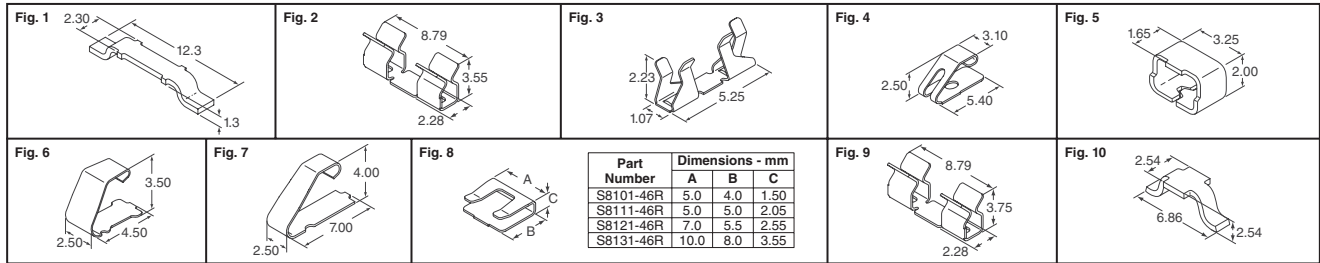


Fig.	Description	Digi-Key Part No.	Cut Tape Price Each			Digi-Key Part No.	Tape and Reel		Harwin Part No.
			1	10	50		Qty.	Pricing	
1	SMT Jumper, 12.3mm	952-1474-1-ND	.31	.25	.21	952-1474-2-ND	5,000	101.58/M	S1621-46R
2	SMT RFI Shield Clip, Mini	952-1475-1-ND	.39	.33	.28	952-1475-2-ND	1,900	164.91/M	S1711-46R
3	SMT RFI Shield Clip, Mini	952-1476-1-ND	.32	.25	.22	952-1476-2-ND	5,000	102.77/M	S1721-46R
4	SMT Ground Spring Contact, 2.5mm	952-1477-1-ND	.36	.28	.24	952-1477-2-ND	2,500	114.72/M	S1741-46R
5	SMT Test Point	952-1478-1-ND	.33	.26	.22	952-1478-2-ND	2,500	109.94/M	S1751-46R
6	SMT Ground Spring Contact, 3.5mm	952-1479-1-ND	.60	.50	.42	952-1479-2-ND	2,000	225.85/M	S1761-42R
7	SMT Ground Spring Contact, 4mm	952-1480-1-ND	.62	.52	.44	952-1480-2-ND	2,000	252.14/M	S1791-42R
8	SMT Cable Clip, 1mm	952-1576-1-ND	.33	.26	.22	952-1576-2-ND	3,000	109.94/M	S8101-46R
8	SMT Cable Clip, 1 - 1.5mm	952-1577-1-ND	.32	.25	.22	952-1577-2-ND	1,500	121.89/M	S8111-46R
8	SMT Cable Clip, 1.5 - 2.0mm	952-1578-1-ND	.30	.24	.21	952-1578-2-ND	1,300	131.45/M	S8121-46R
8	SMT Cable Clip, 2.0 - 3.0mm	952-1579-1-ND	.38	.27	.21	952-1579-2-ND	800	105.16	S8131-46R
9	SMT RFI Shield Clip, Maxi	952-1580-1-ND	.42	.33	.28	952-1580-2-ND	1,900	150.57/M	S1411-46R
10	SMT Jumper, 6.86mm	952-1581-1-ND	.38	.30	.25	952-1581-2-ND	2,500	121.89/M	S1731-46R

Digi-Reel® Most SMT cutdown parts are available on a Digi-Reel®. For Digi-Reel part number, change 1-ND to 6-ND or CT-ND to DKR-ND. See Digi-Key® Services on page 2 for additional information.

**Free shipping on orders over \$200 CAD! All prices in Canadian dollars and include duty and brokerage fees.**

2504 (CA2011) 1-800-344-4539 • www.digikey.ca • 218-681-6674 • Fax: 218-681-3380