



Terminals

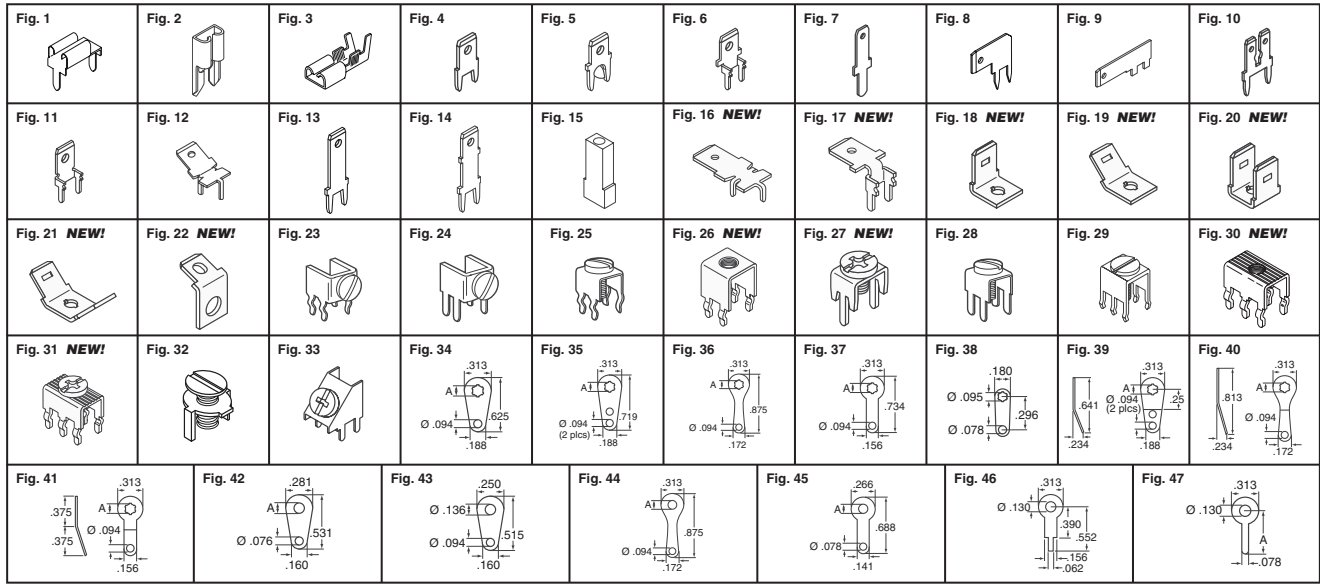


Fig.	Description	Dim. A Inch	Digi-Key Part No.	Pricing 10 100
<b>PC Quick-Fit Tab Terminals</b>				
1	.110" Female, Horizontal	—	3545K-ND	5.76 55.50
1	.110" Female, Horizontal	—	3549K-ND	5.76 55.50
1	.187" Female, Horizontal	—	3571K-ND <b>NEW!</b>	3.02 20.85
1	.205" Female, Horizontal	—	3546K-ND	6.00 57.39
1	.205" Female, Horizontal	—	3550K-ND	6.00 57.39
2	.250" Female, Horizontal	—	3547K-ND	6.30 60.54
2	.110" Female, Vertical	—	3534K-ND	2.73 21.69
2	.110" Female, Vertical	—	3544K-ND	2.73 21.69
2	.205" Female, Vertical	—	3525K-ND	2.73 21.69
2	.250" Female, Vertical	—	3528K-ND	2.73 21.69
2	.187" Female, Vertical	—	3548K-ND	2.73 21.69
2	.187" Female, Vertical	—	3551K-ND	2.73 21.69
2	.205" Female, Vertical	—	3522K-ND	1.84 13.08
2	.205" Female, Vertical	—	3578K-ND <b>NEW!</b>	2.73 21.69
3	.110" Female, 18-22 Gage	—	1252K-ND	2.10 20.05
3	.187" Female, 16-22 Gage	—	1264K-ND	5.03 48.12
3	.205" Female, 16-20 Gage	—	4469K-ND	7.34 66.53
3	.250" Female, 16-20 Gage	—	4470K-ND	3.82 36.54
4	.187" Male, .032 Brass, Tin Plate, .050 Diameter	—	1216K-ND <b>NEW!</b>	2.33 16.24
4	.205" Male, .020 Brass, Tin Plate, .046 Diameter	—	1286K-ND	1.26 9.03
4	.205" Male, .032 Brass, Tin Plate, .052 Diameter	—	1213K-ND	1.43 13.94
5	.205" Male, .020 Brass, Tin Plate, .046 Diameter	—	1286-STK-ND	1.19 11.46
5	.205" Male, .032 Brass, Tin Plate, .052 Diameter	—	1213-STK-ND	1.43 10.25
6	.187" Male, .020 Brass, Tin Plate, .043 Diameter	—	4900K-ND	1.92 18.54
4	.187" Male, .020 Brass, Tin Plate, .046 Diameter	—	1285K-ND	1.12 11.03
4	.187" Male, .032 Brass, Tin Plate, .052 Diameter	—	1212K-ND	1.30 9.27
5	.187" Male, .020 Brass, Tin Plate, .046 Diameter	—	1285-STK-ND	1.18 8.30
5	.187" Male, .032 Brass, Tin Plate, .052 Diameter	—	1212-STK-ND	1.30 9.27
7	.110" Male, .020 Brass, Tin Plate, .046 Diameter	—	1267K-ND	1.45 13.94
7	.110" Male, .032 Brass, Tin Plate, .052 Diameter	—	1211K-ND	1.71 15.70
8	.110" Male, .020 Brass, Tin Plate, .046 Diameter	—	4903K-ND	3.01 28.48
8	.110" Male, .032 Brass, Tin Plate, .052 Diameter	—	4906K-ND	3.07 29.33
8	.187" Male, .020 Brass, Tin Plate, .046 Diameter	—	4904K-ND	2.88 27.57
8	.187" Male, .032 Brass, Tin Plate, .052 Diameter	—	4907K-ND	2.94 27.93
8	.250" Male, .032 Brass, Tin Plate, .056 Diameter	—	4966K-ND	2.15 16.11
8	.250" Male, .032 Brass, Tin Plate, .052 Diameter	—	1266K-ND	3.18 22.36
9	.250" Male, .032 Brass, Tin Plate, .106 Diameter	—	1265K-ND	3.10 21.81
4	.250" Male, .032 Brass, Tin Plate, .052 Diameter	—	1287K-ND	1.38 13.51
5	.250" Male, .032 Brass, Tin Plate, .052 Diameter	—	1287-STK-ND	1.38 13.51
10	.110"/.250" Male, .032 Brass, Tin Plate, .052 Diameter	—	1282K-ND	1.38 13.51
6	.250" Male, .032 Brass, Tin Plate, .067 Diameter	—	4901K-ND	2.84 19.94
11	.250" Male, .032 Brass, Tin Plate, .067 Diameter	—	4902K-ND	1.92 18.54
12	.250" Male, .032 Brass, Tin Plate, .052 Diameter	—	4912K-ND <b>NEW!</b>	4.07 39.14
12	.250" Male, .032 Brass, Tin Plate, .067 Diameter	—	4908K-ND	4.07 39.14
13	.250" Male, .032 Brass, Tin Plate, .052 Diameter	—	1289K-ND	2.14 15.70
13	.250" Male, .032 Brass, Tin Plate, .052 Diameter	—	1289-STK-ND	2.09 14.72
14	.250" Male, .032 Brass, Tin Plate, .052 Diameter	—	1281K-ND	3.47 24.54

Fig.	Description	Dim. A Inch	Digi-Key Part No.	Pricing 10 100
15	.250" Quick-Fit Vinyl Boot, Clear	—	4471K-ND	1.53 14.72
15	.250" Quick-Fit Vinyl Boot, Red	—	4472K-ND	1.53 14.72
15	.250" Quick-Fit Vinyl Boot, Blue	—	4473K-ND	1.53 14.72
—	Terminal Hand Insertion Tool	—	1288K-ND	49.70/1
<b>NEW! Rivet Mount Quick-Fit Terminals NEW!</b>				
16	.250" Male, .032 Brass, Tin Plate, .052 Diameter	—	4910K-ND	4.07 39.14
17	.250" Male, .032 Brass, Tin Plate, .060 Diameter	—	4914K-ND	2.73 19.09
18	.250" Male, .032 Brass 90° Tab, .130 Diameter	—	1256K-ND	2.51 17.75
19	.250" Male, Dual 90° Tabs, .130 Diameter	—	1257K-ND	2.22 15.58
20	.250" Male, 45° Tab, Brass, .130 Diameter	—	1280K-ND	2.51 17.75
21	.250" Male, Dual 45° Tabs, Brass, .130 Diameter	—	1258K-ND	2.18 15.40
22	.187" Male, 45° Tab, .020 Brass, .078 Diameter	—	4095K-ND	1.91 18.30
<b>PC Mount Screw Terminals</b>				
23	Snap-In PC Horizontal, 6-32 Thread	—	7690K-ND‡	6.42 47.57
23	Snap-In PC Horizontal, 6-32 Thread	—	7692K-ND‡‡	6.42 52.11
23	Snap-In PC Horizontal, M3 Thread	—	7695K-ND‡ <b>NEW!</b>	6.42 52.11
23	Snap-In PC Horizontal, M3 Thread	—	7790K-ND <b>NEW!</b>	5.24 45.93
23	Snap-In PC Horizontal, M4 Thread	—	7792K-ND <b>NEW!</b>	5.24 45.93
23	Snap-In PC Horizontal, M4 Thread	—	7794K-ND‡ <b>NEW!</b>	6.86 54.84
24	PC Horizontal, 6-32 Thread	—	8190K-ND‡	5.02 43.93
24	PC Horizontal, 6-32 Thread	—	7700K-ND‡‡	6.05 49.39
25	Snap-In PC Vertical, 6-32 Thread	—	7691K-ND‡	5.05 45.93
25	Snap-In PC Vertical, 6-32 Thread	—	7693K-ND‡‡	6.12 49.94
25	Snap-In PC Vertical, 6-32 Thread	—	7786K-ND <b>NEW!</b>	5.80 53.99
25	Snap-In PC Vertical, 10-32 Thread	—	8174K-ND <b>NEW!</b>	14.08 108.11
25	Snap-In PC Vertical, M3 Thread	—	7788K-ND <b>NEW!</b>	4.80 44.59
25	Snap-In PC Vertical, M4 Thread	—	7795K-ND‡ <b>NEW!</b>	4.60 42.84
25	Snap-In PC Vertical, M4 Thread	—	7797K-ND‡ <b>NEW!</b>	6.72 66.96
26	Snap-In PC Vertical, 10-32 Thread	—	7791K-ND <b>NEW!</b>	10.64 75.21
27	PC Vertical, Low Profile, 6-32 Thread	—	7778K-ND‡ <b>NEW!</b>	5.62 45.69
27	PC Vertical, Low Profile, 6-32 Thread	—	7784K-ND‡ <b>NEW!</b>	4.54 42.42
28	PC Vertical, 6-32 Thread	—	8191K-ND‡	4.61 42.66
28	PC Vertical, 6-32 Thread	—	7701K-ND‡‡	5.76 46.66
29	Snap-In PC Vertical, Heavy Duty, 10-32 Thread	—	8196K-ND‡	9.91 80.04
29	Snap-In PC Vertical, Heavy Duty, M5 Thread	—	7808K-ND <b>NEW!</b>	12.38 97.92
29	Snap-In PC Vertical, Heavy Duty, M5 Thread w/o Screw	—	7807K-ND <b>NEW!</b>	7.22 57.02
30	Snap-In PC Vertical, Heavy Duty, M4 Thread	—	7798K-ND <b>NEW!</b>	5.80 53.99
31	Snap-In PC Vertical, Heavy Duty, M4 Thread	—	7800K-ND <b>NEW!</b>	7.36 59.99
31	Snap-In PC Vertical, 6-32 Thread	—	8199K-ND‡‡ <b>NEW!</b>	7.36 59.99
32	Terminal Insert 10-32 Thread	—	1202K-ND‡	13.65 131.01
32	Screw Terminal Insert 10-32 Thread	—	1299K-ND‡	13.65 131.01
33	PC 45°, Screw Supplied Unassembled, 6-32 Thread	—	8189K-ND‡	11.56 102.96
33	PC 45°, 6-32 Thread	—	7702K-ND‡‡	13.16 107.99
<b>Lockwasher Terminal Lugs</b>				
34	.018 Brass, Tin Plate	.120	908K-ND	1.68 16.11
34	.018 Brass, Tin Plate	.140	914K-ND	1.68 16.11
34	.018 Brass, Tin Plate	.171	915K-ND	1.68 16.11

‡ Screw Installed and Captivated ‡ Available with colored Screw Heads (Continued)

Free shipping on orders over \$200 CAD! All prices in Canadian dollars and include duty and brokerage fees.

1-800-344-4539 • www.digikey.ca • 218-681-6674 • Fax: 218-681-3380

(CA2011) 2505