



Power Strips and Surge Suppressors with Hospital-Grade Receptacles and Plug

Features: • Ideal choice where durability and reliability are required • Rugged all-metal housing • Mounting keyhole slots/flanges

Note: Not for use where NEC requires hospital-grade receptacles.

 


Table with columns: Description, Digi-Key Part No., Price Each, Tripp Lite Part No. Includes sections for Power Strips and Surge Suppressors.

Direct Plug-In/Traveler Surge Suppressors

These direct plug-in models offer a compact surge protection solution for all computers and home/office electronics. Direct plug-in Isobar models offer premium surge protection. The Traveler™ model offers ideal protection for notebook computers and fits easily into any briefcase. Select models offer diagnostic LEDs, transformer friendly designs and up to 600 joules of surge absorption. Up to \$100,000 Ultimate Lifetime Insurance.

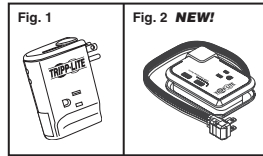


Table with columns: Fig., Description, Digi-Key Part No., Price Each, Tripp Lite Part No. Lists models like Traveler™ Direct Plug-In and Isobar.

◆ RoHS Compliant

Data Line Surge Suppressors

Data networks are increasingly susceptible to problems from dataline transients as transmission rates continue to rise. Tripp Lite's dataline surge suppressors safely divert damaging surges before they reach your critical network equipment. Protects I/O and Serial ports, modem fax cards, network interface cards and motherboards.

Table with columns: Lines Protected, Interface Type, Digi-Key Part No., Price Each, Tripp Lite Part No.

◆ RoHS Compliant

Modem/Fax and Multimedia Surge Suppressors

Protect all computers and home/office electronics, including modem/fax and multimedia equipment against damaging surges, spikes and line noise. Select models offer space saving right angle plugs, transformer friendly designs up to 3,690 joules of surge absorption. Modem/fax, coaxial and/or Ethernet surge protection. Up to \$250,000 Ultimate Lifetime Insurance.



Table with columns: Description, Digi-Key Part No., Price Each, Tripp Lite Part No. Lists various surge suppressor models.

◆ RoHS Compliant

Precision — Regulated DC Power Supplies

Features: • Current limiting electronic foldback for automatic overcurrent protection in case of overload; time controlled on 7 Amp and larger models • Regulated output voltage maintains up to 95% of no load value • High quality filtering provides for very low ripple/low noise operation • Large heat sinks and vented cabinet provide cool operation for continuous use and long life of the unit

Table with columns: Description, Application, Digi-Key Part No., Price Each, Tripp Lite Part No. Lists regulated DC power supplies.

PowerVerter® DC-to-AC Inverters

Ultra-Compact Inverters are housed in a sturdy portable metal case with 12V cigarette lighter plug built-in. Ideal for laptops, test equipment and TV-VCR units.



Peak Power models are able to handle up to twice their normal wattage for short periods of time delivering high start-up current, frequency controlled AC, making them ideal for motors, refrigerators, power tools and microwaves

Table with columns: Description (H x W x D), Digi-Key Part No., Price Each, Tripp Lite Part No. Includes sections for Ultra-Compact Inverters and Peak Power Inverters.

Protect-It!™ Economy Surge Suppressors


Protect all computers and home office electronics against damaging surges, spikes and line noise. Select Protect-It!™ Surge Suppressors offer space saving right angle plugs, transformer friendly designs and up to 2,350 joules of surge absorption. Up to \$75,000 Ultimate Lifetime Insurance.

Table with columns: Description, Digi-Key Part No., Price Each, Tripp Lite Part No. Lists Economy Surge Suppressors.

NEW! Protect-It!™ Safety Series Surge Suppressors and Power-It!™ Safety Series Power Strips



 Protect-It! Safety Series Surge Suppressors provide the highest UL-verified joule ratings of any surge suppressors in their class. Joule ratings measure a surge suppressor's ability to handle surges; more joules mean more protection. In addition, all models filter disruptive EMI/RFI line noise to improve the performance of connected equipment. Up to \$100,000 Ultimate Lifetime Insurance guarantees equipment will stay safe from surge damage, including direct lightning strikes, for life. All-metal housing and OSHA yellow color. All models are backed by a lifetime limited warranty.




Power-It! Safety Series Power Strips provide a reliable source of AC power for a variety of tools and appliances: drills, saws, sanders, compressors, chargers, pumps and more. Premium features and rugged construction make these models ideal for every workshop, garage, laboratory, industrial facility and construction site. High-visibility OSHA yellow color alerts users and others that power cords and tools are in use. All-metal housing.

Table with columns: Description, Digi-Key Part No., Price Each, Tripp Lite Part No. Includes sections for Surge Suppressors and Power Strips.

WEBER®-TRIPP-LITE Power Strips

 Power Strips



Features: • Economical outlet strips wherever you need them • Variety of models for home office/small office computers and other electronic equipment • Seamless steel case with baked-on finish on select models

Table with columns: Description, Digi-Key Part No., Price Each, Tripp Lite Part No. Lists Weber-Tripp-Lite power strips.

◆ RoHS Compliant

Surge Suppressors

Features: • Economical surge suppressors protect against damaging surges, spikes and line noise • Variety of models for home office/small office computers and other electronic equipment • Seamless steel case with baked-on finish

 


Table with columns: Description, Digi-Key Part No., Price Each, Tripp Lite Part No. Lists Surge Suppressors.

Free shipping on orders over \$200 CAD! All prices in Canadian dollars and include duty and brokerage fees.

2560 (CA2011)

1-800-344-4539 • www.digikey.ca • 218-681-6674 • Fax: 218-681-3380