



Battery Holders, Clips, Contacts and Accessories

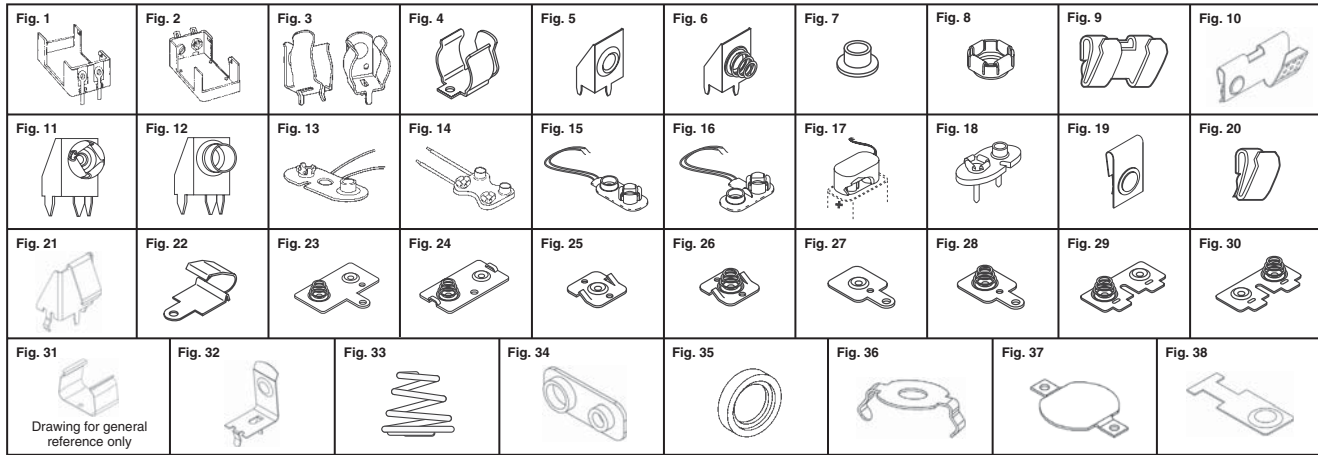


Fig.	Description	Digi-Key Part No.	1	10	100
9 Volt Plastic Holders — RoHS Compliant					
1	1 Cell	1294K-ND	2.37	21.93	190.63
2	1 Cell	1295K-ND	2.27	21.09	186.94
9 Volt Aluminum Holders — RoHS Compliant					
1	1 Cell	1291K-ND	3.73	34.06	300.38
2	1 Cell	1290K-ND	3.55	32.44	293.16
Insulated Polarizing Washers					
35	Red	59K-ND	—	1.50	11.03
35	Black	60K-ND	—	1.50	11.03
9 Volt Battery Straps — RoHS Compliant					
13	Single	72K-ND	1.64	15.24	140.46
14	Dual	227K-ND	3.60	33.27	311.52
Premium 9 Volt Battery Straps (I-Style) — RoHS Compliant					
15	Single, 4"	2238K-ND	1.16	10.87	103.37
15	Single, 6"	2239K-ND	1.18	11.10	105.56
15	Single, 6.5"	83K-ND	2.38	21.76	205.91
15	Single, 8"	2240K-ND	1.20	11.33	107.74
Premium 9 Volt Battery Straps (T-Style) — RoHS Compliant					
16	Single, 4"	2241K-ND	1.21	11.46	108.95
16	Single, 6"	2242K-ND	1.23	11.67	111.02
16	Single, 8"	2243K-ND	1.26	11.91	113.19
Economy 9 Volt Battery Straps (I-Style) — RoHS Compliant					
15	Single, 4"	232K-ND	.58	5.51	52.78
15	Single, 6"	233K-ND	.59	5.63	54.29
15	Single, 8"	234K-ND	.61	5.76	55.50
Economy 9 Volt Battery Straps (T-Style) — RoHS Compliant					
16	Single, 4"	235K-ND	.64	6.00	57.39
16	Single, 6"	236K-ND	.65	6.12	58.90
16	Single, 8"	237K-ND	.66	6.23	59.99
Shielded 9 Volt Battery Straps (I-Style) — RoHS Compliant					
17	Single, 4"	84-4K-ND	.70	6.47	62.17
17	Single, 6"	84-6K-ND	.72	6.72	64.48
17	Single, 8"	84-8K-ND	.73	6.83	65.32
Shielded 9 Volt Battery Straps (T-Style) — RoHS Compliant					
17	Single, 4"	81-4K-ND	.70	6.47	62.17
17	Single, 6"	81-6K-ND	.72	6.72	64.48
17	Single, 8"	81-8K-ND	.73	6.83	65.32
Vertical "9V" PC Snap-On Connector — RoHS Compliant					
18	—	968K-ND	1.27	11.93	113.32
18	Without PC Pins	68K-ND	.67	5.99	51.37
9 Volt PC Mount Snap-On Battery Contacts — RoHS Compliant					
11	Male On-Board Mount	593K-ND	.62	5.78	43.75
11	Male Off-Board Mount	635K-ND	.57	5.03	43.54
12	Female On-Board Mount	594K-ND	.70	6.09	52.36
12	Female Off-Board Mount	636K-ND	.70	6.01	51.62
"9V" Battery Snap-Ons — RoHS Compliant					
7	Stud	261K-ND	.15	1.22	11.46
8	Socket	269K-ND	.30	2.75	27.15
"9V" Battery - Protective Contact Cap — RoHS Compliant					
34	Black	96K-ND	.26	2.44	22.25
"A", "AA" Snap-In PC Battery Clip — RoHS Compliant					
3	1 Cell	92K-ND	.84/2	3.96	30.30
"AAA", "N" Snap-In PC Battery Clip — RoHS Compliant					
3	—	82K-ND	.84/2	3.96	30.30
"AAAA" PC Battery Clip — RoHS Compliant					
3	1 Cell - PC Mount	51K-ND	.43	3.96	30.30
4	1 Cell - SMT	50K-ND	.43	3.96	30.19
"AAA", "N" Surface Mount Battery Clip — RoHS Compliant					
4	1 Cell - Cut Tape	55KCT-ND	.82	7.87	72.08
4	1 Cell - Tape and Reel	55KTR-ND	—	203.25/300	—
"A", "AA", "9V" Surface Mount Cell Contacts — RoHS Compliant					
20	1 Cell - Cut Tape	5231KCT-ND	.85	7.71	72.28
20	1 Cell - Tape and Reel	5231KTR-ND	—	167.40/250	—

Fig.	Description	Digi-Key Part No.	1	10	100
"A", "AA", "AAA" Battery Clips — RoHS Compliant					
32	A, AA - PC Mount	52K-ND	.34	3.16	24.42
32	A, AA - SMT	57K-ND	.45	4.26	29.45
32	AAA - SMT	56K-ND	.44	4.15	28.78
"A", "AA" Snap-On Contacts — RoHS Compliant					
9	Dual Cell	210K-ND	1.00/2	4.67	43.63
19	1 Cell	228K-ND	.49/2	2.36	22.24
19	Dual Cell	292K-ND	1.00/2	4.67	43.63
20	1 Cell	209K-ND	.66/2	3.12	29.21
"A", "AA", "9V", "N" Spring Contacts — RoHS Compliant					
22	A, AA, 9V - 1 Cell	5209K-ND	—	6.34	60.84
"A", "AA" Battery Contacts — RoHS Compliant					
23	Dual w/Tab - Right	5211K-ND	—	4.45	42.66
23	Dual w/Tab - Left	5210K-ND	.47	4.45	42.66
24	Dual - Right	5212K-ND	—	5.46	52.36
24	Dual - Left	5242K-ND	.65	6.13	56.71
25	(+) Button	5224K-ND	—	1.73	16.66
26	(-) Spring	5202K-ND	—	3.31	31.76
27	(+) Button with tabs	5223K-ND	—	1.73	16.66
28	(-) Spring with tabs	5201K-ND	—	2.88	27.57
"AAA", "AAAA", "N" Battery Contacts — RoHS Compliant					
9	Dual Cell	202K-ND	1.00/2	4.67	43.63
10	AAA - Dual Left	296K-ND	.49	4.67	43.63
10	AAA - Dual Right	295K-ND	.49	4.67	43.63
19	1 Cell	238K-ND	.45/2	2.12	20.05
20	1 Cell	204K-ND	.66/2	3.12	29.21
25	(+) Button	5225K-ND	—	1.21	11.76
26	(-) Spring	5203K-ND	—	4.45	42.66
27	(+) Button with tabs	5226K-ND	—	1.73	16.66
28	(-) Spring with tabs	5204K-ND	—	2.88	27.57
29	Dual Right Side	5213K-ND	—	4.04	38.84
30	Dual Left Side	5214K-ND	—	4.04	38.84
"A" PC Contacts — RoHS Compliant					
5	(+) Button	595K-ND	—	2.23	21.15
6	(-) Spring	628K-ND	—	10.19	88.11
"AA", "AAA", "N", "9V" PC Contacts — RoHS Compliant					
5	(+) Button	637K-ND	—	2.03	19.09
5	(+) Button, AA, N	596K-ND	.25	2.23	21.15
6	(-) Spring	629K-ND	—	10.19	88.11
21	Leaf Spring, AA, N, 9V	590K-ND	.25	2.23	21.15
21	Leaf Spring, AAA	591K-ND	.31	2.94	27.15
"A", "AA", "C", "D" Battery Contacts — RoHS Compliant					
25	C (+) Contact	5240K-ND	.33	3.09	28.66
26	C (-) Contact	5241K-ND	.47	4.42	43.63
33	A, AA Spring	211K-ND	.13	1.22	11.76
33	C, D Spring	211-DK-ND	.28	2.67	25.51
Universal Battery Contacts — RoHS Compliant					
36	Coin Cell, PC Mount, Snap-In	2990K-ND	.13	1.22	8.81
37	Coin Cell, Surface Mount	2991K-ND	.13	1.22	8.81
38	AAA, AAAA, N, 12V - Off-Board	230-1K-ND	.18	1.72	14.61
Battery and Component Clips — RoHS Compliant					
31	9 Volt - 1 Cell	71K-ND	.46	4.37	41.99
31	AA - 1 Cell	91K-ND	.48	4.60	33.03
31	AAA - 1 Cell	90K-ND	.42	3.87	27.66
31	C - 1 Cell	93K-ND	.70	5.99	49.23
31	D - 1 Cell	78K-ND	.63	5.96	57.42

♦ RoHS Compliant ‡ Figs. 3, 4, 9, 19 and 20 are sold by the pair, except for Cut Tape and Tape and Reel

Digi-Reel® Most SMT cutdown parts are available on a Digi-Reel®. For Digi-Reel part number, change 1-ND to 6-ND or CT-ND to DKR-ND. See Digi-Key® Services on page 2 for additional information.

Free shipping on orders over \$200 CAD! All prices in Canadian dollars and include duty and brokerage fees.

2580 (CA2011)

1-800-344-4539 • www.digikey.ca • 218-681-6674 • Fax: 218-681-3380