



DC Brushless and Tachometer Fans, Blowers and Impellers



DC Fans - Motor: • Brushless electronic commutation provided by dependable solid-state circuitry • 100% dielectric tested at 600VAC/1 second/400 microamps maximum leakage
 • Polarity protected **Note: Custom Fan Cable Assemblies available upon request.**

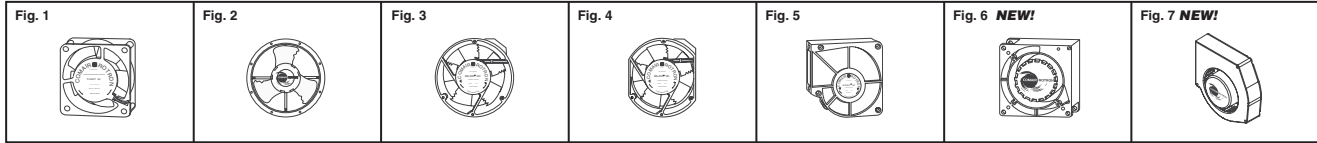


Fig.	Dimensions - mm	Voltage		Connection Type	Bearing	Power (Watts)	Running Current	CFM	Digi-Key Part No.	Price Each		Comair Rotron Part No.	Finger Guards	Price Each
		Nom.	Range							1	25			
Brushless DC Fans														
1	40 x 10	12	10.8 - 13.2	Lead Wires	Ball	1.2	120mA	6.80	CR015-ND	13.59	8.97	032608	CR230-ND	.68
	40 x 20	5	4.5 - 5.5	Lead Wires	Ball	0.7	140mA	7.5	CR523-ND NEW!	13.59	8.97	032620	CR230-ND	.68
	40 x 20	12	10.8 - 13.2	Lead Wires	Ball	1.2	100mA	10	CR016-ND	13.59	8.97	032622	CR230-ND	.68
	40 x 20	24	21.6 - 26.4	Lead Wires	Ball	22	90mA	10	CR360-ND	13.59	8.97	032628	CR230-ND	.68
	60 x 15	12	10.8 - 13.2	Lead Wires	Ball	1.6	130mA	16.60	CR023-ND	14.88	9.82	032886	CR221-ND	.71
	60 x 25	12	10.8 - 13.2	Lead Wires	Ball	2.8	230mA	23	CR024-ND	15.30	10.10	032704	CR221-ND	.71
	60 x 25	24	21.6 - 26.4	Lead Wires	Ball	3.6	150mA	23	CR026-ND	15.30	10.10	032710	CR221-ND	.71
	80 x 25	12	10.8 - 13.2	Lead Wires	Ball	3.0	250mA	38	CR030-ND	15.52	10.25	032736	CR180-ND	.98
	80 x 25	12	10.8 - 13.2	Lead Wires	Ball	1.8	150mA	31	CR031-ND	15.30	10.10	032738	CR180-ND	.98
	80 x 25	24	21.6 - 26.4	Lead Wires	Ball	3.8	160mA	38	CR032-ND	16.32	10.78	032744	CR180-ND	.98
	80 x 32	12	6 - 14	Lead Wires	Ball	3.4	280mA	34	CR014-ND	47.30	31.22	030615	CR180-ND	.98
	80 x 32	24	12 - 28	Lead Wires	Ball	3.3	140mA	34	CR017-ND	47.30	31.22	030616	CR180-ND	.98
	80 x 32	5	4.5 - 6.0	Lead Wires	Ball	2.3	460mA	34	CR353-ND	47.30	31.22	030829	CR180-ND	.98
	80 x 32	12	6 - 14	Lead Wires	Ball	6.2	380mA	45	CR354-ND	48.26	31.86	039067	CR180-ND	.98
	80 x 42	12	6 - 14	Lead Wires	Ball	3.0	250mA	35	CR019-ND	62.23	41.08	028933	CR180-ND	.98
	80 x 42	24	12 - 28	Terminal	Ball	3.0	130mA	35	CR028-ND NEW!	63.14	41.68	032002	CR180-ND	.98
	80 x 42	48	24 - 56	Lead Wires	Ball	3.0	60mA	35	CR021-ND	62.23	41.08	028935	CR180-ND	.98
	92 x 25	12	10.8 - 13.2	Lead Wires	Ball	4.1	340mA	50	CR035-ND	16.32	10.78	032760	CR220-ND	.81
	92 x 25	24	21.6 - 26.4	Lead Wires	Ball	3.6	150mA	50	CR037-ND	16.32	10.78	032768	CR220-ND	.81
	119 x 39	12	6 - 14	Lead Wires	Ball	6.0	500mA	110	CR069-ND NEW!	65.08	42.96	028865	CR210-ND	1.82
	119 x 39	24	12 - 28	Lead Wires	Ball	6.0	250mA	110	CR070-ND	65.08	42.96	028866	CR210-ND	1.82
	119 x 39	48	24 - 56	Lead Wires	Ball	5.8	120mA	110	CR071-ND NEW!	65.08	42.96	028867	CR210-ND	1.82
	119 x 39	12	6 - 14	Terminal	Ball	6.0	500mA	110	CR072-ND	65.08	42.96	028868	CR210-ND	1.82
	119 x 39	24	12 - 28	Terminal	Ball	6.0	250mA	110	CR073-ND	65.08	42.96	028869	CR210-ND	1.82
	119 x 39	48	24 - 56	Terminal	Ball	5.8	120mA	110	CR074-ND	60.26	39.77	028870	CR210-ND	1.82
	119 x 39	12	6 - 14	Lead Wires	Ball	2.2	180mA	75	CR262-ND	47.77	40.54	030715	CR210-ND	1.82
	120 x 32	12	6 - 14	Lead Wires	Sleeve	2.2	180mA	60	CR043-ND	25.73	21.84	032140	CR210-ND	1.82
	120 x 32	12	6 - 14	Lead Wires	Ball	7.9	660mA	102	CR051-ND	48.36	31.92	032489	CR210-ND	1.82
	120 x 32	24	12 - 28	Lead Wires	Ball	5.5	230mA	102	CR055-ND	46.50	30.69	030572	CR210-ND	1.82
	120 x 32	48	24 - 56	Lead Wires	Ball	8.4	180mA	102	CR240-ND	46.50	30.69	030573	CR210-ND	1.82
	120 x 32	24	12 - 28	Lead Wires	Ball	10.6	440mA	118	CR351-ND	47.79	31.54	031618	CR210-ND	1.82
	120 x 38	12	6 - 14	Lead Wires	Ball	7.0	580mA	110	CR341-ND NEW!	44.88	29.62	032525	CR210-ND	1.82
	120 x 38	24	12 - 28	Lead Wires	Ball	7.0	290mA	110	CR342-ND	44.88	29.62	032526	CR210-ND	1.82
	120 x 38	48	24 - 56	Lead Wires	Ball	7.4	150mA	110	CR343-ND NEW!	44.88	29.62	032527	CR210-ND	1.82
	127 x 38	12	6 - 14	Terminal	Ball	15.0	1250mA	150	CR266-ND	86.47	57.07	031074	CR200-ND	2.65
	127 x 38	24	12 - 28	Terminal	Ball	15.0	630mA	150	CR267-ND	87.47	57.73	031075	CR200-ND	2.65
	127 x 38	48	24 - 56	Terminal	Ball	15.0	310mA	150	CR268-ND	87.47	57.73	031076	CR200-ND	2.65
	127 x 38	24	12 - 28	Lead Wires	Ball	15.0	630mA	150	CR529-ND NEW!	91.47	60.37	031636	CR200-ND	2.65
	127 x 38	48	24 - 56	Lead Wires	Ball	15.0	310mA	150	CR526-ND NEW!	91.47	60.37	031377	CR200-ND	2.65
	176 x 112	48	24 - 56	Lead Wires	Ball	33.6	700mA	320	CR301-ND NEW!	161.16	106.37	031520	—	—
2	254 x 89	24	12 - 28	Lead Wires	Ball	29.0	1200mA	550	CR302-ND	159.06	104.99	031573	CR223-ND	4.20
3	172 x 51	12	6 - 14	Terminal	Ball	25.2	2260mA	235	CR520-ND NEW!	107.18	70.74	031083	CR206-ND	3.00
	172 x 51	24	12 - 28	Terminal	Ball	24	1000mA	235	CR242-ND	107.53	70.98	031084	CR206-ND	3.00
	172 x 51	48	24 - 56	Terminal	Ball	22	460mA	235	CR243-ND	107.80	71.15	031085	CR206-ND	3.00
4	171 x 150 x 51	12	6 - 14	Terminal	Ball	27.1	2260mA	235	CR524-ND NEW!	108.86	71.85	031089	CR196-ND	3.19
	171 x 150 x 51	12	6 - 14	Terminal	Ball	18	1500mA	205	CR293-ND	108.86	71.85	031092	CR196-ND	3.19
	171 x 150 x 51	24	12 - 28	Terminal	Ball	24	1000mA	235	CR291-ND	108.86	71.85	031090	CR196-ND	3.19
	171 x 150 x 51	48	24 - 56	Terminal	Ball	22	460mA	235	CR292-ND	109.09	72.00	031091	CR196-ND	3.19
Blowers														
5	80 x 32	12	6 - 14	Lead Wires	Ball	5	420mA	15	CR304-ND	59.01	38.95	031101	—	—
	80 x 32	24	12 - 28	Lead Wires	Ball	4.8	200mA	15	CR305-ND	59.01	38.95	031102	—	—
6	80 x 32	24	12 - 28	Lead Wires	Ball	1.4	60mA	8.7	CR528-ND NEW!	59.95	39.57	031104	CR282-ND	.55
5	121 x 31	12	9 - 14	Lead Wires	Ball	10.8	900mA	26	CR247-ND	63.73	42.06	030619	—	—
	121 x 31	24	12 - 28	Lead Wires	Ball	11.5	480mA	26	CR248-ND	63.73	42.06	030621	—	—
7	160 x 50	24	12 - 28	Lead Wires	Ball	30	1250mA	60	CR249-ND NEW!	118.90	78.47	032183	—	—
Tachometer Output DC Fans														
1	127 x 38	48	24 - 56	Lead Wires	Ball	15	310mA	150	CR521-ND NEW!	91.47	60.37	031239	CR200-ND	2.65
	120 x 32	12	6 - 14	Lead Wires	Ball	7.9	660mA	102	CR339-ND	47.46	31.33	030598	CR210-ND	1.82
	120 x 32	24	12 - 28	Lead Wires	Ball	5.5	230mA	102	CR340-ND	47.46	31.33	030599	CR210-ND	1.82
	119 x 39	12	6 - 14	Lead Wires	Ball	6.0	500mA	110	CR344-ND	64.89	42.83	028885	CR210-ND	1.82
3	171 x 51	24	12 - 28	Lead Wires	Ball	6.0	250mA	110	CR345-ND	64.89	42.83	028886	CR210-ND	1.82
4	171 x 150 x 51	24	12 - 28	Lead Wires	Ball	24	1000mA	235	CR525-ND NEW!	110.12	72.68	031263	CR196-ND	3.19
	171 x 150 x 51	48	24 - 56	Lead Wires	Ball	22	460mA	235	CR522-ND NEW!	113.99	75.24	031328	CR196-ND	3.19

Note: See web site for drawing data.

Free shipping on orders over \$200 CAD! All prices in Canadian dollars and include duty and brokerage fees.

1-800-344-4539 • www.digikey.ca • 218-681-6674 • Fax: 218-681-3380

(CA2011) 2593