


3M 电路板安装互连产品

929 系列: • 材料: 玻璃填充聚酯 (PBT) • 易燃性: 94V-0 • 颜色: 黑色 • 触点材料: 铜合金 • 耐受电压: 1000Vrms • 额定温度: -40°C - 100°C • UL 文件编号 E68080 镀层选项: • 10μ" 金, 200μ" 粗面锡或 100μ" 锡铅

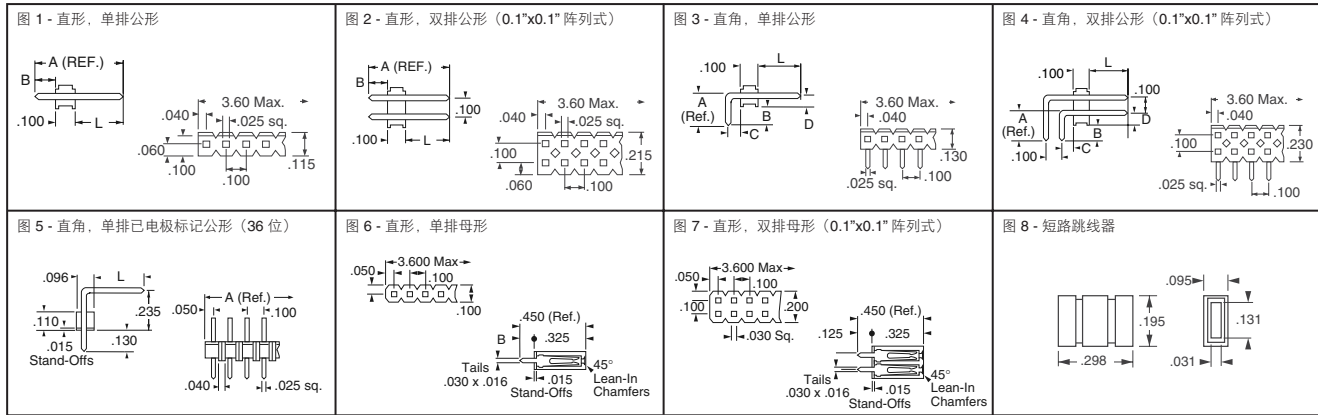

36 引脚接头

图	镀层	引脚数	尺寸 (英寸)				Digi-Key 零件编号	单价		
			L	A (基准)	B	C		1	10	100
直形, 单排公形										
1	焊接	36	.235	.545	.210	—	929834-02-36-ND	1.97	1.76	1.45
			.235	.545	.210	—	929834E-02-36-ND	1.80	1.61	1.33
			.235	.745	.410	—	929834-03-36-ND	2.39	2.15	1.77
			.235	.745	.410	—	929834E-03-36-ND	2.17	1.94	1.60
			.235	.845	.510	—	929834-04-36-ND	2.62	2.35	1.94
			.235	.845	.510	—	929834E-04-36-ND	2.39	2.15	1.77
	金	36	.235	.945	.610	—	929834-05-36-ND	2.68	2.40	1.98
			.235	.945	.610	—	929834E-05-36-ND	2.42	2.17	1.79
			.235	1.245	.910	—	929834-07-36-ND	3.05	2.73	2.25
			.235	1.245	.910	—	929834E-07-36-ND	3.05	2.73	2.25
			.235	.545	.210	—	929647-02-36-ND	3.31	2.96	2.44
			.235	.745	.410	—	929647-03-36-ND	4.10	3.68	3.03
2	焊接	72	.235	.545	.210	—	929836-02-36-ND	3.39	3.04	2.50
			.235	.545	.210	—	929836E-02-36-ND	2.94	2.63	2.17
			.235	.645	.310	—	929836-03-36-ND	2.94	2.63	2.17
			.235	.645	.310	—	929836E-03-36-ND	4.16	3.73	3.07
			.235	.745	.410	—	929836-04-36-ND	3.79	3.40	2.80
			.235	.745	.410	—	929836E-04-36-ND	3.51	3.14	2.59
	金	72	.235	.845	.510	—	929836-05-36-ND	3.88	3.47	2.86
			.235	.845	.510	—	929836E-05-36-ND	4.05	3.63	2.99
			.235	.945	.610	—	929836-06-36-ND	3.68	3.29	2.71
			.235	.945	.610	—	929836E-06-36-ND	4.93	4.42	3.64
			.235	.545	.210	—	929665-02-36-ND	5.36	4.80	3.95
			.235	.545	.210	—	929665E-02-36-ND	5.79	5.18	4.27
3	焊接	36	.235	.480	.145	—	929665-03-36-ND	6.61	5.92	4.88
			.235	.480	.145	—	929665E-03-36-ND	8.49	7.60	6.26
			.235	.645	.310	—	929665-04-36-ND	10.60	9.49	7.82
			.235	.645	.310	—	929665E-04-36-ND	3.39	3.04	2.50
			.235	.545	.210	—	929710-10-36-ND	3.08	2.76	2.27
			.235	.545	.210	—	929710E-10-36-ND	4.39	3.93	3.24
	金	72	.235	.645	.310	—	929665-05-36-ND	5.79	5.18	4.27
			.235	.645	.310	—	929665E-05-36-ND	6.61	5.92	4.88
			.235	.745	.410	—	929665-06-36-ND	8.49	7.60	6.26
			.235	.745	.410	—	929665E-06-36-ND	10.60	9.49	7.82
			.235	.845	.510	—	929710-10-36-ND	3.39	3.04	2.50
			.235	.845	.510	—	929710E-10-36-ND	3.08	2.76	2.27
直形, 单排公形										
4	焊接	72	.235	.185	.110	.070	929835-01-36-ND	2.00	1.79	1.47
			.235	.185	.110	.070	929835E-01-36-ND	1.82	1.64	1.35
			.235	.220	.145	.070	929838-04-36-ND	4.13	3.70	3.05
			.235	.220	.145	.070	929838E-04-36-ND	3.76	3.37	2.78
			.235	.480	.405	.070	929838-02-36-ND	4.16	3.73	3.07
			.235	.480	.405	.070	929838E-02-36-ND	3.79	3.40	2.80
	金	72	.235	.220	.145	.070	929838-03-36-ND	7.55	6.76	5.57
			.235	.220	.145	.070	929838E-03-36-ND	9.35	8.37	6.89
			.235	.480	.405	.070	929667-04-36-ND	7.55	6.76	5.57
			.235	.480	.405	.070	929667E-04-36-ND	9.35	8.37	6.89
			.235	.480	.405	.070	929667-02-36-ND	7.55	6.76	5.57
			.235	.480	.405	.070	929667E-02-36-ND	9.35	8.37	6.89
直形, 单排, 带电极标记, 公形										
5	焊接	36	.295	3.600	—	—	929500-01-36-ND	2.19	1.97	1.62
			.295	3.600	—	—	929500E-01-36-ND	2.00	1.79	1.47
			.295	3.600	—	—	929550-01-36-ND	3.96	3.55	2.92
			.295	3.600	—	—	929550E-01-36-ND	3.96	3.55	2.92
			.295	3.600	—	—	929974-01-36-ND	2.82	2.53	2.08
			.295	3.600	—	—	929974E-01-36-ND	2.57	2.30	1.89
	金	36	.295	3.600	—	—	929850-01-36-ND	3.65	3.27	2.69
			.295	3.600	—	—	929850E-01-36-ND	3.31	2.96	2.44
			.295	3.600	—	—	929974-01-36-ND	2.82	2.53	2.08
			.295	3.600	—	—	929974E-01-36-ND	2.57	2.30	1.89
			.295	3.600	—	—	929850-01-36-ND	3.65	3.27	2.69
			.295	3.600	—	—	929850E-01-36-ND	3.31	2.96	2.44
直形, 双排母形										
6	焊接	72	.295	3.600	—	—	929975-01-36-ND	4.90	4.39	3.62
			.295	3.600	—	—	929975E-01-36-ND	4.45	3.98	3.28
			.295	3.600	—	—	929852-01-36-ND	6.95	6.23	5.13
			.295	3.600	—	—	929852E-01-36-ND	6.33	5.67	4.67
			.295	3.600	—	—	929950-00-ND	2.29	2.10	1.70
			.295	3.600	—	—	929950E-00-ND	2.29	2.10	1.70
	金	36	.295	3.600	—	—	929950-00-ND	2.29	2.10	1.70
			.295	3.600	—	—	929950E-00-ND	2.29	2.10	1.70
			.295	3.600	—	—	929957-08-ND	3.12	2.80	2.28
			.295	3.600	—	—	929957E-08-ND	3.12	2.80	2.28
			.295	3.600	—	—	929957-08-ND	3.12	2.80	2.28
			.295	3.600	—	—	929957E-08-ND	3.12	2.80	2.28
短路跳线器										
8	镀焊层					929950-00-ND	2.29	2.10	1.70	
	10μ 镀金					929955-06-ND	2.70	2.40	1.95	
	30μ 镀金					929957-08-ND	3.12	2.80	2.28	

符合 RoHS 规范要求

1-35 引脚接头

图	镀层	引脚数	尺寸 (英寸)				Digi-Key 零件编号	单价		
			L	A (基准)	B	C		1	10	100
直形, 单排公形										
1	焊接	36	.235	.545	.210	—	929834-02-XX-ND	.55	.04	.04
			.235	.545	.210	—	929834E-02-XX-ND	.55	.04	.04
			.235	.745	.410	—	929834-03-XX-ND	.94	.04	.04
			.235	.745	.410	—	929834E-03-XX-ND	.94	.04	.04
			.235	.845	.510	—	929834-04-XX-ND	.83	.05	.05
			.235	.845	.510	—	929834E-04-XX-ND	.83	.05	.05
	金	36	.235	.945	.610	—	929834-05-XX-ND	.87	.05	.05
			.235	.945	.610	—	929834E-05-XX-ND	.87	.05	.05
			.235	1.245	.910	—	929834-07-XX-ND	.89	.06	.06
			.235	1.245	.910	—	929834E-07-XX-ND	1.19	.06	.06
			.235	.545	.210	—	929647-02-XX-ND	1.13	.07	.07
			.235	.745	.410	—	929647-03-XX-ND	1.63	.08	.08
2	焊接	72	.235	.545	.210	—	929836-02-XX-ND	1.85	.11	.11
			.235	.545	.210	—	929836E-02-XX-ND	1.76	.10	.10
			.235	.645	.310	—	929836-03-XX-ND	2.27	.11	.11
			.235	.645	.310	—	929836E-03-XX-ND	2.27	.11	.11
			.235	.745	.410	—	929836-04-XX-ND	.55	.04	.04
			.235	.745	.410	—	929836E-04-XX-ND	.55	.04	.04
	金	72	.235	.845	.510	—	929836-05-XX-ND	.55	.04	.04
			.235	.845	.510	—	929836E-05-XX-ND	.55	.04	.04
			.235	.945	.610	—	929836-06-XX-ND	1.34	.06	.06
			.235	.945	.610	—	929836E-06-XX-ND	1.55	.06	.06
			.235	.545	.210	—	929665-02-XX-ND	1.42	.05	.05
			.235	.545	.210	—	929665E-02-XX-ND	1.42	.05	.05
3	焊接	36	.235	.480	.145	—	929665-03-XX-ND	1.64	.07	.07
			.235	.480	.145	—	929665E-03-XX-ND	1.64	.07	.07
			.235	.645	.310	—	929665-04-XX-ND	1.73	.07	.07
			.235	.645	.310	—	929665E-04-XX-ND	1.52	.07	.07
			.235	.745	.410	—	929665-05-XX-ND	1.52	.07	.07
			.235	.745	.410	—	929665E-05-XX-ND	1.52	.07	.07
	金	72	.235	.845	.510	—	929665-06-XX-ND	1.83	.10	.10
			.235	.845	.510	—	929665E-06-XX-ND	2.28	.10	.10
			.235	.645	.310	—	929665-07-XX-ND	2.40	.11	.11
			.235	.645	.310	—	929665E-07-XX-ND	2.40	.11	.11
			.235	.745	.410	—	929665-08-XX-ND	2.59	.13	.13
			.235	.745	.410	—	929665E-08-XX-ND	3.22	.17	.17
4	焊接	72	.235	.480	.145	—	929665-09-XX-ND	3.58	.18	.18
			.235	.480	.145	—	929665E-09-XX-ND	1.83	.10	.10
			.235	.545	.210	—	929665-10-XX-ND	1.22	.06	.06
			.235	.545	.210	—	929665E-10-XX-ND	1.22	.06	.06
			.235	.645	.310	—	929710-10-XX-ND	1.22	.06	.06
			.235	.645	.310	—	929710E-10-XX-ND	1.93	.08	.08
	金	72	.235	.845	.510	—	929665-11-XX-ND	1.93	.08	.08
			.235	.845	.510	—	929665E-11-XX-ND	2.24	.11	.11
			.235	.945	.610	—	929665-12-XX-ND	3.03	.14	.14
			.235	.945	.610	—	929665E-12-XX-ND	3.03	.14	.14
			.23							