

图	颜色	Digi-Key 零件编号	1	10	100	250	500	1,000	Johnson 零件编号
尖头插孔 - 适用于标准尖头插头: 2.03mm									
1	白	J330-ND	1.27	11.33	89.68	188.80	354.00	660.80	105-1041-001
	黑	J124-ND	1.27	11.33	89.68	188.80	354.00	660.80	105-1042-001
	绿	J125-ND	1.27	11.33	89.68	188.80	354.00	660.80	105-1043-001
	黄	J331-ND	1.27	11.33	89.68	188.80	354.00	660.80	105-1044-001
	蓝	J333-ND	1.27	11.33	89.68	188.80	354.00	660.80	105-1047-001
水平测试插孔 - 适用于标准尖头插头: 2.03mm									
2	白	J108-ND	4.6	4.06	32.11	67.60	126.75	236.60	105-0751-001
	黑	J109-ND*	4.6	4.06	32.11	67.60	126.75	236.60	105-0752-001
	绿	J110-ND	4.6	4.06	32.11	67.60	126.75	236.60	105-0753-001
	橙	J111-ND	4.6	4.06	32.11	67.60	126.75	236.60	105-0754-001
	黄	J112-ND	4.6	4.06	32.11	67.60	126.75	236.60	105-0756-001
	棕	J113-ND	4.6	4.06	32.11	67.60	126.75	236.60	105-0757-001
	蓝	J114-ND	4.6	4.06	32.11	67.60	126.75	236.60	105-0758-001
	紫	J115-ND	4.6	4.06	32.11	67.60	126.75	236.60	105-0760-001
水平绝缘小型测试插孔 - 适用于标准尖头插头: 2.03mm									
3	白	J575-ND	4.5	3.96	31.35	66.00	123.75	231.00	105-1101-001
	黑	J576-ND	4.5	3.96	31.35	66.00	123.75	231.00	105-1102-001
	绿	J577-ND	4.5	3.96	31.35	66.00	123.75	231.00	105-1103-001
	黄	J578-ND	4.5	3.96	31.35	66.00	123.75	231.00	105-1104-001
	棕	J579-ND	4.5	3.96	31.35	66.00	123.75	231.00	105-1107-001
	蓝	J580-ND	4.5	3.96	31.35	66.00	123.75	231.00	105-1110-001
垂直测试插孔 - 适用于标准尖头插头: 2.03mm									
4	白	J119-ND	.69	6.14	48.64	102.40	192.00	358.40	105-0851-001
	黑	J120-ND	.69	6.14	48.64	102.40	192.00	358.40	105-0852-001
	绿	J121-ND	.69	6.14	48.64	102.40	192.00	358.40	105-0853-001
	黄	J122-ND	.69	6.14	48.64	102.40	192.00	358.40	105-0854-001
	棕	J123-ND	.69	6.14	48.64	102.40	192.00	358.40	105-0857-001
	蓝	J312-ND	.69	6.14	48.64	102.40	192.00	358.40	105-0860-001
垂直绝缘触点测试插孔 - 适用于标准尖头插头: 2.03mm									
5	白	J581-ND	.62	5.54	43.89	92.40	173.25	323.40	105-2201-201
	黑	J582-ND	.62	5.54	43.89	92.40	173.25	323.40	105-2202-201
	绿	J583-ND	.62	5.54	43.89	92.40	173.25	323.40	105-2203-201
	黄	J584-ND	.62	5.54	43.89	92.40	173.25	323.40	105-2204-201
	棕	J585-ND	.62	5.54	43.89	92.40	173.25	323.40	105-2207-201
屏蔽测试插孔 - 水平									
6	锡	J463-ND	4.97	44.14	349.41	735.60	1379.25	2574.60	129-0701-302
	金	J571-ND	7.13	62.56	460.95	987.75	1646.25	—	129-0701-302
屏蔽测试插孔 - 垂直									
7	锡	J462-ND	5.39	47.90	379.24	798.40	1497.00	2794.40	129-0701-201
	金	J570-ND	5.70	50.02	368.55	789.75	1316.25	—	129-0701-202
尖头插孔 - 绝缘高级型: 2.00mm									
8	白	J105-ND	1.33	11.86	93.86	197.60	370.50	691.60	105-0601-001
	黑	J106-ND	1.33	11.86	93.86	197.60	370.50	691.60	105-0602-001
	绿	J107-ND	1.33	11.86	93.86	197.60	370.50	691.60	105-0603-001
	黄	J337-ND	1.33	11.86	93.86	197.60	370.50	691.60	105-0604-001
	蓝	J338-ND	1.33	11.86	93.86	197.60	370.50	691.60	105-0607-001
尖头插孔 - 绝缘标准型: 2.00mm									
9	白	J320-ND	.77	6.84	54.15	114.00	213.75	399.00	105-0801-001
	黑	J117-ND*	.77	6.84	54.15	114.00	213.75	399.00	105-0802-001
	绿	J118-ND*	.77	6.84	54.15	114.00	213.75	399.00	105-0803-001
	黄	J321-ND	.77	6.84	54.15	114.00	213.75	399.00	105-0804-001
	蓝	J323-ND	.77	6.84	54.15	114.00	213.75	399.00	105-0807-001
带有套管的尖头插孔: 2.00mm									
10	红	J451-ND	1.59	14.11	111.72	235.20	441.00	823.20	105-0702-001
	黑	J452-ND	1.59	14.11	111.72	235.20	441.00	823.20	105-0703-001

图	颜色	Digi-Key 零件编号	1	10	100	250	500	1,000	Johnson 零件编号
尖头插孔 - 绝缘无焊型: 2.00mm									
11	白	J300-ND	.93	8.23	65.17	137.20	257.25	480.20	105-0301-001
	黑	J103-ND*	.93	8.23	65.17	137.20	257.25	480.20	105-0302-001
	绿	J104-ND*	.93	8.23	65.17	137.20	257.25	480.20	105-0303-001
	黄	J301-ND	.93	8.23	65.17	137.20	257.25	480.20	105-0304-001
	蓝	J305-ND	.93	8.23	65.17	137.20	257.25	480.20	105-0310-001
尖头插孔 - 绝缘多层单型: 2.00mm									
12	红	J454-ND	2.19	19.44	153.90	324.00	607.50	1134.00	105-1202-001
小型香蕉插头 - 绝缘焊接型: 2.64mm									
13	红	J457-ND	1.84	16.34	129.39	272.40	510.75	953.40	108-1002-001
	黑	J458-ND	1.84	16.34	129.39	272.40	510.75	953.40	108-1003-001
香蕉插孔 - 适用于标准香蕉插头 4.44mm 对边宽度									
14	—	J147-ND*	1.48	13.13	103.93	218.80	410.25	765.80	108-0740-001
非绝缘压花螺帽适用于标准的香蕉插头 4.44mm 对边宽度									
15	—	J587-ND	2.85	25.32	200.45	422.00	791.25	1477.00	111-2223-001
接线柱 - 绝缘标准型: 4.44mm									
16	白	J370-ND	2.40	21.31	168.72	355.20	666.00	1243.20	111-0101-001
	黑	J164-ND*	2.40	21.31	168.72	355.20	666.00	1243.20	111-0102-001
	绿	J165-ND*	2.40	21.31	168.72	355.20	666.00	1243.20	111-0103-001
	黄	J371-ND	2.59	22.99	182.02	383.20	718.50	1341.20	111-0104-001
	紫	J372-ND	2.40	21.31	168.72	355.20	666.00	1243.20	111-0107-001
香蕉插孔 - 绝缘焊接端子: 4.44mm									
17	白	J150-ND*	.59	5.26	41.61	87.60	164.25	306.60	108-0901-001
	黑	J151-ND*	.59	5.26	41.61	87.60	164.25	306.60	108-0902-001
	绿	J152-ND*	.59	5.26	41.61	87.60	164.25	306.60	108-0903-001
	橙	J356-ND	.66	5.83	46.17	97.20	182.25	340.20	108-0904-001
	黄	J154-ND	.59	5.26	41.61	87.60	164.25	306.60	108-0906-001
	棕	J357-ND	.66	5.83	46.17	97.20	182.25	340.20	108-0907-001
	蓝	J155-ND	.59	5.26	41.61	87.60	164.25	306.60	108-0910-001
	紫	J358-ND	.66	5.83	46.17	97.20	182.25	340.20	108-0912-001
香蕉插头 - 无屏蔽面板安装螺线接线柱: 4.23mm									
18	—	J148-ND	1.56	13.90	110.01	231.60	434.25	810.60	108-0750-001
香蕉插头 - 无屏蔽面板安装螺线型: 4.23mm									
19	—	J149-ND	1.34	11.95	94.62	199.20	373.50	697.20	108-0753-001
香蕉插头 - 绝缘无焊圆形手插型: 4.23mm									
20	白	J144-ND*	1.25	11.11	87.97	185.20	347.25	648.20	108-0301-001
	黑	J145-ND*	1.25	11.11	87.97	185.20	347.25	648.20	108-0302-001
	绿	J146-ND*	1.25	11.11	87.97	185.20	347.25	648.20	108-0303-001
	橙	J340-ND	1.25	11.11	87.97	185.20	347.25	648.20	108-0304-001
	黄	J153-ND	1.25	11.11	87.97	185.20	347.25	648.20	108-0306-001
	棕	J343-ND	1.25	11.11	87.97	185.20	347.25	648.20	108-0308-001
	紫	J344-ND	1.25	11.11	87.97	185.20	347.25	648.20	108-0310-001
香蕉插头 - 绝缘固体焊接型: 4.23mm									
21	红	J156-ND	2.51	22.32	176.70	372.00	697.50	1302.00	108-1722-101
	黑	J157-ND	2.51	22.32	176.70	372.00	697.50	1302.00	108-1723-101
香蕉插头 - 绝缘无焊型: 4.23mm									
21	红	J158-ND	1.91	16.97	134.33	282.80	530.25	989.80	108-1722-103
	黑	J159-ND	1.91	16.97	134.33	282.80	530.25	989.80	108-1723-103
香蕉插头 - 绝缘多层单型: 4.23mm									
22	白	J459-ND	2.08	18.48	146.30	308.00	577.50	1078.00	108-1081-001
	黑	J460-ND	2.08	18.48	146.30	308.00	577.50	1078.00	108-1082-001
	蓝	J461-ND	2.08	18.48	146.30	308.00	577.50	1078.00	108-1083-001

J100-KIT-ND Digi-Key® 插头和插孔包 包括表中 (\*) 所示的插头或插孔, 每种 10 个。价格包括带柄的塑料盒, 易于储藏和快速查找。..... 76.95

Tyco Electronics AMP 微型圆形金属外壳连接器

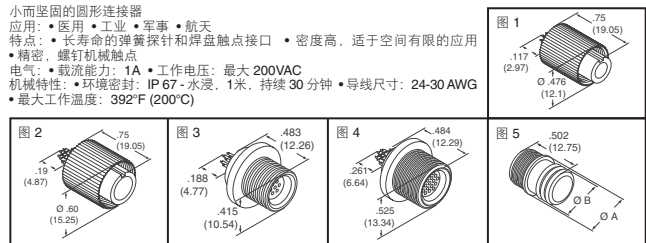


图	位置数量	外壳尺寸	触点系统	尺寸 - 英寸 (mm)		Digi-Key 零件编号	1	100	1,000	Tyco/AMP 零件编号
				A	B					
插头组件										
1	7	M11	弹簧探针	—	—	A30545-ND	40.59	29.11	24.75	1738548-1
	19	M11	引脚	—	—	A30547-ND	35.53	25.48	21.67	1738541-1
2	19	M14	弹簧探针	—	—	A30546-ND	58.34	41.84	35.58	1738552-1
	19	M14	引脚	—	—	A30548-ND	98.01	70.29	59.77	1738550-1
背板安装插座组件										
3	7	M11	弹簧探针	—	—	A30551-ND	26.63	19.10	16.24	1604750-1
	19	M11	插口	—	—	A30543-ND	25.38	18.20	15.48	1738547-1
4	19	M14	弹簧探针	—	—	A30542-ND	40.59	29.11	24.75	1738553-1
	19	M14	插口	—	—	A30544-ND	36.78	26.38	22.43	1738551-1
模压成型适配器 - 符合 RoHS 规范要求										
5	—	M11	—	.326 (8.29)	.295 (7.5)	A30549-ND	11.07	7.94	6.75	1604366-4
	—	M14	—	.424 (10.76)	.385 (9.8)	A30550-ND	12.30	8.82	7.50	1604366