

ASSMANN PLCC 插口

技术规格:

- 触点: 磷青铜, 镀锡和镀金
- 额定电流: 1 A
- 绝缘电阻: 最小 1000MΩ
- 耐受电压: 600Vrms
- 触点电阻: 最大 30mΩ
- 工作温度: -55°C - 110°C
- 绝缘体: PBT, UL 94V-0

A

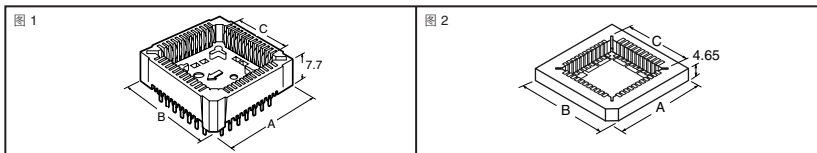



图	触点数	尺寸 (英寸)			Digi-Key 零件编号	单价			Assmann 零件编号
		A	B	C		1	10	100	
PLCC - 通孔									
锡									
1	20	0.61	0.61	0.20	AE7325-ND	.74	.65	.53	A-CCS20-Z
	20	0.61	0.61	0.20	AE10054-ND◆	1.35	1.17	.95	A-CCS20-Z-R
	28	0.71	0.71	0.30	AE10055-ND◆	1.35	1.17	.95	A-CCS28-Z-R
	32	0.71	0.81	0.30	AE7327-ND	.82	.72	.58	A-CCS32-Z
	32	0.71	0.81	0.30	AE10056-ND◆	1.68	1.46	1.18	A-CCS32-Z-R
	44	0.93	0.93	0.50	AE10057-ND◆	1.71	1.49	1.20	A-CCS44-Z-R
	52	1.02	1.02	0.60	AE10058-ND◆	1.86	1.62	1.31	A-CCS52-Z-R
	68	1.23	1.23	0.80	AE10059-ND◆	2.40	2.08	1.68	A-CCS68-Z-R
	84	1.42	1.42	1.00	AE10060-ND◆	2.46	2.14	1.73	A-CCS84-Z-R
	金								
1	20	0.61	0.61	0.20	AE7332-ND	1.21	1.05	.85	A-CCS20-G
	20	0.61	0.61	0.20	AE10061-ND◆	1.47	1.28	1.03	A-CCS20-G-R
	28	0.71	0.71	0.30	AE7333-ND	1.21	1.05	.85	A-CCS28-G
	28	0.71	0.71	0.30	AE10062-ND◆	1.68	1.46	1.18	A-CCS28-G-R
	32	0.71	0.81	0.30	AE7334-ND	1.40	1.21	.98	A-CCS32-G
	32	0.71	0.81	0.30	AE10063-ND◆	1.74	1.51	1.22	A-CCS32-G-R
	44	0.93	0.93	0.50	AE10064-ND◆	1.98	1.72	1.39	A-CCS44-G-R
	52	1.02	1.02	0.60	AE7336-ND	1.52	1.32	1.07	A-CCS52-G
	52	1.02	1.02	0.60	AE10065-ND◆	2.19	1.90	1.54	A-CCS52-G-R
	68	1.23	1.23	0.80	AE10066-ND◆	2.61	2.27	1.83	A-CCS68-G-R
84	1.42	1.42	1.00	AE7338-ND	1.76	1.53	1.23	A-CCS84-G	
84	1.42	1.42	1.00	AE10067-ND◆	3.00	2.60	2.10	A-CCS84-G-R	
PLCC - 表面贴装									
锡									
2	20	0.62	0.62	0.20	AE7339-ND	.67	.58	.47	A-CCS20-Z-SM
	20	0.62	0.62	0.20	AE10068-ND◆	1.17	1.02	.82	A-CCS20-Z-SM-R
	28	0.72	0.72	0.30	AE10069-ND◆	1.35	1.17	.95	A-CCS28-Z-SM-R
	32	0.72	0.82	0.40	AE10070-ND◆	1.35	1.17	.95	A-CCS32-Z-SM-R
	44	0.92	0.92	0.50	AE10071-ND◆	1.53	1.33	1.08	A-CCS44-Z-SM-R
	52	1.02	1.02	0.60	AE7343-ND	.96	.83	.67	A-CCS52-Z-SM
	52	1.02	1.02	0.60	AE10072-ND◆	1.74	1.51	1.22	A-CCS52-Z-SM-R
	68	1.22	1.22	0.80	AE7344-ND	1.04	.90	.73	A-CCS68-Z-SM
	68	1.22	1.22	0.80	AE10073-ND◆	1.98	1.72	1.39	A-CCS68-Z-SM-R

◆ 符合 RoHS 规范要求

IC 插口 双引线焊尾

技术规格:

- 触点: 磷青铜 机械和电气数据: • 过渡电阻: ≤12mΩ. 相邻触点间的电容: <0.9 pF. 相反相邻触点间的电容: <0.4pF. 电介质耐受电压: AC 500V, 持续 1 分钟. • 插入力: ≤1.5N • 抽出力: ≥0.7N. 体座: • PBT 和 30% 玻璃纤维 (UL 94V-0) • 绝缘电阻: 10¹² Ω • 工作温度范围: -55°C - 105°C

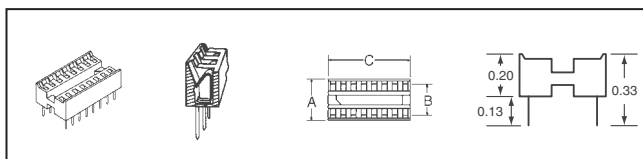

触点数	触点 镀层	尺寸 (英寸)			Digi-Key 零件编号	价格				Assmann 零件编号
		A	B	C		1	10	100	500	
6	锡	0.39	0.30	0.30	AE1485-ND◆	.59	4.68	37.70	136.50	A06-LC-TT-R
	金	0.39	0.30	0.30	AE1486-ND◆	1.26	10.92	88.20	378.00	A06-LCG-T-R
8	锡	0.39	0.30	0.39	AE9986-ND◆	.32	2.52	20.30	73.50	A08-LC-TT-R
	金	0.39	0.30	0.39	AE9987-ND◆	.54	4.68	37.80	162.00	A08-LCG-T-R
	锡	0.40	0.30	0.40	AE9988-ND†◆	.54	4.32	34.80	126.00	A08-LC-TR-R
14	锡	0.39	0.30	0.70	AE9989-ND◆	.41	3.24	26.10	94.50	A14-LC-TT-R
	金	0.39	0.30	0.70	AE9814-ND	.63	5.51	38.00	152.00	A14-LCG-T
	金	0.39	0.30	0.70	AE9990-ND◆	.63	5.46	44.10	189.00	A14-LCG-T-R
	锡	0.40	0.30	0.70	AE9991-ND†◆	.54	4.32	34.80	126.00	A14-LC-TR-R
16	锡	0.39	0.30	0.80	AE9992-ND◆	.45	3.60	29.00	105.00	A16-LC-TT-R
	金	0.39	0.30	0.80	AE9993-ND◆	.72	6.24	50.40	216.00	A16-LCG-T-R
	锡	0.40	0.30	0.80	AE9994-ND†◆	.63	5.04	40.60	147.00	A16-LC-TR-R
18	锡	0.39	0.30	0.90	AE9995-ND◆	.54	4.32	34.80	126.00	A18-LC-TT-R
	金	0.39	0.30	0.90	AE9818-ND	.81	7.08	48.80	195.20	A18-LCG-T
	金	0.39	0.30	0.90	AE9996-ND◆	.81	7.02	56.70	243.00	A18-LCG-T-R
	锡	0.40	0.30	0.90	AE9997-ND†◆	.68	5.40	43.50	157.50	A18-LC-TR-R
20	锡	0.39	0.30	1.00	AE9998-ND◆	.59	4.68	37.70	136.50	A20-LC-TT-R
	金	0.40	0.30	1.00	AE9999-ND◆	.87	7.54	60.90	261.00	A20-LCG-T-R
20	锡	0.40	0.30	1.00	AE9845-ND†	.26	2.09	16.82	60.90	A20-LC-TR
	锡	0.40	0.30	1.00	AE10000-ND†◆	.77	6.12	49.30	178.50	A20-LC-TR-R
22	锡	0.50	0.40	1.10	AE10264-ND◆	.86	6.84	55.10	199.50	A22-LC-T2-R
	金	0.50	0.40	1.10	AE9822-ND	.89	7.75	62.58	268.20	A22-LCG
24	锡	0.70	0.60	1.20	AE8924-ND	.29	2.34	18.85	68.25	A24-LC-TT
	锡	0.70	0.30	1.20	AE10285-ND◆	.63	5.04	40.60	147.00	A24-LC-7-TT-R
	锡	0.70	0.60	1.20	AE10001-ND◆	.72	5.76	46.40	168.00	A24-LC-TT-R
	金	0.70	0.60	1.20	AE10002-ND◆	1.08	9.36	75.60	324.00	A24-LCG-T-R
28	锡	0.70	0.60	1.20	AE10003-ND†◆	.81	6.48	52.20	189.00	A24-LC-TR-R
	锡	0.70	0.60	1.40	AE10004-ND◆	.86	6.84	55.10	199.50	A28-LC-TT-R
	锡	0.70	0.30	1.40	AE10286-ND◆	.77	6.12	49.30	178.50	A28-LC-7-TT-R
	金	0.70	0.60	1.40	AE10005-ND◆	1.26	10.92	88.20	378.00	A28-LCG-T-R
32	锡	0.70	0.60	1.40	AE10006-ND†◆	1.08	8.64	69.60	252.00	A28-LC-TR-R
	锡	0.70	0.60	1.60	AE10007-ND†◆	1.22	9.72	78.30	283.50	A32-LC-TR-R
40	锡	0.70	0.60	2.00	AE10008-ND◆	1.22	9.72	78.30	283.50	A40-LC-TT-R
	金	0.70	0.60	2.00	AE10009-ND◆	1.80	15.60	126.00	540.00	A40-LCG-T-R
	锡	0.70	0.60	2.00	AE9851-ND†	.46	3.67	29.58	107.10	A40-LC-TR
	锡	0.70	0.60	2.00	AE10010-ND†◆	1.53	12.24	98.60	357.00	A40-LC-TR-R

† 固定脚型 ◆ 符合 RoHS 规范要求

全部产品均以美元计价。 免费电话: 10800-1527031 (China Telecom - 中国电讯) — 10800-8527031 (CNCG - 中国网通)