



电压 (标准)	Digi-Key 零件编号	剪切带 价格			带卷†		Comchip 零件编号
		1	10	100	数量	价格	
5.6	641-1062-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C5V6
6.2	641-1063-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C6V2
6.8	641-1064-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C6V8
7.5	641-1065-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C7V5
8.2	641-1066-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C8V2
9.1	641-1067-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C9V1
10.0	641-1068-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C10
11.0	641-1069-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C11
12.0	641-1070-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C12
13.0	641-1071-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C13
15.0	641-1072-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C15


电压 (标准)	Digi-Key 零件编号	剪切带 价格			带卷†		Comchip 零件编号
		1	10	100	数量	价格	
16.0	641-1073-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C16
18.0	641-1074-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C18
20.0	641-1075-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C20
22.0	641-1076-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C22
24.0	641-1077-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C24
27.0	641-1078-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C27
30.0	641-1079-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C30
33.0	641-1080-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C33
36.0	641-1081-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C36
39.0	641-1082-1-ND	.39	2.63	18.20	4,000	70.00/M	CZRF52C39

†将 1-ND 改为 2-ND, 即为带卷包装的零件编号。

## 双向 ESD 瞬态电压抑制器

图	电压	包装	通道 数量	Digi-Key 零件编号	剪切带价格			Digi-Key 零件编号	带卷		Comchip 零件编号
					1	10	100		数量	价格	
1	24	SOT-23	2	641-1197-1-ND	.58	4.60	34.50	641-1197-2-ND	3,000	173.00/M	CEAS0324V-G
	5	SOT-23	2	641-1198-1-ND	.58	4.60	34.50	641-1198-2-ND	3,000	173.00/M	CEAS035V0-G
2	24	SOT23-6	5	641-1199-1-ND	.78	6.21	46.58	641-1199-2-ND	3,000	246.00/M	CECS0624V-G
	5	SOT23-6	5	641-1200-1-ND	.78	6.21	46.58	641-1200-2-ND	3,000	246.00/M	CECS065V0-G
3	24	SOT-143	4	641-1201-1-ND	.78	6.21	46.58	641-1201-2-ND	3,000	246.00/M	CEGS1424V-G
	5	SOT-143	4	641-1202-1-ND	.78	6.21	46.58	641-1202-2-ND	3,000	246.00/M	CEGS145V0-G
	5	SOT-143	1	641-1203-1-ND	2.07	17.25	144.90	641-1203-2-ND	3,000	897.00/M	CLCS145V0-G
4	24	SOT23-6	4	641-1204-1-ND	1.21	10.47	80.50	641-1204-2-ND	3,000	428.00/M	CTDS0624V-G
	5	SOT23-6	4	641-1205-1-ND	1.21	10.47	80.50	641-1205-2-ND	3,000	428.00/M	CTDS065V0-G
5	12	SOT-23	2	641-1206-1-ND	.93	7.45	55.89	641-1206-2-ND	3,000	295.00/M	CTES0312V-G
	5	DO-214AC (SMA)	1	641-1241-1-ND	.42	3.06	21.56	641-1241-2-ND	5,000	83.00/M	TV04A5V0JB-G
	6	DO-214AC (SMA)	1	641-1242-1-ND	.42	3.06	21.56	641-1242-2-ND	5,000	83.00/M	TV04A6V0JB-G
	10	DO-214AC (SMA)	1	641-1233-1-ND	.42	3.06	21.56	641-1233-2-ND	5,000	83.00/M	TV04A100JB-G
	11	DO-214AC (SMA)	1	641-1234-1-ND	.40	2.97	20.90	641-1234-2-ND	5,000	81.00/M	TV04A110JB-G
	12	DO-214AC (SMA)	1	641-1235-1-ND	.40	2.97	20.90	641-1235-2-ND	5,000	81.00/M	TV04A120JB-G
6	22	DO-214AC (SMA)	1	641-1239-1-ND	.40	2.97	20.90	641-1239-2-ND	5,000	81.00/M	TV04A220JB-G
	24	DO-214AC (SMA)	1	641-1240-1-ND	.40	2.97	20.90	641-1240-2-ND	5,000	81.00/M	TV04A240JB-G
	120	DO-214AC (SMA)	1	641-1236-1-ND	.40	2.97	20.90	641-1236-2-ND	5,000	81.00/M	TV04A121JB-G
	130	DO-214AC (SMA)	1	641-1237-1-ND	.40	2.97	20.90	641-1237-2-ND	5,000	81.00/M	TV04A131JB-G
	150	DO-214AC (SMA)	1	641-1238-1-ND	.40	2.97	20.90	641-1238-2-ND	5,000	81.00/M	TV04A151JB-G
6	5	DO-214AA (SMB)	1	641-1252-1-ND	.46	3.50	25.20	641-1252-2-ND	3,000	119.00/M	TV06B5V0JB-G
	6	DO-214AA (SMB)	1	641-1253-1-ND	.46	3.50	25.20	641-1253-2-ND	3,000	119.00/M	TV06B6V0JB-G
	6.5	DO-214AA (SMB)	1	641-1254-1-ND	.46	3.50	25.20	641-1254-2-ND	3,000	119.00/M	TV06B6V5JB-G
	11	DO-214AA (SMB)	1	641-1243-1-ND	.46	3.50	25.20	641-1243-2-ND	3,000	119.00/M	TV06B110JB-G
	12	DO-214AA (SMB)	1	641-1245-1-ND	.46	3.50	25.20	641-1245-2-ND	3,000	119.00/M	TV06B120JB-G
	13	DO-214AA (SMB)	1	641-1247-1-ND	.46	3.50	25.20	641-1247-2-ND	3,000	119.00/M	TV06B130JB-G
	22	DO-214AA (SMB)	1	641-1249-1-ND	.46	3.50	25.20	641-1249-2-ND	3,000	119.00/M	TV06B220JB-G
	24	DO-214AA (SMB)	1	641-1250-1-ND	.46	3.50	25.20	641-1250-2-ND	3,000	119.00/M	TV06B240JB-G
	26	DO-214AA (SMB)	1	641-1251-1-ND	.46	3.50	25.20	641-1251-2-ND	3,000	119.00/M	TV06B260JB-G
	110	DO-214AA (SMB)	1	641-1244-1-ND	.46	3.50	25.20	641-1244-2-ND	3,000	119.00/M	TV06B111JB-G
	120	DO-214AA (SMB)	1	641-1246-1-ND	.46	3.50	25.20	641-1246-2-ND	3,000	119.00/M	TV06B121JB-G
	130	DO-214AA (SMB)	1	641-1248-1-ND	.46	3.50	25.20	641-1248-2-ND	3,000	119.00/M	TV06B131JB-G


ESDTSV-KIT-ND TVS 套件, 28 种型号, 每种 20 件, 共 100 件 .....262.50

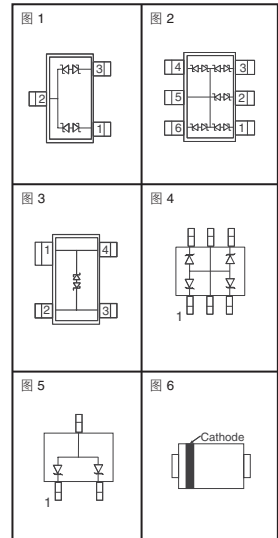

## ESD 抑制器

图	包装	Digi-Key 零件编号	剪切带价格			带卷†		Comchip 零件编号
			1	10	100	数量	价格	
1	SOT23-6	641-1083-1-ND	.68	5.40	40.50	3,000	214.00/M	CDA3S06-G
2	SOT23-6	641-1222-1-ND	1.08	8.64	64.80	3,000	342.00/M	CSRS065V0-G
3	SOT-143	641-1084-1-ND	.68	5.40	40.50	3,000	214.00/M	CDA4S14-G
4	SOT-23	641-1085-1-ND	.65	5.20	39.00	3,000	195.00/M	CDA8S03-G
5	SOT-23	641-1223-1-ND	.81	6.48	48.60	3,000	257.00/M	CTES033V3-G
6	0503 (1308)	641-1218-1-ND	.55	4.23	30.42	5,000	135.00/M	CPDFR5V0
	1005 (2512)	641-1219-1-ND	.42	3.25	23.40	4,000	111.00/M	CPDFR5V0
	0603 (1608)	641-1220-1-ND	.42	3.25	23.40	4,000	111.00/M	CPDUR5V0
	SOD-523F (0603)	641-1088-1-ND	.42	3.25	23.40	4,000	111.00/M	CPDU5V0
	SOD-523F (0603)	641-1089-1-ND	.42	3.25	23.40	4,000	111.00/M	CPDU24V
7	14-SOIC	641-1090-1-ND	.98	8.45	65.00	2,500	346.00/M	CTAN1424V-G
8	SOT23-6	641-1086-1-ND	.50	4.00	30.00	3,000	150.00/M	CEBS065V0-G
8	SOT23-6	641-1087-1-ND	.50	4.00	30.00	3,000	150.00/M	CEBS0624V-G
9	24-QSOP	641-1195-1-ND	3.00	25.00	210.00	2,500	1280.00/M	CDA5Q24-G
10	8-SOIC	641-1196-1-ND	2.25	18.75	157.50	2,500	975.00/M	CDA6N08-G
11	8-SOIC	641-1221-1-ND	2.40	20.00	168.00	2,500	1040.00/M	CSRN085V0-G


†将 1-ND 改为 2-ND, 即为带卷包装的零件编号。

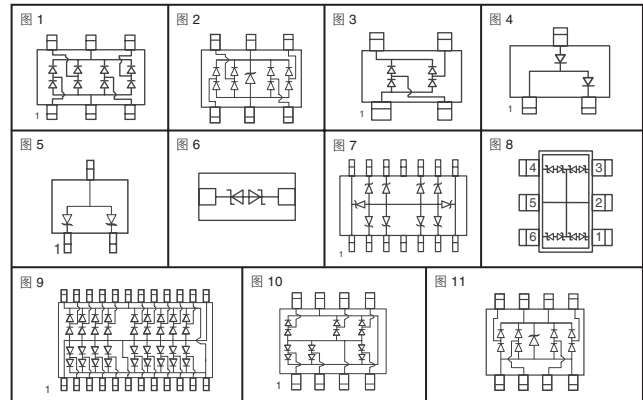

## CREE SIC 肖特基二极管



图	包装	VRRM (V)	IF(AV) (A)	Ptot (W)	Digi-Key 零件编号	单价			
						1	50	100	
1	TO-220-2	300	10	79	CSD10030A-ND	7.45	7.12	6.78	
		600	1	21.4	CSD01060A-ND	.93	.89	.85	
		600	2	31.9	CSD02060A-ND	1.87	1.79	1.70	
		600	4	62.5	CSD04060A-ND	3.73	3.56	3.39	
		600	6	83.3	CSD06060A-ND	5.59	5.34	5.08	
		600	8	107	CSD08060A-ND	7.46	7.12	6.78	
	TO-252-2 (DPAK)	600	10	136.3	CSD10060A-ND	9.32	8.89	8.47	
		1,200	6	136	C2D05120A-ND	9.32	8.89	8.47	
		1,200	10	312	C2D10120A-ND	16.58	15.84	15.08	
		TO-263-2 (D2PAK)	600	1	21.4	CSD01060E-ND	.93	.89	.85
			600	4	62.5	CSD04060E-ND	3.73	3.56	3.39
			600	2	31.9	CSD02060G-ND	1.87	1.79	1.70
2	TO-247	300	20	79	CSD20030D-ND	14.91	14.23	13.55	
		600	20	138	CSD20060D-ND	18.63	17.79	16.94	
		1,200	20	138	C2D10120D-ND	18.63	17.79	16.94	
	TO-220-2	300	20	79	CSD20030D-ND	14.91	14.23	13.55	
		600	20	138	CSD20060D-ND	18.63	17.79	16.94	
		1,200	20	312	C2D20120D-ND	37.27	35.57	33.88	

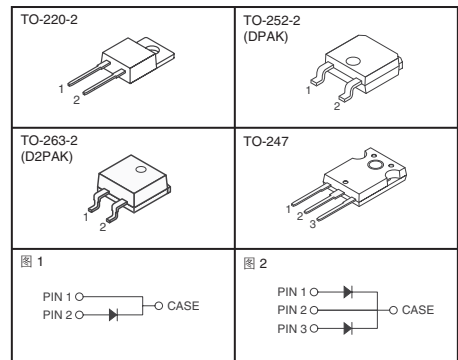

全部产品均以美元计价。 免费电话: 10800-1527031 (China Telecom - 中国电讯) — 10800-8527031 (CNCG - 中国网通)