


尺寸 (mm)

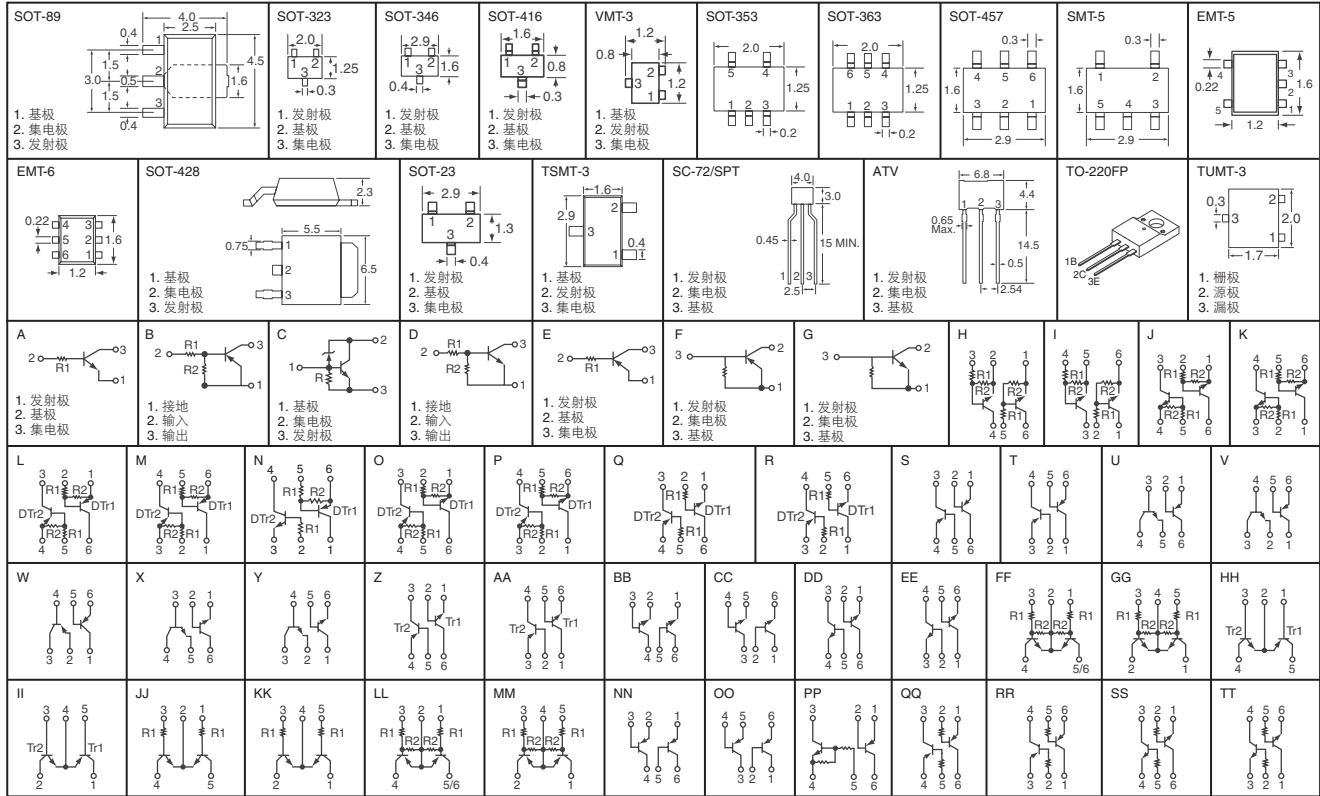

数字晶体管

包装	电路	V _{CEO} (V)	I _O (mA)	增益 (HFE)	R ₁ (kΩ)	Ω 电阻比 R ₂ /R ₁	Digi-Key 零件编号	剪切带价格			Digi-Key 零件编号	带卷		Rohm 零件编号
								1	25	100		数量	价格	
NPN														
SOT-89	C	60	1A	300	13	—	DTDG14GPT100CT-ND	.47	9.00	25.92	DTDG14GPT100TR-ND	1,000	130.00	DTDG14GPT100
	C	60	1A	300	2.86	13	DTDG23YPT100CT-ND	.55	10.50	30.24	DTDG23YPT100TR-ND	1,000	151.00	DTDG23YPT100
	D	50	100	33	1.3	12	DTC113ZUAT106CT-ND	.49	7.25	18.85	DTC113ZUAT106TR-ND	3,000	68.00/M	DTC113ZUAT106
	D	50	500	82	1.3	12	DTD113ZUT106CT-ND	.55	10.50	30.24	DTD113ZUT106TR-ND	3,000	143.00/M	DTD113ZUT106
	D	50	100	30	1.3	1.2	DTC114EUAT106CT-ND	.43	6.25	16.25	DTC114EUAT106TR-ND	3,000	59.00/M	DTC114EUAT106
	D	50	100	30	1.3	—	DTC114GUAT106CT-ND	.34	5.81	16.12	DTC114GUAT106TR-ND	3,000	62.00/M	DTC114GUAT106
	A	50	100	100	13	—	DTC114TUAT106CT-ND	.36	5.25	13.65	DTC114TUAT106TR-ND	3,000	49.00/M	DTC114TUAT106
	D	50	100	24	13	0.57	DTC114WUAT106CT-ND	.43	7.31	20.28	DTC114WUAT106TR-ND	3,000	78.00/M	DTC114WUAT106
	D	50	100	68	13	5.7	DTC114YUAT106CT-ND	.43	6.25	16.25	DTC114YUAT106TR-ND	3,000	59.00/M	DTC114YUAT106
	D	50	20	82	100	1.2	DTC115EUAT106CT-ND	.43	6.25	16.25	DTC115EUAT106TR-ND	3,000	59.00/M	DTC115EUAT106
	D	50	100	20	2.86	1.2	DTC123EUAT106CT-ND	.43	7.31	20.28	DTC123EUAT106TR-ND	3,000	78.00/M	DTC123EUAT106
	D	50	100	80	2.86	2.6	DTC123JUAT106CT-ND	.43	6.25	16.25	DTC123JUAT106TR-ND	3,000	59.00/M	DTC123JUAT106
SOT-323	D	50	100	33	2.86	5.5	DTC123YUAT106CT-ND	.43	7.31	20.28	DTC123YUAT106TR-ND	3,000	78.00/M	DTC123YUAT106
	D	50	30	56	28.6	1.2	DTC124EUAT106CT-ND	.43	6.25	16.25	DTC124EUAT106TR-ND	3,000	59.00/M	DTC124EUAT106
	D	50	50	68	28.6	2.6	DTC124XUAT106CT-ND	.43	7.31	20.28	DTC124XUAT106TR-ND	3,000	78.00/M	DTC124XUAT106
	D	50	100	20	6.11	1.2	DTC143EUAT106CT-ND	.37	5.50	14.30	DTC143EUAT106TR-ND	3,000	52.00/M	DTC143EUAT106
	D	50	100	30	6.11	2.6	DTC143XUAT106CT-ND	.43	6.25	16.25	DTC143XUAT106TR-ND	3,000	59.00/M	DTC143XUAT106
	D	50	100	80	6.11	1.2	DTC143ZUAT106CT-ND	.43	6.25	16.25	DTC143ZUAT106TR-ND	3,000	59.00/M	DTC143ZUAT106
	D	50	100	68	6.11	1.2	DTC144EUAT106CT-ND	.43	6.25	16.25	DTC144EUAT106TR-ND	3,000	59.00/M	DTC144EUAT106
	D	50	100	68	6.11	—	DTC144GUAT106CT-ND	.43	7.31	20.28	DTC144GUAT106TR-ND	3,000	78.00/M	DTC144GUAT106
	A	50	100	100	6.11	—	DTC144TUAT106CT-ND	.43	7.31	20.28	DTC144TUAT106TR-ND	3,000	78.00/M	DTC144TUAT106
	D	50	30	56	6.11	0.57	DTC144WUAT106CT-ND	.43	6.25	16.25	DTC144WUAT106TR-ND	3,000	59.00/M	DTC144WUAT106
	A	15	600	100	13	—	DTC314TUT106CT-ND	.55	10.50	30.24	DTC314TUT106TR-ND	3,000	143.00/M	DTC314TUT106
	A	15	600	100	2.86	—	DTC323TUT106CT-ND	.55	10.50	30.24	DTC323TUT106TR-ND	3,000	143.00/M	DTC323TUT106
SOT-346	D	50	500	33	1.3	1.2	DTD113ZKT146CT-ND	.42	7.66	21.56	DTD113ZKT146TR-ND	3,000	88.00/M	DTD113ZKT146
	D	50	100	33	1.3	1.2	DTC113ZKT146CT-ND	.36	5.25	13.65	DTC113ZKT146TR-ND	3,000	49.00/M	DTC113ZKT146
	D	50	500	56	1.3	1.2	DTD113ZKT146CT-ND	.46	7.88	21.84	DTD113ZKT146TR-ND	3,000	84.00/M	DTD113ZKT146
	D	50	100	30	1.3	1.2	DTC114EKT146CT-ND	.34	5.00	13.00	DTC114EKT146TR-ND	3,000	47.00/M	DTC114EKT146
	D	50	500	56	1.3	1.2	DTD114EKT146CT-ND	.40	7.63	21.96	DTD114EKT146TR-ND	3,000	104.00/M	DTD114EKT146
	D	50	100	30	1.3	—	DTC114GKT146CT-ND	.34	5.81	16.12	DTC114GKT146TR-ND	3,000	62.00/M	DTC114GKT146
	G	50	500	56	1.3	—	DTD114GKT146CT-ND	.50	9.63	27.72	DTD114GKT146TR-ND	3,000	131.00/M	DTD114GKT146
	A	50	100	600	13	—	DTC114TKAT146CT-ND	.31	4.50	11.70	DTC114TKAT146TR-ND	3,000	42.00/M	DTC114TKAT146
	D	50	100	24	13	0.57	DTC114WKAT146CT-ND	.39	6.56	18.20	DTC114WKAT146TR-ND	3,000	70.00/M	DTC114WKAT146
	D	50	100	68	13	5.7	DTC114YKAT146CT-ND	.36	5.25	13.65	DTC114YKAT146TR-ND	3,000	49.00/M	DTC114YKAT146
	D	50	100	82	130	1.2	DTC115EKT146CT-ND	.36	5.25	13.65	DTC115EKT146TR-ND	3,000	49.00/M	DTC115EKT146
	D	50	100	20	2.86	1.2	DTC123EKT146CT-ND	.40	5.25	13.65	DTC123EKT146TR-ND	3,000	49.00/M	DTC123EKT146
D	50	500	39	2.86	1.2	DTD123EKT146CT-ND	.46	7.63	21.96	DTD123EKT146TR-ND	3,000	104.00/M	DTD123EKT146	
D	50	100	80	2.86	2.6	DTC123JKT146CT-ND	.34	5.00	13.00	DTC123JKT146TR-ND	3,000	47.00/M	DTC123JKT146	
A	50	500	100	2.86	—	DTD123TKT146CT-ND	.50	9.63	27.72	DTD123TKT146TR-ND	3,000	131.00/M	DTD123TKT146	
D	50	100	33	2.86	5.5	DTC123YKAT146CT-ND	.36	5.25	13.65	DTC123YKAT146TR-ND	3,000	49.00/M	DTC123YKAT146	
D	50	500	56	2.86	5.5	DTD123YKAT146CT-ND	.40	7.63	21.96	DTD123YKAT146TR-ND	3,000	104.00/M	DTD123YKAT146	
D	50	100	56	28.6	1.2	DTC124EKT146CT-ND	.36	5.25	13.65	DTC124EKT146TR-ND	3,000	49.00/M	DTC124EKT146	
A	50	100	100	28.6	—	DTC124TKAT146CT-ND	.36	5.25	13.65	DTC124TKAT146TR-ND	3,000	49.00/M	DTC124TKAT146	
D	50	100	68	28.6	2.6	DTC124XKAT146CT-ND	.36	5.25	13.65	DTC124XKAT146TR-ND	3,000	49.00/M	DTC124XKAT146	
D	50	100	20	6.11	1.2	DTC143EKT146CT-ND	.34	5.00	13.00	DTC143EKT146TR-ND	3,000	47.00/M	DTC143EKT146	
D	50	500	47	6.11	1.2	DTD143EKT146CT-ND	.50	9.63	27.72	DTD143EKT146TR-ND	3,000	131.00/M	DTD143EKT146	
D	50	100	30	6.11	2.6	DTC143XKAT146CT-ND	.36	5.25	13.65	DTC143XKAT146TR-ND	3,000	49.00/M	DTC143XKAT146	
D	50	100	80	6.11	12	DTC143ZKAT146CT-ND	.36	5.25	13.65	DTC143ZKAT146TR-ND	3,000	49.00/M	DTC143ZKAT146	

(续下页)

Digi-Reel® Digi-Reel® 上含有大多数 SMT 消减零件。将 1-ND 改为 6-ND, 或将 CT-ND 改为 DKR-ND, 即为 Digi-Reel 零件编号。请参见第 2 页上的 Digi-Key® 服务以获得更多信息。

全部产品均以美元计价。 免费电话: 10800-1527031 (China Telecom - 中国电讯) — 10800-8527031 (CNCG - 中国网通)

包装	电路	V _{CEO} (V)	I _O (mA)	增益 (HFE)	R ₁ (kΩ)	Ω 电阻比 R2/R1	Digi-Key 零件编号	剪切带价格			Digi-Key 零件编号	带卷		Rohm 零件编号
								1	25	100		数量	价格	
SOT-346	D	50	100	68	61.1	1.2	DTC144EKAT146CT-ND	.36	5.25	13.65	DTC144EKAT146TR-ND	3,000	49.00/M	DTC144EKAT146
	D	50	100	68	61.1	—	DTC144GKAT146CT-ND	.39	6.56	18.20	DTC144GKAT146TR-ND	3,000	70.00/M	DTC144GKAT146
	A	50	100	100	61.1	—	DTC144TKAT146CT-ND	.36	5.25	13.65	DTC144TKAT146TR-ND	3,000	49.00/M	DTC144TKAT146
	D	50	30	33	61.1	0.26	DTC144VKAT146CT-ND	.39	6.56	18.20	DTC144VKAT146TR-ND	3,000	70.00/M	DTC144VKAT146
	D	50	100	56	61.1	0.57	DTC144WKAT146CT-ND	.39	6.56	18.20	DTC144WKAT146TR-ND	3,000	70.00/M	DTC144WKAT146
	A	50	600	100	13	—	DTC314TKT146CT-ND	.40	7.63	21.96	DTC314TKT146TR-ND	3,000	104.00/M	DTC314TKT146
	A	15	600	600	2.86	—	DTC323TKT146CT-ND	.47	8.06	22.36	DTC323TKT146TR-ND	3,000	86.00/M	DTC323TKT146
	A	15	600	100	6.11	—	DTC343TKT146CT-ND	.50	9.63	27.72	DTC343TKT146TR-ND	3,000	131.00/M	DTC343TKT146
	D	50	50	30	13	1.2	DTC114EETLCT-ND	.36	5.25	13.65	DTC114EETLTR-ND	3,000	49.00/M	DTC114EETL
	A	50	100	100	13	—	DTC114TETLCT-ND	.37	5.50	14.30	DTC114TETLTR-ND	3,000	52.00/M	DTC114TETL
D	50	100	24	13	0.57	DTC114WETLCT-ND	.47	8.06	22.36	DTC114WETLTR-ND	3,000	86.00/M	DTC114WETL	
D	50	70	68	13	5.7	DTC114YETLCT-ND	.43	6.25	16.25	DTC114YETLTR-ND	3,000	59.00/M	DTC114YETL	
D	50	20	82	130	1.2	DTC115EETLCT-ND	.43	6.25	16.25	DTC115EETLTR-ND	3,000	59.00/M	DTC115EETL	
SOT-416	D	50	100	20	2.86	1.2	DTC123EETLCT-ND	.43	6.25	16.25	DTC123EETLTR-ND	3,000	59.00/M	DTC123EETL
	D	50	100	80	2.86	2.6	DTC123JETLCT-ND	.43	6.25	16.25	DTC123JETLTR-ND	3,000	59.00/M	DTC123JETL
	D	50	100	33	2.86	5.5	DTC123YETLCT-ND	.47	8.06	22.36	DTC123YETLTR-ND	3,000	86.00/M	DTC123YETL
	D	50	100	56	28.6	1.2	DTC124EETLCT-ND	.43	6.25	16.25	DTC124EETLTR-ND	3,000	59.00/M	DTC124EETL
	A	50	100	100	28.6	—	DTC124TETLCT-ND	.47	8.06	22.36	DTC124TETLTR-ND	3,000	86.00/M	DTC124TETL
	D	50	50	68	28.6	2.6	DTC124XETLCT-ND	.43	6.25	16.25	DTC124XETLTR-ND	3,000	59.00/M	DTC124XETL
	D	50	100	30	6.11	1.2	DTC143EETLCT-ND	.43	6.25	16.25	DTC143EETLTR-ND	3,000	59.00/M	DTC143EETL
	D	50	100	80	6.11	2.6	DTC143XETLCT-ND	.43	6.25	16.25	DTC143XETLTR-ND	3,000	59.00/M	DTC143XETL
	D	50	100	68	61.1	1.2	DTC144EETLCT-ND	.43	6.25	16.25	DTC144EETLTR-ND	3,000	59.00/M	DTC144EETL
	A	50	100	100	61.1	—	DTC144TETLCT-ND	.43	6.25	16.25	DTC144TETLTR-ND	3,000	59.00/M	DTC144TETL
D	50	30	56	61.1	0.57	DTC144WETLCT-ND	.47	8.06	22.36	DTC144WETLTR-ND	3,000	86.00/M	DTC144WETL	
VMT-3	A	50	50	30	13	1.2	DTC114EMT2LCT-ND	.37	6.38	17.68	DTC114EMT2LTR-ND	8,000	61.00/M	DTC114EMT2L
	A	50	100	100	13	—	DTC114TM2LCT-ND	.37	6.38	17.68	DTC114TM2LTR-ND	8,000	61.00/M	DTC114TM2L
	D	50	70	68	13	5.7	DTC114YM2LCT-ND	.43	7.31	20.28	DTC114YM2LTR-ND	8,000	70.00/M	DTC114YM2L
	D	50	20	82	130	1.2	DTC115EMT2LCT-ND	.43	7.31	20.28	DTC115EMT2LTR-ND	8,000	70.00/M	DTC115EMT2L
	D	50	100	20	2.86	1.2	DTC123EMT2LCT-ND	.43	7.31	20.28	DTC123EMT2LTR-ND	8,000	70.00/M	DTC123EMT2L
	D	50	100	80	2.86	2.6	DTC123JMT2LCT-ND	.44	6.50	16.90	DTC123JMT2LTR-ND	8,000	52.00/M	DTC123JMT2L
	D	50	30	56	28.6	1.2	DTC124EMT2LCT-ND	.37	6.38	17.68	DTC124EMT2LTR-ND	8,000	61.00/M	DTC124EMT2L
	D	50	50	68	28.6	2.6	DTC124XMT2LCT-ND	.39	6.56	18.20	DTC124XMT2LTR-ND	8,000	63.00/M	DTC124XMT2L
	D	50	100	30	6.11	1.2	DTC143EMT2LCT-ND	.49	7.25	18.85	DTC143EMT2LTR-ND	8,000	58.00/M	DTC143EMT2L
	D	50	100	30	6.11	2.6	DTC143XMT2LCT-ND	.34	5.00	13.00	DTC143XMT2LTR-ND	8,000	40.00/M	DTC143XMT2L
D	50	100	80	6.11	1.2	DTC143ZMT2LCT-ND	.94	20.31	62.50	DTC143ZMT2LTR-ND	8,000	319.00/M	DTC143ZMT2L	
D	50	30	68	61.1	1.2	DTC144EMT2LCT-ND	.37	6.38	17.68	DTC144EMT2LTR-ND	8,000	61.00/M	DTC144EMT2L	
PNP														
SOT-323	B	50	50	30	13	1.2	DTA114EUAT106CT-ND	.36	5.25	13.65	DTA114EUAT106TR-ND	3,000	49.00/M	DTA114EUAT106
	B	50	100	33	1.3	1.2	DTA113ZUAT106CT-ND	.49	7.25	18.85	DTA113ZUAT106TR-ND	3,000	68.00/M	DTA113ZUAT106
	F	50	100	30	13	—	DTA114GUAT106CT-ND	.26	3.75	9.75	DTA114GUAT106TR-ND	3,000	35.00/M	DTA114GUAT106
	E	50	100	100	13	—	DTA114TUAT106CT-ND	.43	6.25	16.25	DTA114TUAT106TR-ND	3,000	59.00/M	DTA114TUAT106
	B	50	100	24	13	0.57	DTA114WUAT106CT-ND	.43	7.31	20.28	DTA114WUAT106TR-ND	3,000	78.00/M	DTA114WUAT106
	B	50	70	68	13	5.7	DTA114YUAT106CT-ND	.37	5.50	14.30	DTA114YUAT106TR-ND	3,000	52.00/M	DTA114YUAT106
	B	50	20	82	130	1.2	DTA115EUAT106CT-ND	.43	7.31	20.28	DTA115EUAT106TR-ND	3,000	78.00/M	DTA115EUAT106
	B	50	100	20	2.86	1.2	DTA123EUAT106CT-ND	.43	6.25	16.25	DTA123EUAT106TR-ND	3,000	59.00/M	DTA123EUAT106
	B	50	100	80	2.86	2.6	DTA123JUAT106CT-ND	.43	6.25	16.25	DTA123JUAT106TR-ND	3,000	59.00/M	DTA123JUAT106
	B	50	100	33	2.86	5.5	DTA123YUAT106CT-ND	.43	6.25	16.25	DTA123YUAT106TR-ND	3,000	59.00/M	DTA123YUAT106
B	50	30	56	28.6	1.2	DTA124EUAT106CT-ND	.43	6.25	16.25	DTA124EUAT106TR-ND	3,000	59.00/M	DTA124EUAT106	
B	50	50	68	28.6	2.6	DTA124XUAT106CT-ND	.43	7.31	20.28	DTA124XUAT106TR-ND	3,000	78.00/M	DTA124XUAT106	
B	50	100	30	6.11	1.2	DTA143EUAT106CT-ND	.43	6.25	16.25	DTA143EUAT106TR-ND	3,000	59.00/M	DTA143EUAT106	
E	50	100	100	6.11	—	DTA143TUAT106CT-ND	.43	6.25	16.25	DTA143TUAT106TR-ND	3,000	59.00/M	DTA143TUAT106	
A	50	100	100	6.11	—	DTA143YUAT106CT-ND	.43	6.25	16.25	DTA143YUAT106TR-ND	3,000	59.00/M	DTA143YUAT106	
B	50	100	30	6.11	2.6	DTA143XUAT106CT-ND	.43	6.25	16.25	DTA143XUAT106TR-ND	3,000	59.00/M	DTA143XUAT106	
B	50	100	80	6.11	1.2	DTA143ZUAT106CT-ND	.43	6.25	16.25	DTA143ZUAT106TR-ND	3,000	59.00/M	DTA143ZUAT106	
B	50	30	68	61.1	1.2	DTA144EUAT106CT-ND	.43	6.25	16.25	DTA144EUAT106TR-ND	3,000	59.00/M	DTA144EUAT106	
F	50	100	68	61.1	—	DTA144GUAT106CT-ND	.43	7.31	20.28	DTA144GUAT106TR-ND	3,000	78.00/M	DTA144GUAT106	
E	50	100	100	61.1	—	DTA144TUAT106CT-ND	.43	6.25	16.25	DTA144TUAT106TR-ND	3,000	59.00/M	DTA144TUAT106	
B	50	30	56	61.1	0.57	DTA144WUAT106CT-ND	.43	7.31	20.28	DTA144WUAT106TR-ND	3,000	78.00/M	DTA144WUAT106	
SOT-346	B	50	500	33	1.3	1.2	DTB113EKT146CT-ND	.42	7.66	21.56	DTB113EKT146TR-ND	3,000	88.00/M	DTB113EKT146
	B	50	500	56	1.3	1.2	DTB113ZKT146CT-ND	.42	7.66	21.56	DTB113ZKT146TR-ND	3,000	88.00/M	DTB113ZKT146
	B	50	100	33	1.3	1.2	DTA113ZKAT146CT-ND	.36	5.25	13.65	DTA113ZKAT146TR-ND	3,000	49.00/M	DTA113ZKAT146
	B	50	50	30	13	1.2	DTA114EKAT146CT-ND	.29	4.25	11.05	DTA114EKAT146TR-ND	3,000	40.00/M	DTA114EKAT146
	B	50	500	56	13	1.2	DTB114EKT146CT-ND	.40	7.63	21.96	DTB114EKT146TR-ND	3,000	104.00/M	DTB114EKT146
	F	50	500	56	13	—	DTB114GKT146CT-ND	.50	9.63	27.72	DTB114GKT146TR-ND	3,000	131.00/M	DTB114GKT146
	F	50	100	30	13	—	DTA114GKAT146CT-ND	.43	7.31	20.28	DTA114GKAT146TR-ND	3,000	78.00/M	DTA114GKAT146
	E	50	100	600	13	—	DTA114TKAT146CT-ND	.36	5.25	13.65	DTA114TKAT146TR-ND	3,000	49.00/M	DTA114TKAT146
	B	50	100	24	13	0.57	DTA114WKAT146CT-ND	.39	6.56	18.20	DTA114WKAT146TR-ND	3,000	70.00/M	DTA114WKAT146
	B	50	100	68	13	5.7	DTA114YKAT146CT-ND	.36	5.25	13.65	DTA114YKAT146TR-ND	3,000	49.00/M	DTA114YKAT146
SOT-416	B	50	20	82	130	1.2	DTA115EKAT146CT-ND	.39	6.56	18.20	DTA115EKAT146TR-ND	3,000	70.00/M	DTA115EKAT146
	B	50	100	20	2.86	1.2	DTA123EKAT146CT-ND	.36	5.25	13.65	DTA123EKAT146TR-ND	3,000	49.00/M	DTA123EKAT146
	B	50	500	39	2.86	1.2	DTB123EKT146CT-ND	.40	7.63	21.96	DTB123EKT146TR-ND	3,000	104.00/M	DTB123EKT146
	B	50	100	80	2.86	2.6	DTA123JKAT146CT-ND	.36	5.25	13.65	DTA123JKAT146TR-ND	3,000	49.00/M	DTA123JKAT146
	E	40	500	600	2.86	—	DTB123TKT146CT-ND	.41	7.50	21.12	DTB123TKT146TR-ND	3,000	86.00/M	DTB123TKT146
	B	50	100	33	2.86	5.5	DTA123YKAT146CT-ND	.36	5.25	13.65	DTA123YKAT146TR-ND	3,000	49.00/M	DTA123YKAT146
	B	50	500	56	2.86	5.5	DTB123YKT146CT-ND	.40	7.63	21.96	DTB123YKT146TR-ND	3,000	104.00/M	DTB123YKT146
	B	50	100	56	28.6	1.2	DTA124EKAT146CT-ND	.36	5.25	13.65	DTA124EKAT146TR-ND			

包装	电路	V _{CEO} (V)	I _C (mA)	增益 (HFE)	R1 (kΩ)	Ω 电阻比 R2/R1	Digi-Key 零件编号	剪切带价格			Digi-Key 零件编号	带卷		Rohm 零件编号
								1	25	100		数量	价格	
SOT-416	A	50	100	100	6.11	—	DTC143TETLCT-ND	.43	6.25	16.25	DTC143TETLCT-ND	3,000	59.00/M	DTC143TETL
	B	50	100	30	6.11	2.6	DTA143XETLCT-ND	.43	6.25	16.25	DTA143XETLCT-ND	3,000	59.00/M	DTA143XETL
	B	50	100	80	6.11	12	DTA143ZETLCT-ND	.43	6.25	16.25	DTA143ZETLCT-ND	3,000	59.00/M	DTA143ZETL
	B	50	30	68	6.11	1.2	DTA144EETLCT-ND	.43	6.25	16.25	DTA144EETLCT-ND	3,000	59.00/M	DTA144EETL
	E	50	100	100	6.11	—	DTA144TETLCT-ND	.43	6.25	16.25	DTA144TETLCT-ND	3,000	59.00/M	DTA144TETL
	B	50	30	56	6.11	0.57	DTA144WETLCT-ND	.47	8.06	22.36	DTA144WETLCT-ND	3,000	86.00/M	DTA144WETL
VMT-3	B	50	70	68	13	5.7	DTA114YMT2LCT-ND	.43	7.31	20.28	DTA114YMT2LCT-ND	8,000	70.00/M	DTA114YMT2L
	B	50	50	30	13	1.2	DTA114EMT2LCT-ND	.43	6.25	16.25	DTA114EMT2LCT-ND	8,000	50.00/M	DTA114EMT2L
	E	50	100	100	13	—	DTA114TMT2LCT-ND	.43	6.25	16.25	DTA114TMT2LCT-ND	8,000	50.00/M	DTA114TMT2L
	B	50	20	82	130	1.2	DTA115EMT2LCT-ND	.34	5.00	13.00	DTA115EMT2LCT-ND	8,000	40.00/M	DTA115EMT2L
	B	50	100	20	2.86	1.2	DTA123EMT2LCT-ND	.34	5.00	13.00	DTA123EMT2LCT-ND	8,000	40.00/M	DTA123EMT2L
	B	50	100	80	2.86	2.6	DTA123JMT2LCT-ND	.46	6.75	17.55	DTA123JMT2LCT-ND	8,000	54.00/M	DTA123JMT2L
	B	50	30	56	28.6	1.2	DTA124EMT2LCT-ND	.43	6.25	16.25	DTA124EMT2LCT-ND	8,000	50.00/M	DTA124EMT2L
	B	50	50	68	28.6	2.6	DTA124XMT2LCT-ND	.43	6.25	16.25	DTA124XMT2LCT-ND	8,000	50.00/M	DTA124XMT2L
	B	50	100	30	6.11	1.2	DTA143EMT2LCT-ND	.43	6.25	16.25	DTA143EMT2LCT-ND	8,000	50.00/M	DTA143EMT2L
	E	50	100	100	6.11	—	DTA143TMT2LCT-ND	.43	6.25	16.25	DTA143TMT2LCT-ND	8,000	50.00/M	DTA143TMT2L
	A	50	100	100	6.11	—	DTC143TMT2LCT-ND	.37	6.38	17.68	DTC143TMT2LCT-ND	8,000	61.00/M	DTC143TMT2L
	B	50	100	30	6.11	2.6	DTA143XMT2LCT-ND	.34	5.00	13.00	DTA143XMT2LCT-ND	8,000	40.00/M	DTA143XMT2L
B	50	30	68	6.11	1.2	DTA144EMT2LCT-ND	.43	6.25	16.25	DTA144EMT2LCT-ND	8,000	50.00/M	DTA144EMT2L	
SC-72/SPT	D	50	30	68	32.9	0.8	DTC144ESATPCT-ND	.43	7.31	20.28	DTC144ESATPCT-ND	5,000	70.00/M	DTC144ESATP

数字双晶体管

包装	电路	V _{CEO} (V)	I _C (mA)	增益 (HFE)	R1 (kΩ)	Ω 电阻比 R2/R1	Digi-Key 零件编号	剪切带价格			Digi-Key 零件编号	带卷		Rohm 零件编号	
								1	25	100		数量	价格		
NPN															
SOT-353	FF	50	30	56	28.6	1.2	UMG1NCT-ND	.38	7.03	19.80	UMG1NTR-ND	3,000	81.00/M	UMG1NTR	
	FF	50	30	68	61.1	1.2	UMG2NCT-ND	.38	7.03	19.80	UMG2NTR-ND	3,000	81.00/M	UMG2NTR	
	JJ	50	100	600	13	—	UMG4NCT-ND	.38	7.03	19.80	UMG4NTR-ND	3,000	81.00/M	UMG4NTR	
	FF	50	100	68	13	5.7	UMG5NCT-ND	.38	7.03	19.80	UMG5NTR-ND	3,000	81.00/M	UMG5NTR	
	FF	50	100	80	6.11	12	UMG8NCT-ND	.38	7.03	19.80	UMG8NTR-ND	3,000	81.00/M	UMG8NTR	
	FF	50	50	30	13	1.2	UMG9NCT-ND	.38	7.03	19.80	UMG9NTR-ND	3,000	81.00/M	UMG9NTR	
SOT-363	FF	50	100	80	2.2	26	UMG11NCT-ND	.38	7.03	19.80	UMG11NTR-ND	3,000	81.00/M	UMG11NTR	
	J	50	30	56	28.6	1.2	UMH1NCT-ND	.38	7.03	19.80	UMH1NTR-ND	3,000	81.00/M	UMH1NTR	
	J	50	30	68	61.1	1.2	UMH2NCT-ND	.38	7.03	19.80	UMH2NTR-ND	3,000	81.00/M	UMH2NTR	
	DD	50	100	600	6.11	—	UMH3NCT-ND	.38	7.03	19.80	UMH3NTR-ND	3,000	81.00/M	UMH3NTR	
	SS	50	100	600	13	—	UMH4NCT-ND	.38	7.03	19.80	UMH4NTR-ND	3,000	81.00/M	UMH4NTR	
	H	50	30	68	61.1	1.2	UMH6NCT-ND	.38	7.03	19.80	UMH6NTR-ND	3,000	81.00/M	UMH6NTR	
	J	50	70	68	13	5.7	UMH9NCT-ND	.38	7.03	19.80	UMH9NTR-ND	3,000	81.00/M	UMH9NTR	
	J	50	100	80	2.86	2.6	UMH10NCT-ND	.38	7.03	19.80	UMH10NTR-ND	3,000	81.00/M	UMH10NTR	
	J	50	50	30	13	1.2	UMH11NCT-ND	.38	7.03	19.80	UMH11NTR-ND	3,000	81.00/M	UMH11NTR	
	BB	50	100	100	6.11	—	UMH14NCT-ND	.52	10.00	28.80	UMH14NTR-ND	3,000	136.00/M	UMH14NTR	
	SOT-457	K	50	30	56	28.6	1.2	IMH1AT110CT-ND	.41	7.88	22.68	IMH1AT110TR-ND	3,000	107.00/M	IMH1AT110
		K	50	30	68	61.1	1.2	IMH2AT110CT-ND	.49	7.25	18.85	IMH2AT110TR-ND	3,000	68.00/M	IMH2AT110
EE		50	100	600	6.11	—	IMH3AT110CT-ND	.46	8.44	23.76	IMH3AT110TR-ND	3,000	97.00/M	IMH3AT110	
TT		50	100	600	13	—	IMH4AT110CT-ND	.46	8.44	23.76	IMH4AT110TR-ND	3,000	97.00/M	IMH4AT110	
I		50	30	68	61.1	1.2	IMH6AT108CT-ND	.53	10.13	29.16	IMH6AT108TR-ND	3,000	138.00/M	IMH6AT108	
K		50	70	68	13	5.7	IMH9AT110CT-ND	.46	8.44	23.76	IMH9AT110TR-ND	3,000	97.00/M	IMH9AT110	
K		50	100	80	2.86	2.6	IMH10AT110CT-ND	.40	6.75	18.72	IMH10AT110TR-ND	3,000	72.00/M	IMH10AT110	
K		50	50	30	13	1.2	IMH11AT110CT-ND	.49	7.25	18.85	IMH11AT110TR-ND	3,000	68.00/M	IMH11AT110	
CC		50	100	100	6.11	—	IMH14AT108CT-ND	.55	10.50	30.24	IMH14AT108TR-ND	3,000	143.00/M	IMH14AT108	
SMT-5		GG	50	30	56	28.6	1.2	FMG1AT148CT-ND	.46	8.88	25.56	FMG1AT148TR-ND	3,000	121.00/M	FMG1AT148
		GG	50	30	68	61.1	1.2	FMG2AT148CT-ND	.42	8.13	23.40	FMG2AT148TR-ND	3,000	111.00/M	FMG2AT148
		KK	50	100	600	13	—	FMG4AT148CT-ND	.46	8.88	25.56	FMG4AT148TR-ND	3,000	121.00/M	FMG4AT148
	GG	50	100	68	13	5.7	FMG5AT148CT-ND	.46	8.88	25.56	FMG5AT148TR-ND	3,000	121.00/M	FMG5AT148	
	GG	50	100	80	6.11	12	FMG8AT148CT-ND	.37	6.38	17.68	FMG8AT148TR-ND	3,000	68.00/M	FMG8AT148	
	GG	50	50	30	13	1.2	FMG9AT148CT-ND	.46	8.88	25.56	FMG9AT148TR-ND	3,000	121.00/M	FMG9AT148	
EMT-5	GG	50	100	80	2.2	26	FMG11AT148CT-ND	.48	8.75	24.64	FMG11AT148TR-ND	3,000	101.00/M	FMG11AT148	
	FF	50	30	56	28.6	1.2	EMG1T2RCT-ND	.46	8.44	23.76	EMG1T2RTR-ND	8,000	92.00/M	EMG1T2R	
	FF	50	30	68	61.1	1.2	EMG2T2RCT-ND	.46	8.44	23.76	EMG2T2RTR-ND	8,000	92.00/M	EMG2T2R	
	JJ	50	100	100	13	—	EMG4T2RCT-ND	.46	8.44	23.76	EMG4T2RTR-ND	8,000	92.00/M	EMG4T2R	
	FF	50	70	68	13	5.7	EMG5T2RCT-ND	.46	8.44	23.76	EMG5T2RTR-ND	8,000	92.00/M	EMG5T2R	
	FF	50	100	80	6.11	12	EMG8T2RCT-ND	.46	8.44	23.76	EMG8T2RTR-ND	8,000	92.00/M	EMG8T2R	
EMT-6	FF	50	50	30	13	1.2	EMG9T2RCT-ND	.46	8.44	23.76	EMG9T2RTR-ND	8,000	92.00/M	EMG9T2R	
	FF	50	100	80	2.2	26	EMG11T2RCT-ND	.44	7.50	20.80	EMG11T2RTR-ND	8,000	72.00/M	EMG11T2R	
	J	50	30	56	28.6	1.2	EMH1T2RCT-ND	.46	8.44	23.76	EMH1T2RTR-ND	8,000	92.00/M	EMH1T2R	
	J	50	30	68	61.1	1.2	EMH2T2RCT-ND	.46	8.44	23.76	EMH2T2RTR-ND	8,000	92.00/M	EMH2T2R	
	DD	50	100	600	6.11	—	EMH3T2RCT-ND	.46	8.44	23.76	EMH3T2RTR-ND	8,000	92.00/M	EMH3T2R	
	SS	50	100	600	13	—	EMH4T2RCT-ND	.46	8.44	23.76	EMH4T2RTR-ND	8,000	92.00/M	EMH4T2R	
	H	50	30	68	61.1	1.2	EMH6T2RCT-ND	.46	8.44	23.76	EMH6T2RTR-ND	8,000	92.00/M	EMH6T2R	
	J	50	70	68	13	5.7	EMH9T2RCT-ND	.50	9.63	27.72	EMH9T2RTR-ND	8,000	123.00/M	EMH9T2R	
	J	50	100	80	2.86	2.6	EMH10T2RCT-ND	.46	8.44	23.76	EMH10T2RTR-ND	8,000	92.00/M	EMH10T2R	
	J	50	50	30	13	1.2	EMH11T2RCT-ND	.46	8.44	23.76	EMH11T2RTR-ND	8,000	92.00/M	EMH11T2R	
	X	50	150	120	—	—	EMX3T2RCT-ND	.46	8.44	23.76	EMX3T2RTR-ND	8,000	92.00/M	EMX3T2R	
	PNP														
SOT-353	LL	50	30	68	61.1	1.2	UMA2NCT-ND	.38	7.03	19.80	UMA2NTR-ND	3,000	81.00/M	UMA2NTR	
	LL	50	100	68	10	5.7	UMA8NCT-ND	.38	7.03	19.80	UMA8NTR-ND	3,000	81.00/M	UMA8NTR	
	LL	50	50	30	13	1.2	UMA9NCT-ND	.38	7.03	19.80	UMA9NTR-ND	3,000	81.00/M	UMA9NTR	
SOT-363	L	50	30	68	61.1	1.2	UMB2NCT-ND	.38	7.03	19.80	UMB2NTR-ND	3,000	81.00/M	UMB2NTR	
	QQ	50	100	600	13	—	UMB4NCT-ND	.38	7.03	19.80	UMB4NTR-ND	3,000	81.00/M	UMB4NTR	
	L	50	100	80	2.86	2.6	UMB10NCT-ND	.38	7.03	19.80	UMB10NTR-ND	3,000	81.00/M	UMB10NTR	
SOT-428	L	50	50	30	13	1.2	UMB11NCT-ND	.38	7.03	19.80	UMB11NTR-ND	3,000	81.00/M	UMB11NTR	
	L	50	70	68	13	5.7	UMB9NCT-ND	.38	7.03	19.80</					

包装	电路	V _{CEO} (V)	I _C (mA)	增益 (HFE)	R ₁ (kΩ)	Ω 电阻比 R2/R1	Digi-Key 零件编号	剪切带价格			Digi-Key 零件编号	带卷		Rohm 零件编号	
								1	25	100		数量	价格		
EMT-6	L	50	100	30	2.86	26	EMB10T2RCT-ND	.46	8.44	23.76	EMB10T2RTR-ND	8,000	92.00/M	EMB10T2R	
	L	50	50	80	13	1.2	EMB11T2RCT-ND	.46	8.44	23.76	EMB11T2RTR-ND	8,000	92.00/M	EMB11T2R	
PNP/NPN															
SOT-353	HH	50	150	120	—	—	UMY1NCT-ND	.37	6.38	17.68	UMY1NTR-ND	3,000	68.00/M	UMY1NTR	
	SOT-363	O	50	30	56	28.6	1.2	UMD2NCT-ND	.38	7.03	19.80	UMD2NTR-ND	3,000	81.00/M	UMD2NTR
		O	50	50	30	13	1.2	UMD3NCT-ND	.43	7.31	20.28	UMD3NTR-ND	3,000	78.00/M	UMD3N
		Q	50	100	100	6.11	—	UMD6NCT-ND	.38	7.03	19.80	UMD6NTR-ND	3,000	81.00/M	UMD6NTR
		O	50	70	68	13	5.7	UMD9NCT-ND	.38	7.03	19.80	UMD9NTR-ND	3,000	81.00/M	UMD9NTR
		Q	50	30	68	61.1	1.2	UMD12NCT-ND	.38	7.03	19.80	UMD12NTR-ND	3,000	81.00/M	UMD12NTR
U	50	150	120	—	—	UMZ2NCT-ND	.43	7.31	20.28	UMZ2NTR-ND	3,000	78.00/M	UMZ2NTR		
SOT-457	P	50	30	56	28.6	1.2	IMD2AT108CT-ND	.44	8.13	22.88	IMD2AT108TR-ND	3,000	94.00/M	IMD2AT108	
	R	50	100	600	6.11	—	IMD6AT108CT-ND	.44	8.13	22.88	IMD6AT108TR-ND	3,000	94.00/M	IMD6AT108	
	P	50	100	68	13	5.7	IMD9AT108CT-ND	.44	8.13	22.88	IMD9AT108TR-ND	3,000	94.00/M	IMD9AT108	
	N	50	500	68	130	120	IMD10AT108CT-ND	.41	7.50	21.12	IMD10AT108TR-ND	3,000	86.00/M	IMD10AT108	
SMT-5	AA	50	500	82	2.86	1.2	IMD16AT108CT-ND	.46	8.88	25.56	IMD16AT108TR-ND	3,000	121.00/M	IMD16AT108	
	AA	32	500	120	—	—	IMZ4T108CT-ND	.46	8.44	23.76	IMZ4T108TR-ND	3,000	97.00/M	IMZ4T108	
EMT-5	II	50	150	120	—	—	FMY1AT148CT-ND	.44	8.50	24.48	FMY1AT148TR-ND	3,000	116.00/M	FMY1AT148	
	HH	50	150	120	—	—	EMY1T2RCT-ND	.46	8.44	23.76	EMY1T2RTR-ND	8,000	92.00/M	EMY1T2R	
EMT-6	O	50	30	56	28.6	1.2	EMD2T2RCT-ND	.46	8.44	23.76	EMD2T2RTR-ND	8,000	92.00/M	EMD2T2R	
	O	50	50	30	13	1.2	EMD3T2RCT-ND	.46	8.44	23.76	EMD3T2RTR-ND	8,000	92.00/M	EMD3T2R	
	Q	50	100	100	6.11	—	EMD6T2RCT-ND	.46	8.44	23.76	EMD6T2RTR-ND	8,000	92.00/M	EMD6T2R	
	O	50	70	68	13	5.7	EMD9T2RCT-ND	.46	8.44	23.76	EMD9T2RTR-ND	8,000	92.00/M	EMD9T2R	
	O	50	30	68	61.1	1.2	EMD12T2RCT-ND	.46	8.44	23.76	EMD12T2RTR-ND	8,000	92.00/M	EMD12T2R	

双晶体管

包装	电路	V _{CEO} (V)	V _{CB0} (V)	I _C (mA)	最大 HFE	饱和 V _{CE}	V _{CE} I _C (mA)	Digi-Key 零件编号	剪切带价格			Digi-Key 零件编号	带卷		Rohm 零件编号	
									1	25	100		数量	价格		
NPN																
SOT-363	DD	50	60	150	560	0.4	50	5	UMX1NTNCT-ND	.43	7.31	20.28	UMX1NTNTR-ND	3,000	78.00/M	UMX1NTN
	BB	50	60	150	560	0.4	50	5	UMX2NTRCT-ND	.43	7.31	20.28	UMX2NTRTR-ND	3,000	78.00/M	UMX2NTR
	X	50	60	150	560	0.4	50	5	UMX3NTRCT-ND	.49	7.25	18.85	UMX3NTRTR-ND	3,000	68.00/M	UMX3NTR
	X	20	30	50	270	0.5	20	4	UMX4NCT-ND	.44	8.13	22.88	UMX4NTR-ND	3,000	94.00/M	UMX4NTR
	X	11	20	50	270	0.5	10	5	UMX5NCT-ND	.44	8.38	24.12	UMX5NTR-ND	3,000	114.00/M	UMX5NTR
SOT-457	EE	50	60	150	560	0.4	50	5	IMX1T110CT-ND	.48	8.25	22.88	IMX1T110TR-ND	3,000	88.00/M	IMX1T110
	CC	50	60	150	560	0.4	50	5	IMX2T108CT-ND	.49	7.25	18.85	IMX2T108TR-ND	3,000	68.00/M	IMX2T108
	Y	50	60	150	560	0.4	50	5	IMX3T108CT-ND	.46	8.88	25.56	IMX3T108TR-ND	3,000	121.00/M	IMX3T108
	Y	20	30	50	270	0.5	20	4	IMX4T108CT-ND	.55	10.90	32.70	IMX4T108TR-ND	3,000	164.00/M	IMX4T108
	Y	11	20	50	120	0.5	10	5	IMX5T108CT-ND	.46	8.88	25.56	IMX5T108TR-ND	3,000	121.00/M	IMX5T108
	Y	120	120	50	820	0.5	10	1	IMX8T108CT-ND	.43	7.81	22.00	IMX8T108TR-ND	3,000	90.00/M	IMX8T108
	EE	20	25	500	2,700	0.4	500	20	IMX9T110CT-ND	.46	8.44	23.76	IMX9T110TR-ND	3,000	97.00/M	IMX9T110
	EE	50	60	500	390	0.6	500	50	IMX17T110CT-ND	.46	8.44	23.76	IMX17T110TR-ND	3,000	97.00/M	IMX17T110
EMT-6	DD	50	60	150	560	0.4	50	5	EMX1T2RCT-ND	.46	8.44	23.76	EMX1T2RTR-ND	8,000	92.00/M	EMX1T2R
	BB	50	60	150	560	0.4	50	5	EMX2T2RCT-ND	.46	8.44	23.76	EMX2T2RTR-ND	8,000	92.00/M	EMX2T2R
	X	30	30	50	270	0.5	20	4	EMX4T2RCT-ND	.58	11.60	34.80	EMX4T2RTR-ND	8,000	162.00/M	EMX4T2R
	X	11	20	50	120	0.5	10	5	EMX5T2RCT-ND	.58	11.60	34.80	EMX5T2RTR-ND	8,000	162.00/M	EMX5T2R
PNP																
SOT-363	S	50	60	150	560	0.5	50	5	UMT1NTNCT-ND	.42	7.13	19.76	UMT1NTNTR-ND	3,000	76.00/M	UMT1NTN
	PP	12	15	500	680	0.25	200	10	UMF5NCT-ND	.55	10.50	30.24	UMF5NTR-ND	3,000	143.00/M	UMF5NTR
	OO	50	60	150	560	0.5	50	5	UMT2NCT-ND	.42	7.13	19.76	UMT2NTR-ND	3,000	76.00/M	UMT2NTR
SOT-457	W	120	120	50	820	0.5	10	1	IMT4T108CT-ND	.43	7.81	22.00	IMT4T108TR-ND	3,000	90.00/M	IMT4T108
	T	50	60	150	560	0.5	50	5	IMT1AT110CT-ND	.48	8.25	22.88	IMT1AT110TR-ND	3,000	88.00/M	IMT1AT110
	OO	50	60	150	560	0.5	50	5	IMT2AT108CT-ND	.45	9.00	27.00	IMT2AT108TR-ND	3,000	135.00/M	IMT2AT108
EMT-6	S	50	60	150	560	0.5	50	5	EMT1T2RCT-ND	.46	8.44	23.76	EMT1T2RTR-ND	8,000	92.00/M	EMT1T2R
	NN	50	60	150	560	0.5	50	5	EMT2T2RCT-ND	.46	8.44	23.76	EMT2T2RTR-ND	8,000	92.00/M	EMT2T2R
PNP/NPN																
SOT-363	Z	50	60	150	560	0.4	50	5	UMZ1NTRCT-ND	.37	6.38	17.68	UMZ1NTRTR-ND	3,000	68.00/M	UMZ1NTR
	V	50	60	150	560	0.4	50	5	IMZ2AT108CT-ND	.46	8.44	23.76	IMZ2AT108TR-ND	3,000	97.00/M	IMZ2AT108
SOT-457	AA	50	60	150	560	0.5	50	5	IMZ1AT108CT-ND	.43	7.81	22.00	IMZ1AT108TR-ND	3,000	90.00/M	IMZ1AT108
	AA	50	60	150	560	0.5	50	5	IMZ1AT108CT-ND	.43	7.81	22.00	IMZ1AT108TR-ND	3,000	90.00/M	IMZ1AT108
EMT-6	PP	12	15	500	680	0.25	200	10	EMF21T2RCT-ND	.50	9.22	25.96	EMF21T2RTR-ND	8,000	100.00/M	EMF21T2R
	PP	12	15	100	30	0.25	200	10	EMF21T2RCT-ND	.50	9.22	25.96	EMF21T2RTR-ND	8,000	100.00/M	EMF21T2R
	PP	12	15	500	680	0.25	200	10	EMF5T2RCT-ND	.50	9.63	27.72	EMF5T2RTR-ND	8,000	123.00/M	EMF5T2R
	PP	12	15	100	68	0.25	200	10	EMF5T2RCT-ND	.50	9.63	27.72	EMF5T2RTR-ND	8,000	123.00/M	EMF5T2R
	Z	50	60	150	560	0.4	50	5	EMZ1T2RCT-ND	.46	8.44	23.76	EMZ1T2RTR-ND	8,000	92.00/M	EMZ1T2R
	U	50	60	150	560	0.5	50	5	EMZ2T2RCT-ND	.46	8.44	23.76	EMZ2T2RTR-ND	8,000	92.00/M	EMZ2T2R
PNP/DTR																
SOT-363	OO	12	15	500	680	250	200	10	UMF21NCT-ND	.44	8.50	24.48	UMF21NTR-ND	3,000	116.00/M	UMF21NTR

通用晶体管

包装	V _{CEO} (V)	V _{CB0} (V)	I _C (A)	最大 HFE	最大饱和 V _{CE} (V)	V _{CE} I _C (mA)	V _{CE} I _B (mA)	Digi-Key 零件编号	剪切带价格			带卷		Rohm 零件编号	
									25	100	数量	价格			
NPN															
SOT-89	20	40	3	390	0.5	2A	100	2SD2150T100RCT-ND	.52	10.30	30.90	1,000	165.00	2SD2150T100R	
	20	50	5	390	1.0	4A	100	2SD2098T100RCT-ND	.76	15.12	45.36	1,000	260.00	2SD2098T100R	
	20	40	3	560	0.5	2A	100	2SD2150T100SCT-ND	.52	10.30	30.90	1,000	165.00	2SD2150T100S	
	25	30	1.2	1,800	0.3	500	10	2SD2537T100VCT-ND	.80	15.93	47.79	1,000	274.00	2SD2537T100V	
	25	30	2	2,700	0.5	1	20	2SD2153T100VCT-ND	.94	18.72	56.16	1,000	322.00	2SD2153T100V	
	32	40	1	390	0.4	500	50	2SD1664T100QCT-ND	.48	8.75	24.64	1,000	112.00	2SD1664T100Q	
	32	40	1	390	0.4	500	50	2SD1664T100RCT-ND	.55	10.63	30.60	1,000	153.00	2SD1664T100R	
	32	40	2	390	0.8	2A	200	2SD1766T100QCT-ND	.45	9.00	27.00	1,000	144.00	2SD1766T100Q	
	32	40	2	390	0.8	2A	200	2SD1766T100RCT-ND	.56	10.75	30.96	1,000	155.00	2SD1766T100R	
	50	60	3	270	0.35	1A	50	2SC4672T100PCT-ND	.70	14.04	42.12	1,000	242.00	2SC4672T100P	
	50	60	3	270											

C

包装	V _{CEO} (V)	V _{CB0} (V)	I _C (A)	最大 HFE	最大饱和 V _{CE} (V)	V _{CE} I _C (mA)	V _{CE} I _B (mA)	Digi-Key 零件编号	剪切带价格			带卷†		Rohm 零件编号	
									1	25	100	数量	价格		
SOT-89	80	80	0.7	390	0.4	500	50	2SD1767T100RCT-ND	.71	14.20	42.60	1,000	227.00	2SD1767T100R	
	90	90	2	10K	1.5	1A	1	2SD2170T100CT-ND	.61	12.20	36.60	1,000	195.00	2SD2170T100	
	120	120	2	390	2	1A	100	2SC4132T100QCT-ND	.65	12.90	38.70	1,000	206.00	2SC4132T100Q	
	120	120	2	390	2	1A	100	2SC4132T100RCT-ND	.65	12.90	38.70	1,000	206.00	2SC4132T100R	
	400	400	0.1	270	0.5	10	1	2SC4505T100PCT-ND	.96	19.17	57.51	1,000	330.00	2SC4505T100P	
	400	400	0.1	270	0.5	10	1	2SC4505T100QCT-ND	.96	19.17	57.51	1,000	330.00	2SC4505T100Q	
SOT-323	6	12	50mA	560	0.3	10	1	2SC4774T106SCT-ND	.41	7.50	21.12	3,000	86.00	2SC4774T106S	
	11	20	50mA	180	0.5	10	5	2SC4083T106NCT-ND	.43	6.25	16.25	3,000	59.00	2SC4083T106N	
	11	20	50mA	180	0.5	10	5	2SC4083T106PCT-ND	.43	6.25	16.25	3,000	59.00	2SC4083T106P	
	12	15	1.5	680	0.2	500	25	2SD2652T106CT-ND	.56	10.75	30.96	3,000	146.00	2SD2652T106	
	20	30	50mA	180	0.5	20	4	2SC4082T106RCT-ND	.41	7.50	21.12	3,000	86.00	2SC4082T106R	
	120	120	50mA	560	0.5	10	1	2SC4102T106RCT-ND	.37	6.38	17.68	3,000	68.00	2SC4102T106R	
	25	40	50mA	180	0.35	10	1	2SC4098T106PCT-ND	.41	7.50	21.12	3,000	86.00	2SC4098T106P	
	30	30	1	680	0.35	500	25	2SD2656T106CT-ND	.50	9.63	27.72	3,000	131.00	2SD2656T106	
	32	40	0.5	390	0.6	500	50	2SC4097T106QCT-ND	.47	8.06	22.36	3,000	86.00	2SC4097T106Q	
	32	40	0.5	390	0.6	500	50	2SC4097T106RCT-ND	.47	8.06	22.36	3,000	86.00	2SC4097T106R	
	40	75	0.6	75	1	500	50	UMT2222AT106CT-ND	.44	6.50	16.90	3,000	61.00	UMT2222AT106	
	40	60	0.2	300	0.3	50	5	UMT3904T106CT-ND	.44	6.50	16.90	3,000	61.00	UMT3904T106	
	50	60	0.15	270	0.4	50	5	2SC4081T106QCT-ND	.34	5.00	13.00	3,000	47.00	2SC4081T106Q	
	50	60	0.15	390	0.4	50	5	2SC4081T106RCT-ND	.34	5.00	13.00	3,000	47.00	2SC4081T106R	
	50	60	0.15	2,700	0.3	50	5	2SD2351T106VCT-ND	.46	8.44	23.76	3,000	97.00	2SD2351T106V	
	50	60	0.15	2,700	0.3	50	5	2SD2351T106WCT-ND	.45	8.28	23.32	3,000	95.00	2SD2351T106W	
	50	50	0.5	390	0.4	150	15	2SD1949T106QCT-ND	.46	8.44	23.76	3,000	97.00	2SD1949T106Q	
	50	50	0.5	390	0.4	150	15	2SD1949T106RCT-ND	.46	8.44	23.76	3,000	97.00	2SD1949T106R	
	60	60	0.5	390	0.3	100	10	2SC5876T106QCT-ND	.55	10.63	30.60	3,000	145.00	2SC5876T106Q	
	60	60	0.5	390	0.3	100	10	2SC5876T106RCT-ND	.55	10.63	30.60	3,000	145.00	2SC5876T106R	
	SOT-346	6	12	50mA	560	0.3	10	1	2SC4713KT146SCT-ND	.46	8.88	25.56	3,000	121.00	2SC4713KT146S
		11	20	50mA	180	0.5	10	5	2SC3838KT146NCT-ND	.46	7.88	21.84	3,000	84.00	2SC3838KT146N
		11	20	50mA	180	0.5	10	5	2SC3838KT146PCT-ND	.46	7.88	21.84	3,000	84.00	2SC3838KT146P
		12	15	2	680	0.18	1A	50	2SD2653KT146CT-ND	.55	10.90	32.70	3,000	164.00	2SD2653KT146
15		30	0.5	560	0.4	500	50	2SD1757KT146QCT-ND	.46	9.20	27.60	3,000	138.00	2SD1757KT146Q	
15		30	0.5	560	0.4	500	50	2SD1757KT146RCT-ND	.46	9.20	27.60	3,000	138.00	2SD1757KT146R	
20		30	50mA	180	0.5	20	4	2SC3837KT146PCT-ND	.40	7.75	22.32	3,000	105.00	2SC3837KT146P	
20		25	0.5	2,700	0.4	500	20	2SD2114KT146VCT-ND	.43	7.31	20.28	3,000	78.00	2SD2114KT146V	
20		25	0.5	2,700	0.4	500	20	2SD2114KT146WCT-ND	.43	7.31	20.28	3,000	78.00	2SD2114KT146W	
25		40	50mA	180	0.3	10	1	2SC2413KT146PCT-ND	.46	8.44	23.76	3,000	97.00	2SC2413KT146P	
32		40	0.5	390	0.6	500	50	2SC2411KT146QCT-ND	.43	7.31	20.28	3,000	78.00	2SC2411KT146Q	
32		40	0.5	390	0.6	500	50	2SC2411KT146RCT-ND	.43	7.31	20.28	3,000	78.00	2SC2411KT146R	
32		40	0.8	390	1.5	200	0.4	2SD1938KT146BCT-ND	.55	10.50	30.24	3,000	143.00	2SD1938KT146B	
32		40	0.8	390	0.4	500	50	2SD1781KT146QCT-ND	.43	7.31	20.28	3,000	78.00	2SD1781KT146Q	
32		40	0.3	500	0.4	500	50	2SD1781KT146RCT-ND	.43	7.31	20.28	3,000	78.00	2SD1781KT146R	
40		60	0.2	300	0.2	10	1	MMST3904T146CT-ND	.43	6.25	16.25	3,000	59.00	MMST3904T146	
40		75	0.6	75	1	500	50	MMST2222AT146CT-ND	.33	5.63	15.60	3,000	60.00	MMST2222AT146	
40		60	0.6	80	0.75	500	50	MMST4401T146CT-ND	.46	6.75	17.55	3,000	63.00	MMST4401T146	
50		60	0.15	270	0.4	50	5	2SC2412KT146QCT-ND	.29	4.25	11.05	3,000	40.00	2SC2412KT146Q	
50		60	0.15	390	0.4	50	5	2SC2412KT146RCT-ND	.29	4.25	11.05	3,000	40.00	2SC2412KT146R	
50		60	0.15	560	0.4	50	5	2SC2412KT146SCT-ND	.31	4.50	11.70	3,000	42.00	2SC2412KT146S	
80		80	0.5	390	0.25	100	10	MMSTA06T146CT-ND	.49	9.06	25.52	3,000	104.00	MMSTA06T146	
50		50	0.5	390	0.4	150	15	2SD1484KT146QCT-ND	.33	5.63	15.60	3,000	60.00	2SD1484KT146Q	
50		50	0.5	390	0.4	150	15	2SD1484KT146RCT-ND	.33	5.63	15.60	3,000	60.00	2SD1484KT146R	
50	60	0.15	2,700	0.3	50	5	2SD2226KT146WCT-ND	.55	10.63	30.60	3,000	145.00	2SD2226KT146W		
50	60	0.15	2,700	0.3	50	5	2SD2226KT146VCT-ND	.55	10.63	30.60	3,000	145.00	2SD2226KT146V		
80	80	0.5	390	0.5	500	50	2SD1782KT146RCT-ND	.45	8.28	23.32	3,000	95.00	2SD1782KT146R		
80	80	0.5	390	0.5	500	50	2SD1782KT146QCT-ND	.45	8.28	23.32	3,000	95.00	2SD1782KT146Q		
120	120	50mA	560	0.5	10	1	2SC3906KT146RCT-ND	.48	8.91	25.08	3,000	103.00	2SC3906KT146R		
300	300	0.1	180	2	50	5	2SC4061KT146NCT-ND	.54	10.38	29.88	3,000	141.00	2SC4061KT146N		
SOT-416	11	20	50mA	180	0.5	10	5	2SC4726TLPCT-ND	.48	9.50	28.50	3,000	143.00	2SC4726TLP	
	12	15	0.5	680	0.25	200	10	2SC5585TLPCT-ND	.50	9.22	25.96	3,000	106.00	2SC5585TLP	
	20	30	50mA	180	0.5	20	4	2SC4725TLPCT-ND	.55	10.63	30.60	3,000	145.00	2SC4725TLP	
	25	40	50mA	180	0.3	10	1	2SC4618TLRCT-ND	.40	7.75	22.32	3,000	105.00	2SC4618TLR	
	25	40	50mA	180	0.3	10	1	2SC4618TLPCT-ND	.40	7.75	22.32	3,000	105.00	2SC4618TLP	
	50	60	0.15	2,700	0.3	50	5	2SD2654TLVCT-ND	.41	7.88	22.68	3,000	107.00	2SD2654TLV	
	50	60	0.15	270	0.4	50	5	2SC4617TLQCT-ND	.34	5.00	13.00	3,000	47.00	2SC4617TLQ	
	50	60	0.15	390	0.4	50	5	2SC4617TLRCT-ND	.34	5.00	13.00	3,000	47.00	2SC4617TLR	
	VMT-3	11	20	50mA	180	0.5	10	5	2SC5662T2LPCT-ND	.44	8.38	24.12	8,000	107.00	2SC5662T2LP
		12	15	0.5	680	0.25	200	10	2SC5663T2LPCT-ND	.47	9.00	25.92	8,000	115.00	2SC5663T2LP
20		30	50mA	180	0.5	20	4	2SC5661T2LPCT-ND	.47	9.30	27.90	8,000	130.00	2SC5661T2LP	
25		40	50mA	180	0.3	10	1	2SC5659T2LPCT-ND	.45	7.69	21.32	8,000	74.00	2SC5659T2LP	
25		40	50mA	180	0.3	10	1	2SC5659T2LPCT-ND	.45	7.69	21.32	8,000	74.00	2SC5659T2LP	
50		60	0.15	560	0.4	50	5	2SC5658T2LRCT-ND	.42	7.13	19.76	8,000	68.00	2SC5658T2LR	
SOT-428	50	60	0.15	270	0.4	50	5	2SC5658T2LQCT-ND	.42	7.13	19.76	8,000	68.00	2SC5658T2LQ	
	50	60	0.15	2,700	0.3	50	5	2SD2707T2LVCT-ND	.48	8.91	25.08	8,000	97.00	2SD2707T2LV	
	20	30	10	390	0.25	4A	50	2SC5001TLQCT-ND	.96	20.88	64.25	2,500	342.00	2SC5001TLQ	
	20	30	10	390	0.25	4A	50	2SC5001TLRCT-ND	.98	19.62	58.86	2,500	311.00	2SC5001TLR	
	20	50	5	390	1	4A	100	2SD2118TLQCT-ND	.75	15.03	45.09	2,500	238.00	2SD2118TLQ	
	20	50	5	390	1	4A	100	2SD2118TLRCT-ND	.75	15.03	45.09	2,500	238.00	2SD2118TLR	
	32	40	2	390	0.8	2A	200	2SD1758TLQCT-ND	.72	14.49	43.47	2,500	229.00	2SD1758TLQ	
	32	40	2	39											

包装	VCEO (V)	VCBO (V)	IC (A)	最大 HFE	最大饱和 VCE (V)	VCE IC (mA)	VCE IB (mA)	Digi-Key 零件编号	剪切带价格			带卷†		Rohm 零件编号	
									1	25	100	数量	价格		
ATV	80	100	1	390	0.4	500	20	2SD1863TV2RCT-ND‡	.55	10.90	32.70	2,500	164.00/M	2SD1863TV2R	
	80	120	1	390	0.4	500	20	2SD1863TV2QCT-ND‡	.61	12.20	36.60	2,500	183.00/M	2SD1863TV2Q	
	50	60	3	390	1	2A	200	2SD1864TV2QCT-ND‡	1.09	21.78	65.34	2,500	345.00/M	2SD1864TV2Q	
	50	60	3	390	1	2A	200	2SD1864TV2RCT-ND‡	1.09	21.78	65.34	2,500	345.00/M	2SD1864TV2R	
	80	80	0.7	390	0.4	500	50	2SD1859TV2QCT-ND‡	.69	13.80	41.40	2,500	207.00/M	2SD1859TV2Q	
	80	80	0.7	390	0.4	500	50	2SD1859TV2RCT-ND‡	.69	13.80	41.40	2,500	207.00/M	2SD1859TV2R	
TO-200FP	60	80	3	320	1	2A	200	2SD2096T114ECT-ND	1.31	28.44	87.50	1,000	508.00	2SD2096T114E	
	160	160	1.5	200	2	1A	100	2SD2033AT114ECT-ND	1.58	34.13	105.00	1,000	609.00	2SD2033AT114E	
<i>PNP</i>															
SOT-89	20	20	3	270	0.5	2A	100	2SB1424T100QCT-ND	.45	9.00	27.00	1,000	144.00	2SB1424T100Q	
	20	20	3	390	0.5	2A	100	2SB1424T100RCT-ND	.42	8.13	23.40	1,000	117.00	2SB1424T100R	
	20	30	5	390	1	4A	100	2SB1386T100QCT-ND	.58	11.50	34.50	1,000	184.00	2SB1386T100Q	
	20	30	5	390	1	4A	100	2SB1386T100RCT-ND	.58	11.50	34.50	1,000	184.00	2SB1386T100R	
	20	20	2	820	0.5	1A	50	2SB1427T100ECT-ND	.58	11.60	34.80	1,000	186.00	2SB1427T100E	
	32	40	1	390	0.5	50A	50	2SB1132T100RCT-ND	.40	7.63	21.96	1,000	110.00	2SB1132T100R	
	32	40	1	270	0.5	500	50	2SB1132T100QCT-ND	.44	8.50	24.48	1,000	122.00	2SB1132T100Q	
	32	40	2	270	0.8	2A	200	2SB1188T100QCT-ND	.45	9.00	27.00	1,000	144.00	2SB1188T100Q	
	32	40	2	390	0.8	2A	200	2SB1188T100RCT-ND	.45	9.00	27.00	1,000	144.00	2SB1188T100R	
	50	60	1	270	0.4	500	50	2SA1900T100QCT-ND	.65	12.90	38.70	1,000	206.00	2SA1900T100Q	
	50	50	3	270	0.35	1A	50	2SA1797T100PCT-ND	.69	13.80	41.40	1,000	221.00	2SA1797T100P	
	50	50	3	270	0.35	1A	50	2SA1797T100QCT-ND	.65	13.00	39.00	1,000	208.00	2SA1797T100Q	
	60	60	2	270	0.35	1A	50	2SB1561T100QCT-ND	.74	14.80	44.40	1,000	237.00	2SB1561T100Q	
	80	80	1	270	0.4	500	50	2SB1260T100QCT-ND	.52	10.00	28.80	1,000	144.00	2SB1260T100Q	
	80	80	0.7	390	0.4	500	50	2SB1189T100QCT-ND	.52	10.30	30.90	1,000	165.00	2SB1189T100Q	
	80	80	0.7	390	0.4	500	50	2SB1189T100RCT-ND	.52	10.30	30.90	1,000	165.00	2SB1189T100R	
	400	400	0.1	180	0.5	20	2	2SA1759T100PCT-ND	.83	16.56	49.68	1,000	285.00	2SA1759T100P	
	400	400	0.5	270	1	100	10	2SA1812T100QCT-ND	.88	17.55	52.65	1,000	302.00	2SA1812T100Q	
SOT-323	12	15	1.5	680	0.20	500	25	2SB1689T106CT-ND	.44	8.50	24.48	3,000	116.00/M	2SB1689T106	
	30	30	1	680	0.38	500	25	2SB1694T106CT-ND	.44	8.50	24.48	3,000	104.00/M	2SB1694T106	
	32	40	0.5	390	0.6	300	30	2SA1577T106QCT-ND	.37	5.50	14.30	3,000	52.00/M	2SA1577T106Q	
	32	40	0.5	390	0.6	300	30	2SA1577T106RCT-ND	.37	5.50	14.30	3,000	52.00/M	2SA1577T106R	
	40	40	0.2	300	0.4	50	5	UMT3906T106CT-ND	.44	6.50	16.90	3,000	61.00/M	UMT3906T106	
	50	60	0.15	270	0.5	50	5	2SA1576AT106QCT-ND	.34	5.00	13.00	3,000	47.00/M	2SA1576AT106Q	
	50	60	0.15	390	0.5	50	5	2SA1576AT106RCT-ND	.34	5.00	13.00	3,000	47.00/M	2SA1576AT106R	
	60	60	0.6	100	1.6	500	50	UMT2907AT106CT-ND	.44	6.50	16.90	3,000	61.00/M	UMT2907AT106	
	120	120	50mA	560	0.5	10	1	2SA1579T106RCT-ND	.48	8.75	24.64	3,000	101.00/M	2SA1579T106R	
	120	120	50mA	560	0.5	10	1	2SA1579T106SCT-ND	.48	8.75	24.64	3,000	101.00/M	2SA1579T106S	
SOT-346	12	15	2	680	0.18	1A	50	2SB1690KT146CT-ND	.55	10.50	30.24	3,000	143.00/M	2SB1690KT146	
	32	40	0.5	390	0.6	300	30	2SA1036KT146QCT-ND	.50	9.22	25.96	3,000	106.00/M	2SA1036KT146Q	
	32	40	0.5	390	0.6	300	30	2SA1036KT146RCT-ND	.50	9.22	25.96	3,000	106.00/M	2SA1036KT146R	
	32	40	0.8	390	0.5	500	50	2SB1197KT146RCT-ND	.43	7.31	20.28	3,000	78.00/M	2SB1197KT146R	
	32	40	0.8	270	0.5	0.5A	50	2SB1197KT146QCT-ND	.43	7.31	20.28	3,000	78.00/M	2SB1197KT146Q	
	40	40	0.2	300	0.25	10	1	MMST3906T146CT-ND	.43	6.25	16.25	3,000	59.00/M	MMST3906T146	
	40	40	0.6	100	0.75	500	50	MMST4403T146CT-ND	.46	6.75	17.55	3,000	63.00/M	MMST4403T146	
	50	60	0.15	270	0.5	50	5	2SA1037AKT146QCT-ND	.29	4.25	11.05	3,000	40.00/M	2SA1037AKT146Q	
	50	60	0.15	390	0.5	50	5	2SA1037AKT146RCT-ND	.29	4.25	11.05	3,000	40.00/M	2SA1037AKT146R	
	60	60	0.6	100	1.6	500	50	MMST2907AT146CT-ND	.49	7.25	18.85	3,000	68.00/M	MMST2907AT146	
	80	80	0.5	390	0.5	500	50	MMST456T146CT-ND	.49	9.06	25.52	3,000	104.00/M	MMST456T146	
	80	80	0.5	390	0.5	500	50	2SB1198KT146QCT-ND	.43	7.81	22.00	3,000	90.00/M	2SB1198KT146Q	
80	80	0.5	390	0.5	500	50	2SB1198KT146RCT-ND	.43	7.81	22.00	3,000	90.00/M	2SB1198KT146R		
120	120	50mA	560	0.5	10	1	2SA1514KT146RCT-ND	.48	8.91	25.08	3,000	103.00/M	2SA1514KT146R		
120	120	50mA	560	0.5	10	1	2SA1514KT146SCT-ND	.48	8.91	25.08	3,000	103.00/M	2SA1514KT146S		
SOT-416	12	15	0.5	680	0.25	200	10	2SA2018TLCT-ND	.48	8.91	25.08	3,000	103.00/M	2SA2018TL	
	50	60	0.15	270	0.5	50	5	2SA1774TLQCT-ND	.37	5.50	14.30	3,000	52.00/M	2SA1774TLQ	
	50	60	0.15	560	0.5	50	5	2SA1774TLRCT-ND	.37	5.50	14.30	3,000	52.00/M	2SA1774TLR	
VMT-3	12	15	1.0	680	0.25	200	10	2SA2029T2LQCT-ND	.47	9.00	25.92	3,000	115.00/M	2SA2029T2LQ	
	50	60	0.15	560	0.5	50	5	2SA2029T2LQCT-ND	.49	7.25	18.85	8,000	58.00/M	2SA2029T2LQ	
SOT-428	20	30	10	560	0.25	4A	50	2SA1834TLRCT-ND	1.20	26.08	80.25	2,500	427.00/M	2SA1834TLR	
	20	30	5	390	1	4A	100	2SB1412TLQCT-ND	.69	13.86	41.58	2,500	219.00/M	2SB1412TLQ	
	20	30	5	390	1	4A	100	2SB1412TLRCT-ND	.95	20.64	63.50	2,500	338.00/M	2SB1412TLR	
	32	40	2	390	0.8	2A	200	2SB1182TLQCT-ND	1.01	20.25	60.75	2,500	321.00/M	2SB1182TLQ	
	32	40	2	390	0.8	2A	200	2SB1182TLRCT-ND	1.01	20.25	60.75	2,500	321.00/M	2SB1182TLR	
	50	60	3	390	1	2A	200	2SB1184TLRCT-ND	.65	12.90	38.70	2,500	194.00/M	2SB1184TLR	
	50	60	3	270	1	2A	200	2SB1184TLQCT-ND	.65	12.90	38.70	2,500	194.00/M	2SB1184TLQ	
	60	100	5	270	0.3	3A	150	2SA1952TLQCT-ND	1.59	34.45	106.00	2,500	564.00/M	2SA1952TLQ	
	80	80	1	390	0.4	500	50	2SB1181TLQCT-ND	.98	19.62	58.86	2,500	311.00/M	2SB1181TLQ	
	80	80	1	390	0.4	500	50	2SB1181TLRCT-ND	.98	19.62	58.86	2,500	311.00/M	2SB1181TLR	
400	400	0.5	270	1	100	10	2SA1727TLPCT-ND	.98	19.62	58.86	2,500	311.00/M	2SA1727LP		
400	400	0.5	270	1	100	10	2SA1727TLRCT-ND	.98	19.62	58.86	2,500	311.00/M	2SA1727LR		
400	400	0.5	180	0.5	500	180	2SA1982TLRCT-ND	1.35	29.17	85.25	2,500	477.00/M	2SA1982TLR		
SOT-23	40	40	0.6	100	0.75	600	50	SST4403T116CT-ND	.44	6.50	16.90	3,000	61.00/M	SST4403T116	
	60	60	0.6	100	1.6	500	50	SST2907AT116CT-ND	.26	3.75	9.75	3,000	35.00/M	SST2907AT116	
TUMT-3	12	15	2	680	0.18	1A	50	2SB1730TLCT-ND	.50	10.00	30.00	3,000	150.00/M	2SB1730TL	
	30	30	1.5	680	0.37	1A	50	2SB1731TLCT-ND	.50	10.00	30.00	3,000	150.00/M	2SB1731TL	
TSMT-3	12	15	2	680	0.18	1A	50	2SB1690TLCT-ND	.58	11.60	34.80	3,000	174.00/M	2SB1690TL	
	30	30	1.5	680	0.37	1A	50	2SB1695TLCT-ND	.45	9.00	27.00	3,000	135.00/M	2SB1695TL	
30	30	3	680	0.25	1.5A	30	2SB1708TLCT-ND	.78	15.66	46.98	3,000	248.00/M	2SB1708TL		
SPT	20	20	3	390	0.5	2A	100	2SA1585STPQCT-ND‡	.45	9.00	27.00				