

开关二极管


包装	电路	VRM (V)	VR (V)	IFM (mA)	IO (mA)	Digi-Key 零件编号	剪切带价格			带卷*		Rohm 零件编号
							1	25	100	数量	价格	
SOD-323	—	40	80	225	100	1SS355TE-17CT-ND	.26	3.75	9.75	3,000	35.00/M	1SS355TE-17
	—	30	35	225	100	1SS380TE-17CT-ND	.43	6.25	16.25	3,000	59.00/M	1SS380TE-17
	—	—	50	50	—	RN731VTE-17CT-ND	.41	7.50	21.12	3,000	86.00/M	RN731VTE-17
SOD-523	—	90	80	225	100	1SS400TE61CT-ND	.34	5.00	13.00	3,000	47.00/M	1SS400TE61
SOT-23	G	85	70	450	—	BAW56T116CT-ND	.43	6.25	16.25	3,000	59.00/M	BAW56T116
SOT-323	E	80	80	300	100	DAN202UT106CT-ND	.44	6.50	16.90	3,000	61.00/M	DAN202UT106
	G	80	80	300	100	DAP202UT106CT-ND	.41	6.00	15.60	3,000	56.00/M	DAP202UT106
	E	—	35	—	—	DAN235UT106CT-ND	.43	7.31	20.28	3,000	78.00/M	DAN235UT106
SOT-343	C	80	80	300	100	DA227TLCT-ND	.40	7.75	22.32	3,000	105.00/M	DA227TL
SOT-346	E	80	80	300	100	DAN202KT146CT-ND	.36	5.25	13.65	3,000	49.00/M	DAN202KT146
	G	80	80	300	100	DAP202KT146CT-ND	.36	5.25	13.65	3,000	49.00/M	DAP202KT146
	B	80	80	300	100	DAN217T146CT-ND	.44	6.50	16.90	3,000	61.00/M	DAN217T146
	B	20	20	200	100	DA204KT146CT-ND	.49	7.25	18.85	3,000	68.00/M	DA204KT146
SOT-353	H	80	80	80	25	UMN1NCT-ND	.46	8.88	25.56	3,000	121.00/M	UMN1N
SOT-416	E	80	80	300	100	DAN222TLCT-ND	.49	7.25	18.85	3,000	68.00/M	DAN222TL
	G	80	80	300	100	DAP222TLCT-ND	.37	5.50	14.30	3,000	52.00/M	DAP222TL
	B	20	20	200	100	DA221TLCT-ND	.34	5.81	16.12	3,000	62.00/M	DA221TL
SOT-457	I	80	80	300	100	IMN10T108CT-ND	.41	7.88	22.68	3,000	107.00/M	IMN10T108
VMD2	—	90	80	225	100	1SS400G2RCT-ND	.46	6.75	17.55	8,000	54.00/M	1SS400G2R
VMD3	B	20	20	200	100	DA221MT2LCT-ND	.44	7.50	20.80	8,000	72.00/M	DA221MT2L
	E	80	80	300	100	DAN222MT2LCT-ND	.44	7.50	20.80	8,000	72.00/M	DAN222MT2L
	G	80	80	300	100	DAP222MT2LCT-ND	.49	7.25	18.85	8,000	58.00/M	DAP222MT2L
LL-34	—	250	220	625	200	RLS245TE-11CT-ND	.29	4.25	11.05	2,500	40.00/M	RLS245TE-11
	—	100	75	450	150	RLS4148TE-11CT-ND	.36	4.80	10.80	2,500	32.00/M	RLS4148TE-11
	—	100	75	450	150	RLS4448TE-11CT-ND	.34	5.00	13.00	2,500	47.00/M	RLS4448TE-11
	—	50	50	600	200	RLS4150TE-11CT-ND	.36	5.25	13.65	2,500	49.00/M	RLS4150TE-11
SC-74A	H	80	80	80	25	FMN1T148CT-ND	.44	8.50	24.48	3,000	116.00/M	FMN1T148

* 将 CT-ND 改为 TR-ND, 即为带卷包装的零件编号。 † 将 CT-ND 改为 TB-ND, 即为带盒包装的零件编号。

齐纳二极管



尺寸: mm

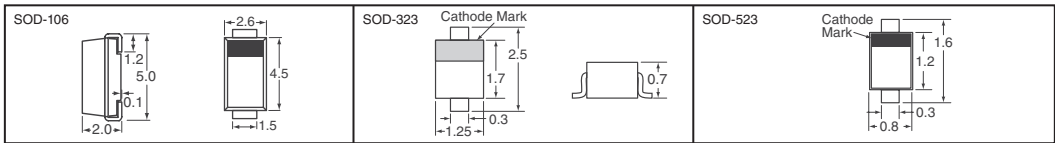

技术规格:
PTZ 系列: 1000 mW
UDZ 系列: 200 mW
EDZ 系列: 150 mW

包装	齐纳电压		电阻 Ω		反向电流 IR (μA)		Digi-Key 零件编号	剪切带价格			带卷*		Rohm 零件编号
	最小	最大	最大	Iz (mA) 时	最大	VR (V)		1	25	100	数量	价格	
SOD-106	4.300	4.800	15	40.0	20.0	1.0	PTZTE254.3BCT-ND	.50	9.63	27.72	1,500	139.00/M	PTZTE254.3B
	5.100	5.700	8	40.0	20.0	1.0	PTZTE255.1BCT-ND	.50	9.63	27.72	1,500	139.00/M	PTZTE255.1B
	7.500	8.400	4	40.0	20.0	4.0	PTZTE257.5BCT-ND	.50	9.63	27.72	1,500	139.00/M	PTZTE257.5B
	12.000	13.500	8	20.0	10.0	9.0	PTZTE2512BCT-ND	.50	9.63	27.72	1,500	139.00/M	PTZTE2512B
	18.000	20.300	12	20.0	10.0	13.0	PTZTE2518BCT-ND	.50	9.63	27.72	1,500	139.00/M	PTZTE2518B
	27.000	30.800	16	10.0	10.0	21.0	PTZTE2527BCT-ND	.50	9.63	27.72	1,500	139.00/M	PTZTE2527B
SOD-323	3.600	3.845	100	5.0	10.0	1.0	UDZSTE-173.6BCT-ND	.49	7.25	18.85	3,000	68.00/M	UDZSTE-173.6B
	3.890	4.160	100	5.0	5.0	1.0	UDZSTE-173.9BCT-ND	.49	7.25	18.85	3,000	68.00/M	UDZSTE-173.9B
	4.170	4.430	100	5.0	5.0	1.0	UDZSTE-174.3BCT-ND	.43	6.25	16.25	3,000	59.00/M	UDZSTE-174.3B
	4.980	5.200	80	5.0	2.0	1.5	UDZSTE-175.1BCT-ND	.43	6.25	16.25	3,000	59.00/M	UDZSTE-175.1B
	5.490	5.730	60	5.0	1.0	2.5	UDZSTE-175.6BCT-ND	.43	6.25	16.25	3,000	59.00/M	UDZSTE-175.6B
	6.060	6.330	60	5.0	1.0	3.0	UDZSTE-176.2BCT-ND	.43	6.25	16.25	3,000	59.00/M	UDZSTE-176.2B
	6.650	6.930	40	5.0	0.5	3.5	UDZSTE-176.8BCT-ND	.41	6.00	15.60	3,000	56.00/M	UDZSTE-176.8B
	7.280	7.600	30	5.0	0.5	4.0	UDZSTE-177.5BCT-ND	.43	6.25	16.25	3,000	59.00/M	UDZSTE-177.5B
	8.850	9.230	30	5.0	0.5	6.0	UDZSTE-179.1BCT-ND	.43	6.25	16.25	3,000	59.00/M	UDZSTE-179.1B
	9.770	10.210	30	5.0	0.1	7.0	UDZSTE-1710BCT-ND	.43	6.25	16.25	3,000	59.00/M	UDZSTE-1710B
	11.740	12.240	30	5.0	0.1	9.0	UDZSTE-1712BCT-ND	.49	7.25	18.85	3,000	68.00/M	UDZSTE-1712B
	14.340	14.980	42	5.0	0.1	11.0	UDZSTE-1715BCT-ND	.49	7.25	18.85	3,000	68.00/M	UDZSTE-1715B
17.560	18.350	65	5.0	0.1	13.0	UDZSTE-1718BCT-ND	.49	7.25	18.85	3,000	68.00/M	UDZSTE-1718B	
21.540	22.470	100	5.0	0.1	17.0	UDZSTE-1722BCT-ND	.49	7.25	18.85	3,000	68.00/M	UDZSTE-1722B	
26.190	27.530	150	5.0	0.1	21.0	UDZSTE-1727BCT-ND	.49	7.25	18.85	3,000	68.00/M	UDZSTE-1727B	
SOD-523	3.600	3.845	100	5.0	10.0	1.0	EDZTE613.6BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE613.6B
	3.890	4.160	100	5.0	5.0	1.0	EDZTE613.9BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE613.9B
	4.170	4.430	100	5.0	5.0	1.0	EDZTE614.3BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE614.3B
	4.550	4.750	100	5.0	2.0	1.0	EDZTE614.7BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE614.7B
	6.650	6.930	40	5.0	0.5	3.5	EDZTE616.8BCT-ND	.43	7.03	20.28	3,000	78.00/M	EDZTE616.8B
	7.280	7.600	30	5.0	0.5	4.0	EDZTE617.5BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE617.5B
	8.020	8.360	30	5.0	0.5	5.0	EDZTE618.2BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE618.2B
	8.850	9.230	30	5.0	0.5	6.0	EDZTE619.1BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE619.1B
	9.770	10.210	30	5.0	0.1	7.0	EDZTE6110BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE6110B
	10.760	11.220	30	5.0	0.1	8.0	EDZTE6111BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE6111B
	11.740	12.240	30	5.0	0.1	9.0	EDZTE6112BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE6112B
	12.910	13.490	37	5.0	0.1	10.0	EDZTE6113BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE6113B
	14.340	14.980	42	5.0	0.1	11.0	EDZTE6115BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE6115B
	15.850	16.510	50	5.0	0.1	12.0	EDZTE6116BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE6116B
	17.560	18.350	65	5.0	0.1	13.0	EDZTE6118BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE6118B
	19.520	20.390	85	5.0	0.1	15.0	EDZTE6120BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE6120B
	21.540	22.470	100	5.0	0.1	17.0	EDZTE6122BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE6122B
	23.720	24.780	120	5.0	0.1	19.0	EDZTE6124BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE6124B
	26.190	27.530	150	2.0	0.1	21.0	EDZTE6127BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE6127B
	29.190	30.690	200	2.0	0.1	23.0	EDZTE6130BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE6130B
	32.150	33.790	250	2.0	0.1	25.0	EDZTE6133BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE6133B
	35.070	36.870	300	2.0	0.1	27.0	EDZTE6136BCT-ND	.38	7.03	19.80	3,000	81.00/M	EDZTE6136B

* 将 CT-ND 改为 TR-ND, 即为带卷包装的零件编号。


齐纳二极管阵列 - SOT-353



尺寸: mm

图	电压		最大电阻	逆向电流	Digi-Key 零件编号	剪切带价格			带卷*		Rohm 零件编号
	最小	最大				1	25	100	数量	价格	
1	6.47	7.14	40Ω	0.5μA	UMZ6.8ENCT-ND	.46	8.44	23.76	3,000	97.00/M	UMZ6.8EN
2	6.47	7.14	—	0.5μA	VMZ6.8NT2LCT-ND	.47	8.59	24.20	8,000	94.00/M	VMZ6.8NT2L

* 将 CT-ND 改为 TR-ND, 即为带卷包装的零件编号。

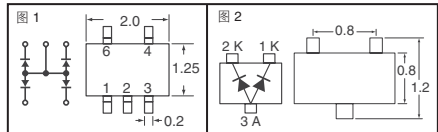

Digi-Reel® Digi-Reel® 中含有大多数的 SMT 切割零件。将 1-ND 改为 6-ND, 或将 CT-ND 改为 DKR-ND, 即为 Digi-Reel 零件编号。请参见第 2 页上的 Digi-Key® 服务以获得更多信息。

全部产品均以美元计价。 免费电话: 10800-1527031 (China Telecom - 中国电信) — 10800-8527031 (CNCG - 中国网通)

digikkey.com.cn — 电话: (852) 3104 0500 — 传真: (852) 3104 0686

(CN082-09) 1453