


ECS INC. VC-TCXO 和 VCXO 振荡器

图	频率 (MHz)	电源电压	Digi-Key 零件编号	剪切带 单价			ECS 零件编号
				1	10	100	
VC-TCXO, -40°C ~ 85°C, ±2.5ppm							
1	10.00	3.0	X493CT-ND	15.13	12.38	11.00	500 4950.00 VC-TXO-39SM-100-TR
	13.00	3.0	X490CT-ND	15.13	12.38	11.00	500 4950.00 VC-TXO-39SM-130-TR
	16.80	3.0	X491CT-ND	15.13	12.38	11.00	500 4950.00 VC-TXO-39SM-168-TR
	19.44	3.0	X492CT-ND	15.13	12.38	11.00	500 4950.00 VC-TXO-39SM-194.4-TR
	10.00	3.0	X1126CT-ND	15.13	12.38	11.00	500 4950.00 VC-TXO-39SMX-100-TR
	12.80	3.0	X1127CT-ND	15.13	12.38	11.00	500 4950.00 VC-TXO-39SMX-128-TR
	13.00	3.0	X1128CT-ND	15.13	12.38	11.00	500 4950.00 VC-TXO-39SMX-130-TR
	16.80	3.0	X1129CT-ND	15.13	12.38	11.00	500 4950.00 VC-TXO-39SMX-168-TR
	19.44	3.0	X1130CT-ND	15.13	12.38	11.00	500 4950.00 VC-TXO-39SMX-194.4-TR
	2	12.00	3.0	XC1018CT-ND	17.85	16.07	13.39
12.80		3.0	XC348CT-ND	14.85	13.37	11.14	1,000 7425.00 VC-TXO-35SM-128-B-TR
13.00		3.0	XC1019CT-ND	17.85	16.07	13.39	1,000 8925.00 VC-TXO-35SM-130-B-TR
14.40		3.0	XC1020CT-ND	17.85	16.07	13.39	500 5355.00 VC-TXO-35SM-144-B-TR
16.80		3.0	XC349CT-ND	14.85	13.37	11.14	1,000 7425.00 VC-TXO-35SM-168-B-TR
19.20		3.0	XC1021CT-ND	17.85	16.07	13.39	500 5355.00 VC-TXO-35SM-192-B-TR
19.44		3.0	XC350CT-ND	14.85	13.37	11.14	1,000 7425.00 VC-TXO-35SM-194-B-TR
10.00		3.0	XC1618CT-ND	9.57	8.62	7.18	1,000 4785.00 VC-TXO-23SM-100-B
19.20		3.0	XC1462CT-ND	6.57	5.92	4.93	1,000 3285.00 VC-TXO-23SM-192-B
19.68		3.0	XC1463CT-ND	6.57	5.92	4.93	1,000 3285.00 VC-TXO-23SM-196.8-B
3	20.00	3.0	XC1464CT-ND	6.57	5.92	4.93	1,000 3285.00 VC-TXO-23SM-200-B
	26.00	3.0	XC1465CT-ND	6.57	5.92	4.93	1,000 3285.00 VC-TXO-23SM-260-B
VCXOs, -40°C ~ 85°C, ±50ppm - 符合 RoHS 规范要求							
4	19.44	3.3	XC1110CT-ND	3.87	3.49	2.91	1,000 1935.00 ECS-VXO-73-19.440-TR
	20.00	3.3	XC1111CT-ND	3.87	3.49	2.91	— — ECS-VXO-73-20.00-TR
	27.00	3.3	XC1112CT-ND	3.87	3.49	2.91	1,000 1935.00 ECS-VXO-73-27.00-TR
	32.77	3.3	XC1113CT-ND	3.87	3.49	2.91	1,000 1935.00 ECS-VXO-73-32.768-TR
	35.33	3.3	XC1114CT-ND	3.87	3.49	2.91	1,000 1935.00 ECS-VXO-73-35.328-TR
	40.00	3.3	XC1115CT-ND	4.77	4.30	3.58	1,000 2385.00 ECS-VXO-73-40.00-TR
5	44.74	3.3	XC1116CT-ND	5.67	5.11	4.26	1,000 2835.00 ECS-VXO-73-44.736-TR
	27.00	2.8	XC1487CT-ND	27.63	24.87	20.73	500 6907.50 ECS-2532VXO-270B-2.8
54.00	2.8	XC1488CT-ND	27.63	24.87	20.73	500 6907.50 ECS-2532VXO-540B-2.8	

◆符合 RoHS 规范要求 †将 CT-ND 改为 TR-ND, 即为带卷包装的零件编号。

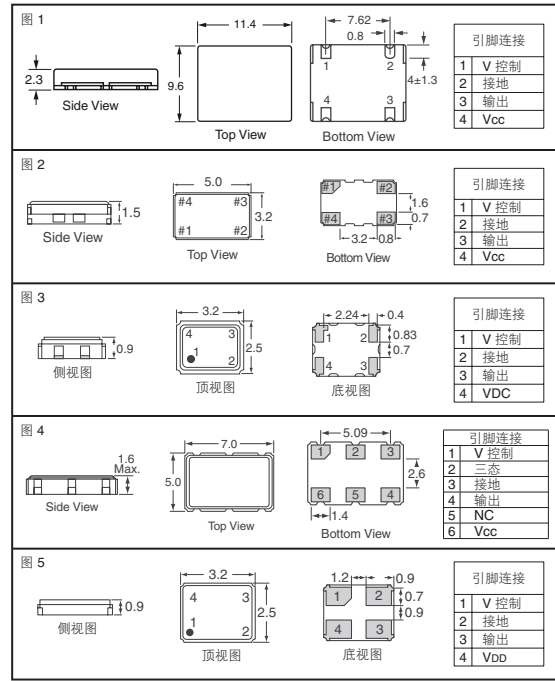

通孔振荡器

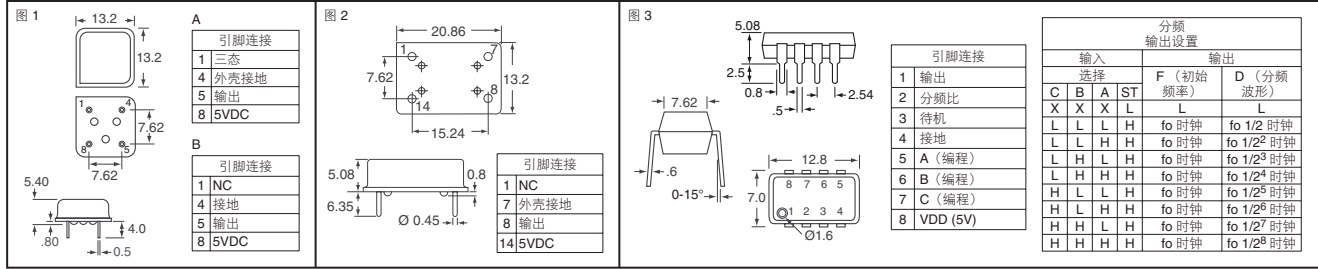


图	频率 (MHz)	Digi-Key 零件编号	单价			ECS 零件编号
			1	10	100	
ECS-2200B, 半尺寸振荡器, 5.0V, 0°C ~ 70°C, ±50ppm						
1A	4.00000	XC259-ND	2.63	2.37	1.89	1.68 ECS-2200B-040
	4.91520	XC260-ND	2.63	2.37	1.89	1.68 ECS-2200B-049
	6.00000	XC261-ND	2.63	2.37	1.89	1.68 ECS-2200B-060
	6.14400	XC262-ND	2.63	2.37	1.89	1.68 ECS-2200B-061
	7.37280	XC263-ND	2.63	2.37	1.89	1.68 ECS-2200B-073
	8.00000	XC264-ND	2.63	2.37	1.89	1.68 ECS-2200B-080
	9.21600	XC265-ND	2.63	2.37	1.89	1.68 ECS-2200B-092.1
	9.83040	XC266-ND	2.63	2.37	1.89	1.68 ECS-2200B-098
	10.00000	XC267-ND	2.63	2.37	1.89	1.68 ECS-2200B-100
	11.05920	XC268-ND	2.63	2.37	1.89	1.68 ECS-2200B-110.5
	12.00000	XC269-ND	2.63	2.37	1.89	1.68 ECS-2200B-120
	14.31818	XC270-ND	2.63	2.37	1.89	1.68 ECS-2200B-143
	16.00000	XC271-ND	2.63	2.37	1.89	1.68 ECS-2200B-160
	18.43200	XC272-ND	2.63	2.37	1.89	1.68 ECS-2200B-184
	19.66080	XC273-ND	2.63	2.37	1.89	1.68 ECS-2200B-196
	20.00000	XC274-ND	2.63	2.37	1.89	1.68 ECS-2200B-200
	24.00000	XC275-ND	2.63	2.37	1.89	1.68 ECS-2200B-240
	25.00000	XC276-ND	2.63	2.37	1.89	1.68 ECS-2200B-250
	28.32000	XC277-ND	2.63	2.37	1.89	1.68 ECS-2200B-283
	32.00000	XC278-ND	2.63	2.37	1.89	1.68 ECS-2200B-320
40.00000	XC279-ND	2.63	2.37	1.89	1.68 ECS-2200B-400	
48.00000	XC280-ND	2.63	2.37	1.89	1.68 ECS-2200B-480	
50.00000	XC281-ND	2.63	2.37	1.89	1.68 ECS-2200B-500	
66.66600	XC282-ND	2.63	2.37	1.89	1.68 ECS-2200B-666	
80.00000	XC283-ND	2.63	2.37	1.89	1.68 ECS-2200B-800	
ECS-2200BX, 半尺寸振荡器, 5.0V, 0°C ~ 70°C, ±50ppm - 符合 RoHS 规范要求						
1A	4.00000	XC1178-ND	2.63	2.37	1.89	1.68 ECS-2200BX-040
	4.91520	XC1179-ND	2.63	2.37	1.89	1.68 ECS-2200BX-049
	6.00000	XC1180-ND	2.63	2.37	1.89	1.68 ECS-2200BX-060
	7.37280	XC1181-ND	2.63	2.37	1.89	1.68 ECS-2200BX-073
	8.00000	XC1182-ND	2.63	2.37	1.89	1.68 ECS-2200BX-080
	9.83040	XC1183-ND	2.63	2.37	1.89	1.68 ECS-2200BX-098
	10.00000	XC1184-ND	2.63	2.37	1.89	1.68 ECS-2200BX-100
	11.05920	XC1185-ND	2.63	2.37	1.89	1.68 ECS-2200BX-110.5
	16.00000	XC1186-ND	2.63	2.37	1.89	1.68 ECS-2200BX-160
	19.66080	XC1187-ND	2.63	2.37	1.89	1.68 ECS-2200BX-196

图	频率 (MHz)	Digi-Key 零件编号	单价				ECS 零件编号	
			1	10	100	500		
1A	20.00000	XC1188-ND	2.63	2.37	1.89	1.68	ECS-2200BX-200	
	24.00000	XC1189-ND	2.63	2.37	1.89	1.68	ECS-2200BX-240	
	32.00000	XC1190-ND	2.63	2.37	1.89	1.68	ECS-2200BX-320	
	40.00000	XC1191-ND	2.63	2.37	1.89	1.68	ECS-2200BX-400	
	48.00000	XC1192-ND	2.63	2.37	1.89	1.68	ECS-2200BX-480	
	50.00000	XC1193-ND	2.63	2.37	1.89	1.68	ECS-2200BX-500	
	80.00000	XC1194-ND	2.63	2.37	1.89	1.68	ECS-2200BX-800	
	ECS-2100A, 半尺寸振荡器, 5.0V, 0°C ~ 70°C, ±100ppm							
	1B	1.000000	XC229-ND	2.13	1.92	1.53	1.36	ECS-2100A-010
		1.228800	XC230-ND	2.13	1.92	1.53	1.36	ECS-2100A-012.2
1.843200		XC231-ND	2.13	1.92	1.53	1.36	ECS-2100A-018	
2.000000		XC232-ND	2.13	1.92	1.53	1.36	ECS-2100A-020	
2.457600		XC233-ND	2.13	1.92	1.53	1.36	ECS-2100A-024	
3.579545		XC235-ND	2.13	1.92	1.53	1.36	ECS-2100A-035	
3.686400		XC234-ND	2.13	1.92	1.53	1.36	ECS-2100A-036	
4.000000		XC202-ND	2.13	1.92	1.53	1.36	ECS-2100A-040	
4.915200		XC236-ND	2.13	1.92	1.53	1.36	ECS-2100A-049	
5.000000		XC237-ND	2.13	1.92	1.53	1.36	ECS-2100A-050	
5.068800		XC238-ND	2.13	1.92	1.53	1.36	ECS-2100A-051	
6.000000		XC239-ND	2.13	1.92	1.53	1.36	ECS-2100A-060	
6.144000		XC240-ND	2.13	1.92	1.53	1.36	ECS-2100A-061	
7.372800		XC208-ND	2.13	1.92	1.53	1.36	ECS-2100A-073.2	
8.000000		XC209-ND	2.13	1.92	1.53	1.36	ECS-2100A-080	
9.216000		XC241-ND	2.13	1.92	1.53	1.36	ECS-2100A-092.1	
9.830400		XC242-ND	2.13	1.92	1.53	1.36	ECS-2100A-098.3	
10.000000		XC243-ND	2.13	1.92	1.53	1.36	ECS-2100A-100	
11.059200		XC244-ND	2.13	1.92	1.53	1.36	ECS-2100A-110.5	
12.000000		XC245-ND	2.13	1.92	1.53	1.36	ECS-2100A-120	
14.318180		XC246-ND	2.13	1.92	1.53	1.36	ECS-2100A-143	
14.745600		XC247-ND	2.13	1.92	1.53	1.36	ECS-2100A-147.4	
16.000000		XC216-ND	2.13	1.92	1.53	1.36	ECS-2100A-160	
16.257000		XC248-ND	2.13	1.92	1.53	1.36	ECS-2100A-162.5	
18.000000		XC249-ND	2.13	1.92	1.53	1.36	ECS-2100A-180	

(续下页)

全部产品均以美元计价。 免费电话: 10800-1527031 (China Telecom - 中国电讯) — 10800-8527031 (CNCG - 中国网通)

digikkey.com.cn — 电话: (852) 3104 0500 — 传真: (852) 3104 0686

(CN082-09) 1471