


图	中心频率 (MHz)	通带 (kHz)	极数	Digi-Key 零件编号	剪切带 单价			带卷†		ECS 零件编号
					1	10	100	数量	价格	
SMD										
1	21.4	7.5	2	X715CT-ND	8.10	7.29	6.08	500	2025.00	ECS-96SMF21A7.5
	21.4	15	2	X713CT-ND	7.31	6.08	4.84	1,000	3375.00	ECS-96SMF21A15
	21.4	20	2	X716CT-ND	8.10	7.29	6.08	500	2025.00	ECS-96SMF21A20
	21.4	30	2	X717CT-ND	8.31	7.48	6.24	500	2077.50	ECS-96SMF21A30
	45	30	2	X714CT-ND	10.56	8.78	6.99	1,000	4875.00	ECS-96SMF45A30
	45	7.5	4	X718CT-ND	27.99	25.20	21.00	500	6997.50	ECS-75SMF45A7.5B
2	45	30	4	X719CT-ND	27.99	25.20	21.00	500	6997.50	ECS-75SMF45A30B
	45	15	2	X720CT-ND	21.00	18.90	15.75	500	5250.00	ECS-38SMF45A15
45	30	2	X721CT-ND	21.00	18.90	15.75	500	5250.00	ECS-38SMF45A30	
通孔										
3	10.7	7.5	2	X701-ND†	5.20	4.32	3.44	—	—	ECS-10.7-7.5A
	10.7	7.5	4	X702-ND†	12.03	9.99	7.96	—	—	ECS-10.7-7.5B
	10.7	15	2	X703-ND†	3.09	2.57	2.05	—	—	ECS-10.7-15A
	10.7	15	4	X704-ND†	6.34	5.27	4.20	—	—	ECS-10.7-15B
	10.7	30	2	X705-ND†	4.23	3.51	2.80	—	—	ECS-10.7-30A
10.7	30	4	X706-ND†	8.78	7.29	5.81	—	—	ECS-10.7-30B	
4	21.4	7.5	2	X707-ND†	4.39	3.65	2.91	—	—	ECS-21K-7.5A
	21.4	7.5	4	X708-ND†	10.24	8.51	6.78	—	—	ECS-21K-7.5B
	21.4	15	2	X709-ND†	4.39	3.65	2.91	—	—	ECS-21K-15A
	21.4	15	4	X710-ND†	10.24	8.51	6.78	—	—	ECS-21K-15B
	21.4	30	2	X711-ND†	4.39	3.65	2.91	—	—	ECS-21K-30A
	21.4	30	4	X712-ND†	10.24	8.51	6.78	—	—	ECS-21K-30B

† 将 CT-ND 改为 TR-N, 即为带卷包装的零件编号。  
‡ 散装  
§ 通孔 4 极滤波器以匹配的形式封装。

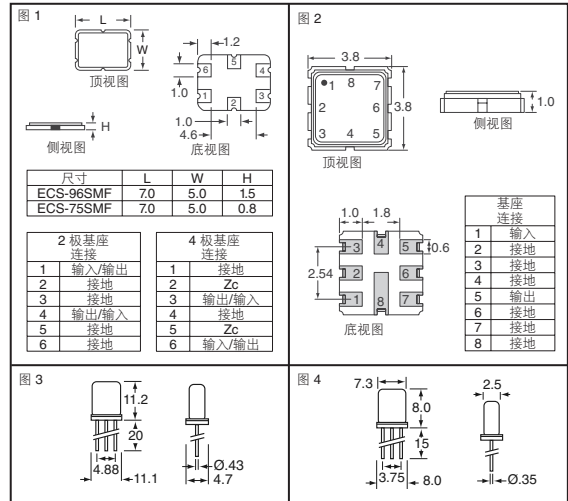


### 陶瓷谐振器 - 表面贴装型

CR-2 系列: • 频率精度:  $\pm 0.5\%$  • 温度稳定性:  $-20^{\circ}\text{C} \sim 80^{\circ}\text{C}$ ,  $\pm 0.3\%$  • 十年老化:  $\pm 0.5\%$  • 内置电容 CR-2B: 10.0 ~ 12.0MHz 30pF, 16.0 ~ 20.0MHz 15pF  $\pm 20\%$   
HFR 系列: • 频率精度:  $\pm 0.5\%$  • 温度稳定性:  $-20^{\circ}\text{C} \sim 80^{\circ}\text{C}$ ; 20.0 ~ 30.0MHz  $\pm 0.4\%$ ; 40.0 ~ 50.0MHz  $\pm 0.3\%$  • 十年老化:  $\pm 0.3\%$  • 内置电容 HFR-B: 8pF  $\pm 20\%$   
SR1 系列: • 频率精度:  $\pm 0.5\%$  • 温度稳定性:  $-20^{\circ}\text{C} \sim 80^{\circ}\text{C}$ ,  $\pm 0.3\%$  • 十年老化:  $\pm 0.3\%$  • 内置电容 SR1-B: 30pF  $\pm 20\%$


图	系列	频率 (MHz)	Digi-Key 零件编号	剪切带 单价			带卷†		ECS 零件编号
				1	10	100	数量	价格	
1	ECS-CR2-A	10.00	XC1102CT-ND	.51	.46	.39	1,000	255.00	ECS-CR2-10.00-A-TR
		12.00	XC1103CT-ND	.51	.46	.39	1,000	255.00	ECS-CR2-12.00-A-TR
		16.00	XC1104CT-ND	.51	.46	.39	1,000	255.00	ECS-CR2-16.00-A-TR
2	ECS-CR2-B	10.00	XC1105CT-ND	.51	.46	.39	1,000	255.00	ECS-CR2-20.00-A-TR
		10.00	XC1106CT-ND	.57	.52	.43	1,000	285.00	ECS-CR2-10.00-B-TR
		12.00	XC1107CT-ND	.57	.52	.43	1,000	285.00	ECS-CR2-12.00-B-TR
	ECS-HFR-B	16.00	XC1108CT-ND	.57	.52	.43	1,000	285.00	ECS-CR2-16.00-B-TR
		20.00	XC1109CT-ND	.57	.52	.43	1,000	285.00	ECS-CR2-20.00-B-TR
		20.00	XC1094CT-ND	.57	.52	.43	2,000	285.00/M	ECS-HFR-20.00-B-TR
3	ECS-SR1-A	24.00	XC1095CT-ND	.57	.52	.43	—	—	ECS-HFR-24.00-B-TR
		25.00	XC1096CT-ND	.57	.52	.43	—	—	ECS-HFR-25.00-B-TR
		27.00	XC1097CT-ND	.57	.52	.43	—	—	ECS-HFR-27.00-B-TR
		30.00	XC1098CT-ND	.57	.52	.43	1,000	285.00	ECS-HFR-30.00-B-TR
		40.00	XC1099CT-ND	.57	.52	.43	1,000	285.00	ECS-HFR-40.00-B-TR
	ECS-SR1-B	48.00	XC1100CT-ND	.57	.52	.43	—	—	ECS-HFR-48.00-B-TR
		3.58	X932CT-ND	.70	.60	.47	2,500	280.00/M	ECS-SR1-3.58-A-TR
		4.00	X933CT-ND	.70	.60	.47	2,500	280.00/M	ECS-SR1-4.00-A-TR
		4.19	X934CT-ND	.70	.60	.47	2,500	280.00/M	ECS-SR1-4.19-A-TR
		6.00	X935CT-ND	.70	.60	.47	2,500	280.00/M	ECS-SR1-6.00-A-TR
4	ECS-SR1-B	8.00	X936CT-ND	.70	.60	.47	2,500	280.00/M	ECS-SR1-8.00-A-TR
		3.58	X927CT-ND	.77	.66	.52	2,500	308.00/M	ECS-SR1-3.58-B-TR
		4.00	X928CT-ND	.77	.66	.52	2,500	308.00/M	ECS-SR1-4.00-B-TR
	4.19	X929CT-ND	.77	.66	.52	2,500	308.00/M	ECS-SR1-4.19-B-TR	
	6.00	X930CT-ND	.77	.66	.52	2,500	308.00/M	ECS-SR1-6.00-B-TR	
	8.00	X931CT-ND	.77	.66	.52	2,500	308.00/M	ECS-SR1-8.00-B-TR	

† 将 CT-ND 改为 TR-N, 即为带卷包装的零件编号。

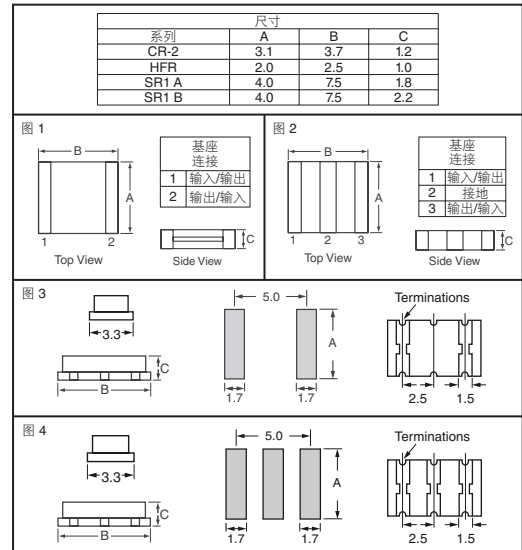

### 陶瓷谐振器 - 通孔

图	型号/系列	频率	Digi-Key 零件编号	1	10	100	ECS 零件编号
1	ZTB	200kHz	X919-ND	.84	.70	.56	ZTB200
		400kHz	X920-ND	.68	.57	.45	ZTB400P
		455kHz	X921-ND	.68	.57	.45	ZTB455E
		500kHz	X922-ND	.68	.57	.45	ZTB500E
		540kHz	X923-ND	.68	.57	.45	ZTB540P
		640kHz	X924-ND	.68	.57	.45	ZTB640P
		800kHz	X925-ND	.68	.57	.45	ZTB800J
2	ZTT	1,000kHz	X926-ND	.68	.57	.45	ZTB1000J
		3.58MHz	X901-ND	.54	.45	.36	ZTT-3.58MG
		3.68MHz	XC1017-ND	.50	.45	.36	ZTT-3.68MG
		4MHz	X902-ND	.54	.45	.36	ZTT-4.00MG
		4.19MHz	X903-ND	.54	.45	.36	ZTT-4.19MG
		6MHz	X904-ND	.54	.45	.36	ZTT-6.00MT
		8MHz	X905-ND	.54	.45	.36	ZTT-8.00MT
		10MHz	X906-ND	.54	.45	.36	ZTT-10.00MT
		12MHz	X907-ND	.54	.45	.36	ZTT-12.00MT
		16MHz	X908-ND	.54	.45	.36	ZTT-16.00MX
3	ZTA	20MHz	X909-ND	.54	.45	.36	ZTT-20.00MX
		6MHz	X913-ND	.49	.41	.33	ZTA-6.00MT
		8MHz	X914-ND	.49	.41	.33	ZTA-8.00MT
		10MHz	X915-ND	.49	.41	.33	ZTA-10.00MT
		12MHz	X916-ND	.49	.41	.33	ZTA-12.00MT
		16MHz	X917-ND	.49	.41	.33	ZTA-16.00MX
		20MHz	X918-ND	.49	.41	.33	ZTA-20.00MX
4	ZTA	3.58MHz	X910-ND	.49	.41	.33	ZTA-3.58MG
		4MHz	X911-ND	.49	.41	.33	ZTA-4.00MG
		4.19MHz	X912-ND	.49	.41	.33	ZTA-4.19MG

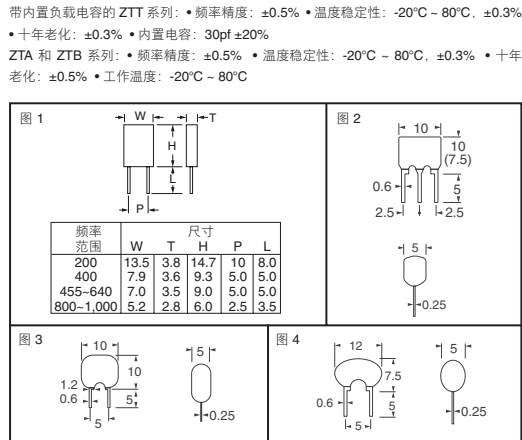

全部产品均以美元计价。 免费电话: 10800-1527031 (China Telecom - 中国电讯) — 10800-8527031 (CNCG - 中国网通)

digikoy.com.cn — 电话: (852) 3104 0500 — 传真: (852) 3104 0686

(CN082-09) 1521