

技术规格: 电容公差: ±20%


**LS 系列:**

温度范围: -40°C ~ 85°C (160 ~ 250V),  
-25°C ~ 85°C (400 ~ 450V)

**GU 系列:**

温度范围: -40°C ~ 105°C (160 ~ 250V),  
-25°C ~ 105°C (400 ~ 450V)

**LS 系列**

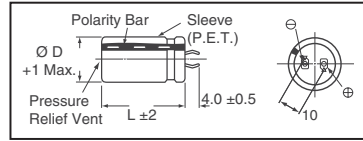

W.V. (VDC)	电容 (µF)	外壳尺寸 ØD x L (mm)	Tan δ	在 85°C 时的 额定 纹波电流 (mA)	Digi-Key 零件编号	价格			Nichicon 零件编号
						1	10	100	
160	270	20 x 25	0.15	1280	493-2443-ND	1.88	14.23	112.77	L2S2C271MELY
	330	20 x 25	0.15	1550	493-2444-ND	2.05	15.53	123.06	L2S2C331MELY
	390	20 x 30	0.15	1630	493-2445-ND	2.22	16.83	133.35	L2S2C391MELZ
	390	22 x 25	0.15	1630	493-2446-ND	2.22	16.83	133.35	L2S2C391MELZ
	470	20 x 30	0.15	1900	493-2447-ND	2.36	17.89	141.75	L2S2C471MELY
	470	22 x 30	0.15	1860	493-2448-ND	2.36	17.89	141.75	L2S2C471MELZ
	470	25 x 25	0.15	1860	493-2449-ND	2.48	18.76	148.68	L2S2C471MELA
	560	20 x 35	0.15	2140	493-2450-ND	2.53	19.16	151.83	L2S2C561MELY
	560	22 x 30	0.15	2150	493-2451-ND	2.53	19.16	151.83	L2S2C561MELZ
	560	25 x 25	0.15	2150	493-2452-ND	2.64	20.01	158.55	L2S2C561MELA
	680	20 x 40	0.15	2350	493-2453-ND	3.02	22.84	181.02	L2S2C681MELY
	680	22 x 35	0.15	2350	493-2454-ND	3.02	22.84	181.02	L2S2C681MELZ
	680	25 x 30	0.15	2330	493-2455-ND	2.96	22.42	177.66	L2S2C681MELA
	680	30 x 25	0.15	2330	493-2456-ND	3.20	24.19	191.73	L2S2C681MELB
	820	22 x 40	0.15	2680	493-2457-ND	3.20	24.19	191.73	L2S2C821MELZ
	820	25 x 30	0.15	2650	493-2458-ND	3.32	25.12	199.08	L2S2C821MELA
	820	30 x 25	0.15	2640	493-2459-ND	3.53	26.74	211.89	L2S2C821MELB
	1000	22 x 45	0.15	3020	493-2460-ND	3.78	28.59	226.59	L2S2C102MELZ
	1000	25 x 35	0.15	3000	493-2461-ND	3.80	28.75	227.85	L2S2C102MELA
	1000	30 x 30	0.15	2960	493-2462-ND	4.04	30.58	242.34	L2S2C102MELB
1200	25 x 40	0.15	3430	493-2464-ND	4.15	31.43	249.06	L2S2C122MELA	
	1200	30 x 30	0.15	3410	493-2465-ND	4.39	33.23	263.34	L2S2C122MELB
	1200	35 x 25	0.15	3400	493-2466-ND	4.75	35.99	285.18	L2S2C122MELC
	1500	25 x 50	0.15	3960	493-2467-ND	4.84	36.65	290.43	L2S2C152MELA
	1500	30 x 35	0.15	3960	493-2468-ND	5.10	38.64	306.18	L2S2C152MELB
	1500	35 x 30	0.15	3940	493-2469-ND	5.35	40.52	321.09	L2S2C152MELC
	1800	30 x 40	0.15	4310	493-2470-ND	6.19	46.85	371.28	L2S2C182MELA
	1800	35 x 35	0.15	4280	493-2471-ND	6.02	45.55	360.99	L2S2C182MELB
	2200	30 x 50	0.15	4960	493-2472-ND	7.28	55.12	436.80	L2S2C222MELB
	2200	35 x 40	0.15	4960	493-2473-ND	7.01	53.08	420.63	L2S2C222MELC
	2700	35 x 45	0.15	5570	493-2474-ND	8.95	67.73	536.76	L2S2C272MELC
	180	270	20 x 25	0.15	1290	493-2475-ND	2.09	15.79	125.16
330		22 x 30	0.15	1770	493-2476-ND	2.09	15.79	125.16	L2S2Z331MELY
330		22 x 25	0.15	1770	493-2477-ND	2.09	15.79	125.16	L2S2Z331MELZ
390		20 x 30	0.15	1840	493-2478-ND	2.27	17.17	136.08	L2S2Z391MELY
390		22 x 25	0.15	1840	493-2479-ND	2.27	17.17	136.08	L2S2Z391MELZ
470		20 x 35	0.15	1910	493-2480-ND	2.55	19.29	152.88	L2S2Z471MELY
470		22 x 30	0.15	1910	493-2481-ND	2.55	19.29	152.88	L2S2Z471MELZ
470		25 x 25	0.15	2080	493-2482-ND	2.64	19.98	158.34	L2S2Z471MELA
560		20 x 40	0.15	2150	493-2483-ND	2.82	21.39	169.47	L2S2Z561MELY
560		22 x 35	0.15	2250	493-2484-ND	2.82	21.39	169.47	L2S2Z561MELZ
680		25 x 25	0.15	2150	493-2485-ND	2.92	22.10	175.14	L2S2Z561MELA
680		22 x 35	0.15	2480	493-2486-ND	3.24	24.57	194.67	L2S2Z681MELZ
680	25 x 30	0.15	2500	493-2487-ND	3.34	25.25	200.13	L2S2Z681MELA	
680	30 x 25	0.15	2460	493-2488-ND	3.57	27.00	213.99	L2S2Z681MELB	
820	22 x 40	0.15	2860	493-2489-ND	3.71	28.06	222.39	L2S2Z821MELZ	
820	25 x 35	0.15	2750	493-2490-ND	3.80	28.75	227.85	L2S2Z821MELA	
820	30 x 25	0.15	2690	493-2491-ND	3.98	30.16	238.98	L2S2Z821MELB	
1000	22 x 20	0.15	3100	493-2492-ND	3.88	29.39	232.89	L2S2Z102MELZ	
1000	25 x 40	0.15	3060	493-2493-ND	4.31	32.62	258.51	L2S2Z102MELA	
1000	30 x 30	0.15	3100	493-2494-ND	4.54	34.37	272.37	L2S2Z102MELB	
1200	25 x 45	0.15	3630	493-2495-ND	4.96	37.52	297.36	L2S2Z122MELA	
1200	30 x 35	0.15	3550	493-2496-ND	5.18	39.25	311.01	L2S2Z122MELB	
1200	35 x 30	0.15	3490	493-2497-ND	5.47	41.39	328.02	L2S2Z122MELC	
1500	30 x 40	0.15	4100	493-2498-ND	5.93	44.92	355.95	L2S2Z152MELB	
1500	35 x 35	0.15	4020	493-2499-ND	6.35	48.07	380.94	L2S2Z152MELC	
1800	30 x 45	0.15	4550	493-2500-ND	6.92	52.36	414.96	L2S2Z182MELB	
1800	35 x 35	0.15	4540	493-2501-ND	7.32	55.39	438.90	L2S2Z182MELC	
2200	35 x 40	0.15	4830	493-2502-ND	8.57	64.87	514.08	L2S2Z222MELC	
2700	35 x 50	0.15	5300	493-2503-ND	9.79	74.15	587.58	L2S2Z272MELC	

W.V. (VDC)	电容 (µF)	外壳尺寸 ØD x L (mm)	Tan δ	在 85°C 时的 额定 纹波电流 (mA)	Digi-Key 零件编号	价格			Nichicon 零件编号
						1	10	100	
200	220	20 x 25	0.15	1190	493-2504-ND	2.05	15.53	123.06	L2S2D221MELY
	270	20 x 25	0.15	1390	493-2505-ND	2.09	15.79	125.16	L2S2D271MELY
	270	22 x 25	0.15	1370	493-2506-ND	2.22	16.83	133.35	L2S2D271MELZ
	330	20 x 30	0.15	1560	493-2507-ND	2.27	17.17	136.08	L2S2D331MELY
	330	22 x 25	0.15	1510	493-2508-ND	2.36	17.89	141.75	L2S2D331MELZ
	390	20 x 35	0.15	1740	493-2509-ND	2.59	19.64	155.61	L2S2D391MELY
	390	22 x 30	0.15	1730	493-2510-ND	2.59	19.64	155.61	L2S2D391MELZ
	390	25 x 25	0.15	1710	493-2511-ND	2.71	20.51	162.54	L2S2D391MELA
	470	20 x 35	0.15	2030	493-2512-ND	2.72	20.59	163.17	L2S2D471MELY
	470	22 x 30	0.15	1970	493-2513-ND	2.72	20.59	163.17	L2S2D471MELZ
	470	25 x 25	0.15	1950	493-2514-ND	2.96	22.42	177.66	L2S2D471MELA
	560	20 x 40	0.15	2180	493-2515-ND	3.20	24.19	191.73	L2S2D561MELY
	560	22 x 35	0.15	2180	493-2516-ND	3.20	24.19	191.73	L2S2D561MELZ
	560	25 x 30	0.15	2150	493-2517-ND	3.48	26.37	208.95	L2S2D561MELA
	560	30 x 25	0.15	2150	493-2518-ND	3.44	26.02	206.22	L2S2D561MELB
	680	22 x 40	0.15	2480	493-2519-ND	3.59	27.19	215.46	L2S2D681MELZ
	680	25 x 30	0.15	2480	493-2520-ND	3.66	27.69	219.45	L2S2D681MELA
	680	30 x 25	0.15	2480	493-2521-ND	3.80	28.75	227.85	L2S2D681MELB
	820	22 x 45	0.15	2810	493-2522-ND	4.04	30.58	242.34	L2S2D821MELZ
	820	25 x 35	0.15	2790	493-2523-ND	4.04	30.58	242.34	L2S2D821MELA
820	30 x 30	0.15	2800	493-2524-ND	4.28	32.38	256.62	L2S2D821MELB	
1000	22 x 50	0.15	3280	493-2525-ND	4.74	35.91	284.55	L2S2D102MELZ	
1000	25 x 40	0.15	3280	493-2526-ND	4.74	35.91	284.55	L2S2D102MELA	
1000	30 x 35	0.15	3150	493-2527-ND	4.87	36.86	292.11	L2S2D102MELB	
1200	30 x 35	0.15	3610	493-2528-ND	5.58	42.27	334.95	L2S2D122MELB	
1200	35 x 30	0.15	3570	493-2529-ND	5.83	44.12	349.65	L2S2D122MELC	
1500	30 x 45	0.15	4130	493-2530-ND	6.11	46.24	366.45	L2S2D152MELB	
1500	35 x 35	0.15	4060	493-2531-ND	6.90	52.23	413.91	L2S2D152MELC	
1800	30 x 50	0.15	4600	493-2532-ND	7.33	55.49	439.74	L2S2D182MELB	
1800	35 x 40	0.15	4590	493-2533-ND	7.85	59.44	471.03	L2S2D182MELC	
2200	35 x 45	0.15	5250	493-2534-ND	10.09	76.43	605.64	L2S2D222MELC	
180	180	20 x 25	0.15	1200	493-2535-ND	2.36	17.89	141.75	L2S2E181MELY
	220	20 x 25	0.15	1260	493-2536-ND	2.36	17.89	141.75	L2S2E221MELY
	220	22 x 25	0.15	1240	493-2537-ND	2.36	17.89	141.75	L2S2E221MELZ
	270	20 x 30	0.15	1420	493-2538-ND	2.59	19.64	155.61	L2S2E271MELY
	270	22 x 25	0.15	1500	493-2539-ND	2.59	19.64	155.61	L2S2E271MELZ
	330	20 x 35	0.15	1680	493-2540-ND	2.82	21.39	169.47	L2S2E331MELY
	330	22 x 30	0.15	1660	493-2541-ND	2.82	21.39	169.47	L2S2E331MELZ
	330	25 x 25	0.15	1610	493-2542-ND	3.03	22.92	181.65	L2S2E331MELA
	390	20 x 40	0.15	1920	493-2543-ND	3.08	23.32	184.80	L2S2E391MELY
	390	22 x 35	0.15	1880	493-2544-ND	3.08	23.32	184.80	L2S2E391MELZ
	390	25 x 30	0.15	1880	493-2545-ND	3.20	24.19	191.73	L2S2E391MELA
	470	22 x 35	0.15	2150	493-2546-ND	3.44	26.02	206.22	L2S2E471MELZ
470	25 x 35	0.15	2150	493-2547-ND	3.56	26.95	213.57	L2S2E471MELA	
470	30 x 25	0.15	2040	493-2548-ND	3.68	27.83	220.50	L2S2E471MELB	
560	22 x 40	0.15	2480	493-2549-ND	3.92	29.65	234.99	L2S2E561MELZ	
560	25 x 35	0.15	2350	493-2550-ND	3.92	29.65	234.99	L2S2E561MELA	
560	30 x 25	0.15	2350	493-2551-ND	4.15	31.43	249.06	L2S2E561MELB	
680	25 x 40	0.15	2670	493-2552-ND	4.63	35.03	277.62	L2S2E681MELA	
680	30 x 30	0.15	2710	493-2553-ND	4.63	35.03	277.62	L2S2E681MELB	
820	25 x 45	0.15	3010	493-2554-ND	5.37	40.62	321.93	L2S2E821M	



W.V. (VDC)	电容 (μF)	外壳尺寸 ØD x L (mm)	Tan δ	在 85°C 时的 额定 纹波电流 (mA)	Digi-Key 零件编号	价格			Nichicon 零件编号	
						1	10	100		
400	180	25 x 30	0.15	1440	493-2575-ND	3.30	24.96	197.82	LLS2G181MELA	
	180	30 x 25	0.15	1520	493-2576-ND	3.40	25.76	204.12	LLS2G181MELB	
	220	22 x 45	0.15	1580	493-2577-ND	3.49	26.45	209.58	LLS2G221MELZ	
	220	25 x 35	0.15	1640	493-2578-ND	3.71	28.06	222.39	LLS2G221MELA	
	220	30 x 30	0.15	1660	493-2579-ND	3.80	28.81	228.27	LLS2G221MELB	
	270	25 x 40	0.15	1790	493-2580-ND	4.10	31.06	246.12	LLS2G271MELA	
	270	30 x 30	0.15	1820	493-2581-ND	4.30	32.54	257.88	LLS2G271MELB	
	330	25 x 45	0.15	2000	493-2582-ND	4.91	37.15	294.42	LLS2G331MELA	
	330	30 x 35	0.15	2050	493-2583-ND	4.91	37.15	294.42	LLS2G331MELB	
	330	35 x 30	0.15	2050	493-2584-ND	5.31	40.17	318.36	LLS2G331MELC	
	390	30 x 40	0.15	2260	493-2585-ND	5.51	41.68	330.33	LLS2G391MELB	
	390	35 x 35	0.15	2280	493-2586-ND	5.90	44.68	354.06	LLS2G391MELC	
	470	30 x 45	0.15	2510	493-2587-ND	6.72	50.85	402.99	LLS2G471MELB	
	470	35 x 35	0.15	2510	493-2588-ND	6.72	50.85	402.99	LLS2G471MELC	
	560	30 x 50	0.15	2850	493-2589-ND	7.93	60.08	476.07	LLS2G561MELB	
	560	35 x 40	0.15	2850	493-2590-ND	7.62	57.66	456.96	LLS2G561MELC	
	680	35 x 50	0.15	3100	493-2591-ND	10.67	80.77	640.08	LLS2G681MELC	
	450	56	20 x 25	0.20	610	493-2592-ND	2.00	15.11	119.70	LLS2W560MELY
		68	20 x 30	0.20	710	493-2593-ND	2.14	16.19	128.31	LLS2W680MELY
		68	22 x 25	0.20	710	493-2594-ND	2.14	16.19	128.31	LLS2W680MELZ
82		20 x 35	0.20	800	493-2595-ND	2.29	17.33	137.34	LLS2W820MELY	
82		22 x 25	0.20	860	493-2596-ND	2.29	17.33	137.34	LLS2W820MELZ	
100		20 x 35	0.20	880	493-2597-ND	2.59	19.64	155.61	LLS2W101MELY	
100		22 x 30	0.20	950	493-2598-ND	2.59	19.64	155.61	LLS2W101MELZ	
100		25 x 25	0.20	970	493-2599-ND	2.69	20.38	161.49	LLS2W101MELA	
120		20 x 40	0.20	990	493-2600-ND	2.79	21.15	167.58	LLS2W121MELY	
120		25 x 35	0.20	1070	493-2601-ND	2.79	21.15	167.58	LLS2W121MELZ	
120		25 x 30	0.20	1090	493-2602-ND	2.89	21.92	173.67	LLS2W121MELA	
120		30 x 25	0.20	1120	493-2603-ND	3.09	23.43	185.64	LLS2W121MELB	
150		22 x 40	0.20	1180	493-2604-ND	3.30	24.96	197.82	LLS2W151MELZ	
150		25 x 30	0.20	1250	493-2605-ND	3.30	24.96	197.82	LLS2W151MELA	
150		30 x 25	0.20	1290	493-2606-ND	3.50	26.47	209.79	LLS2W151MELB	
180		22 x 45	0.20	1320	493-2607-ND	3.49	26.45	209.58	LLS2W181MELZ	
180		25 x 35	0.20	1400	493-2608-ND	3.80	28.81	228.27	LLS2W181MELA	
180		30 x 30	0.20	1450	493-2609-ND	4.22	31.96	253.26	LLS2W181MELB	
220		25 x 40	0.20	1590	493-2610-ND	4.30	32.54	257.88	LLS2W221MELA	
220		30 x 30	0.20	1640	493-2611-ND	4.30	32.54	257.88	LLS2W221MELB	
220	35 x 25	0.20	1590	493-2612-ND	4.50	34.11	270.27	LLS2W221MELC		
270	30 x 35	0.20	1830	493-2613-ND	5.31	40.17	318.36	LLS2W271MELB		
270	35 x 30	0.20	1900	493-2614-ND	5.51	41.68	330.33	LLS2W271MELC		
330	30 x 40	0.20	2120	493-2615-ND	6.41	48.52	384.51	LLS2W331MELB		
330	35 x 35	0.20	2150	493-2616-ND	6.41	48.52	384.51	LLS2W331MELC		
390	30 x 45	0.20	2350	493-2617-ND	7.33	55.46	439.53	LLS2W391MELB		
390	35 x 40	0.20	2380	493-2618-ND	7.21	54.59	432.60	LLS2W391MELC		
470	35 x 45	0.20	2680	493-2619-ND	10.14	76.80	608.58	LLS2W471MELC		
560	35 x 50	0.20	2880	493-2620-ND	11.49	87.03	689.64	LLS2W561MELC		

GU 系列

W.V. (VDC)	电容 (μF)	外壳尺寸 ØD x L (mm)	Tan δ	在 105°C 时的 额定 纹波电流 (mA)	Digi-Key 零件编号	价格			Nichicon 零件编号
						1	10	100	
160	270	20 x 25	0.15	1100	493-2621-ND	2.14	16.22	128.52	LGU2C271MELY
	330	20 x 30	0.15	1200	493-2622-ND	2.25	17.07	135.24	LGU2C331MELY
	390	20 x 30	0.15	1300	493-2623-ND	2.31	17.52	138.81	LGU2C391MELY
	390	22 x 25	0.15	1300	493-2624-ND	2.31	17.52	138.81	LGU2C391MELZ
	470	20 x 35	0.15	1340	493-2625-ND	2.54	19.24	152.46	LGU2C471MELY
	470	22 x 30	0.15	1550	493-2626-ND	2.54	19.24	152.46	LGU2C471MELZ
	470	25 x 25	0.15	1550	493-2627-ND	2.66	20.17	159.81	LGU2C471MELA
	560	20 x 40	0.15	1500	493-2628-ND	2.78	21.07	166.95	LGU2C561MELY
	560	22 x 35	0.15	1670	493-2629-ND	2.78	21.07	166.95	LGU2C561MELZ
	560	25 x 30	0.15	1670	493-2630-ND	2.90	21.97	174.09	LGU2C561MELA
	560	30 x 25	0.15	1670	493-2631-ND	3.05	23.08	182.91	LGU2C561MELB
	680	20 x 45	0.15	1700	493-2632-ND	3.13	23.72	187.95	LGU2C681MELZ
	680	22 x 40	0.15	1820	493-2633-ND	3.13	23.72	187.95	LGU2C681MELA
	680	25 x 30	0.15	1820	493-2634-ND	3.25	24.62	195.09	LGU2C681MELB
	680	30 x 25	0.15	1820	493-2635-ND	3.37	25.49	202.02	LGU2C681MELC
	820	22 x 45	0.15	2040	493-2636-ND	2.43	18.42	145.95	LGU2C821MELZ
	820	25 x 35	0.15	2040	493-2637-ND	3.60	27.27	216.09	LGU2C821MELA
	820	30 x 30	0.15	2040	493-2638-ND	3.84	29.04	230.16	LGU2C821MELB
	820	35 x 25	0.15	2040	493-2639-ND	4.07	30.79	244.02	LGU2C821MELC
	1000	22 x 50	0.15	2250	493-2640-ND	3.90	29.55	234.15	LGU2C102MELZ

W.V. (VDC)	电容 (μF)	外壳尺寸 ØD x L (mm)	Tan δ	在 105°C 时的 额定 纹波电流 (mA)	Digi-Key 零件编号	价格			Nichicon 零件编号
						1	10	100	
160	1000	25 x 40	0.15	2250	493-2641-ND	4.19	31.72	251.37	LGU2C102MELA
	1000	30 x 30	0.15	2250	493-2642-ND	4.19	31.72	251.37	LGU2C102MELB
	1000	35 x 25	0.15	2250	493-2643-ND	4.66	35.30	279.72	LGU2C102MELC
	1200	25 x 45	0.15	2490	493-2644-ND	4.77	36.12	286.23	LGU2C122MELA
	1200	30 x 35	0.15	2490	493-2645-ND	4.77	36.12	286.23	LGU2C122MELB
	1200	35 x 30	0.15	2490	493-2646-ND	5.00	37.87	300.09	LGU2C122MELC
	1500	30 x 40	0.15	2840	493-2647-ND	5.83	44.12	349.65	LGU2C152MELB
	1500	35 x 30	0.15	2840	493-2648-ND	5.83	44.12	349.65	LGU2C152MELC
	1800	30 x 45	0.15	3320	493-2649-ND	6.52	49.40	391.44	LGU2C182MELB
	1800	35 x 35	0.15	3000	493-2650-ND	6.52	49.40	391.44	LGU2C182MELC
	2200	35 x 45	0.15	3500	493-2651-ND	8.59	65.00	515.13	LGU2C222MELC
	2700	35 x 50	0.15	4000	493-2652-ND	9.30	70.44	558.18	LGU2C272MELC
	220	20 x 25	0.15	1000	493-2653-ND	2.15	16.30	129.15	LGU2Z221MELY
	270	20 x 30	0.15	1100	493-2654-ND	2.28	17.25	136.71	LGU2Z271MELY
	330	20 x 30	0.15	1200	493-2655-ND	2.36	17.89	141.75	LGU2Z331MELY
	330	22 x 25	0.15	1200	493-2656-ND	2.36	17.89	141.75	LGU2Z331MELZ
	390	20 x 35	0.15	1300	493-2657-ND	2.59	19.58	155.19	LGU2Z391MELY
	390	22 x 30	0.15	1350	493-2658-ND	2.59	19.58	155.19	LGU2Z391MELZ
	390	25 x 25	0.15	1350	493-2659-ND	2.68	20.27	160.65	LGU2Z391MELA
	470	20 x 40	0.15	1400	493-2660-ND	2.91	22.00	174.30	LGU2Z471MELY
470	22 x 35	0.15	1500	493-2661-ND	2.91	22.00	174.30	LGU2Z471MELZ	
470	25 x 30	0.15	1500	493-2662-ND	3.00	22.68	179.76	LGU2Z471MELA	
470	30 x 25	0.15	1500	493-2663-ND	3.20	24.25	192.15	LGU2Z471MELB	
560	20 x 45	0.15	1550	493-2664-ND	3.22	24.41	193.41	LGU2Z561MELY	
560	22 x 40	0.15	1670	493-2665-ND	3.22	24.41	193.41	LGU2Z561MELZ	
560	25 x 30	0.15	1670	493-2666-ND	3.31	25.10	198.87	LGU2Z561MELA	
560	30 x 25	0.15	1670	493-2667-ND	3.54	26.82	212.52	LGU2Z561MELB	
680	22 x 45	0.15	1780	493-2668-ND	3.72	28.17	223.23	LGU2Z681MELZ	
680	25 x 35	0.15	1780	493-2669-ND	3.82	28.89	228.90	LGU2Z681MELA	
680	30 x 30	0.15	1780	493-2670-ND	4.04	30.58	242.34	LGU2Z681MELB	
680	35 x 25	0.15	1780	493-2671-ND	4.42	33.44	265.02	LGU2Z681MELC	
820	22 x 50	0.15	2040	493-2672-ND	4.22	31.96	253.26	LGU2Z821MELZ	
820	25 x 40	0.15	2040	493-2673-ND	4.36	32.99	261.45	LGU2Z821MELA	
820	30 x 30	0.15	2040	493-2674-ND	4.58	34.69	274.89	LGU2Z821MELB	
820	35 x 25	0.15	2040	493-2675-ND	4.95	37.47	296.94	LGU2Z821MELC	
1000	25 x 45	0.15	2300	493-2676-ND	4.95	37.47	296.94	LGU2Z102MELA	
1000	30 x 35	0.15	2300</						



W.V. (VDC)	电容 (μF)	外壳尺寸 ØD x L (mm)	Tan δ	在 105°C 时的 额定 纹波电流 (mA)	Digi-Key 零件编号	价格			Nichicon 零件编号
						1	10	100	
220	180	20 x 25	0.15	900	493-2719-ND	2.27	17.20	136.29	LGU2P181MELY
	220	20 x 30	0.15	1000	493-2720-ND	2.34	17.73	140.49	LGU2P221MELY
	220	22 x 25	0.15	1000	493-2721-ND	2.34	17.73	140.49	LGU2P221MELZ
	270	20 x 35	0.15	1150	493-2722-ND	2.65	20.03	158.76	LGU2P271MELY
	270	22 x 30	0.15	1150	493-2723-ND	2.65	20.03	158.76	LGU2P271MELZ
	330	20 x 40	0.15	1250	493-2724-ND	2.95	22.34	177.03	LGU2P331MELY
	330	22 x 35	0.15	1250	493-2725-ND	2.95	22.34	177.03	LGU2P331MELZ
	330	25 x 25	0.15	1250	493-2726-ND	3.07	23.24	184.17	LGU2P331MELA
	390	20 x 45	0.15	1400	493-2727-ND	3.26	24.65	195.30	LGU2P391MELY
	390	22 x 35	0.15	1400	493-2728-ND	3.26	24.65	195.30	LGU2P391MELZ
	390	25 x 30	0.15	1400	493-2729-ND	3.43	26.00	206.01	LGU2P391MELA
	470	20 x 50	0.15	1450	493-2730-ND	3.62	27.37	216.93	LGU2P471MELY
	470	22 x 40	0.15	1450	493-2731-ND	3.62	27.37	216.93	LGU2P471MELZ
	470	25 x 35	0.15	1450	493-2732-ND	3.67	27.80	220.29	LGU2P471MELA
	470	30 x 25	0.15	1450	493-2733-ND	3.92	29.71	235.41	LGU2P471MELB
	560	22 x 45	0.15	1700	493-2734-ND	4.01	30.37	240.66	LGU2P561MELZ
	560	25 x 40	0.15	1700	493-2735-ND	4.28	32.38	256.62	LGU2P561MELA
	560	30 x 30	0.15	1700	493-2736-ND	4.38	33.13	262.50	LGU2P561MELB
	680	25 x 45	0.15	1780	493-2737-ND	4.81	36.41	288.54	LGU2P681MELA
	680	30 x 35	0.15	1780	493-2738-ND	4.87	36.84	291.90	LGU2P681MELZ
680	35 x 25	0.15	1780	493-2739-ND	5.23	39.59	313.74	LGU2P681MELC	
820	25 x 50	0.15	2100	493-2740-ND	5.52	41.82	331.38	LGU2P821MELA	
820	30 x 40	0.15	2100	493-2741-ND	5.47	41.45	328.44	LGU2P821MELB	
820	35 x 30	0.15	2100	493-2742-ND	6.29	47.59	377.16	LGU2P821MELC	
1000	30 x 45	0.15	2400	493-2743-ND	6.08	46.06	364.98	LGU2P102MELZ	
1000	35 x 35	0.15	2400	493-2744-ND	6.78	51.30	406.56	LGU2P102MELC	
1200	30 x 50	0.15	2600	493-2745-ND	7.45	56.39	446.88	LGU2P122MELB	
1200	35 x 40	0.15	2600	493-2746-ND	8.45	63.94	506.73	LGU2P122MELC	
1500	35 x 45	0.15	3000	493-2747-ND	9.29	70.30	557.13	LGU2P152MELC	
250	150	20 x 25	0.15	790	493-2748-ND	2.32	17.57	139.23	LGU2E151MELY
	180	20 x 30	0.15	900	493-2749-ND	2.42	18.29	144.90	LGU2E181MELY
	220	20 x 30	0.15	1000	493-2750-ND	2.54	19.24	152.46	LGU2E221MELY
	220	22 x 25	0.15	1000	493-2751-ND	2.54	19.24	152.46	LGU2E221MELZ
	270	20 x 35	0.15	1100	493-2752-ND	2.90	21.97	174.09	LGU2E271MELY
	270	22 x 35	0.15	1180	493-2753-ND	2.90	21.97	174.09	LGU2E271MELZ
	270	25 x 25	0.15	1180	493-2754-ND	3.02	22.87	181.23	LGU2E271MELA
	330	20 x 40	0.15	1200	493-2755-ND	3.25	24.62	195.09	LGU2E331MELY
	330	22 x 40	0.15	1300	493-2756-ND	3.25	24.62	195.09	LGU2E331MELZ
	330	25 x 30	0.15	1300	493-2757-ND	3.35	25.39	201.18	LGU2E331MELA
	330	30 x 25	0.15	1300	493-2758-ND	3.49	26.39	209.16	LGU2E331MELB
	390	20 x 50	0.15	1450	493-2759-ND	3.60	27.27	216.09	LGU2E391MELY
	390	22 x 45	0.15	1490	493-2760-ND	3.60	27.27	216.09	LGU2E391MELZ
	390	25 x 35	0.15	1490	493-2761-ND	3.84	29.04	230.16	LGU2E391MELA
	390	30 x 25	0.15	1490	493-2762-ND	3.84	29.04	230.16	LGU2E391MELB
	470	22 x 50	0.15	1650	493-2763-ND	4.07	30.79	244.02	LGU2E471MELZ
	470	25 x 40	0.15	1650	493-2764-ND	4.07	30.79	244.02	LGU2E471MELA
	470	30 x 30	0.15	1650	493-2765-ND	4.32	32.67	258.93	LGU2E471MELB
	470	35 x 25	0.15	1650	493-2766-ND	4.66	35.30	279.72	LGU2E471MELC
	560	25 x 45	0.15	1800	493-2767-ND	4.90	37.07	293.79	LGU2E561MELA
560	30 x 35	0.15	1800	493-2768-ND	4.90	37.07	293.79	LGU2E561MELB	
560	35 x 25	0.15	1800	493-2769-ND	5.24	39.70	314.58	LGU2E561MELC	
680	25 x 50	0.15	2000	493-2770-ND	5.60	42.37	335.79	LGU2E681MELA	
680	30 x 40	0.15	2000	493-2771-ND	5.47	41.42	328.23	LGU2E681MELB	
680	35 x 30	0.15	2000	493-2772-ND	5.83	44.12	349.65	LGU2E681MELC	
820	30 x 45	0.15	2300	493-2773-ND	6.06	45.87	363.51	LGU2E821MELB	
820	35 x 35	0.15	2300	493-2774-ND	6.55	49.56	392.70	LGU2E821MELC	
1000	30 x 50	0.15	2470	493-2775-ND	6.66	50.46	399.84	LGU2E102MELB	
1000	35 x 40	0.15	2470	493-2776-ND	7.70	58.27	461.79	LGU2E102MELC	
1200	35 x 45	0.15	2600	493-2777-ND	10.03	75.98	602.07	LGU2E122MELC	
1500	35 x 50	0.15	3000	493-2778-ND	10.86	82.23	651.63	LGU2E152MELC	
400	56	20 x 25	0.15	510	493-2779-ND	2.02	15.29	121.17	LGU2G560MELY
	68	20 x 30	0.15	560	493-2780-ND	2.17	16.46	130.41	LGU2G680MELY
	82	20 x 30	0.15	640	493-2781-ND	2.24	16.99	134.61	LGU2G820MELY
	82	22 x 25	0.15	640	493-2782-ND	2.24	16.99	134.61	LGU2G820MELZ
	100	20 x 35	0.15	700	493-2783-ND	2.54	19.27	152.67	LGU2G101MELY
	100	22 x 30	0.15	700	493-2784-ND	2.54	19.27	152.67	LGU2G101MELZ
	100	25 x 25	0.15	700	493-2785-ND	2.64	19.98	158.34	LGU2G101MELA
	120	20 x 40	0.15	750	493-2786-ND	2.84	21.49	170.31	LGU2G121MELY
	120	22 x 35	0.15	750	493-2787-ND	2.84	21.49	170.31	LGU2G121MELZ
	120	25 x 25	0.15	750	493-2788-ND	2.94	22.23	176.19	LGU2G121MELA
	150	20 x 45	0.15	830	493-2789-ND	3.23	24.46	193.83	LGU2G151MELY
	150	22 x 40	0.15	880	493-2790-ND	3.23	24.46	193.83	LGU2G151MELZ
	150	25 x 30	0.15	880	493-2791-ND	3.33	25.23	199.92	LGU2G151MELA
	150	30 x 25	0.15	880	493-2792-ND	3.54	26.77	212.10	LGU2G151MELB
	180	22 x 45	0.15	980	493-2793-ND	3.62	27.43	217.35	LGU2G181MELZ
	180	25 x 35	0.15	980	493-2794-ND	3.62	27.43	217.35	LGU2G181MELA
	180	30 x 30	0.15	980	493-2795-ND	3.82	28.91	229.11	LGU2G181MELB
	180	35 x 25	0.15	980	493-2796-ND	4.12	31.16	246.96	LGU2G181MELC

W.V. (VDC)	电容 (μF)	外壳尺寸 ØD x L (mm)	Tan δ	在 105°C 时的 额定 纹波电流 (mA)	Digi-Key 零件编号	价格			Nichicon 零件编号	
						1	10	100		
400	220	22 x 50	0.15	1100	493-2797-ND	4.23	32.01	253.68	LGU2G221MELZ	
	220	25 x 40	0.15	1100	493-2798-ND	4.32	32.67	258.93	LGU2G221MELA	
	220	30 x 30	0.15	1100	493-2799-ND	4.41	33.42	264.81	LGU2G221MELB	
	220	35 x 25	0.15	1100	493-2800-ND	4.71	35.64	282.45	LGU2G221MELC	
	270	25 x 45	0.15	1200	493-2801-ND	5.11	38.66	306.39	LGU2G271MELA	
	270	30 x 35	0.15	1220	493-2802-ND	5.11	38.66	306.39	LGU2G271MELB	
	270	35 x 30	0.15	1220	493-2803-ND	5.39	40.84	323.61	LGU2G271MELC	
	330	25 x 50	0.15	1440	493-2804-ND	6.19	46.85	371.28	LGU2G331MELA	
	330	30 x 40	0.15	1440	493-2805-ND	6.09	46.11	365.40	LGU2G331MELB	
	330	35 x 30	0.15	1440	493-2806-ND	6.19	46.85	371.28	LGU2G331MELC	
	390	30 x 45	0.15	1600	493-2807-ND	7.27	55.01	435.96	LGU2G391MELB	
	390	35 x 35	0.15	1600	493-2808-ND	7.27	55.01	435.96	LGU2G391MELC	
	470	30 x 50	0.15	1900	493-2809-ND	8.75	66.22	524.79	LGU2G471MELB	
	470	35 x 40	0.15	1900	493-2810-ND	8.05	60.98	483.21	LGU2G471MELC	
	560	35 x 45	0.15	2120	493-2811-ND	11.50	87.11	690.27	LGU2G561MELC	
	420	56	20 x 25	0.15	510	493-2812-ND	2.42	18.31	145.11	LGUW6560MELY
		68	20 x 30	0.15	560	493-2813-ND	2.67	20.22	160.23	LGUW6680MELY
		82	20 x 35	0.15	640	493-2814-ND	2.81	21.25	168.42	LGUW6820MELY
		82	22 x 25	0.15	640	493-2815-ND	2.81	21.25	168.42	LGUW6820MELZ
		100	20 x 35	0.15	700	493-2816-ND	3.22	24.35	192.99	LGUW6101MELY
100		22 x 30	0.15	700	493-2817-ND	3.22	24.35	192.99	LGUW6101MELZ	
100		25 x 25	0.15	700	493-2818-ND	3.22	24.41	193.41	LGUW6101MELA	
120		20 x 40	0.15	750	493-2819-ND	3.72	28.14	223.02	LGUW6121MELZ	
120		22 x 35	0.15	750	493-2820-ND	3.72	28.14	223.02	LGUW6121MELC	
120		25 x 30	0.15	750	493-2821-ND	3.68	27.85	220.71	LGUW6121MELA	
150		20 x 50	0.15	880	493-2822-ND	4.24	32.07	254.10	LGUW6151MELZ	
150		22 x 40	0.15	880	493-2823-ND	4.24	32.07	254.10	LGUW6151MELC	
150		25 x 35	0.15	880	493-2824-ND	4.55	34.45	273.00	LGUW6151MELA	
150		30 x 25	0.15	880	493-2825-ND	4.54	34.40	272.58	LGUW6151MELB	
180		22 x 45	0.15	950	493-2826-ND	4.56	34.56	273.84	LGUW6181MELZ	
180		25 x 35	0.15	950	493-2827-ND	4.96	37.58	297.78	LGUW6181MELA	
180		30 x 30	0.15	950	493-2828-ND	5.45	41.26	326.97	LGUW6181MELB	
220		22 x 50	0.15	1100	493-2829-ND	5.32	40.28	319.20	LGUW6221MELZ	
220		25 x 45	0.15	1100	493-2830-ND	6.40	48.47	384.09	LGUW6221MELA	
220		30 x 35	0.15	1100	493-2831-ND	5.79	43.86	347.55	LGUW6221MELC	
450	220	35 x 25	0.15	1100	493-2832-ND	6.11	46.24	366.45	LGUW6221MELB	
	270	25 x 50	0.15	1220	493-2833-ND	6.81	51.60	408.87	LGUW6271MELA	
	270	30 x 40	0.15	1220	493-2834-ND	6.79	51.38	407.19	LGUW6271MELB	
	270	35 x 30	0.15							