

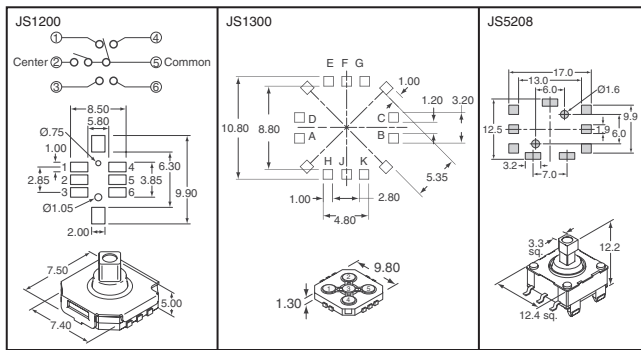


图	说明	Digi-Key 零件编号	单价			E-Switch 零件编号	
			1	10	100		
16	3.15mm 直角触头器, 130gf, 鸥翼形	EG4391CT-ND\$.60	.48	.43	TL3320AF130Q	
	3.15mm 直角触头器, 130gf, 鸥翼形	EG4391TR-NDΔ	139.13/500			TL3320AF130Q	
	3.15mm 直角触头器, 160gf, 鸥翼形	EG4392CT-ND\$.60	.48	.43	TL3320AF160Q	
	3.15mm 直角触头器, 160gf, 鸥翼形	EG4392TR-NDΔ	139.13/500			TL3320AF160Q	
	3.15mm 直角触头器, 250gf, 鸥翼形	EG4404CT-ND\$.60	.48	.43	TL3320AF250Q	
	3.15mm 直角触头器, 250gf, 鸥翼形	EG4404TR-NDΔ	139.13/500			TL3320AF250Q	
	3.85mm 直角触头器, 100gf, 鸥翼形	EG4393CT-ND\$.60	.48	.43	TL3320BF100Q	
	3.85mm 直角触头器, 100gf, 鸥翼形	EG4393TR-NDΔ	139.13/500			TL3320BF100Q	
	3.85mm 直角触头器, 130gf, 鸥翼形	EG4394CT-ND\$.60	.48	.43	TL3320BF130Q	
	3.85mm 直角触头器, 130gf, 鸥翼形	EG4394TR-NDΔ	139.13/500			TL3320BF130Q	
	3.85mm 直角触头器, 160gf, 鸥翼形	EG4395CT-ND\$.60	.48	.43	TL3320BF160Q	
	3.85mm 直角触头器, 160gf, 鸥翼形	EG4395TR-NDΔ	139.13/500			TL3320BF160Q	
	3.85mm 直角触头器, 250gf, 鸥翼形	EG4396CT-ND\$.60	.48	.43	TL3320BF250Q	
	3.85mm 直角触头器, 250gf, 鸥翼形	EG4396TR-NDΔ	139.13/500			TL3320BF250Q	
	17	3.5mm 直角触头器, 130gf, 鸥翼形	EG4388CT-ND\$.53	.43	.39	TL3330AF130Q
		3.5mm 直角触头器, 130gf, 鸥翼形	EG4388TR-NDΔ	470.24/2,300			TL3330AF130Q
3.5mm 直角触头器, 260gf, 鸥翼形		EG4389CT-ND\$.53	.43	.39	TL3330AF260Q	
3.5mm 直角触头器, 260gf, 鸥翼形		EG4389TR-NDΔ	470.24/2,300			TL3330AF260Q	
6.2mm 方形, H=4.3mm 触头器, 160gf		EG2532CT-ND\$.33	.27	.24	TL59NF160Q	
6.2mm 方形, H=4.3mm 触头器, 160gf		EG2532TB-ND†	127.60/1,000			TL59NF160Q	
6.2mm 方形, H=4.3mm 触头器, 260gf		EG4568CT-ND\$.33	.27	.24	TL59NF260Q	
6.2mm 方形, H=4.3mm 触头器, 260gf		EG4568TB-ND†	127.60/1,000			TL59NF260Q	
6.2mm 方形, H=5.00mm 触头器, 100gf		EG4378CT-ND\$.33	.27	.24	TL59AF100Q	
6.2mm 方形, H=5.00mm 触头器, 100gf		EG4378TR-NDΔ	127.60/1,000			TL59AF100Q	
6.2mm 方形, H=5.00mm 触头器, 160gf		EG2533CT-ND\$.33	.27	.24	TL59AF160Q	
6.2mm 方形, H=5.00mm 触头器, 160gf		EG2533TB-ND†	127.60/1,000			TL59AF160Q	
18	6.2mm 方形, H=7.00mm 触头器, 160gf	EG4566CT-ND\$.33	.27	.24	TL59FF160Q	
	6.2mm 方形, H=7.00mm 触头器, 160gf	EG4566TR-NDΔ	127.60/1,000			TL59FF160Q	
	6.2mm 方形, H=7.00mm 触头器, 260gf	EG4567CT-ND\$.32	.26	.23	TL59FF260Q	
	6.2mm 方形, H=7.00mm 触头器, 260gf	EG4567TR-NDΔ	123.25/1,000			TL59FF260Q	
	SMT 1.5mm 触头器, 160gf, 鸥翼形	EG2531CT-ND\$.72	.58	.52	TL3342F1600G/TR	
	SMT 1.5mm 触头器, 160gf, 鸥翼形	EG2531TR-NDΔ	1146.00/4,000			TL3342F1600G/TR	
	6 x 3.5mm, H=4.3mm 130gf	EG2510-ND	.38	.34	.30	TL1107AF130WQ	
	6 x 3.5mm, H=4.3mm 180gf	EG2511-ND	.38	.34	.30	TL1107AF180WQ	
	6 x 3.5mm, H=5.0mm 130gf	EG2512-ND	.38	.34	.30	TL1107BF130WQ	
	6 x 3.5mm, H=5.0mm 180gf	EG2513-ND	.38	.34	.30	TL1107BF180WQ	
	SMT 4.3mm 触头器, 180gf, 鸥翼形	EG2528CT-ND\$.72	.58	.52	TL3302AF1800G	
	SMT 4.3mm 触头器, 180gf, 鸥翼形	EG2528TR-NDΔ	498.51/1,800			TL3302AF1800G	
SMT 5.0mm 触头器, 180gf, 鸥翼形	EG2529CT-ND\$.72	.58	.52	TL3302BF1800G/TR		
SMT 5.0mm 触头器, 180gf, 鸥翼形	EG2529TR-NDΔ	498.51/1,800			TL3302BF1800G/TR		
20	2 引线, 6.2mm 方形, 70gf	EG4413-ND	.60	.54	.46	TL1140AF070Q	
	2 引线, 6x6mm, 70gf	EG4414-ND	.54	.49	.42	TL1150AF070Q	
	180gf 鸥翼形, 无凸耳	EG4342CT-ND\$.93	.75	.67	TL1014AF1800G	
	180gf 鸥翼形, 无凸耳	EG4342TR-NDΔ	1116.00/3,000			TL1014AF1800G	
	180gf 鸥翼形, 带凸耳	EG4343CT-ND\$.93	.75	.67	TL1014BF1800G	
	180gf 鸥翼形, 带凸耳	EG4343TR-NDΔ	1116.00/3,000			TL1014BF1800G	
	160gf 鸥翼形, 无凸耳	EG4344CT-ND\$	1.05	.84	.76	TL1015AF1600G	
	160gf 鸥翼形, 无凸耳	EG4344TR-NDΔ	1046.25/2,500			TL1015AF1600G	
	160gf 鸥翼形, 带凸耳	EG4345CT-ND\$	1.05	.84	.76	TL1015BF1600G	
	160gf 鸥翼形, 带凸耳	EG4345TR-NDΔ	1046.25/2,500			TL1015BF1600G	
	7.8mm 方形, 5.0mm 触头器, 120gf	EG4346-ND	.43	.38	.33	TL9000F120Q	
	25	4.7mm 触头器, 130gf	EG2638-ND	1.25	1.12	.96	TL6100AF1300P
4.7mm 触头器, 160gf		EG2639-ND	1.25	1.12	.96	TL6100AF1300P	

图	说明	Digi-Key 零件编号	单价			E-Switch 零件编号	
			1	10	100		
25	4.7mm 触头器, 160gf, 带 ESD 引脚	EG2650-ND	1.67	1.34	1.21	TL6100AF1600P	
	4.7mm 触头器, 300gf	EG2640-ND	1.26	1.13	.97	TL6100AF3000P	
	4.7mm 触头器, 130gf	EG2517-ND	.95	.85	.74	GS4.70F1300P	
	4.7mm 触头器, 300gf	EG2518-ND	.95	.85	.74	GS4.70F3000P	
	4.7mm 触头器, 130gf, 带 ESD 引脚	EG2523-ND	1.16	.93	.84	GS4.70F1300P	
	5.2mm 触头器, 130gf	EG2641-ND	1.25	1.12	.96	TL6100BF1300P	
	5.2mm 触头器, 160gf	EG2642-ND	1.26	1.13	.97	TL6100BF1600P	
	5.2mm 触头器, 160gf, 带 ESD 引脚	EG2651-ND	1.67	1.34	1.21	TL6105BF1600P	
	5.2mm 触头器, 300gf	EG2643-ND	1.26	1.13	.97	TL6100BF3000P	
	6.34mm 直角触头器, 130gf	EG2521-ND	1.15	1.03	.89	GSR6.34F1300R	
	6.9mm 触头器, 130gf	EG2644-ND	1.63	1.56	.49	TL6100CF1300P	
	6.9mm 触头器, 160gf	EG2645-ND	1.26	1.13	.97	TL6100CF1600P	
	6.9mm 触头器, 160gf, 带 ESD 引脚	EG2652-ND	1.62	1.30	1.17	TL6105CF1600P	
	6.9mm 触头器, 300gf	EG2646-ND	1.26	1.13	.97	TL6100CF3000P	
	8.54mm 直角触头器, 130gf	EG2522-ND	1.22	.98	.89	GSR8.54F1300R	
	26	10mm 触头器, 130gf	EG2647-ND	1.63	1.56	.49	TL6100DF1300P
10mm 触头器, 160gf		EG2648-ND	1.26	1.13	.97	TL6100DF1600P	
10mm 触头器, 160gf, 带 ESD 引脚		EG2653-ND	1.46	1.31	1.13	TL6105DF1600P	
10mm 触头器, 300gf		EG2649-ND	1.26	1.13	.97	TL6100DF3000P	
10mm 触头器, 130gf		EG2519-ND	.95	.85	.74	GS10.00F1300P	
10mm 触头器, 300gf		EG2520-ND	.95	.85	.74	GS10.00F3000P	
10mm 触头器, 130gf, 带 ESD 引脚		EG2524-ND	1.22	.98	.88	GS10.00F1300P	
密封触摸开关							
27		3.5mm 直角触头器, 130gf	EG4362-ND	1.41	1.27	1.09	TL6110AF1300P
		3.5mm 直角触头器, 160gf	EG4361-ND	1.41	1.27	1.09	TL6110AF1600P
		4.0mm 直角触头器, 130gf	EG4347-ND	1.41	1.27	1.09	TL6110BF1300P
		4.0mm 直角触头器, 300gf	EG4348-ND	1.42	1.27	1.10	TL6110BF3000P
		5.7mm 直角触头器, 160gf	EG4349-ND	1.44	1.29	1.11	TL6110CF1600P
		8.7mm 直角触头器, 160gf	EG4359-ND	1.44	1.29	1.11	TL6110DF1600P
		8.7mm 直角触头器, 300gf	EG4360-ND	1.45	1.30	1.12	TL6110DF3000P
		SMT 4.7mm 触头器, 160gf	EG4350CT-ND\$	1.64	1.32	1.19	TL6120AF1600G
	SMT 4.7mm 触头器, 160gf	EG4350TR-NDΔ	635.10/1,000			TL6120AF1600G	
	SMT 4.7mm 触头器, 300gf	EG4354CT-ND\$	1.64	1.32	1.19	TL6120AF3000G	
	SMT 4.7mm 触头器, 300gf	EG4354TR-NDΔ	635.10/1,000			TL6120AF3000G	
	SMT 5.2mm 触头器, 130gf	EG4351CT-ND\$	1.64	1.32	1.19	TL6120BF1300G	
	SMT 5.2mm 触头器, 130gf	EG4351TR-NDΔ	635.10/1,000			TL6120BF1300G	
	SMT 5.2mm 触头器, 300gf	EG4352CT-ND\$	1.64	1.32	1.19	TL6120BF3000G	
	SMT 5.2mm 触头器, 300gf	EG4352TR-NDΔ	635.10/1,000			TL6120BF3000G	
	28	SMT 6.9mm 触头器, 160gf	EG4353CT-ND\$	1.64	1.32	1.19	TL6120CF1600G
SMT 6.9mm 触头器, 160gf		EG4353TR-NDΔ	536.55/700			TL6120CF1600G	
SMT 6.9mm 触头器, 300gf		EG4355CT-ND\$	1.64	1.32	1.19	TL6120CF3000G	
SMT 6.9mm 触头器, 300gf		EG4355TR-NDΔ	536.55/700			TL6120CF3000G	
SMT 10mm 触头器, 300gf		EG4356CT-ND\$	1.64	1.32	1.19	TL6120DF3000G	
SMT 10mm 触头器, 300gf		EG4356TR-NDΔ	262.80/300			TL6120DF3000G	
按键底座							
W=12 x 12mm 黑色, 适合 12mm 加长型触头器		EG1080-ND	.19	.17	.15	4JBLK	
W=12 x 12mm 灰色, 适合 12mm 加长型触头器		EG1079-ND	.19	.17	.15	4JGRY	
W=12 x 12mm 红色, 适合 12mm 加长型触头器		EG1078-ND	.19	.17	.15	4JRED	
W=12 x 12mm 白色, 适合 12mm 加长型触头器		EG1077-ND	.19	.17	.15	4JWHT	
W=8 x 8mm 黑色, 适合 12mm 加长型触头器		EG1885-ND	.19	.17	.15	6JBLK	
W=8 x 8mm 红色, 适合 12mm 加长型触头器		EG1886-ND	.19	.17	.15	6JRED	
W=8 x 8mm 白色, 适合 12mm 加长型触头器		EG1887-ND	.19	.17	.15	6JWHT	
W=8 x 8mm 灰色, 适合 12mm 加长型触头器		EG1888-ND	.19	.17	.15	6JGRY	

†TB=带盒 □CT=剪切带 ΔTR=带卷

导航开关 JS1200、JS1300 和 JS5208 多向



JS1200 系列: 机械规格: • 机械寿命: 任意方向 200,000 次触头 • 标准行程: 按下: 0.15±/0.01mm, 倾斜: 0.20±/0.01 • 开关功能: 瞬时 电气规格: • 触点额定值: 12VDC, 20mA • 初始最大触点电阻: 500mΩ • 绝缘电阻: 100MΩ • 绝缘强度: 100VAC 环境规格: • 工作温度: -25°C ~ 70°C

JS1300 系列: 机械规格: • 机械寿命: 100,000 次 • 标准行程: 中心: 0.19 ±/ 0.15mm, 倾斜: 0.35±/0.15mm • 开关功能: 瞬时 电气规格: • 触点额定值: 12VDC, 50mA • 初始最大触点电阻: 100mΩ • 绝缘电阻: 100MΩ • 绝缘强度: 250VAC 环境规格: • 工作温度: -25°C ~ 70°C

JS5208 系列: 技术规格: • 触点额定值: 20mA, 15VDC • 预期寿命: 100,000 次操作 • 初始最大触点电阻: 100mΩ • 操作力: 倾角: 280°/100g; 按下: 500±/150g • 电介质: 250VAC • 工作温度: -20°C ~ 70°C • 行程: 倾角: 8°, 按下: 1.0 ±/0.2mm


功能	Digi-Key 零件编号	单价			Digi-Key 零件编号	带卷 数量	带卷 价格	E-Switch 零件编号
		1	10	100				
JS1200 系列								
带选择功能, 带凸耳	EG4357CT-ND	3.32	2.66	2.39	750	1160.25	JS1200AAQ	
带选择功能, 无凸耳	EG4358CT-ND	3.32	2.66	2.39	1,500	1281.80/M	JS1200ABQ	
JS1300 系列								
带选择功能, 无凸耳	EG4408CT-ND	2.44	1.96	1.76	2,500	1106.70/M	JS1300AAQ	
JS5208 系列								
带选择功能, 带凸耳	EG4561-ND	3.68	3.29	2.83	—	—	JS5208	

双 LED 触摸开关



技术规格:

- 额定: 12VDC, 最大 50mA • 触点电阻: 最大 500mΩ • 绝缘电阻: 100VDC, 最小 100MΩ • 行程: 0.25mm
- 操作力: 160 ±75/30gf • 工作温度: -20°C ~ 70°C • 工作寿命: 30,000 次 • 开关功能: 瞬时

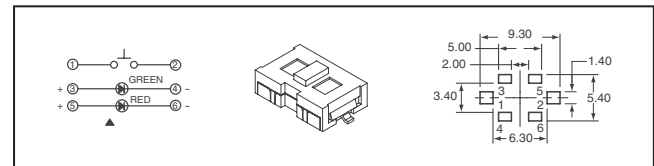


颜色	Digi-Key 零件编号	1	10	100	Digi-Key 零件编号	带卷价格 3,000	E-Switch 零件编号
绿/红	EG4409CT-ND	3.14	2.52	2.27	EG4409TR-ND	1424.60/M	TL3200AF160GRQ
红/红	EG4410CT-ND	3.14	2.52	2.27	EG4410TR-ND	1424.60/M	TL3200AF160RRQ

双向触摸开关



技术规格:

- 触点电阻: 最大 200mΩ • 额定值: 30VDC, 20mA • 行程: 1次 - 0.30±0.10, 2次 - 0.55±0.15
- 寿命: 10,000 次 • 力度: 1次 - 100±40gf, 2次 - 250±80gf

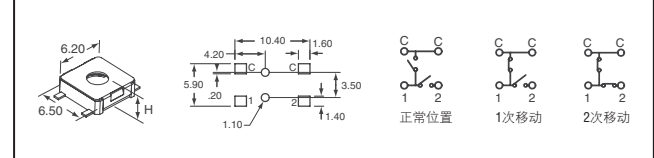

功能	尺寸 H (mm)	Digi-Key 零件编号	单价			Digi-Key 零件编号	带卷价格 1,200	E-Switch 零件编号
			1	10	100			
无触头器	2.00	EG4411CT-ND	1.27					