

DELTA DC 轴向风扇和鼓风机

产品范围广, 包括 25mm 至 172mm 的轴流式风机和 30mm 至 159mm 的鼓风机。
 特点: • 独特的叶片设计 • 无刷 • 通过 TS16949 认证 • 通过 ISO-9001 认证 • 滚珠轴承 • 引线

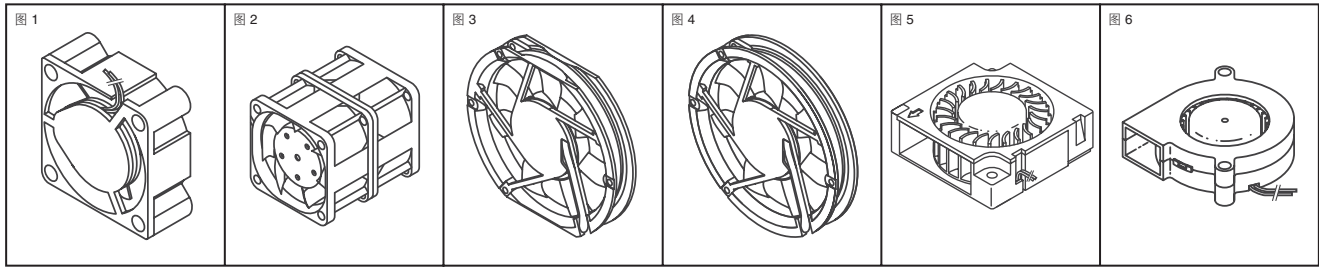


图	尺寸 (mm)	额定电压	工作温度范围	额定电流 (A)	额定输入功率 (W)	速度 (RPM)	CFM	噪音 (Db)	传感器	Digi-Key 零件编号	1	10	100	Delta 零件编号	护指罩	单价
轴向风扇																
1	25 x 25 x 10	12	7.0 - 13.2	.080	0.96	13000	2.40	28.0	—	603-1129-ND	12.72	8.40	6.96	AFB02512HHA-A	—	—
	35 x 35 x 10	12	9.5 - 13.8	.090	1.08	7000	5.50	22.0	—	603-1128-ND	12.72	8.40	6.96	AFB03512HA-A	CR378-ND	.66
	40 x 40 x 10	12	7.0 - 13.8	.060	.72	5000	5.90	24.5	—	603-1002-ND	9.78	7.44	6.38	EFB0412MA	CR230-ND	.65
		12	7.0 - 13.8	.080	.96	6000	6.92	28.5	—	603-1003-ND	9.78	7.44	6.38	EFB0412HA	CR230-ND	.65
		12	7.0 - 13.8	.100	1.20	7000	8.09	33.0	—	603-1004-ND	11.26	7.44	6.17	EFB0412HHA	CR230-ND	.65
		12	7.0 - 13.8	.130	1.56	8300	11.48	32.0	—	603-1005-ND	11.81	9.09	7.62	AFB0412HHB	CR230-ND	.65
	40 x 40 x 15	12	7.0 - 13.8	.250	3.00	11000	14.83	41.5	—	603-1006-ND	11.81	9.09	7.62	AFB0412SHB	CR230-ND	.65
		5	4.5 - 5.5	.250	1.25	7600	8.54	28.5	—	603-1007-ND	10.93	8.32	7.13	EFB0405HD	CR230-ND	.65
	40 x 40 x 20	5	4.5 - 5.5	.320	1.60	9000	10.10	32.5	Tac	603-1008-ND	13.25	8.75	7.25	EFB0405VHD-F00	CR230-ND	.65
		12	7.0 - 13.8	.080	0.96	7600	8.54	28.5	—	603-1009-ND	12.59	8.32	6.89	EFB0412HD	CR230-ND	.65
		12	7.0 - 13.8	.120	1.44	9000	10.10	32.5	—	603-1010-ND	12.59	8.32	6.89	EFB0412VHD	CR230-ND	.65
		24	14.0 - 27.6	.040	0.96	5000	5.54	22.0	—	603-1011-ND	10.93	8.32	7.13	EFB0424LD	CR230-ND	.65
		12	4.5 - 13.8	.070	0.84	6500	10.59	32.1	Tac	603-1012-ND	16.43	10.85	8.99	FFB0412HN-F00	CR230-ND	.65
	40 x 40 x 28	12	4.0 - 13.8	.500	6.00	13000	24.00	51.5	Tac	603-1013-ND	18.82	12.43	10.30	FFB0412SHN-F00	CR230-ND	.65
		12	4.5 - 13.2	.160	1.92	9500	15.79	41.9	—	603-1014-ND	13.39	10.30	8.63	FFB0412VHN	CR230-ND	.65
		12	4.5 - 13.2	.160	1.92	9500	15.79	41.9	—	603-1015-ND	16.43	10.85	8.99	FFB0412VHN-B	CR230-ND	.65
		12	4.5 - 13.2	.160	1.92	9500	15.79	41.9	Tac	603-1016-ND	16.43	10.85	8.99	FFB0412VHN-F00	CR230-ND	.65
		12	4.5 - 13.2	.160	1.92	9500	15.79	41.9	—	603-1017-ND	16.43	10.85	8.99	FFB0412VHN-R00	CR230-ND	.65
		24	14.0 - 26.4	.100	2.40	9500	15.79	41.9	锁定转子	603-1018-ND	15.77	10.42	8.63	FFB0424VHN	CR230-ND	.65
		12	7.0 - 13.2	.850	10.20	12000	24.00	60.0	Tac	603-1019-ND	31.14	20.57	17.04	GFB0412SHG-F00	CR230-ND	.65
12		7.0 - 13.2	1.25	15.00	15000	27.30	59.5	Tac	603-1020-ND	31.14	20.57	17.04	GFB0412EHS-F00	CR230-ND	.65	
1	45 x 45 x 10	12	7.0 - 13.8	.110	1.32	5000	9.85	30.0	—	603-1021-ND	11.81	9.09	7.62	AFB04512MA	—	—
	50 x 50 x 10	5	4.5 - 5.5	.130	0.65	4500	9.21	25.0	Tac	603-1022-ND	11.93	7.88	6.53	EFB0505MA-F00	CR379-ND	.86
		12	7.0 - 13.8	.100	1.20	5500	11.4	30.0	—	603-1023-ND	9.78	7.44	6.38	EFB0512HA	CR379-ND	.86
	50 x 50 x 15	12	7.0 - 13.8	.100	1.20	5600	14.13	32.0	—	603-1024-ND	13.91	9.19	7.62	AFB0512HB	CR379-ND	.86
	50 x 50 x 20	12	7.0 - 13.8	.160	1.92	7000	20.30	40.5	—	603-1025-ND	13.91	9.19	7.62	AFB0512VHD	CR379-ND	.86
	60 x 60 x 10	12	7.0 - 13.8	.180	2.16	4800	21.19	36.5	—	603-1026-ND	12.59	8.32	6.89	EFB0612HHA	CR221-ND	.68
	60 x 60 x 15	5	4.0 - 6.0	.300	1.50	4000	15.36	32.0	—	603-1027-ND	13.91	9.19	7.62	AFB0605HB	CR221-ND	.68
		24	14.0 - 27.6	.080	1.92	4000	15.36	32.0	—	603-1028-ND	13.91	9.19	7.62	AFB0624HB	CR221-ND	.68
	60 x 60 x 20	12	7.0 - 13.8	.150	1.80	4400	18.36	31.0	—	603-1029-ND	11.81	9.09	7.62	AFB0612HHD	CR221-ND	.68
	60 x 60 x 25.4	12	4.0 - 13.8	.080	0.96	3100	16.81	26.5	—	603-1030-ND	15.50	10.24	8.49	AFB0612L-A	CR221-ND	.68
		12	4.0 - 13.8	.140	1.68	4250	23.38	34.0	—	603-1031-ND	13.16	10.13	8.49	AFB0612H-A	CR221-ND	.68
		12	4.0 - 13.8	.170	2.04	5000	27.55	40.0	—	603-1032-ND	11.81	9.09	7.62	AFB0612HH-A	CR221-ND	.68
		12	4.0 - 13.8	.270	3.24	6000	34.15	44.5	Tac	603-1033-ND	16.83	11.12	9.21	AFB0612SH-ABF00	CR221-ND	.68
		12	4.0 - 13.8	.270	3.24	6000	34.15	44.5	Tac	603-1034-ND	16.17	10.68	8.85	AFB0612SH-AF00	CR221-ND	.68
		12	4.0 - 13.8	.380	4.56	6800	38.35	46.5	Tac	603-1035-ND	16.83	11.12	9.21	AFB0612EH-ABF00	CR221-ND	.68
		24	14.0 - 27.6	.090	2.16	4250	23.38	34.0	—	603-1036-ND	15.50	10.24	8.49	AFB0624H-A	CR221-ND	.68
		24	14.0 - 27.6	.110	2.64	5000	27.55	40.0	—	603-1037-ND	15.50	10.24	8.49	AFB0624HH-A	CR221-ND	.68
	60 x 60 x 38	12	4.5 - 13.8	.340	4.08	6000	36.73	46.5	—	603-1038-ND	18.15	11.99	9.94	FFB0612VHE	CR221-ND	.68
12		4.5 - 13.8	.550	6.60	7000	43.44	50.5	—	603-1039-ND	15.07	11.86	9.94	FFB0612SHE	CR221-ND	.68	
12		4.5 - 13.8	.800	9.60	8000	50.15	54.5	—	603-1040-ND	18.15	11.99	9.94	FFB0612EHE	CR221-ND	.68	
12		7.0 - 13.8	.680	8.16	9000	49.54	54.0	—	603-1041-ND	20.41	13.48	11.17	AFB0612VHE-A	CR221-ND	.68	
2	60 x 60 x 50.8	12	7.0 - 13.8	.430	5.16	5000	32.14	50.5	—	603-1042-ND	24.70	20.14	17.29	GFB0612HHG	CR221-ND	.68
1	70 x 70 x 20	12	5.0 - 13.8	.250	3.00	4400	40.43	40.5	—	603-1043-ND	11.81	9.09	7.62	AFB0712HHD	—	—
		12	5.0 - 12.6	.440	5.28	5500	51.97	47.5	—	603-1044-ND	13.91	9.19	7.62	AFB0712VH-A	—	—
	70 x 70 x 25.4	12	5.0 - 13.8	.650	7.80	6300	61.05	50.5	—	603-1045-ND	16.96	11.20	9.28	AFB0712SH-AB	—	—
		24	14.0 - 26.4	.090	2.16	3100	28.85	31.5	—	603-1046-ND	13.16	10.13	8.49	AFB0724M-A	—	—
	80 x 80 x 15	12	7.0 - 13.8	.190	2.28	3700	39.20	39.5	Tac	603-1047-ND	14.58	9.63	7.98	AFB0812VHB-F00	CR180-ND	.93
		12	7.0 - 13.8	.220	2.64	4000	48.20	41.0	—	603-1048-ND	13.91	9.19	7.62	AFB0812SHD	CR180-ND	.93
	80 x 80 x 25.4	5	4.5 - 5.5	.430	2.15	3000	35.31	31.0	—	603-1049-ND	13.91	9.19	7.62	AFB0805H	CR180-ND	.93
		12	7.0 - 13.8	.160	1.92	3000	35.31	31.0	—	603-1050-ND	13.91	9.19	7.62	AFB0812H	CR180-ND	.93
		12	7.0 - 13.8	.200	2.40	3250	37.43	34.0	—	603-1051-ND	13.91	9.19	7.62	AFB0812HH	CR180-ND	.93
		12	7.0 - 13.8	.200	2.40	3250	37.43	34.0	—	603-1051-ND	13.91	9.19	7.62	AFB0812HH	CR180-ND	.93

(转下页)

全部产品均以美元计价。 免费电话: 10800-1527031 (China Telecom - 中国电讯) — 10800-8527031 (CNCG - 中国网通)

2294 (CN082-09)

digikey.com.cn — 电话: (852) 3104 0500 — 传真: (852) 3104 0686