

图	发射颜色	峰值波长 (nm)	数字尺寸 英寸 (mm)	数字个数	正向电压 (标准) (V)	正向电流 (mA)	lv (mcd) (最小) (标准)	Digi-Key 零件编号	1	单价 25	100	Rohm 零件编号	
1	红	626	.31 (8.0)	1	2.05	25	36 90	511-1517-ND	2.92	1.60	1.43	LA-301AB	
	红	626	.31 (8.0)	1	2.05	25	36 90	511-1518-ND	2.92	1.60	1.43	LA-301AL	
	橙	610	.31 (8.0)	1	2.05	25	36 90	511-1519-ND	3.20	1.75	1.52	LA-301EB	
	橙	610	.31 (8.0)	1	2.05	25	36 90	511-1520-ND	3.20	1.75	1.52	LA-301EL	
	绿	563	.31 (8.0)	1	2.1	20	3.6 10	511-1563-ND	2.28	1.28	1.14	LA-301MB	
	绿	563	.31 (8.0)	1	2.1	20	3.6 10	511-1564-ND	2.28	1.28	1.14	LA-301ML	
	红	650	.31 (8.0)	1	2.0	15	3.6 10	511-1565-ND	1.69	.83	.73	LA-301VB	
	红	650	.31 (8.0)	1	2.0	15	3.6 10	511-1566-ND	2.28	1.28	1.14	LA-301VL	
	黄	589	.31 (8.0)	1	2.05	25	36 90	511-1567-ND	3.20	1.75	1.52	LA-301XB	
	黄	589	.31 (8.0)	1	2.05	25	36 90	511-1521-ND	3.20	1.75	1.52	LA-301XL	
2	红	626	.40 (10.16)	1	2.05	25	36 90	511-1522-ND	2.80	1.53	1.37	LA-401AD	
	红	626	.40 (10.16)	1	2.05	25	36 90	511-1523-ND	2.80	1.53	1.37	LA-401AN	
	蓝	470	.40 (10.16)	1	3.6	10	14 56	511-1524-ND	10.25	6.62	6.09	LA-401BD	
	蓝	470	.40 (10.16)	1	3.6	10	14 56	511-1525-ND	10.25	6.62	6.09	LA-401BN	
	橙	610	.40 (10.16)	1	2.05	25	36 90	511-1526-ND	3.45	2.13	1.88	LA-401ED	
	橙	610	.40 (10.16)	1	2.05	25	36 90	511-1527-ND	3.45	2.13	1.88	LA-401EN	
	绿	563	.40 (10.16)	1	2.1	20	5.6 16	511-1528-ND	2.80	1.53	1.37	LA-401MD	
	绿	563	.40 (10.16)	1	2.1	20	5.6 16	511-1529-ND	2.80	1.53	1.37	LA-401MN	
	红	650	.40 (10.16)	1	2.0	15	5.6 16	511-1530-ND	2.80	1.53	1.37	LA-401VD	
	红	650	.40 (10.16)	1	2.0	15	5.6 16	511-1531-ND	2.80	1.53	1.37	LA-401VN	
3	黄	589	.40 (10.16)	1	2.05	25	36 90	511-1532-ND	3.45	2.13	1.88	LA-401XD	
	黄	589	.40 (10.16)	1	2.05	25	36 90	511-1533-ND	3.45	2.13	1.88	LA-401XN	
	红	626	.57 (14.6)	1	2.05	25	36 90	511-1534-ND	3.00	1.86	1.64	LA-601AB	
	红	626	.57 (14.6)	1	2.05	25	36 90	511-1535-ND	3.00	1.86	1.64	LA-601AL	
	蓝	470	.57 (14.6)	1	3.6	10	14 56	511-1536-ND	10.11	6.53	6.01	LA-601BB	
	蓝	470	.57 (14.6)	1	3.6	10	14 56	511-1537-ND	11.66	8.42	7.49	LA-601BL	
	橙	610	.57 (14.6)	1	2.05	25	36 90	511-1538-ND	3.61	2.17	1.96	LA-601EB	
	橙	610	.57 (14.6)	1	2.05	25	36 90	511-1539-ND	3.61	2.17	1.96	LA-601EL	
	绿	563	.57 (14.6)	1	2.1	20	9 22	511-1540-ND	2.60	1.46	1.28	LA-601MB	
	绿	563	.57 (14.6)	1	2.1	20	9 22	511-1541-ND	2.60	1.46	1.28	LA-601ML	
4	红	650	.57 (14.6)	1	2.0	20	5.6 14	511-1542-ND	2.60	1.46	1.28	LA-601VB	
	红	650	.57 (14.6)	1	2.0	20	5.6 14	511-1543-ND	2.60	1.46	1.28	LA-601VL	
	黄	589	.57 (14.6)	1	2.05	25	36 90	511-1544-ND	3.45	2.13	1.88	LA-601XL	
	黄	589	.57 (14.6)	1	2.05	25	36 90	511-1571-ND	3.45	2.13	1.88	LA-601XB	
	绿	563	.30 (7.62)	2	2.1	20	2.2 6.3	511-1545-ND	4.45	2.68	2.42	LB-302MF	
	绿	563	.30 (7.62)	2	2.1	20	2.2 6.3	511-1546-ND	7.72	5.21	4.59	LB-302MP	
	红	650	.30 (7.62)	2	2.0	15	2.2 6.3	511-1547-ND	5.38	3.14	2.88	LB-302VF	
	红	650	.30 (7.62)	2	2.0	15	2.2 6.3	511-1548-ND	6.35	3.67	3.28	LB-302VP	
	5	橙	610	.40 (10.16)	2	2.0	15	3.6 10	511-1549-ND	4.14	2.49	2.25	LB-402DN
		橙	610	.40 (10.16)	2	2.0	15	3.6 10	511-1550-ND	4.14	2.49	2.25	LB-402DD
绿		563	.40 (10.16)	2	2.1	20	9.0 25	511-1551-ND	7.11	4.10	3.68	LB-402MD	
绿		563	.40 (10.16)	2	2.1	20	9.0 25	511-1552-ND	7.11	4.10	3.68	LB-402MN	
红		650	.40 (10.16)	2	2.0	15	5.6 16	511-1553-ND	7.11	4.10	3.68	LB-402VD	
红		650	.40 (10.16)	2	2.0	15	5.6 16	511-1554-ND	7.11	4.10	3.68	LB-402VN	
6	红	626	.56 (14.3)	2	2.05	25	36 90	511-1555-ND	6.11	3.53	3.16	LB-602AA2	
	红	626	.56 (14.3)	2	2.05	25	36 90	511-1556-ND	6.11	3.53	3.16	LB-602AK2	
	蓝	470	.56 (14.3)	2	3.6	10	14 56	511-1557-ND	16.68	11.82	10.71	LB-602BA2	
	蓝	470	.56 (14.3)	2	3.6	10	14 56	511-1558-ND	16.68	11.82	10.71	LB-602BK2	
	绿	563	.56 (14.3)	2	2.1	20	9 25	511-1559-ND	4.28	2.57	2.33	LB-602MA2	
	绿	563	.56 (14.3)	2	2.1	20	9 25	511-1560-ND	4.28	2.57	2.33	LB-602MK2	
7	红	650	.56 (14.3)	2	2.0	20	5.6 16	511-1561-ND	4.45	2.68	2.42	LB-602VA2	
	红	650	.56 (14.3)	2	2.0	20	5.6 16	511-1562-ND	4.28	2.57	2.33	LB-602VK2	
	绿	563	.31 (8.0)	1	2.1	20	3.6 10	511-1568-1-ND	3.11	1.92	1.69	LF-301MA	
	绿	563	.31 (8.0)	1	2.1	20	3.6 10	511-1568-2-ND	1449.00/1,000			LF-301MA	
	红	650	.31 (8.0)	1	2.0	15	3.6 10	511-1569-1-ND	3.11	1.92	1.69	LF-301VA	
	红	650	.31 (8.0)	1	2.0	15	3.6 10	511-1569-2-ND	1449.00/1,000			LF-301VA	
7	红	650	.31 (8.0)	1	2.0	15	3.6 10	511-1570-1-ND	3.11	1.92	1.69	LF-301VK	
	红	650	.31 (8.0)	1	2.0	15	3.6 10	511-1570-2-ND	1449.00/1,000			LF-301VK	

† 剪切带 ▲ 带卷

## LED 点阵显示器

尺寸 (mm)

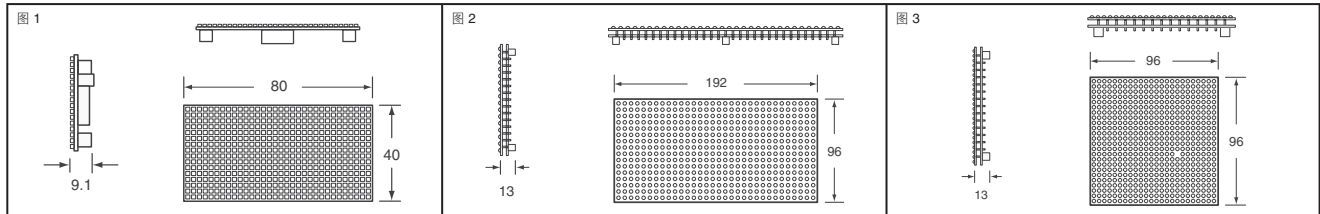


图	阵列	发射颜色	透镜	波长 (nm)	正向电压 (标准) (V)	输出 (烛光)	视角	Digi-Key 零件编号	1	单价 25	100	Rohm 零件编号
1	16x32	红/绿	圆顶	630/570	5	100/200	160°	511-1572-ND	296.24	245.33	231.44	LUM-512CMU300
2	16x32	红/绿	圆顶	624/571	5	250/200	140°	511-1574-ND	170.78	142.32	131.97	LPM-5123MU350
3	24x24	红/绿	圆顶	624/571	5	300/300	140°	511-1575-ND	170.78	142.32	131.97	LPM-5763MU301

全部产品均以美元计价。 免费电话: 10800-1527031 (China Telecom - 中国电讯) — 10800-8527031 (CNCG - 中国网通)