




Dip 线缆组件 (接上页)

双端型号 0

MC=多色
GR=灰色

 
所示为不带应力释放的 DIP 连接器。连接器的引脚 #1 连接到线缆上的第 2 导线芯



触点数	触点表面材料	长度: 英寸 (厘米)	带状线缆* 零件编号	Digi-Key 零件编号		价格		
				1	10	1	10	
14	金	18(45.72)	MC	COPPG-1406M-ND	4.14	31.35		
			MC	COPPS-1406M-ND	3.45	26.18		
			GR	COPPG-1406G-ND	3.71	28.13		
			GR	COPPS-1406G-ND	3.03	22.96		
			MC	COPPG-1418M-ND	5.34	40.47		
			MC	COPPS-1418M-ND	4.66	35.30		
	金	18(45.72)	MC	COPPG-1418G-ND	4.06	30.81		
			MC	COPPS-1418G-ND	3.38	25.64		
			GR	COPPG-1436M-ND	7.14	54.15		
			GR	COPPS-1436M-ND	6.46	48.98		
			MC	COPPG-1436G-ND	4.60	34.84		
			MC	COPPS-1436G-ND	3.91	29.67		
16	金	18(45.72)	MC	COPPG-1606M-ND	4.42	33.53		
			MC	COPPS-1606M-ND	3.58	27.89		
			GR	COPPG-1606G-ND	3.98	30.20		
			GR	COPPS-1606G-ND	3.24	24.56		
			MC	COPPG-1618M-ND	5.71	43.26		
			MC	COPPS-1618M-ND	4.96	37.62		
	金	18(45.72)	MC	COPPG-1618G-ND	4.39	33.26		
			MC	COPPS-1618G-ND	3.64	27.62		
			GR	COPPG-1636M-ND	7.63	57.86		
			GR	COPPS-1636M-ND	6.89	52.22		
			MC	COPPG-1636G-ND	4.99	37.85		
			MC	COPPS-1636G-ND	4.25	32.21		
24	金	18(45.72)	MC	COPPG-2406M-ND	7.20	54.60		
			MC	COPPS-2406M-ND	6.02	45.67		
			GR	COPPG-2406G-ND	6.47	49.04		
			GR	COPPS-2406G-ND	5.29	40.11		
			MC	COPPG-2418M-ND	9.21	69.80		
			MC	COPPS-2418M-ND	8.03	60.87		
	金	18(45.72)	MC	COPPG-2418G-ND	7.01	53.12		
			MC	COPPS-2418G-ND	5.83	44.19		
			GR	COPPG-2436M-ND	12.22	92.60		
			GR	COPPS-2436M-ND	11.04	83.67		
			MC	COPPG-2436G-ND	7.81	59.24		
			MC	COPPS-2436G-ND	6.64	50.31		
40	金	18(45.72)	MC	COPPG-4006M-ND	10.53	79.84		
			MC	COPPS-4006M-ND	8.80	66.68		
			GR	COPPG-4006G-ND	9.46	71.72		
			GR	COPPS-4006G-ND	7.72	58.56		
			MC	COPPG-4018M-ND	13.74	104.16		
			MC	COPPS-4018M-ND	12.00	91.00		
	金	18(45.72)	MC	COPPG-4018G-ND	10.53	79.80		
			MC	COPPS-4018G-ND	8.79	66.64		
			GR	COPPG-4036M-ND	18.55	140.65		
			GR	COPPS-4036M-ND	16.82	127.49		
			MC	COPPG-4036G-ND	12.13	91.92		
			MC	COPPS-4036G-ND	10.39	78.76		

也有下列型号:
CORR□□□□□□-ND - 有应力释放带的 DIP 连接器
欢迎来电咨询完整的零件编号与价格!

插口连接器

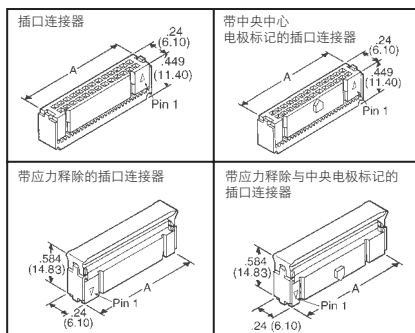

技术规格: • 触点: 磷青铜 • 触点镀层: 在 50μ 英寸镍或 100μ 英寸锡镀层上镀 10μ 英寸金 (在配接区) • 绝缘体材料: UL 94V-0 阻燃热塑性塑料 • 应力释放带材料: 绝缘不锈钢 • 颜色: 蓝色 • 工作温度: -55°C - 125°C • 额定电流: 每个接触最大 1A • 电介质耐受电压: 大于 500VDC (海平面) • 绝缘电阻: 大于 5x10⁹Ω • 标准拔出力: 56.7g - 226.79g/触点 • 盖板最小拉出力 226.79g/触点 (沿触点主轴施力)

触点数	触点表面材料	尺寸A 英寸 (mm)	Digi-Key 零件编号	单价	
				1	10
10	金	.677(17.20)	CSC10G-ND	1.24	.94
	锡	.677(17.20)	CSC10S-ND	1.05	.80
	锡	.677(17.20)	CSC10T-ND	—	—
14	金	.877(22.28)	CSC14G-ND	1.74	1.32
	锡	.877(22.28)	CSC14S-ND	1.49	1.13

触点数	触点表面材料	尺寸 A 英寸 (mm)	Digi-Key 零件编号	单价		
				1	10	100
16	金	.977(24.82)	CSC16G-ND	2.02	1.53	1.17
	锡	.977(24.82)	CSC16S-ND	1.71	1.30	.99
20	金	1.177(29.90)	CSC20G-ND	2.11	1.60	1.23
	锡	1.177(29.90)	CSC20S-ND	1.80	1.37	1.05
	锡	1.177(29.90)	CSC20T-ND	1.80	1.37	1.05
26	金	1.477(37.52)	CSC26G-ND	2.51	1.91	1.46
	锡	1.477(37.52)	CSC26S-ND	2.14	1.63	1.25
34	金	1.877(47.68)	CSC34G-ND	3.10	2.35	1.80
	锡	1.877(47.68)	CSC34S-ND	2.64	2.00	1.53
	锡	1.877(47.68)	CSC34T-ND	2.64	2.00	1.53
40	金	2.177(55.30)	CSC40G-ND	3.41	2.59	1.98
	锡	2.177(55.30)	CSC40S-ND	2.88	2.19	1.68
	锡	2.177(55.30)	CSC40T-ND	2.88	2.19	1.68
50	金	2.677(68.00)	CSC50G-ND	4.09	3.11	2.38
	锡	2.677(68.00)	CSC50S-ND	3.47	2.64	2.02
	锡	2.677(68.00)	CSC50T-ND	—	—	—
60	金	3.177(80.70)	CSC60G-ND	4.99	3.79	2.90
	锡	3.177(80.70)	CSC60S-ND	4.25	3.22	2.47
	锡	3.177(80.70)	CSC60T-ND	4.25	3.22	2.47

带应力释放的插口连接器						
10	金	.677(17.20)	CSR10G-ND	1.52	1.16	.89
	锡	.677(17.20)	CSR10S-ND	1.30	.99	.76
14	金	.877(22.28)	CSR14G-ND	2.02	1.53	1.17
	锡	.877(22.28)	CSR14S-ND	1.71	1.30	.99
16	金	.977(24.82)	CSR16G-ND	2.23	1.70	1.30
	锡	.977(24.82)	CSR16S-ND	1.89	1.44	1.10
20	金	1.177(29.90)	CSR20G-ND	2.36	1.79	1.37
	锡	1.177(29.90)	CSR20S-ND	2.02	1.53	1.17
26	金	1.477(37.52)	CSR26G-ND	2.73	2.07	1.59
	锡	1.477(37.52)	CSR26S-ND	2.33	1.77	1.35
34	金	1.877(47.68)	CSR34G-ND	3.35	2.54	1.95
	锡	1.877(47.68)	CSR34S-ND	2.85	2.17	1.66
40	金	2.177(55.30)	CSR40G-ND	3.63	2.75	2.11
	锡	2.177(55.30)	CSR40S-ND	3.07	2.33	1.79
50	金	2.677(68.00)	CSR50G-ND	4.31	3.27	2.51
	锡	2.677(68.00)	CSR50S-ND	3.66	2.78	2.13
60	金	3.177(80.70)	CSR60G-ND	5.24	3.98	3.05
	锡	3.177(80.70)	CSR60S-ND	4.46	3.39	2.60


带电极标记的插口连接器						
10	金	.677(17.20)	CKC10G-ND	1.24	.94	.72
	锡	.677(17.20)	CKC10S-ND	1.05	.80	.62
14	金	.877(22.28)	CKC14G-ND	1.74	1.32	1.01
	锡	.877(22.28)	CKC14S-ND	1.49	1.13	.87
16	金	.977(24.82)	CKC16G-ND	2.02	1.53	1.17
	锡	.977(24.82)	CKC16S-ND	1.71	1.30	.99
20	金	1.177(29.90)	CKC20G-ND	2.11	1.60	1.23
	锡	1.177(29.90)	CKC20S-ND	1.80	1.37	1.05
26	金	1.477(37.52)	CKC26G-ND	2.51	1.91	1.46
	锡	1.477(37.52)	CKC26S-ND	2.14	1.63	1.25
34	金	1.877(47.68)	CKC34G-ND	3.10	2.35	1.80
	锡	1.877(47.68)	CKC34S-ND	2.64	2.00	1.53
40	金	2.177(55.30)	CKC40G-ND	3.41	2.59	1.98
	锡	2.177(55.30)	CKC40S-ND	2.88	2.19	1.68
50	金	2.677(68.00)	CKC50G-ND	4.09	3.11	2.38
	锡	2.677(68.00)	CKC50S-ND	3.47	2.64	2.02
60	金	3.177(80.70)	CKC60G-ND	4.99	3.79	2.90
	锡	3.177(80.70)	CKC60S-ND	4.25	3.22	2.47

带电极标记与应力释放的插口连接器						
10	金	.677(17.20)	CKR10G-ND	1.52	1.16	.89
	锡	.677(17.20)	CKR10S-ND	1.30	.99	.76
14	金	.877(22.28)	CKR14G-ND	2.02	1.53	1.17
	锡	.877(22.28)	CKR14S-ND	1.71	1.30	.99
16	金	.977(24.82)	CKR16G-ND	2.23	1.70	1.30
	锡	.977(24.82)	CKR16S-ND	1.89	1.44	1.10
20	金	1.177(29.90)	CKR20G-ND	2.36	1.79	1.37
	锡	1.177(29.90)	CKR20S-ND	2.02	1.53	1.17
26	金	1.477(37.52)	CKR26G-ND	2.73	2.07	1.59
	锡	1.477(37.52)	CKR26S-ND	2.33	1.77	1.35
34	金	1.877(47.68)	CKR34G-ND	3.35	2.54	1.95
	锡	1.877(47.68)	CKR34S-ND	2.85	2.17	1.66
40	金	2.177(55.30)	CKR40G-ND	3.63	2.75	2.11
	锡	2.177(55.30)	CKR40S-ND	3.07	2.33	1.79
50	金	2.677(68.00)	CKR50G-ND	4.31	3.27	2.51
	锡	2.677(68.00)	CKR50S-ND	3.66	2.78	2.13
60	金	3.177(80.70)	CKR60G-ND	5.24	3.98	3.05
	锡	3.177(80.70)	CKR60S-ND	4.46	3.39	2.60

PK-1-ND 电极标记..... 25/2 .94/10 7.20/100
◆符合 RoHS 规范要求

PCB 连接器

技术规格: • 触点: 磷青铜 • 触点镀层: 100μ 英寸锡镀层 • 绝缘体材料: UL 94V-0 阻燃热塑性塑料 • 颜色: 蓝色 • 工作温度: -55°C - 125°C • 额定电流: 每个接触最大 1A • 电介质耐受电压: 大于 500VDC (海平面) • 绝缘电阻: 大于 5x10⁹Ω • 无应力释放的盖板, 最小拉出力为 5.60kg (沿触点主轴施力)

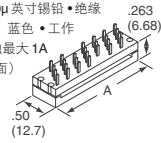

触点数	触点表面材料	尺寸 A 英寸 (mm)	Digi-Key 零件编号	单价		
				1	10	100
10	锡	0.700(17.78)	CPC10S-ND	1.36	1.04	.80
	锡	0.700(17.78)	CPC10T-ND	—	—	.80
20	锡	1.200(30.48)	CPC20S-ND	1.58	1.20	.92
	锡	1.500(38.10)	CPC26S-ND	2.05	1.56	1.19
26	锡	1.500(38.10)	CPC26T-ND	—	—	1.19
	锡	1.900(48.26)	CPC34S-ND	2.51	1.91	1.46
34	锡	1.900(48.26)	CPC34T-ND	—	—	1.46
	锡	2.200(55.88)	CPC40S-ND	2.85	2.17	1.66
50	锡	2.200(55.88)	CPC40T-ND	2.85	2.17	1.66
	锡	2.700(68.58)	CPC50S-ND	3.57	2.71	2.07
60	锡	3.200(81.28)	CPC60S-ND	4.09	3.11	2.38
	锡	3.200(81.28)	CPC60T-ND	4.09	3.11	2.38

◆ 整排型。(上面所示为“特殊中心”型。)
◆ 符合 RoHS 规范要求

卡边连接器

技术规格: • 触点: 磷青铜 • 触点镀层: 在 50μ 英寸镍或 100μ 英寸锡镀层上镀 10μ 英寸金 (在配接区) • 绝缘体材料: UL 94V-0 阻燃热塑性塑料 • 颜色: 蓝色 • 工作温度: -55°C - 125°C • 额定电流: 每个接触最大 1A • 电介质耐受电压: 大于 500Vdc (海平面) • 绝缘电阻: 大于 5x10⁹Ω • 盖板最小拉出力, 每触点 226.79g (沿触点主轴施力)

