

# ASSMANN 计算机线缆组件

A

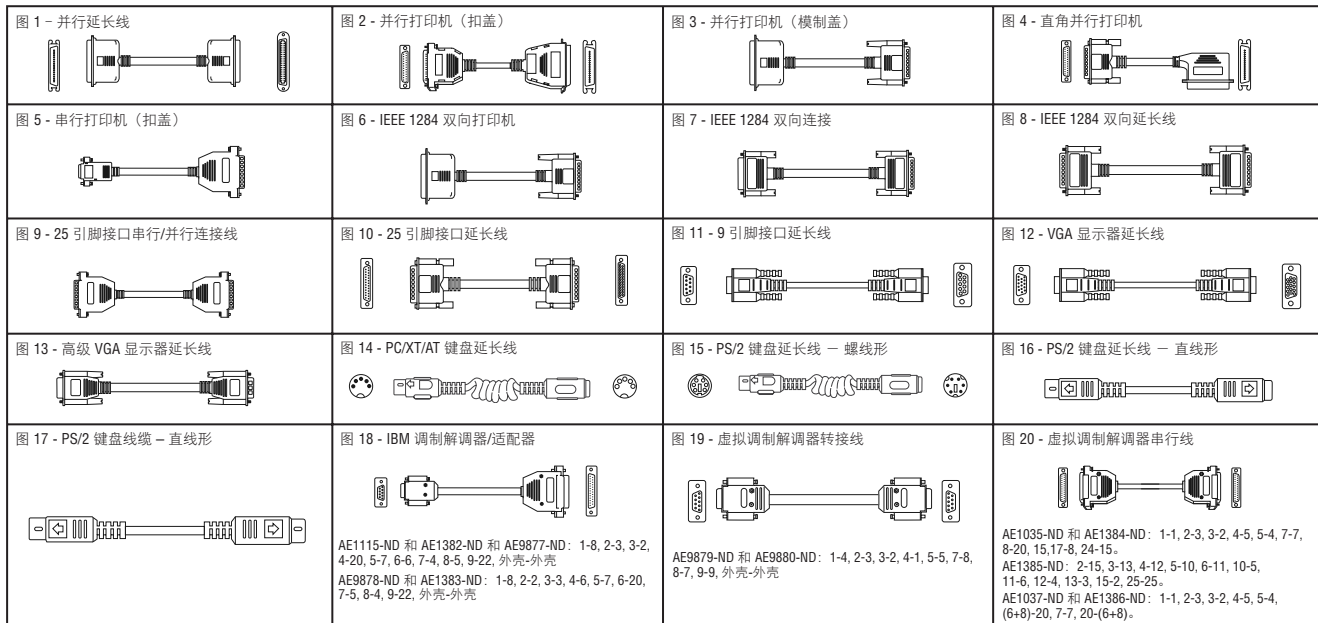


图	长度英尺 (米)	线数	说明	Digi-Key 零件编号	1	单价 10	25	Assmann 零件编号	
<i>用于 36 引脚 Centronics 接口的模制延长线</i>									
1	6.56 (2) 9.84 (3)	36	2x Centronics 36 引脚母形至母形	AE1000-ND AE1001-ND	12.38 16.50	10.88 14.50	9.75 13.00	AK155-2 AK434-3	
	6.56 (2) 6.56 (2) 9.84 (3)	36	2x Centronics 36 引脚公形至公形	AE1002-ND AE1362-ND◆ AE1363-ND◆	10.73 14.92 20.36	9.43 13.11 17.90	8.45 11.76 16.05	AK138-2 AK138-2-R AK426-3-R	
	6.56 (2) 6.56 (2) 9.84 (3) 9.84 (3)	36	2x Centronics 36 引脚公形至母形	AE1004-ND AE1364-ND◆ AE1005-ND AE1365-ND◆	11.55 15.68 15.68 17.99	10.15 13.78 13.78 15.81	9.10 12.35 12.35 14.17	AK140-2 AK140-2-R AK430-3 AK430-3-R	
	<i>并行打印机线缆, IBM 计算机与兼容计算机</i>								
	2	5.90 (1.8) 9.84 (3) 9.84 (3) 22.96 (7)	25	D-Sub 25 引脚公形至 Centronics 36 引脚公形, 扣盖	AE1366-ND◆ AE1007-ND AE1367-ND◆ AE9853-ND◆	9.77 7.99 12.41 16.17	8.59 7.02 10.91 14.21	7.70 6.30 9.78 12.74	AK101-1.8-R AK102-3 AK102-3-R AK104-7-R
		6.56 (2) 9.84 (3) 22.96 (7)	25	D-Sub 25 引脚公形至 Centronics 36 引脚公形, 模制盖	AE9858-ND◆ AE1368-ND◆ AE9859-ND◆	9.34 9.14 14.52	8.21 8.04 12.76	7.36 7.21 11.44	AK108-2-R AK127-3-R AK159-7-R
6.56 (2) 6.56 (2) 6.56 (2)		25	D-Sub 25 引脚公形至直角 Centronics 36 引脚公形 D-Sub 25 引脚公形至左角 Centronics 36 引脚公形	AE9860-ND◆ AE1009-ND AE1369-ND◆	10.92 8.25 9.74	9.60 7.25 8.56	8.61 6.50 7.67	AK525-2-R AK525-L2 AK525-L2-R	
<i>串行打印机线缆, IBM 计算机与兼容计算机 - 符合 RoHS 规范要求</i>									
5	9.84 (3)	8	D-Sub 9 引脚母形至 D-Sub 25 引脚公形, 扣盖	AE1370-ND	7.46	6.56	5.88	AK150-3-R	
<i>IEEE 1284 双向线缆 - 模制盖</i>									
6	5.90 (1.8) 5.90 (1.8) 9.84 (3) 16.40 (5) 16.40 (5)	25	D-Sub 25 引脚公形至 Centronics 36 引脚公形, 打印机	AE1105-ND AE1371-ND◆ AE1372-ND◆ AE1107-ND AE1373-ND◆	10.26 16.14 22.61 18.65 31.61	9.02 14.19 19.87 16.39 27.79	8.09 12.72 17.81 14.69 24.91	AK711-1.8 AK711-1.8-R AK712-3-R AK713-5 AK713-5-R	
	5.90 (1.8) 9.84 (3) 9.84 (3) 16.40 (5) 16.40 (5)			25	D-Sub 25 引脚公形至 D-Sub 25 引脚母形, 连接线	AE9861-ND◆ AE1109-ND AE1374-ND◆ AE1110-ND AE1375-ND◆	17.16 14.59 24.16 20.53 31.61	15.08 12.82 21.23 18.04 27.79	13.52 11.50 19.04 16.18 24.91
8	5.90 (1.8) 9.84 (3) 16.40 (5)	25	D-Sub 25 引脚公形至 D-Sub 25 引脚公形, 延长线	AE9862-ND◆ AE1376-ND◆ AE1377-ND◆	18.32 24.16 31.61	16.10 21.23 27.79	14.43 19.04 24.91	AK736-1.8-R AK737-2-R AK738-5-R	
<i>用于 25 引脚接口的扣盖连接线 - 符合 RoHS 规范要求</i>									
9	6.56 (2)	25	D-Sub 25 引脚公形至 D-Sub 25 引脚公形, 扣盖	AE9863-ND	7.59	6.67	5.98	AK401-2-R	
<i>用于 25 引脚接口的模制延长线</i>									
10	6.56 (2) 6.56 (2) 9.84 (3)	25	2x D-Sub 25 引脚公形至公形	AE1010-ND AE1378-ND◆ AE9864-ND◆	6.93 10.00 13.40	6.09 8.79 11.78	5.46 7.88 10.56	AK137-2 AK137-2-R AK162-3-R	
	6.56 (2) 9.84 (3)	25	2x D-Sub 25 引脚公形至母形	AE9865-ND◆ AE9866-ND◆	11.45 11.02	10.07 9.69	9.03 8.69	AK135-2-R AK166-3-R	
	6.56 (2) 9.84 (3)	25	2x D-Sub 25 引脚母形至母形	AE9867-ND◆ AE9868-ND◆	9.64 12.94	8.47 11.37	7.60 10.20	AK133-2-R AK170-3-R	
<i>用于 9 引脚接口的模制延长线 - 符合 RoHS 规范要求</i>									
11	6.56 (2) 9.84 (3)	9	2x D-Sub 9 引脚公形至公形	AE9869-ND AE9870-ND	7.36 8.15	6.47 7.17	5.80 6.43	AK129-2-R AK174-3-R	

◆ 符合 RoHS 规范要求

(转下页)

全部产品均以美元计价。 免费电话: 10800-1527031 (China Telecom - 中国电讯) — 10800-8527031 (CNCG - 中国网通)  
digikey.com.cn — 电话: (852) 3104 0500 — 传真: (852) 3104 0686