


ASSMANN SCSI、串行 ATA、USB、CAT5e 和 CAT6 计算机线缆组件 (接上页)

A

图	长度 (米)	线数	说明	Digi-Key 零件编号	1	10	25	Assmann 零件编号
IEEE 1394 线缆双屏蔽								
30	1.8	6	6 引脚公形至 6 引脚公形	AE1432-ND◆	15.08	13.26	11.89	AK-1394-18-R
	3.0			AE1433-ND◆	18.68	16.42	14.72	AK-1394-30-R
	5.0			AE1131-ND	24.16	22.30	20.74	AK-1394-50
	5.0			AE1434-ND◆	23.04	21.27	19.78	AK-1394-50-R
31	1.8	4	6 引脚公形至 4 引脚公形	AE1126-ND	21.81	19.17	17.19	AK-1394-184
	1.8			AE1435-ND◆	13.96	12.27	11.00	AK-1394-184-R
	3.0			AE1129-ND	22.25	20.23	18.21	AK-1394-304
	3.0			AE1436-ND◆	13.34	12.13	10.92	AK-1394-304-R
	5.0			AE1132-ND	24.63	22.73	21.14	AK-1394-504
	5.0			AE1437-ND◆	21.04	19.42	18.06	AK-1394-504-R
32	1.8	4	4 引脚公形至 4 引脚公形	AE1127-ND	23.38	21.25	19.13	AK-1394-1844
	1.8			AE1438-ND◆	11.94	10.85	9.77	AK-1394-1844-R
	5.0			AE1133-ND	29.03	26.79	24.92	AK-1394-5044
IEEE 1394 和 USB 连接器								
33	—	—	IEEE 1394 插座, 水平, SMT	AE7348-ND	2.00	1.76	1.58	A-IE-S-SMT
34	—	—	IEEE 1394 插座, 水平, PCB	AE9920-ND◆	2.84	2.50	2.24	A-IE-S-SMT-R
35	—	—	IEEE 1394 插座, 垂直, PCB	AE9921-ND◆	2.71	2.38	2.14	A-IE-S-DIP-R
36	—	4	USB 4P 插座通孔, A 型	AE9923-ND◆	.86	.76	.68	AU-Y1005-R
	—	4	USB 4P 插座, SMT, A 型	AE9924-ND◆	1.09	.96	.86	AU-Y1006-R
37	—	4	USB 4P 插座通孔, B 型	AE9925-ND◆	1.09	.96	.86	AU-Y1007-R
38	—	4	USB 4P 插座, 双端口, A 型	AE9926-ND◆	1.65	1.45	1.30	AU-Y1008-R
USB 插头和挡盖								
39	—	—	USB A-公形, 焊接型	AE10091-ND◆	.43	.38	.34	A-USBPA-R
	—	—	用于 USB A 公形的挡盖	AE10090-ND◆	.40	.35	.32	A-USBPA-HOOD-R
	—	—	用于 USB B 公形的挡盖	AE1137-ND	.43	.38	.34	A-USBPB-HOOD
	—	—	用于 USB B 公形的挡盖	AE1441-ND◆	.40	.35	.32	A-USBPB-HOOD-R
	—	—	USB B-公形, 焊接型	AE10178-ND◆	.43	.38	.34	A-USBPB-R
USB 线缆								
40	1.0	4	Mini USB 线缆, 4 引脚公形	AE1442-ND◆	4.59	4.04	3.62	AK670M-1-R
	2.0			AE1281-ND	3.00	2.64	2.37	AK670M-2
	2.0			AE1443-ND◆	5.64	4.96	4.45	AK670M-2-R
	5.0			AE1283-ND	4.36	3.83	3.44	AK670M-5
41	1.0	4	Mini USB 2.0 线缆, 4 引脚公形	AE1444-ND◆	5.18	4.56	4.09	AK670M/2-1-R
	2.0			AE1445-ND◆	6.24	5.49	4.92	AK670M/2-2-R
	3.0			AE1290-ND	3.76	3.31	2.97	AK670M/2-3
	3.0			AE1446-ND◆	7.66	6.73	6.04	AK670M/2-3-R
	5.0			AE1447-ND◆	10.79	9.49	8.51	AK670M/2-5-R
42	1.0	4	Mini USB 线缆, 5 引脚公形	AE1448-ND◆	5.97	5.25	4.71	AK672M-1-R
	2.0			AE9927-ND◆	6.47	5.69	5.10	AK672M-2-R
	3.0			AE9928-ND◆	6.60	5.80	5.20	AK672M-3-R
	3.0			AE1449-ND◆	9.37	8.24	7.39	AK672M-5-R
	5.0			AE1450-ND◆	3.42	2.44	2.32	AK672M/2-1-R
43	1.0	4	Mini USB 2.0 线缆, 5 引脚公形	AE9929-ND◆	4.93	3.52	3.35	AK672M/2-2-R
	2.0			AE1451-ND◆	5.99	4.28	4.07	AK672M/2-3-R
	3.0			AE1452-ND◆	9.17	8.07	7.23	AK672M/2-5-R
	5.0			AE10311-ND◆	5.48	4.82	4.32	AK669M-1-R
44	1.0	4	USB 线缆, A 公形, 开端	AE10312-ND◆	6.07	5.34	4.79	AK669M-2-R
	2.0			AE9855-ND◆	3.47	2.48	2.36	AK670-OE-R
45	2.0	4	USB 线缆, A-A 公形	AE9930-ND◆	6.34	5.57	5.00	AK670/2-R
	5.0			AE1453-ND◆	11.52	10.13	9.08	AK670-5-R
	1.0			AE1454-ND◆	4.72	4.15	3.72	AK670/2-1-R
	3.0			AE1455-ND◆	8.09	7.11	6.37	AK670/2-3-R
46	5.0	4	USB 2.0 线缆, A-A 公形	AE1456-ND◆	11.65	10.24	9.18	AK670/2-5-R
	2.0			AE1151-ND	4.95	4.35	3.90	AK673-2
	2.0			AE1457-ND◆	7.13	6.27	5.62	AK673-2-R
	5.0			AE1152-ND	7.95	6.99	6.27	AK673-5
47	1.0	4	USB 2.0 线缆, B-B 公形	AE1458-ND◆	4.72	4.15	3.72	AK673/2-1-R
	2.0			AE1305-ND	3.50	3.08	2.76	AK673/2-2
	2.0			AE1459-ND◆	5.97	5.25	4.71	AK673/2-2-R
	3.0			AE1306-ND	4.22	3.72	3.33	AK673/2-3
48	5.0	4	USB 2.0 线缆, B-B 公形	AE1460-ND◆	11.52	10.13	9.08	AK673/2-5-R
	1.5			AE9931-ND◆	5.87	5.17	4.63	AU-Y1002A-R
	2.0			AE9932-ND◆	6.01	5.28	4.74	AK672-2-R
	5.0			AE1461-ND◆	10.26	9.02	8.09	AK672-5-R
49	1.0	—	USB 2.0 线缆, A-B 公形	AE1462-ND◆	2.77	1.98	1.89	AK672/2-1-R
	2.0			AE1493-ND◆	3.95	2.82	2.68	AK672/2-2-R
	3.0			AE1463-ND◆	5.54	3.96	3.77	AK672/2-3-R
	3.0			AE9933-ND◆	9.90	8.70	7.80	AK672/2-5-R
	5.0			AE1361-ND◆	7.49	6.59	5.91	AK672MB-R
50	2.0	4	USB 线缆, A-B 公形, iMac 蓝色	AE1464-ND◆	7.49	6.59	5.91	AK672MG-R
	2.0			AE1465-ND◆	7.49	6.59	5.91	AK672ML-R
	2.0			AE1466-ND◆	7.49	6.59	5.91	AK672MS-R
	2.0			AE9934-ND◆	6.80	5.98	5.36	AK669-1.8-R
51	3.0	4	USB A 公形至 USB A 母形, 双屏蔽	AE9935-ND◆	8.61	7.57	6.79	AK669-3-R
	5.0			AE1468-ND◆	13.23	11.63	10.43	AK669-50-R
	5.0			AE1470-ND◆	5.38	4.73	4.24	AK673-OE-R

◆ 符合 RoHS 规范要求

(转下页)

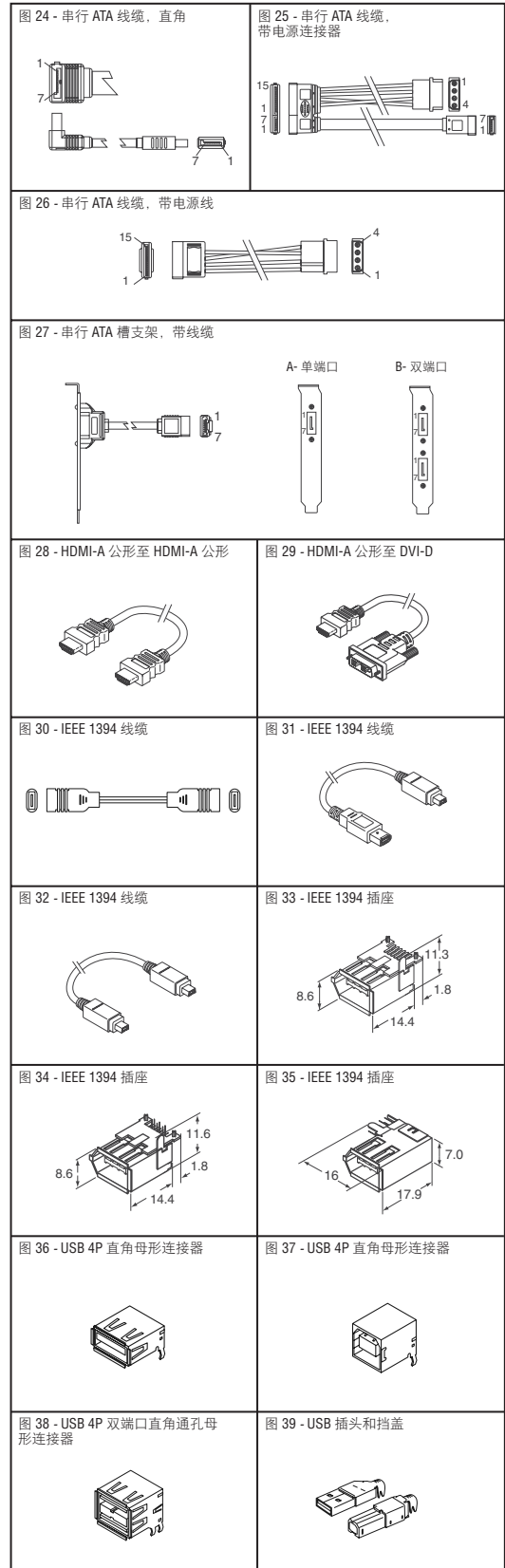

全部产品均以美元计价。 免费电话: 10800-1527031 (China Telecom - 中国电讯) — 10800-8527031 (CNCG - 中国网通)

60 (CN082-09)

digikey.com.cn — 电话: (852) 3104 0500 — 传真: (852) 3104 0686