

A

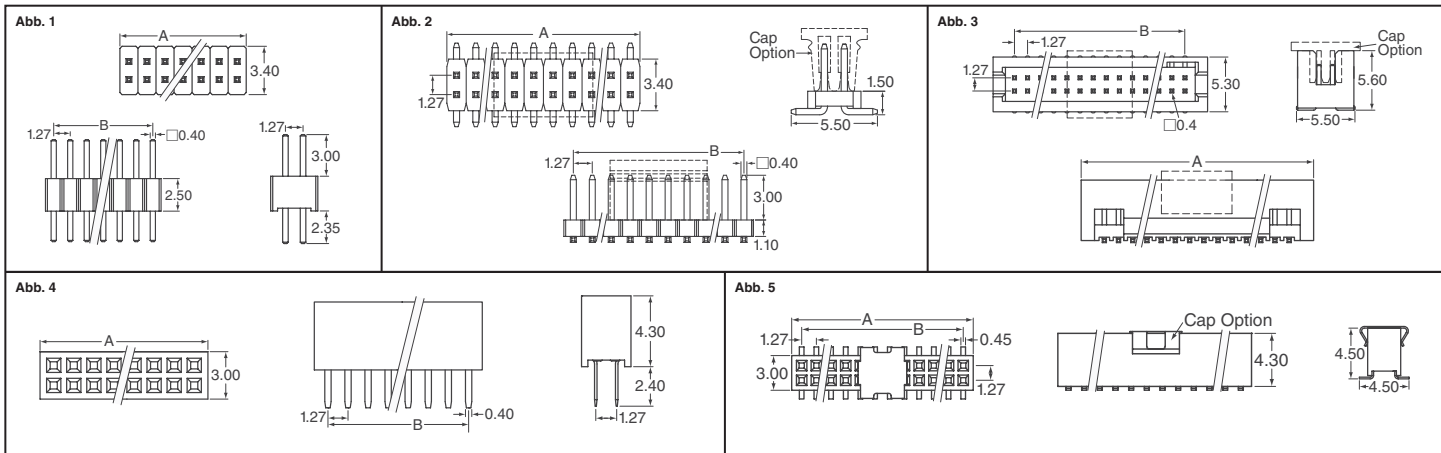


Abb.	Anz. d. Pole	Abm. (mm)		Digi-Key Teile-Nr.	Preisangaben			FCI Teile-Nr.
		A	B		1	25	100	
<b>Zweireihig, vertikale Steckleiste, ohne Kontaktschutz, Durchsteckmontage</b>								
1	6	3.81	2.81	609-3710-ND	.56	7.02	22.44	20021111-00006T4LF
	8	5.08	4.08	609-3711-ND	.71	8.92	28.98	20021111-00008T4LF
	10	6.35	5.35	609-3712-ND	.84	10.55	35.64	20021111-00010T4LF
	12	7.62	6.62	609-3713-ND	.94	12.33	42.60	20021111-00012T4LF
	14	8.89	7.89	609-3714-ND	1.04	14.29	48.06	20021111-00014T4LF
	16	10.16	9.16	609-3715-ND	1.16	15.59	53.46	20021111-00016T4LF
	18	11.43	10.43	609-3716-ND	1.26	17.59	60.31	20021111-00018T4LF
	20	12.70	11.70	609-3717-ND	1.38	18.67	65.32	20021111-00020T4LF
	22	13.97	12.97	609-3718-ND	1.51	20.46	71.60	20021111-00022T4LF
	24	15.24	14.24	609-3719-ND	1.61	22.39	78.35	20021111-00024T4LF
	26	16.51	15.51	609-3720-ND	1.70	24.20	83.73	20021111-00026T4LF
	30	19.05	18.05	609-3721-ND	1.91	27.34	97.03	20021111-00030T4LF
	34	21.59	20.59	609-3722-ND	2.09	30.85	109.47	20021111-00034T4LF
	36	22.86	21.86	609-3723-ND	2.19	32.74	114.15	20021111-00036T4LF
	40	25.40	24.40	609-3724-ND	2.39	35.55	127.23	20021111-00040T4LF
	50	31.75	30.75	609-3725-ND	2.79	42.95	151.38	20021111-00050T4LF
	60	38.10	37.10	609-3726-ND	3.26	52.00	183.24	20021111-00060T4LF
	80	50.80	49.80	609-3727-ND	4.16	65.07	237.98	20021111-00080T4LF
90	57.15	56.15	609-3728-ND	4.64	73.88	270.18	20021111-00090T4LF	
<b>Zweireihig, vertikale Steckleiste, ohne Kontaktschutz, SMD</b>								
2	4	2.54	1.54	609-3692-1-ND†	.62	7.87	25.58	20021121-00004C4LF
	4	2.54	1.54	609-3692-2-ND‡	221.33/900			20021121-00004C4LF
	6	3.81	2.81	609-3693-1-ND†	.75	9.43	31.88	20021121-00006C4LF
	6	3.81	2.81	609-3693-2-ND‡	278.02/900			20021121-00006C4LF
	8	5.08	4.08	609-3694-1-ND†	.82	11.22	37.73	20021121-00008C4LF
	8	5.08	4.08	609-3694-2-ND‡	327.21/900			20021121-00008C4LF
	10	6.35	5.35	609-3729-ND	.97	12.66	43.73	20021121-00010T4LF
	10	6.35	5.35	609-3695-1-ND†	.94	13.21	43.24	20021121-00010C4LF
	10	6.35	5.35	609-3695-2-ND‡	380.54/900			20021121-00010C4LF
	12	7.62	6.62	609-3696-1-ND†	1.08	14.53	49.83	20021121-00012C4LF
	12	7.62	6.62	609-3696-2-ND‡	429.84/900			20021121-00012C4LF
	14	8.89	7.89	609-3730-ND	1.23	16.50	56.56	20021121-00014T4LF
	16	10.16	9.16	609-3697-1-ND†	1.29	17.47	61.13	20021121-00016C4LF
	16	10.16	9.16	609-3697-2-ND‡	542.38/900			20021121-00016C4LF
	18	11.43	10.43	609-3731-ND	1.47	19.87	69.54	20021121-00018T4LF
	20	12.70	11.70	609-3698-1-ND†	1.47	21.08	72.91	20021121-00020C4LF
	20	12.70	11.70	609-3698-2-ND‡	654.38/900			20021121-00020C4LF
	22	13.97	12.97	609-3732-ND	1.68	24.03	83.15	20021121-00022T4LF
	24	15.24	14.24	609-3733-ND	1.78	26.13	90.41	20021121-00024T4LF
	26	16.51	15.51	609-3734-ND	1.92	27.51	97.63	20021121-00026T4LF
	30	19.05	18.05	609-3735-ND	2.11	31.57	110.08	20021121-00030T4LF
	34	21.59	20.59	609-3736-ND	2.38	35.66	124.36	20021121-00034T4LF
	36	22.86	21.86	609-3737-ND	2.47	36.74	131.49	20021121-00036T4LF
	40	25.40	24.40	609-3738-ND	2.66	40.68	141.32	20021121-00040T4LF
50	31.75	30.75	609-3739-ND	3.20	49.25	173.58	20021121-00050T4LF	
60	38.10	37.10	609-3740-ND	3.69	57.32	207.62	20021121-00060T4LF	
80	50.80	49.80	609-3741-ND	4.65	74.06	270.85	20021121-00080T4LF	
90	57.15	56.15	609-3742-ND	4.94	82.18	294.52	20021121-00090T4LF	
<b>Zweireihig, vertikale Steckleiste, mit Kontaktschutz, SMD</b>								
3	6	6.80	2.54	609-3699-1-ND†	1.11	15.34	52.60	20021221-00006C4LF
	6	6.80	2.54	609-3699-2-ND‡	411.38/800			20021221-00006C4LF
	8	8.07	3.81	609-3743-ND	1.23	17.14	58.77	20021221-00008T4LF
	10	9.34	5.08	609-3700-1-ND†	1.27	17.26	60.39	20021221-00010C4LF
	10	9.34	5.08	609-3700-2-ND‡	476.35/800			20021221-00010C4LF
	12	10.16	6.35	609-3701-1-ND†	1.30	18.02	63.06	20021221-00012C4LF
	12	10.16	6.35	609-3701-2-ND‡	497.39/800			20021221-00012C4LF
	14	11.88	7.62	609-3744-ND	1.47	19.81	69.33	20021221-00014T4LF

Abb.	Anz. d. Pole	Abm. (mm)		Digi-Key Teile-Nr.	Preisangaben			FCI Teile-Nr.
		A	B		1	25	100	
3	16	13.15	8.89	609-3702-1-ND†	1.41	20.13	69.65	20021221-00016C4LF
	16	13.15	8.89	609-3702-2-ND‡	555.72/800			20021221-00016C4LF
	20	15.69	11.43	609-3703-1-ND†	1.64	23.49	83.35	20021221-00020C4LF
	20	15.69	11.43	609-3703-2-ND‡	1329.78/1600			20021221-00020C4LF
	26	19.50	15.24	609-3745-ND	2.13	31.98	111.54	20021221-00026T4LF
	30	22.04	17.78	609-3746-ND	2.45	36.40	130.28	20021221-00030T4LF
	34	24.58	20.32	609-3747-ND	2.66	40.70	141.37	20021221-00034T4LF
	40	28.39	24.13	609-3748-ND	3.05	47.06	165.83	20021221-00040T4LF
	50	34.74	30.48	609-3749-ND	3.71	57.55	208.43	20021221-00050T4LF
	60	41.09	36.83	609-3750-ND	4.23	66.08	241.67	20021221-00060T4LF
80	53.79	49.53	609-3751-ND	5.32	88.44	316.96	20021221-00080T4LF	
<b>Zweireihig, vertikale Steckbuchse, Durchsteckmontage</b>								
4	6	5.19	2.81	609-3752-ND	.90	11.93	40.30	20021311-00006T4LF
	8	6.92	4.08	609-3753-ND	.98	13.38	45.02	20021311-00008T4LF
	10	8.65	5.35	609-3754-ND	1.20	16.16	55.39	20021311-00010T4LF
	12	10.38	6.62	609-3755-ND	1.38	19.28	66.11	20021311-00012T4LF
	14	12.11	7.89	609-3756-ND	1.53	21.28	74.46	20021311-00014T4LF
	16	13.84	9.16	609-3757-ND	1.70	24.27	83.98	20021311-00016T4LF
	18	15.57	10.43	609-3758-ND	1.88	27.01	95.84	20021311-00018T4LF
	20	17.30	11.70	609-3759-ND	2.00	29.62	105.12	20021311-00020T4LF
	22	19.03	12.97	609-3760-ND	2.20	33.05	115.25	20021311-00022T4LF
	24	20.76	14.24	609-3761-ND	2.36	35.45	123.64	20021311-00024T4LF
	26	22.49	15.51	609-3762-ND	2.48	38.09	136.30	20021311-00026T4LF
	30	25.95	18.05	609-3763-ND	2.83	43.42	150.83	20021311-00030T4LF
	34	29.41	20.59	609-3764-ND	3.13	48.31	170.27	20021311-00034T4LF
	36	31.14	21.86	609-3765-ND	3.22	49.95	180.92	20021311-00036T4LF
	40	34.60	24.40	609-3766-ND	3.53	54.83	198.60	20021311-00040T4LF
	50	43.25	30.75	609-3767-ND	4.24	66.18	242.01	20021311-00050T4LF
	60	51.90	37.10	609-3768-ND	4.93	79.94	292.35	20021311-00060T4LF
	80	69.20	49.80	609-3769-ND	6.17	106.70	377.44	20021311-00080T4LF
90	77.85	56.15	609-3770-ND	6.82	116.05	417.78	20021311-00090T4LF	
<b>Zweireihig, vertikale Steckbuchse, SMD</b>								
5	6	5.19	2.81	609-3704-1-ND†	.97	13.65	44.68	20021321-00006C4LF
	6	5.19	2.81	609-3704-2-ND‡	354.10/800			20021321-00006C4LF
	8	6.92	4.08	609-3705-1-ND†	1.03	13.88	47.57	20021321-00008C4LF
	8	6.92	4.08	609-3705-2-ND‡	984.90/2,400			20021321-00008C4LF
	10	8.65	5.35	609-3706-1-ND†	1.07	14.77	50.63	20021321-00010C4LF
	10	8.65	5.35	609-3706-2-ND‡	1187.68/2,400			20021321-00010C4LF
	12	10.38	6.62	609-3707-1-ND†	1.22	16.42	57.49	20021321-00012C4LF
	12	10.38	6.62	609-3707-2-ND‡	453.38/800			20021321-00012C4LF
	14	12.11	7.89	609-3771-ND	1.24	17.35	59.49	20021321-00014T4LF
	16	13.84	9.16	609-3708-1-ND†	1.49	21.25	73.51	20021321-00016C4LF
	16	13.84	9.16	609-3708-2-ND‡	586.38/800			20021321-00016C4LF
	18	15.57	10.43	609-3772-ND	1.73	24.66	85.31	20021321-00018T4LF
	20	17.30	11.70	609-3709-1-ND†	1.77	25.42	90.19	20021321-00020C4LF
	20	17.30	11.70	609-3709-2-ND‡	695.58/800			20021321-00020C4LF
	22	19.03	12.97	609-3773-ND	1.99	29.39	104.29	20021321-00022T4LF
	24	20.76	14.24	609-3774-ND	2.16	32.45	113.15	20021321-00024T4LF
	26	22.49	15.51	609-3775-ND	2.33	34.95	121.87	20021321-00026T4LF
	30	25.95	18.05	609-3776-ND	2.58	39.54	137.34	20021321-00030T4LF
	34	29.41	20.59	609-3777-ND	2.83	43.64	153.78	20021321-00034T4LF
	36	31.14	21.86	609-3778-ND	2.99	46.18	162.77	20021321-00036T4LF
	40	34.60	24.40	609-3779-ND	3.21</			