

Abb.	Anz. d. Pole	Überzug	Abmessungen – Zoll (mm)		Digi-Key Teile-Nr.	Preisangaben			FCI Teile-Nr.	
			A	B		1	25	100		
<b>Geräte, zweireihig, SMT</b>										
5	40	30 µ" Gold	0.230 (5.84)	—	609-2231-ND	1.19	18.51	95157-140LF		
	40	15 µ" Gold	0.230 (5.84)	—	609-2232-ND	1.21	18.72	95157-240LF		
	40	Zinn	0.230 (5.84)	—	609-3124-ND	.94	14.51	95157-440LF		
	10	30 µ" Gold	0.230 (5.84)	—	609-3483-1-ND	1.11	15.58	95278-101A10LF		
	10	30 µ" Gold	0.230 (5.84)	—	609-3483-2-ND	155.74/300	—	95278-101A10LF		
	12	30 µ" Gold	0.230 (5.84)	—	609-3484-1-ND	1.04	14.64	95278-101A12LF		
	12	30 µ" Gold	0.230 (5.84)	—	609-3484-2-ND	148.13/300	—	95278-101A12LF		
	14	30 µ" Gold	0.230 (5.84)	—	609-3485-1-ND	1.19	14.87	95278-101A14LF		
	14	30 µ" Gold	0.230 (5.84)	—	609-3485-2-ND	167.33/300	—	95278-101A14LF		
	16	30 µ" Gold	0.230 (5.84)	—	609-3486-1-ND	1.10	15.45	95278-101A16LF		
	16	30 µ" Gold	0.230 (5.84)	—	609-3486-2-ND	154.48/300	—	95278-101A16LF		
	06	30 µ" Gold	0.230 (5.84)	—	609-3487-1-ND	.95	13.45	95278-101A06LF		
	06	30 µ" Gold	0.230 (5.84)	—	609-3487-2-ND	156.88/350	—	95278-101A06LF		
	<b>Einreihiges Gehäuse mit Polarisationsstecker</b>									
	6	2	—	0.273 (6.93)	0.200 (5.08)	609-3605-ND	.95	13.15	67954-001LF	
		3	—	0.373 (9.47)	0.300 (7.62)	609-3606-ND	1.11	15.54	67954-002LF	
4		—	0.473 (12.01)	0.400 (10.16)	609-3607-ND	1.24	17.11	67954-003LF		
<b>Einreihige vertikale Steckbuchse, Durchsteckmontage</b>										
7	6	30 µ" Gold	0.597 (15.16)	0.500 (12.70)	609-3558-ND	.99	13.61	75915-306LF		
	8	30 µ" Gold	0.797 (20.24)	0.700 (17.78)	609-3559-ND	1.25	16.80	75915-308LF		
	10	30 µ" Gold	0.997 (25.32)	0.900 (22.86)	609-3550-ND	1.43	19.40	75915-310LF		
	12	30 µ" Gold	1.197 (30.4)	1.100 (27.94)	609-3553-ND	1.63	23.27	75915-312LF		
8	6	30 µ" Gold	0.617 (15.67)	—	609-3588-ND	2.30	34.46	68685-306LF		
	8	30 µ" Gold	0.817 (20.75)	—	609-3589-ND	2.56	39.30	68685-308LF		
10	30 µ" Gold	1.017 (25.83)	—	609-3584-ND	3.21	49.54	68685-310LF			

Abb.	Anz. d. Pole	Überzug	Abmessungen – Zoll (mm)		Digi-Key Teile-Nr.	Preisangaben			FCI Teile-Nr.
			A	B		1	25	100	
8	16	30 µ" Gold	1.617 (41.07)	—	609-3586-ND	3.90	60.48	68685-316LF	
	20	30 µ" Gold	2.017 (51.23)	—	609-3587-ND	4.17	65.25	68685-320LF	
<b>Zweireihige vertikale Steckbuchse, Durchsteckmontage</b>									
9	16	30 µ" Gold	0.797 (20.24)	0.700 (17.78)	609-3554-ND	2.11	31.20	87606-308LF	
	20	30 µ" Gold	0.997 (25.32)	0.900 (22.86)	609-3555-ND	2.48	36.84	87606-310LF	
	40	30 µ" Gold	1.997 (50.72)	1.900 (48.26)	609-3556-ND	6.33	109.53	87606-320LF	
10	6	30 µ" Gold	0.317 (8.05)	—	609-3582-ND	1.75	25.67	68683-303LF	
	8	30 µ" Gold	0.417 (10.59)	—	609-3583-ND	1.98	29.22	68683-304LF	
	10	30 µ" Gold	0.517 (13.13)	—	609-3573-ND	1.52	20.53	68683-305LF	
	14	30 µ" Gold	0.717 (18.21)	—	609-3574-ND	1.96	28.09	68683-307LF	
	16	30 µ" Gold	0.817 (20.75)	—	609-3575-ND	2.16	32.38	68683-308LF	
	26	30 µ" Gold	1.317 (33.45)	—	609-3577-ND	3.27	50.37	68683-313LF	
11	36	30 µ" Gold	1.817 (46.15)	—	609-3578-ND	4.32	67.49	68683-318LF	
	40	30 µ" Gold	2.017 (51.23)	—	609-3579-ND	4.72	75.20	68683-320LF	
	50	30 µ" Gold	2.517 (63.93)	—	609-3580-ND	5.42	90.21	68683-325LF	
	64	30 µ" Gold	3.217 (81.71)	—	609-3581-ND	8.08	138.83	68683-332LF	



Abb.	Gehäusefarbe	Überzug	Abmessungen – Zoll (mm)			Digi-Key Teile-Nr.	Preisangaben			FCI Teile-Nr.
			A	B	C		1	25	100	
<b>Shunts</b>										
11	Weiß	30 µ" Gold	0.236 (6.0)	0.199 (5.05)	0.098 (2.49)	609-2997-ND	.19	2.13	63429-202LF	
	Blau	Zinn	0.385 (9.78)	0.205 (5.21)	0.100 (2.54)	609-2215-ND	.30	3.56	65474-002LF	
	Blau	Goldüberzug	0.385 (9.78)	0.205 (5.21)	0.100 (2.54)	609-3608-ND	.71	8.98	65474-004LF	
	Blau	30 µ" Gold	0.385 (9.78)	0.205 (5.21)	0.100 (2.54)	609-2216-ND	.49	5.77	65474-010LF	
	Blau	40 µ" Gold	0.385 (9.78)	0.205 (5.21)	0.100 (2.54)	609-2835-ND	.57	6.93	65474-001LF	
	Schwarz	15 µ" Gold	0.200 (5.08)	0.198 (5.03)	0.098 (2.49)	609-3121-ND	.29	3.20	68786-102LF	
	Schwarz	30 µ" Gold	0.200 (5.08)	0.198 (5.03)	0.098 (2.49)	609-2217-ND	.34	3.66	68786-202LF	
	Schwarz	Zinn	0.200 (5.08)	0.198 (5.03)	0.098 (2.49)	609-2218-ND	.32	3.54	68786-302LF	
	Schwarz	15 µ" Gold	0.360 (9.15)	0.198 (5.03)	0.098 (2.49)	609-2462-ND	.26	2.94	71363-102LF	
	Schwarz	30 µ" Gold	0.360 (9.15)	0.198 (5.03)	0.098 (2.49)	609-2463-ND	.30	3.23	71363-202LF	

**Leiterplattenmontierte Buchsen, 0,100" (2,54 mm)**

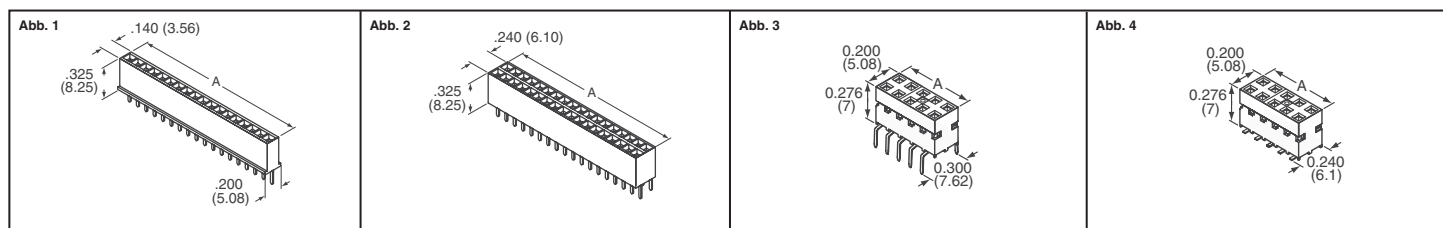


Abb.	Anz. d. Pole	Abmessung A Zoll (mm)	Digi-Key Teile-Nr.	Stückpreis			FCI Teile-Nr.
				1	25	100	
<b>Einzelreihe, senkrecht</b>							
1	3	0.30 (7.62)	609-2233-ND	1.66	.85	.72	66951-003LF
	4	0.40 (10.16)	609-2234-ND	2.26	1.16	.98	66951-004LF
	5	0.50 (12.70)	609-2235-ND	2.10	1.20	1.04	66951-005LF
	6	0.60 (15.24)	609-2236-ND	2.29	1.29	1.10	66951-006LF
	7	0.70 (17.78)	609-2237-ND	2.15	1.18	1.00	66951-007LF
	8	0.80 (20.32)	609-2238-ND	2.35	1.31	1.15	66951-008LF
	9	0.90 (22.86)	609-2239-ND	4.68	2.77	2.46	66951-009LF
	10	1.00 (25.40)	609-2240-ND	1.97	1.17	1.01	66951-010LF
	12	1.20 (30.48)	609-2242-ND	3.77	2.23	1.98	66951-012LF
	13	1.30 (33.02)	609-2243-ND	2.94	1.77	1.54	66951-013LF
	14	1.40 (35.56)	609-2244-ND	3.20	1.93	1.68	66951-014LF
	15	1.50 (38.10)	609-2245-ND	7.60	4.52	4.04	66951-015LF
	16	1.60 (40.64)	609-2246-ND	3.85	2.37	2.12	66951-016LF
	17	1.70 (43.18)	609-2247-ND	4.97	3.05	2.65	66951-017LF
	18	1.80 (45.72)	609-2248-ND	3.66	2.26	2.00	66951-018LF
	20	2.00 (50.80)	609-2250-ND	4.68	2.89	2.55	66951-020LF
	26	2.60 (66.04)	609-2256-ND	3.33	2.07	1.88	66951-026LF
	32	3.20 (81.28)	609-2262-ND	6.09	4.22	3.73	66951-032LF
35	3.50 (88.90)	609-2265-ND	7.64	5.09	4.56	66951-035LF	
36	3.60 (91.44)	609-2266-ND	7.62	4.85	4.44	66951-036LF	
<b>Vertikal, zweireihig</b>							
2	6	0.30 (7.62)	609-2267-ND	1.62	.90	.79	66953-003LF
	8	0.40 (10.16)	609-2268-ND	4.48	2.48	2.13	66953-004LF
	10	0.50 (12.70)	609-2269-ND	2.69	1.50	1.31	66953-005LF
	12	0.60 (15.24)	609-2270-ND	3.98	2.35	2.03	66953-006LF
	14	0.70 (17.78)	609-2271-ND	3.42	2.03	1.80	66953-007LF
	16	0.80 (20.32)	609-2272-ND	2.42	1.46	1.27	66953-008LF
	18	0.90 (22.86)	609-2273-ND	2.68	1.60	1.43	66953-009LF
	20	1.00 (25.40)	609-2274-ND	3.45	2.12	1.84	66953-010LF
	24	1.20 (30.48)	609-2276-ND	4.70	2.90	2.56	66953-012LF
	26	1.30 (33.02)	609-2277-ND	4.78	2.97	2.69	66953-013LF

Abb.	Anz. d. Pole	Abmessung A Zoll (mm)	Digi-Key Teile-Nr.	Stückpreis			FCI Teile-Nr.
				1	25	100	
2	28	1.40 (35.56)	609-2278-ND	4.24	2.64	2.39	66953-014LF
	30	1.50 (38.10)	609-2279-ND	4.48	2.79	2.52	66953-015LF
	32	1.60 (40.64)	609-2280-ND	4.51	2.82	2.58	66953-016LF
	34	1.70 (43.18)	609-2281-ND	5.88	3.65	3.31	66953-017LF
	40	2.00 (50.80)	609-2284-ND	6.49	4.13	3.78	66953-020LF
	50	2.50 (63.50)	609-2289-ND	5.98	3.99	3.57	66953-025LF
60	3.00 (76.20)	609-2294-ND	5.41	3.61	3.23	66953-030LF	
64	3.20 (81.28)	609-2296-ND	11.48	7.81	7.03	66953-032LF	
<b>Vertikal, zweireihig – zwei Zugangsöffnungen</b>							
3	10	0.497 (12.62)	609-2998-ND	1.73	1.02	.88	71991-305LF
	12	0.597 (15.16)	609-3035-ND	1.98	1.18	1.04	71991-306LF
	16	0.797 (20.24)	609-3037-ND	2.49	1.48	1.33	71991-308LF
	20	0.997 (25.32)	609-3000-ND	2.91	1.80	1.59	71991-310LF
	22	1.097 (27.86)	609-3001-ND	3.11	1.92	1.69	71991-311LF
	24	1.197 (30.4)	609-3002-ND	3.28	2.04	1.85	71991-312LF
	26	1.297 (32.94)	609-3003-ND	3.55	2.21	2.00	71991-313LF
	30	1.497 (38.02)	609-3005-ND	3.96	2.55	2.27	71991-315LF
32	1.597 (40.56)	609-3006-ND	4.22	2.64	2.42	71991-316LF	
40	1.997 (50.72)	609-3010-ND	4.89	3.26	2.92	71991-320LF	
<b>Vertikal, zweireihig – zwei Zugangsöffnungen, SMD</b>							
4	4	0.197 (5.0)	609-3038-ND	.96	.51	.44	89898-302LF
	6	0.297 (7.54)	609-3039-ND	1.23	.67	.57	89898-303LF
	8	0.397 (10.08)	609-3040-ND	1.73	1.02	.88	89898-304LF
	10	0.497 (12.62)	609-3041-ND	2.11	1.25	1.11	89898-305LF
	12	0.597 (15.16)	609-3042-ND	1.79	1.06	.92	89898-306LF
	16	0.797 (20.24)	609-3043-ND	2.28	1.38	1.20	89898-308LF
	20	0.997 (25.32)	609-3044-ND	3.30	2.05	1.86	89898-3