



SCSI, Serial ATA, USB, CAT5e and CAT6 Computer Cable Assemblies



HP = Half Pitch

A

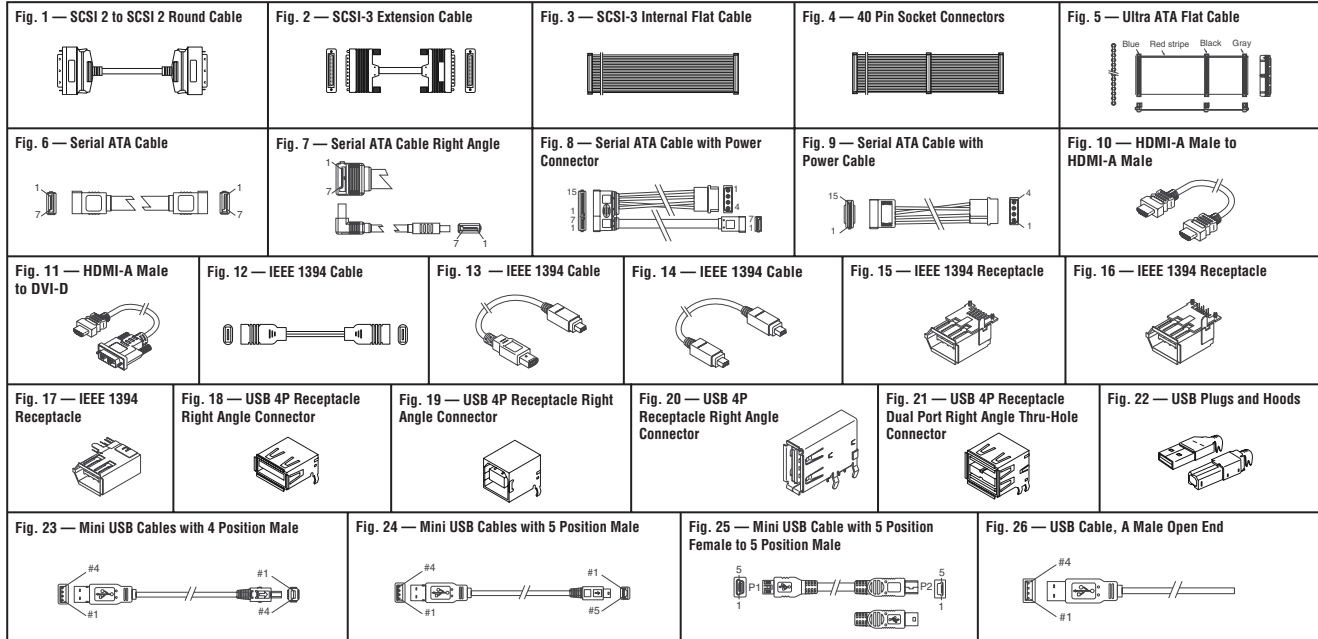


Fig.	Length Meters	Lines	Description	Digi-Key Part No.	Price Each	1	10	25	Assmann Part No.	
FAST SCSI 2 to SCSI 2 Cable, Shielded, UL 2919										
1	0.90	50	HP D-sub 50, HP D-sub, Male	AE1428-ND	12.57	11.84	11.51		AK579/F-1-R	
	2.0	50	HP D-sub 50, HP D-sub, Male	AE1429-ND	14.40	13.92	13.44		AK579/F-2-R	
SCSI-3 Series, Round Cable										
2	0.91	68	HP D-sub 68 Male x 2, A Cable	AE1430-ND	13.73	13.28	12.82		AK-Y1301-R	
SCSI-3 Series, Flat Cable										
3	0.45	68	635mm HP D-sub 68 Male x 2, P Cable	AE1489-ND	9.42	8.72	8.25		AK-Y2301-R	
Hard Drive Cable for 2 x IDE / AT Bus Hard Drives										
4	0.5	40	(3) 40 Pin Socket Connectors	AE10263-ND	3.35	2.77	2.60		AK5430-5-R	
Ultra ATA Flat Cable										
5	0.46	40	Ultra ATA HDD 100Mbps	AE10184-ND	3.90	3.23	3.03		AK-ATA-100-R	
Serial ATA Cables										
6	0.3	7	Serial ATA Cable	AE10077-ND	2.77	2.30	2.15		AK-SATA-030-R	
	0.5	7	Serial ATA Cable	AE10079-ND	2.67	2.22	2.08		AK-SATA-050-R	
	0.75	7	Serial ATA Cable	AE10081-ND	3.22	2.67	2.50		AK-SATA-075-R	
	1.0	7	Serial ATA Cable	AE10083-ND	3.24	2.69	2.52		AK-SATA-100-R	
7	0.3	7	Serial ATA Cable Right Angle	AE10078-ND	2.77	2.30	2.15		AK-SATA-030DL-R	
	0.5	7	Serial ATA Cable Right Angle	AE10080-ND	2.67	2.22	2.08		AK-SATA-050DL-R	
8	0.5	7	Serial ATA Cable 4-Position Power Connector	AE10084-ND	5.15	4.27	4.00		AK-SATA-SP-050-R	
	0.75	7	Serial ATA Cable 4-Position Power Connector	AE10085-ND	5.49	4.55	4.27		AK-SATA-SP-075-R	
9	0.15	4	Power Supply Cable 15-Position to 4-Position	AE10087-ND	2.60	2.16	2.00		AK-SATA-PC-015-R	
HDMI / DVI Cables and Adapters										
10	2.0	—	HDMI-A Male to HDMI-A Male Cable	AE10256-ND	6.12	5.18	4.95		AK627-2-R	
	3.0	—	HDMI-A Male to HDMI-A Male Cable	AE10257-ND	7.74	7.07	6.73		AK627-3-R	
	5.0	—	HDMI-A Male to HDMI-A Male Cable	AE10246-ND	11.23	10.39	9.83		AK627-5-R	
11	2.0	—	HDMI-A Male to DVI-D Cable	AE10258-ND	8.62	7.87	7.50		AK639-2-R	
	3.0	—	HDMI-A Male to DVI-D Cable	AE10259-ND	8.46	7.82	7.40		AK639-3-R	
	5.0	—	HDMI-A Male to DVI-D Cable	AE10260-ND	10.65	10.03	9.75		AK639-5-R	
—	—	—	HDMI-A Male to DVI-D 24+1, Female Adapter	AE10249-ND	7.62	7.06	6.68		AB556-R	
	—	—	HDMI-A Female to DVI-D 24+1, Female Adapter	AE10254-ND	8.40	7.77	7.35		AB566-R	
	—	—	HDMI-A Female to DVI-D 24+1, Male Adapter	AE10255-ND	8.88	8.22	7.77		AB567-R	
	—	—	HDMI-A Female to HDMI-A, Female Adapter	AE10251-ND	7.62	7.06	6.68		AB560-R	
	—	—	HDMI-A Male to HDMI-A, Female Adapter	AE10252-ND	8.40	7.77	7.35		AB561-R	
	—	—	HDMI-A Male to HDMI-A, Male Adapter	AE10253-ND	7.62	7.06	6.68		AB562-R	
	IEEE 1394 Cable Double Shielded									
	12	1.8	6	6-Pin Male to 6-Pin Male	AE1432-ND	8.14	7.53	7.13		AK-1394-18-R
3.0		6	6-Pin Male to 6-Pin Male	AE1433-ND	10.07	9.32	8.81		AK-1394-30-R	
5.0		6	6-Pin Male to 6-Pin Male	AE1434-ND	13.20	12.76	12.32		AK-1394-50-R	
13	1.8	5	6-Pin Male to 4-Pin Male	AE1435-ND	8.66	7.91	7.53		AK-1394-184-R	
	5.0	4	6-Pin Male to 4-Pin Male	AE1437-ND	10.35	10.01	9.67		AK-1394-504-R	
14	1.8	4	4-Pin Male to 4-Pin Male	AE1438-ND	8.87	8.11	7.72		AK-1394-184-R	

Fig.	Length Meters	Lines	Description	Digi-Key Part No.	Price Each	1	10	25	Assmann Part No.
IEEE 1394 and USB Connectors									
15	—	—	IEEE 1394 Receptacle Horizontal SMT	AE9920-ND	2.49	2.07	1.92		A-IE-S-SMT-R
	—	—	IEEE 1394 Receptacle Horizontal PCB	AE9921-ND	2.39	1.98	1.84		A-IE-S-DIP-R
16	—	—	IEEE 1394 Receptacle Vertical PCB	AE9922-ND	2.39	1.98	1.84		A-IE-E-DIP-R
	—	4	USB 4P Receptacle Thru-hole, Type A	AE9923-ND	.68	.53	.50		AU-Y1005-R
18	—	4	USB 2.0, 4P Receptacle Thru-hole, Type A	AE10331-ND	.74	.58	.54		AU-Y1005-2-R
	—	4	USB 3.0, 4P Receptacle Thru-hole, Type A	AE10410-ND	1.84	1.53	1.42		AU-Y1005-3-R
	—	4	USB 4P Receptacle SMT, Type A	AE9924-ND	.90	.71	.66		AU-Y1006-R
	—	4	USB 2.0, 4P Receptacle SMT, Type A	AE10332-ND	.97	.76	.71		AU-Y1006-2-R
19	—	4	USB 4P Receptacle Thru-hole, Type B	AE9925-ND	.86	.67	.63		AU-Y1007-R
	—	4	USB 2.0, 4P Receptacle Thru-hole, Type B	AE10333-ND	1.04	.81	.76		AU-Y1007-2-R
20	—	4	USB 1.1, 4P Receptacle Thru-hole, Type A	AE10401-ND	1.13	.88	.82		A-USB-A-E-R
	—	4	USB 2.0, 4P Receptacle Thru-hole, Type A	AE10400-ND	1.24	.97	.90		A-USB/2-A-E-R
21	—	4	USB 4P Receptacle Dual Port, Type A	AE9926-ND	1.19	.93	.87		AU-Y1008-R
	—	4	USB 2.0, 4P Receptacle Dual Port, Type A	AE10334-ND	1.26	.98	.91		AU-Y1008-2-R
USB Plugs and Hoods									
22	—	—	USB A-Male, Solder Version	AE10091-ND	.60	.42	.37		A-USBPA-R
	—	—	USB 3.0 A-Male, Solder Version	AE10411-ND	1.32	1.10	1.02		A-USBPA-3-R
	—	—	Hood for USB A Male	AE10090-ND	.55	.39	.33		A-USBPA-HOOD-R
	—	—	Hood for USB B Male	AE1441-ND	.55	.39	.33		A-USBPB-HOOD-R
	—	—	USB B-Male, Solder Version	AE10178-ND	.60	.42	.37		A-USBPB-R
USB Cables									
23	1.0	4	Cable Mini USB 4-Pin Male	AE1442-ND	3.60	2.98	2.80		AK670M-1-R
	2.0	4	Cable Mini USB 4-Pin Male	AE1443-ND	4.41	3.65	3.43		AK670M-2-R
	1.0	4	Cable Mini USB 2.0, 4-Pin Male	AE1444-ND	3.48	2.88	2.70		AK670M/2-1-R
23	2.0	4	Cable Mini USB 2.0, 4-Pin Male	AE1445-ND	4.87	4.04	3.78		AK670M/2-2-R
	3.0	4	Cable Mini USB 2.0, 4-Pin Male	AE1446-ND	5.37	4.55	4.35		AK670M/2-3-R
	5.0	4	Cable Mini USB 2.0, 4-Pin Male	AE1447-ND	6.69	6.11	5.82		AK670M/2-5-R
	1.0	4	Cable Mini USB 5-Pin Male	AE1448-ND	4.67	3.87	3.63		AK672M-1-R
24	2.0	4	Cable Mini USB 5-Pin Male	AE9927-ND	5.06	4.19	3.93		AK672M-2-R
	3.0	4	Cable Mini USB 5-Pin Male	AE9928-ND	5.16	4.28	4.01		AK672M-3-R
	5.0	4	Cable Mini USB 5-Pin Male	AE1449-ND	6.57	5.56	5.31		AK672M-5-R
	1.0	4	Cable Mini USB 2.0, 5-Pin Male	AE1450-ND	3.16	2.62	2.45		AK672M/2-1-R
	2.0	4	Cable Mini USB 2.0, 5-Pin Male	AE9929-ND	4.56	3.77	3.54		AK672M/2-2-R
3.0	4	Cable Mini USB 2.0, 5-Pin Male	AE1451-ND	5.53	4.58	4.29		AK672M/2-3-R	

(Continued)