



Crimp-to-Wire Mini-PV™ Receptacle Housings and Headers



A

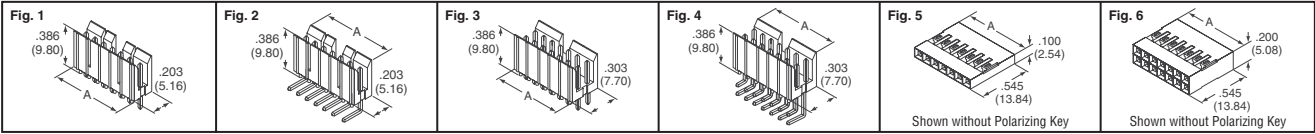


Fig.	No. of Pos.	Dimension A Inch (mm)	Digi-Key Part No.	1	Pricing 25	100	FCI Part No.		
Vertical Single Row Header									
1	3	0.30 (7.62)	609-2410-ND	.96	11.56	38.53	69167-103HLF		
	4	0.40 (10.16)	609-2411-ND	1.03	12.86	43.51	69167-104HLF		
	5	0.50 (12.70)	609-2412-ND	.99	13.18	44.53	69167-105HLF		
	6	0.60 (15.24)	609-2413-ND	1.03	14.25	47.93	69167-106HLF		
	7	0.70 (17.78)	609-2414-ND	1.22	16.42	56.30	69167-107HLF		
	8	0.80 (20.32)	609-2415-ND	1.31	17.58	60.25	69167-108HLF		
	9	0.90 (22.86)	609-2416-ND	1.35	18.67	64.00	69167-109HLF		
	10	1.00 (25.40)	609-2417-ND	1.55	20.92	73.21	69167-110HLF		
	11	1.10 (27.94)	609-2418-ND	1.72	24.54	85.91	69167-111HLF		
	12	1.20 (30.48)	609-2419-ND	1.42	19.72	68.99	69167-112HLF		
	14	1.40 (35.56)	609-2421-ND	1.53	21.89	75.76	69167-114HLF		
	15	1.50 (38.10)	609-2422-ND	1.87	25.99	89.91	69167-115HLF		
	Right Angle Single Row Header								
	2	3	0.30 (7.62)	609-2449-ND	.70	8.45	28.16	78208-103HLF	
		4	0.40 (10.16)	609-2450-ND	.89	11.33	38.43	78208-104HLF	
5		0.50 (12.70)	609-2451-ND	1.03	13.55	46.80	78208-105HLF		
6		0.60 (15.24)	609-2452-ND	1.13	15.49	52.09	78208-106HLF		
7		0.70 (17.78)	609-2453-ND	1.28	17.25	59.14	78208-107HLF		
8		0.80 (20.32)	609-2454-ND	1.43	19.71	67.57	78208-108HLF		
9		0.90 (22.86)	609-2455-ND	2.86	38.65	135.25	78208-109HLF		
10		1.00 (25.40)	609-2456-ND	1.69	23.46	82.11	78208-110HLF		
12		1.20 (30.48)	609-2458-ND	1.46	19.72	68.20	78208-112HLF		
15		1.50 (38.10)	609-2461-ND	1.95	27.88	98.95	78208-115HLF		
Vertical Dual Row Header									
3		6	0.30 (7.62)	609-2423-ND	1.09	14.96	50.32	69168-106HLF	
		8	0.40 (10.16)	609-2424-ND	1.43	19.71	67.57	69168-108HLF	
		10	0.50 (12.70)	609-2425-ND	1.67	22.49	78.73	69168-110HLF	
		12	0.60 (15.24)	609-2426-ND	1.48	20.70	70.96	69168-112HLF	
	14	0.70 (17.78)	609-2427-ND	1.66	22.99	80.47	69168-114HLF		
	16	0.80 (20.32)	609-2428-ND	1.84	26.27	90.91	69168-116HLF		
	18	0.90 (22.86)	609-2429-ND	2.01	29.57	102.29	69168-118HLF		
	20	1.00 (25.40)	609-2430-ND	2.17	32.02	113.63	69168-120HLF		
	22	1.10 (27.94)	609-2431-ND	2.23	33.55	116.98	69168-122HLF		
	24	1.20 (30.48)	609-2432-ND	2.56	38.41	133.97	69168-124HLF		
	26	1.30 (33.02)	609-2433-ND	2.60	38.64	138.27	69168-126HLF		
	28	1.40 (35.56)	609-2434-ND	2.85	43.68	151.74	69168-128HLF		
	30	1.50 (38.10)	609-2435-ND	3.05	46.80	162.56	69168-130HLF		
	Right Angle Dual Row Header								
	4	6	0.30 (7.62)	609-2436-ND	1.19	16.26	54.71	78207-106HLF	
		8	0.40 (10.16)	609-2437-ND	1.42	19.80	67.88	78207-108HLF	
		10	0.50 (12.70)	609-2438-ND	1.08	14.82	49.85	78207-110HLF	
		12	0.60 (15.24)	609-2439-ND	1.53	20.70	72.44	78207-112HLF	
		14	0.70 (17.78)	609-2440-ND	1.66	22.99	80.47	78207-114HLF	
		16	0.80 (20.32)	609-2441-ND	1.93	27.58	95.42	78207-116HLF	
		20	1.00 (25.40)	609-2443-ND	2.17	32.02	113.63	78207-120HLF	
		24	1.20 (30.48)	609-2445-ND	2.52	37.44	134.00	78207-124HLF	
		26	1.30 (33.02)	609-2446-ND	5.26	80.60	288.47	78207-126HLF	
		30	1.50 (38.10)	609-2448-ND	3.05	45.57	160.61	78207-130HLF	
		Single Row Housing Without Center Polarizing Key							
		5	1	0.10 (2.54)	609-2342-ND	.65	8.15	26.07	65039-036LF
			2	0.20 (5.08)	609-2341-ND	.76	9.12	30.41	65039-035LF
			3	0.30 (7.62)	609-2340-ND	.82	10.43	33.89	65039-034LF
			4	0.40 (10.16)	609-2339-ND	.86	10.61	36.00	65039-033LF
	5		0.50 (12.70)	609-2338-ND	.98	12.22	41.28	65039-032LF	
6	0.60 (15.24)		609-2337-ND	1.06	14.04	47.41	65039-031LF		
7	0.70 (17.78)		609-2336-ND	1.07	14.06	47.49	65039-030LF		
8	0.80 (20.32)		609-2335-ND	1.09	14.93	50.23	65039-029LF		
9	0.90 (22.86)		609-2334-ND	1.18	16.14	54.27	65039-028LF		
10	1.00 (25.40)		609-2333-ND	1.23	17.33	56.70	65039-027LF		
11	1.10 (27.94)		609-2332-ND	1.27	17.92	58.65	65039-026LF		
12	1.20 (30.48)		609-2331-ND	1.32	18.51	63.44	65039-025LF		
13	1.30 (33.02)		609-2330-ND	1.37	18.47	64.66	65039-024LF		
14	1.40 (35.56)		609-2329-ND	1.49	20.12	70.42	65039-023LF		
15	1.50 (38.10)		609-2328-ND	1.72	23.90	83.65	65039-022LF		
16	1.60 (40.64)		609-2327-ND	1.84	25.53	89.35	65039-021LF		
17	1.70 (43.18)		609-2326-ND	1.87	26.07	91.24	65039-020LF		
18	1.80 (45.72)		609-2325-ND	1.87	26.63	92.12	65039-019LF		
20	2.00 (50.80)		609-2323-ND	2.01	29.61	102.46	65039-017LF		
21	2.10 (53.34)		609-2322-ND	2.11	31.09	110.33	65039-016LF		
22	2.20 (55.88)		609-2321-ND	2.19	27.31	96.90	65039-015LF		
25	2.50 (63.50)		609-2318-ND	2.39	35.78	124.78	65039-012LF		
32	3.20 (81.28)		609-2311-ND	2.72	41.71	144.90	65039-005LF		
36	3.60 (91.44)		609-2307-ND	2.74	41.93	145.67	65039-001LF		
Single Row Housing With Center Polarizing Key									
5	3		0.30 (7.62)	609-2395-ND	.89	11.34	38.31	78211-003LF	
	4		0.40 (10.16)	609-2396-ND	1.03	14.17	47.67	78211-004LF	
	5		0.50 (12.70)	609-2397-ND	1.23	16.46	56.42	78211-005LF	
	6		0.60 (15.24)	609-2398-ND	1.37	18.47	64.63	78211-006LF	
	7		0.70 (17.78)	609-2399-ND	1.45	19.60	68.61	78211-007LF	
	8		0.80 (20.32)	609-2400-ND	1.31	18.01	61.73	78211-008LF	
	9		0.90 (22.86)	609-2401-ND	1.76	25.85	89.44	78211-009LF	
	10		1.00 (25.40)	609-2402-ND	1.27	17.64	60.48	78211-010LF	
	12		1.20 (30.48)	609-2404-ND	1.68	24.07	83.28	78211-012LF	
	14		1.40 (35.56)	609-2406-ND	2.49	38.20	136.70	78211-014LF	
	Dual Row Housing Without Center Polarizing Key								
	6	4	0.20 (5.08)	609-2377-ND	1.10	14.33	49.53	65043-035LF	
		6	0.30 (7.62)	609-2376-ND	1.06	14.04	47.41	65043-034LF	
		8	0.40 (10.16)	609-2375-ND	1.22	16.70	56.19	65043-033LF	
10		0.50 (12.70)	609-2374-ND	1.57	21.19	74.15	65043-032LF		
12		0.60 (15.24)	609-2373-ND	.45	6.62	21.39	65043-031LF		
14		0.70 (17.78)	609-2372-ND	2.03	29.88	103.37	65043-030LF		
16		0.80 (20.32)	609-2371-ND	1.87	26.07	91.24	65043-029LF		
18		0.90 (22.86)	609-2370-ND	2.25	32.31	114.65	65043-028LF		
20		1.00 (25.40)	609-2369-ND	2.39	35.93	125.32	65043-027LF		
22		1.10 (27.94)	609-2368-ND	2.65	39.70	138.47	65043-026LF		

Fig.	No. of Pos.	Dimension A Inch (mm)	Digi-Key Part No.	1	Pricing 25	100	FCI Part No.
6	24	1.20 (30.48)	609-2367-ND	2.71	40.22	143.97	65043-025LF
	26	1.30 (33.02)	609-2366-ND	2.76	42.32	151.46	65043-024LF
	28	1.40 (35.56)	609-2365-ND	2.90	44.38	158.83	65043-023LF
	30	1.50 (38.10)	609-2364-ND	3.13	47.99	166.69	65043-022LF
	32	1.60 (40.64)	609-2363-ND	2.72	41.71	144.90	65043-021LF
	34	1.70 (43.18)	609-2362-ND	2.74	41.97	145.78	65043-020LF
	36	1.80 (45.72)	609-2361-ND	2.81	43.05	149.55	65043-019LF
	40	2.00 (50.80)	609-2359-ND	3.09	47.66	167.95	65043-017LF
	44	2.20 (55.88)	609-2357-ND	3.26	50.23	177.02	65043-015LF
	46	2.30 (58.24)	609-2356-ND	2.92	45.04	158.71	65043-014LF
	48	2.40 (60.96)	609-2355-ND	3.35	51.92	188.04	65043-013LF
	50	2.50 (63.50)	609-2354-ND	3.29	50.71	178.70	65043-012LF
	54	2.70 (68.58)	609-2352-ND	3.76	58.41	211.56	65043-010LF
	58	2.90 (73.66)	609-2350-ND	3.47	53.81	194.88	65043-008LF
	64	3.20 (81.28)	609-2347-ND	4.10	65.95	234.49	65043-005LF
72	3.60 (91.44)	609-2343-ND	4.00	61.99	224.55	65043-001LF	
Dual Row Housing With Center Polarizing Key							
6	4	0.20 (5.08)	609-2379-ND	1.51	21.10	72.34	69176-004LF
	6	0.30 (7.62)	609-2380-ND	1.61	21.73	76.03	69176-006LF
	8	0.40 (10.16)	609-2381-ND	1.84	25.53	89.35	69176-008LF
	10	0.50 (12.70)	609-2382-ND	1.98	28.24	97.72	69176-010LF
	12	0.60 (15.24)	609-2383-ND	2.18	31.24	110.87	69176-012LF
	14	0.70 (17.78)	609-2384-ND	2.36	34.95	124.04	69176-014LF
	16	0.80 (20.32)	609-2385-ND	2.47	37.08	129.29	69176-016LF
	18	0.90 (22.86)	609-2386-ND	2.61	39.19	136.66	69176-018LF
	20	1.00 (25.40)	609-2387-ND	2.76	42.31	151.46	69176-020LF
	22	1.10 (27.94)	609-2388-ND	2.96	45.41	157.71	69176-022LF
	24	1.20 (30.48)	609-2389-ND	3.10	47.47	164.90	69176-024LF
	26	1.30 (33.02)	609-2390-ND	3.24	49.54	172.09	69176-026LF
	28	1.40 (35.56)	609-2391-ND	3.39	52.25	184.15	69176-028LF
	30	1.50 (38.10)	609-2392-ND	3			