

**A**

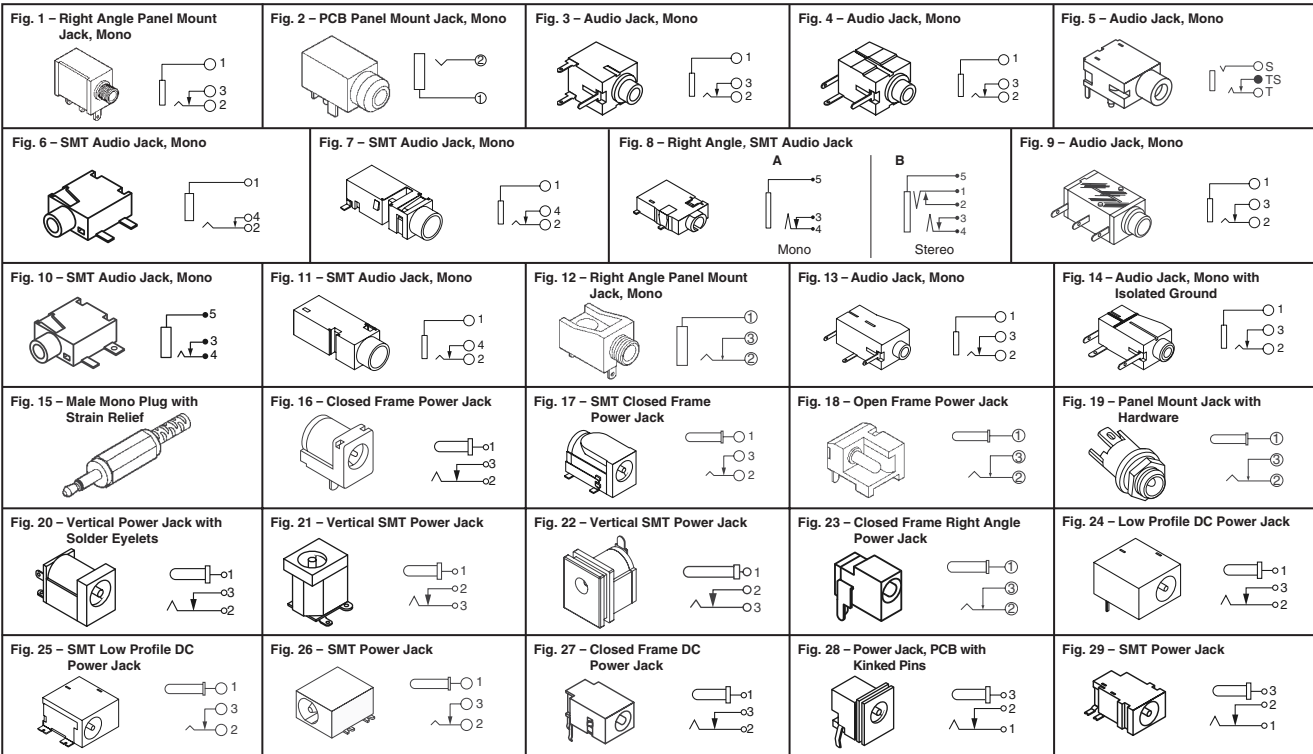


Fig.	Mates With	Dia. (mm)	Digi-Key Part No.	Price Each			CUI Part No.
				1	10	100	
1	MP3-2501	2.5	CP1-2502-ND▲†◆	1.19	.93	.71	MJ1-2502
2	MP3-2501	2.5	CP1-2503AM-ND★◆	.62	.44	.30	MJ1-2503A
3	MP3-2501	2.5	CP-2506-ND▲†◆	1.03	.72	.49	MJ-2506
	MP3-2501	2.5	CP-2506N-ND★◆	.89	.63	.42	MJ-2506N
4	MP3-2501	2.5	CP-2508-ND▲†◆	.97	.68	.46	MJ-2508
	MP3-2501	2.5	CP-2508N-ND★◆	.99	.70	.47	MJ-2508N
5	MP3-2501	2.5	CP-M2509N-ND★◆	.73	.51	.34	MJ-2509N
	MP3-2501	2.5	CP1-2510MJCT-ND★◆	.83	.69	.52	MJ1-2510-SMT
6	MP3-2501	2.5	CP1-2510MJTR-ND★◆	416.35/1,000			MJ1-2510-SMT
	MP3-2501	2.5	CP-2523MJCT-ND★◆	.69	.58	.44	MJ-2523-SMT
7	MP3-2501	2.5	CP-2523MJTR-ND★◆	347.62/1,000			MJ-2523-SMT
	MP3-2501	2.5	CP-2533MJCT-ND★◆	353.31/1,000			MJ-2533-SMT
8A	MP3-2501	2.5	CP1-2533MJCT-ND★◆	.81	.68	.51	MJ1-2533-SMT
	MP3-2501	2.5	CP1-2533MJTR-ND★◆	407.10/1,000			MJ1-2533-SMT
8B	SP-2501	2.5	CP1-2535MJCT-ND★◆	.83	.69	.52	SJ1-2535-SMT
	SP-2501	2.5	CP1-2535MJTR-ND★◆	416.35/1,000			SJ1-2535-SMT
9	MP3-3501	3.5	CP-3502M-ND▲†◆	.93	.73	.56	MJ-3502
	MP3-3501	3.5	CP-3502N-ND★◆	.87	.67	.52	MJ-3502N
10	MP3-3501	3.5	CP1-3510MJCT-ND★◆	.90	.75	.56	MJ1-3510-SMT
	MP3-3501	3.5	CP1-3510MJTR-ND★◆	384.24/800			MJ1-3510-SMT
11	MP3-3501	3.5	CP-3523MJCT-ND★◆	.74	.61	.46	MJ-3523-SMT
	MP3-3501	3.5	CP-3523MJTR-ND★◆	368.77/1,000			MJ-3523-SMT
12	MP3-3501	3.5	CP-3536-ND▲†◆	.80	.62	.48	MJ-3536
	MP3-3501	3.5	CP-3536N-ND★◆	.79	.56	.38	MJ-3536N
14	MP3-3501	3.5	CP-3536NG-ND★◆	.86	.61	.41	MJ-3536NG
	—	2.5	CP3-1004-ND◆	.79	.62	.48	MP3-2501
15	—	3.5	CP3-1005-ND◆	.79	.62	.48	MP3-3501
	PP3-002A	2.1	CP-002A-ND◆	.66	.47	.32	PJ-002A
16	PP3-002B	2.5	CP-002B-ND◆	.66	.47	.32	PJ-002B
	PP3-002A	2.0	CP-002AH-ND◆	.73	.51	.34	PJ-002AH
17	PP3-002B	2.5	CP-002BH-ND◆	.73	.51	.34	PJ-002BH
	PP3-002A	2.0	CP-002AHPJCT-ND★◆	1.03	.86	.65	PJ-002AH-SMT
18	PP3-002A	2.0	CP-002AHPJTR-ND★◆	215.90/350			PJ-002AH-SMT
	PP3-002B	2.5	CP-002BHPJCT-ND★◆	1.03	.86	.65	PJ-002BH-SMT
19	PP3-002B	2.5	CP-002BHPJTR-ND★◆	215.90/350			PJ-002BH-SMT
	PP3-002A	2.1	CP-002APJCT-ND★◆	.96	.80	.60	PJ-002A-SMT
20	PP3-002A	2.1	CP-002APJTR-ND★◆	199.42/350			PJ-002A-SMT
	PP3-002B	2.5	CP-002BPJCT-ND★◆	.96	.80	.60	PJ-002B-SMT
21	PP3-002B	2.5	CP-002BPJTR-ND★◆	199.42/350			PJ-002B-SMT
	PP3-002A	2.1	CP-003A-ND◆	.66	.47	.32	PJ-003A
22	PP3-002B	2.5	CP-003B-ND◆	.66	.47	.32	PJ-003B
	PP3-002A	2.0	CP-5-ND▲†◆	1.74	1.45	1.08	PJ-005A
23	PP3-002B	2.5	CP-6-ND▲†◆	1.74	1.45	1.08	PJ-005B
	PP3-002A	2.1	CP-006A-ND◆	.95	.67	.45	PJ-006A
24	PP3-002B	2.5	CP-006B-ND◆	.93	.66	.44	PJ-006B
	PP3-002A	2.0	CP-060A-ND◆	1.02	.72	.49	PJ-060A
25	PP3-002B	2.5	CP-060B-ND◆	1.02	.72	.49	PJ-060B
	PP3-002A	2.1	CP-006APJCT-ND★◆	.82	.68	.51	PJ-006A-SMT
26	PP3-002A	2.1	CP-006APJTR-ND★◆	121.64/250			PJ-006A-SMT
	PP3-002B	2.5	CP-006BPJCT-ND★◆	.82	.68	.51	PJ-006B-SMT
27	PP3-002B	2.5	CP-006BPJTR-ND★◆	121.64/250			PJ-006B-SMT
	PP3-002A	2.1	CP-015APJCT-ND★◆	1.01	.84	—	PJ-015A-SMT

Fig.	Mates With	Dia. (mm)	Digi-Key Part No.	Price Each			CUI Part No.
				1	10	100	
22	PP3-002A	2.1	CP-015APJTR-ND★◆	107.06/150			PJ-015A-SMT
	PP3-002B	2.5	CP-015BPJCT-ND★◆	1.01	.84	—	PJ-015B-SMT
23	PP3-002B	2.5	CP-015BPJTR-ND★◆	107.06/150			PJ-015B-SMT
	PP3-002C	1.0	CP-014C-ND◆	.62	.44	.30	PJ-007
24	PP3-002D	1.3	CP-014C-ND◆	.78	.55	.37	PJ-014C
	PP3-002D	1.3	CP-014D-ND◆	.72	.51	.34	PJ-014D
25	PP3-002C	1.0	CP-014CHPJCT-ND★◆	.82	.68	.51	PJ-014CH-SMT
	PP3-002C	1.0	CP-014CHPJTR-ND★◆	347.16/800			PJ-014CH-SMT
26	PP3-002D	1.3	CP-014DHPJCT-ND★◆	.82	.68	.51	PJ-014DH-SMT
	PP3-002D	1.3	CP-014DHPJTR-ND★◆	347.16/800			PJ-014DH-SMT
27	PP3-002C	1.0	CP-014CPJCT-ND★◆	.74	.61	.46	PJ-014C-SMT
	PP3-002D	1.3	CP-014DPJCT-ND★◆	314.58/800			PJ-014D-SMT
28	PP3-002D	1.3	CP-014DPJTR-ND★◆	314.58/800			PJ-014D-SMT
	PP-013	1.65	CP-018HPJCT-ND★◆	.71	.59	.45	PJ-018H-SMT
29	PP-013	1.65	CP-018HPJTR-ND★◆	303.34/800			PJ-018H-SMT
	PP-013	1.65	CP-016-ND◆	.88	.68	.52	PJ-016
30	PP-014	1.65	CP-021-ND◆	.97	.68	.46	PJ-021
	PP-014	1.65	CP-021PJCT-ND★◆	.72	.60	.45	PJ-021-SMT
31	PP-014	1.65	CP-021PJTR-ND★◆	190.71/500			PJ-021-SMT
	PP-012	0.65	CP-022-ND◆	.89	.63	.42	PJ-022
32	PP-012	0.65	CP-022PJCT-ND★◆	.74	.61	.46	PJ-022-SMT
	PP-012	0.65	CP-022PJTR-ND★◆	367.45/1,000			PJ-022-SMT
33	PP-012	0.65	CP-031HPJCT-ND★◆	.70	.58	.44	PJ-031H-SMT
	PP-012	0.65	CP-031HPJTR-ND★◆	351.59/1,000			PJ-031H-SMT
34	PP-012	0.65	CP-023-ND◆	.96	.67	.45	PJ-023
	PP-012	0.65	CP-023PJCT-ND★◆	.76	.63	.48	PJ-023-SMT
35A	PP-012	0.65	CP-023PJTR-ND★◆	381.99/1,000			PJ-023-SMT
	PP3-002C	1.0	CP-030CPJCT-ND★◆	.74	.61	.46	PJ-030C-SMT
36	PP3-002C	1.0	CP-030CPJTR-ND★◆	249.81/600			PJ-030C-SMT
	PP3-002D	1.3	CP-030DPJCT-ND★◆	.74	.61	.46	PJ-030D-SMT
37	PP3-002D	1.3	CP-030DPJTR-ND★◆	249.81/600			PJ-030D-SMT
	PP-017	0.8	CP-028PJCT-ND★◆	.71	.59	.44	PJ-028-SMT
38	PP-017	0.8	CP-028PJTR-ND★◆	337.05/1,000			PJ-028-SMT
	CA-2221	0.8	CP-029PJCT-ND★◆	.67	.56	.42	PJ-029-SMT
39	CA-2221	0.8	CP-029PJTR-ND★◆	337.05/1,000			PJ-029-SMT
	PP-012	0.65	CP-032HPJCT-ND★◆	.76	.63	.47	PJ-032H-SMT
40	PP-012	0.65	CP-032HPJTR-ND★◆	379.35/1,000			PJ-032H-SMT
	PP-012	0.65	CP-034PJCT-ND★◆	.74	.61	.46	PJ-034-SMT
41	PP-012	0.65	CP-034PJTR-ND★◆	370.09/1,000			PJ-034-SMT
	PP-018	1.0	CP-035PJCT-ND★◆	.74	.61	.46	PJ-035-SMT
42	PP-018	1.0	CP-035PJTR-ND★◆	331.85/850			PJ-035-SMT
	PP3-002A	2.0	CP-036APJCT-ND★◆	.92	.76	.57	PJ-036A-SMT
43	PP3-002A	2.0	CP-036APJTR-ND★◆	129.00/200			PJ-036A-SMT
	PP3-002A	2.0	CP-036AHPJCT-ND★◆	.95	.79	.59	PJ-036AH-SMT
44	PP3-002A	2.0	CP-036AHPJTR-ND★◆	133.46/200			PJ-036AH-SMT
	PP3-002B	2.5	CP-036BPJCT-ND★◆	.92	.76	.57	PJ-036B-SMT
45	PP3-002B	2.5	CP-036BPJTR-ND★◆	129.00/200			PJ-036B-SMT
	PP3-002B	2.5	CP-036BHPJCT-ND★◆	.95	.79	.59	PJ-036BH-SMT
46	PP3-002B	2.5	CP-036BHPJTR-ND★◆	133.46/200			PJ-036BH-SMT
	PP3-002A	2.0	CP-037APJCT-ND★◆	.92	.76	.57	PJ-037A-SMT

▲ Threaded with nut ★ Non-threaded ▼ Shielded version ✂ Cut Tape ♣ Tape and Reel ◆ RoHS Compliant (Continued)

Digi-Reel® Most SMT cutdown parts are available on a Digi-Reel®. For Digi-Reel part number, change 1-ND to 6-ND or CT-ND to DKR-ND. See Digi-Key® Services on page 2 for additional information.

480 (EU2011-EN) **Free shipping on orders over €65!** All prices in euro and include duties.