

A

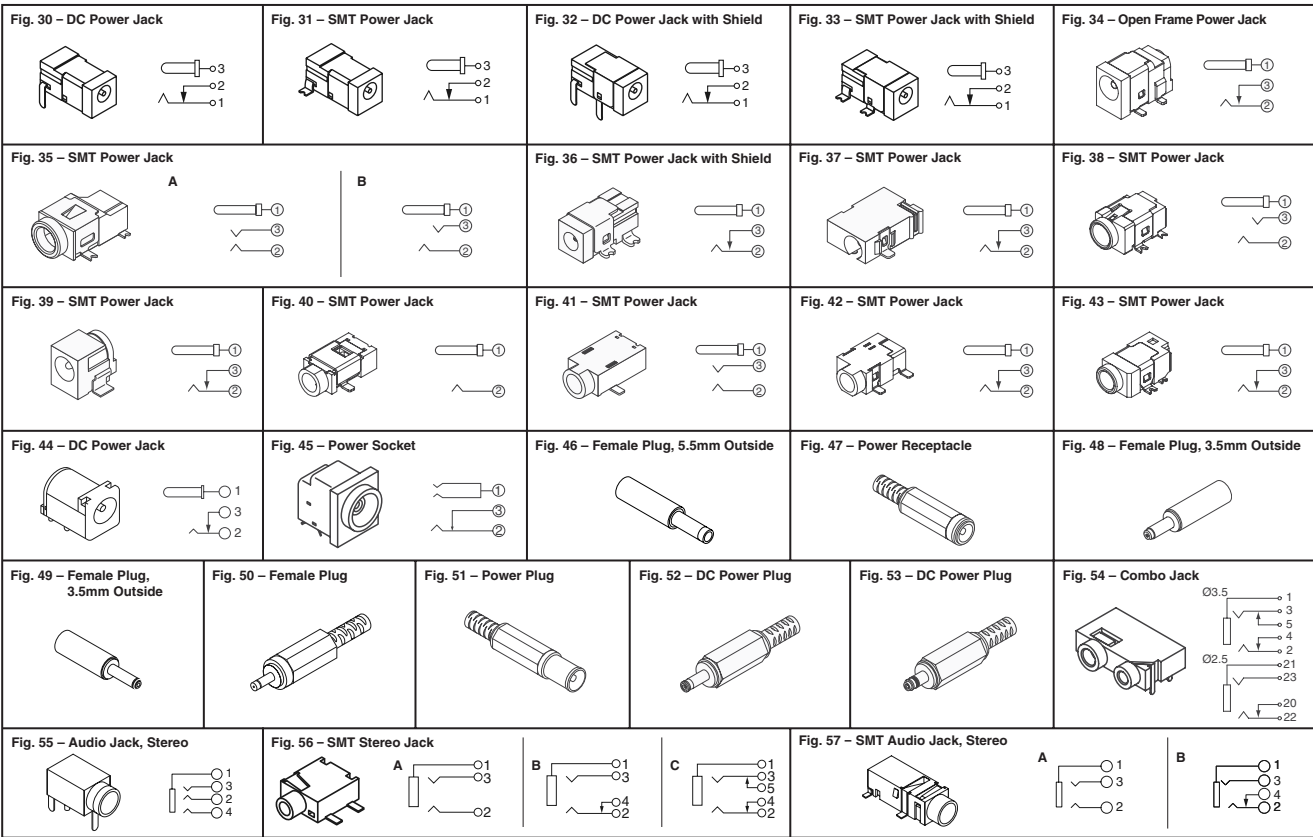


Fig.	Mates With	Dia. (mm)	Digi-Key Part No.	Price Each			CUI Part No.
				1	10	100	
39	PP3-002A	2.0	CP-037APJTR-ND	129.00	200		PJ-037A-SMT
	PP3-002A	2.0	CP-037AHPJCT-ND	.95	.79	.59	PJ-037AH-SMT
	PP3-002A	2.0	CP-037AHPJTR-ND	133.46	200		PJ-037AH-SMT
	PP3-002B	2.5	CP-037BPJCT-ND	.92	.76	.57	PJ-037B-SMT
	PP3-002B	2.5	CP-037BPJTR-ND	129.00	200		PJ-037B-SMT
	PP3-002B	2.5	CP-037BHPJCT-ND	.95	.79	.59	PJ-037BH-SMT
40	PP-012	0.65	CP-038PJCT-ND	133.46	200		PJ-038-SMT
	PP-012	0.65	CP-038PJTR-ND	569.41	1,200		PJ-038-SMT
	PP-012	0.65	CP-039PJCT-ND	.95	.79	.59	PJ-039-SMT
	PP-012	0.65	CP-039PJTR-ND	569.41	1,200		PJ-039-SMT
41	PP-012	0.65	CP-040PJCT-ND	.78	.66	.49	PJ-040-SMT
	PP-012	0.65	CP-040PJTR-ND	474.25	1,200		PJ-040-SMT
	PP-012	0.65	CP-041PJCT-ND	.78	.66	.49	PJ-041-SMT
42	PP-012	0.65	CP-042PJCT-ND	.83	.69	.52	PJ-042-SMT
	PP-012	0.65	CP-042PJTR-ND	560.59	1,500		PJ-042-SMT
43	PP-019	1.0	CP-043PJCT-ND	.77	.64	.48	PJ-043-SMT
	PP-019	1.0	CP-043PJTR-ND	366.54	900		PJ-043-SMT
44	PP3-002A	2.1	CP-102A-ND	.66	.47	.32	PJ-102A
	PP3-002B	2.5	CP-102B-ND	.66	.47	.32	PJ-102B
	PP3-002A	2.1	CP-102AH-ND	.73	.51	.34	PJ-102AH
	PP3-002B	2.5	CP-102BH-ND	.73	.51	.34	PJ-102BH
	PP3-002A	2.1	CP-202A-ND	.66	.47	.32	PJ-202A
	PP3-002B	2.5	CP-202B-ND	.66	.47	.32	PJ-202B
45	PP-015	1.1	CP-019-ND	.85	.60	.40	PJ-019
	PP-016	1.45	CP-025-ND	.85	.60	.40	PJ-025
46	—	2.1	CP3-1000-ND	.97	.76	.58	PP3-002A
	—	2.5	CP3-1001-ND	.97	.76	.58	PP3-002B
	PJ-063AH	2.1	CP3-002AH-ND	1.50	1.17	.90	PP3-002AH
	PJ-063BH	2.5	CP3-002BH-ND	1.50	1.17	.90	PP3-002BH
47	—	2.1	CP-024A-ND	2.04	1.70	1.26	PR-002A
	—	2.5	CP-024B-ND	2.04	1.70	1.26	PR-002B
48	—	1.0	CP3-1002-ND	.97	.76	.58	PP3-002C
49	—	1.3	CP3-1003-ND	.97	.76	.58	PP3-002D
	—	0.7x2.35	CP-012-ND	.94	.74	.56	PP-012
	—	1.7x4.0	CP-013-ND	.88	.69	.53	PP-013
50	—	1.7x4.75	CP-014-ND	.88	.69	.53	PP-014
	—	1.0x5.5	CP-015-ND	1.26	.98	.75	PP-015
51	—	—	CP-026-ND	1.13	.88	.67	PP-016
	—	0.9	CP-017-ND	1.13	.88	.67	PP-017
52	—	1.1	CP-119-ND	1.13	.88	.67	PP-019
	—	—	CP-018-ND	1.26	.98	.75	PP-018
53	PJ-035-SMT	1.1	CP-018-ND	1.26	.98	.75	PP-018
54	SP-3501, SP-2501	3.5/2.5	CP1-320154-ND	.85	.67	.51	SJ1-3201-54
55	SP-2501	2.5	CP1-2503A-ND	.64	.45	.30	SJ1-2503A
56A	SP-2501	2.5	CP1-2513SJCT-ND	.83	.69	.52	SJ1-2513-SMT
	SP-2501	2.5	CP1-2513SJTR-ND	416.35	1,000		SJ1-2513-SMT

Fig.	Mates With	Dia. (mm)	Digi-Key Part No.	Price Each			CUI Part No.
				1	10	100	
56B	SP-2501	2.5	CP-2514TR-ND	682.36	1,000		SJ-2513-SMT
	SP-2501	2.5	CP1-2514SJCT-ND	.84	.70	.53	SJ1-2514-SMT
	SP-2501	2.5	CP1-2514SJTR-ND	422.96	1,000		SJ1-2514-SMT
56C	SP-2501	2.5	CP1-2515SJCT-ND	.85	.71	.53	SJ1-2515-SMT
	SP-2501	2.5	CP1-2515SJTR-ND	428.25	1,000		SJ1-2515-SMT
57A	SP-2501	2.5	CP-2523SJCT-ND	.69	.58	.44	SJ-2523-SMT
	SP-2501	2.5	CP-2523SJTR-ND	347.62	1,000		SJ-2523-SMT
57B	SP-2501	2.5	CP-2524SJCT-ND	.70	.59	.44	SJ-2524-SMT
	SP-2501	2.5	CP-2524SJTR-ND	352.91	1,000		SJ-2524-SMT
58	SP-2501	2.5	CP1-2533SJCT-ND	.81	.68	.51	SJ1-2533-SMT
	SP-2501	2.5	CP1-2533SJTR-ND	407.10	1,000		SJ1-2533-SMT
59	SP-2501	2.5	CP1-2534SJCT-ND	.82	.68	.51	SJ1-2534-SMT
	SP-2501	2.5	CP1-2534SJTR-ND	411.07	1,000		SJ1-2534-SMT
60A	SP-3501	3.5	CP-3504-ND	1.84	1.54	1.14	SJ-3504
60B	SP-3501	3.5	CP-3505-ND	1.88	1.57	1.16	SJ-3505
	SP-3501	3.5	CP1-3513-ND	1.06	.82	.63	SJ1-3513
61A	SP-3501	3.5	CP1-3513N-ND	.85	.67	.51	SJ1-3513N
	SP-3501	3.5	CP1-3514-ND	1.07	.83	.64	SJ1-3514
61B	SP-3501	3.5	CP1-3514N-ND	.87	.68	.52	SJ1-3514N
	SP-3501	3.5	CP1-3515-ND	1.07	.84	.64	SJ1-3515
61C	SP-3501	3.5	CP1-3515N-ND	.88	.68	.52	SJ1-3515N
	SP-3501	3.5	CP1-3515NG-ND	.90	.75	.56	SJ1-3515-SMT
62A	SP-3501	3.5	CP1-3513SJCT-ND	384.24	800		SJ1-3513-SMT
	SP-3501	3.5	CP1-3513SJTR-ND	388.73	800		SJ1-3513-SMT
62B	SP-3501	3.5	CP1-3514SJCT-ND	.91	.76	.57	SJ1-3514-SMT
	SP-3501	3.5	CP1-3514SJTR-ND	388.73	800		SJ1-3514-SMT
62C	SP-3501	3.5	CP1-3515SJCT-ND	.92	.77	.58	SJ1-3515-SMT
	SP-3501	3.5	CP1-3515SJTR-ND	392.10	800		SJ1-3515-SMT
	SP-3501	3.5	CP1-3515JBECT-ND	.80	.67	.50	SJ1-3515-SMT-BE
	SP-3501	3.5	CP1-3515JBCTR-ND	340.42	800		SJ1-3515-SMT-BE
	SP-3501	3.5	CP1-3515JGRCR-ND	.80	.67	.50	SJ1-3515-SMT-GR
63A	SP-3501	3.5	CP1-3515SJGRCR-ND	340.42	800		SJ1-3515-SMT-GR
	SP-3501	3.5	CP1-3515SJPICR-ND	.80	.67	.50	SJ1-3515-SMT-PI
63B	SP-3501	3.5	CP1-3515SJPIR-ND	340.42	800		SJ1-3515-SMT-PI
	SP-2501	2.5	CP-S2504N-ND	.72	.51	.34	SJ-2504N
64A	SP-2501	2.5	CP-S2509N-ND	.67	.47	.32	SJ-2509N
64B	SP-3501	3.5	CP1-3523NG-ND	.84	.59	.40	SJ1-3523N
	SP-3501	3.5	CP1-3523NG-ND	.84	.59	.40	SJ1-3523NG
64C	SP-3501	3.5	CP1-3524NG-ND	.86	.60	.41	SJ1-3524NG
	SP-3501	3.5	CP1-3524NG-ND	.86	.60	.41	SJ1-3524NG
64D	SP-3501	3.5	CP1-3525NG-ND	.87	.61	.41	SJ1-3525N
	SP-3501	3.5	CP1-3525NG-ND	.87	.61	.41	SJ1-3525NG
	SP-3501	3.5	CP1-3525NG-GR-ND	.84	.59	.40	SJ1-3525NG-GR
65A	SP-3501	3.5	CP1-3525NG-PI-ND	.84	.59	.40	SJ1-3525NG-PI
	SP-3501	3.5	CP-3523SJCT-ND	.74	.61	.46	SJ-3523-SMT
	SP-3501	3.5	CP-3523SJTR-ND	368.77	1,000		SJ-3523-SMT

▲ Threaded with nut ★ Non-threaded ▼ Shielded version ✚ Cut Tape ☆ Tape and Reel ♦ RoHS Compliant (Continued)

Digi-Reel® Most SMT cutdown parts are available on a Digi-Reel®. For Digi-Reel part number, change 1-ND to 6-ND or CT-ND to DKR-ND. See Digi-Key® Services on page 2 for additional information.

Free shipping on orders over €65! All prices in euro and include duties. (EU2011-EN) 481