




Crystals



ABM8 Series — 3.2 x 2.5 SMD Crystals (Cont.)

Table with columns: Frequency (MHz), Digi-Key Part No., Cut Tape Price Each (1, 10, 50), Digi-Key Part No., T & R Pricing (1,000), Abracon Part No. Lists various ABM8 series crystals with their specifications and pricing.

 
ABM8G Series — 3.2 x 2.5 SMD Crystals



Series Specifications table for ABM8G series. Columns: Frequency Stability, Frequency Tolerance, Operating Temperature, Load Capacitance. Values: ±30ppm, ±20ppm, -40°C - 85°C, 18.0pF.

Main table for ABM8G series. Columns: Frequency (MHz), Digi-Key Part No., Cut Tape Price Each (1, 10, 50), Digi-Key Part No., T & R Pricing (1,000), Abracon Part No. Lists various ABM8G series crystals with their specifications and pricing.

 
ABM9 Series — 4.0 x 2.5 SMD RF Transceiver Crystals



Specifications: • Frequency Stability: ±10ppm • Frequency Tolerance: ±10ppm @ 25°C • Operating Temperature Range: -40°C - 85°C • Load Capacitance: 10.0pF

Table with columns: Frequency (MHz), Digi-Key Part No., Cut Tape Price Each (1, 10, 50), Digi-Key Part No., T & R Pricing (1,000), Abracon Part No. Lists ABM9 series crystals.


ABM10 Series — 2.5 x 2.0 SMD Crystals

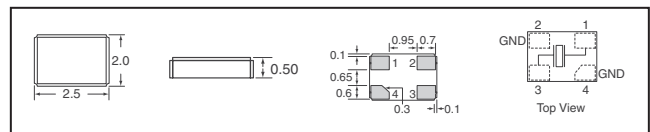

Series Specifications table for ABM10 series. Columns: Frequency Stability, Frequency Tolerance, Operating Temperature, Load Capacitance. Values: ±20ppm, ±15ppm, -20°C - 70°C, 10.0pF.

Main table for ABM10 series. Columns: Frequency (MHz), Digi-Key Part No., Cut Tape Price Each (1, 10, 50), Digi-Key Part No., T & R Pricing (1,000), Abracon Part No. Lists various ABM10 series crystals with their specifications and pricing.


ABM11 Series — 2.0 x 1.6 SMD Crystals

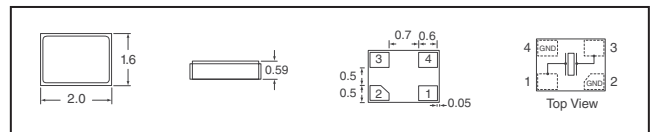

Specifications: • Frequency Stability: ±15ppm; -20°C - 70°C • Frequency Tolerance: ±15ppm • Operating Temperature Range: -20°C - 70°C • Load Capacitance: 10.0pF

Table with columns: Frequency (MHz), Digi-Key Part No., Cut Tape Price Each (1, 10, 50), Digi-Key Part No., T & R Pricing (1,000), Abracon Part No. Lists various ABM11 series crystals with their specifications and pricing.

ABM12 Series — 1.6 x 1.2 SMD Crystals

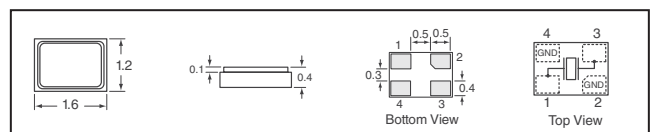

Specifications: • Frequency Stability: ±20ppm; -20°C - 70°C • Frequency Tolerance: ±20ppm • Operating Temperature Range: -20°C - 70°C • Load Capacitance: 8pF

Table with columns: Frequency (MHz), Digi-Key Part No., Cut Tape Price Each (1, 10, 50), Digi-Key Part No., T & R Pricing (3,000), Abracon Part No. Lists various ABM12 series crystals with their specifications and pricing.

(Continued)

Digi-Reel® Most SMT cutdown parts are available on a Digi-Reel®. For Digi-Reel part number, change 1-ND to 6-ND or CT-ND to DKR-ND. See Digi-Key® Services on page 2 for additional information.

Free shipping on orders over €65! All prices in euro and include duties. (EU2011-EN) 1425