


CTS CB3 Series 7.0 x 5.0 SMD Oscillators



Features:

- Standard miniature surface mount footprint
- PCMCIA Type II and III compatible
- HCMOS/TTL compatible
- 16mm Tape and Reel
- Ceramic construction for long-term reliability
- Seam welded and shielded with Kovar cover

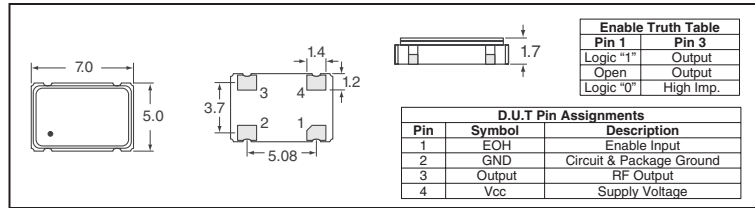

Frequency (MHz)	Digi-Key Part No.	Cut Tape Price Each			T & R Pricing† 1,000	CTS Part No.
		1	10	50		
CB3-3C 5.0V, ±50ppm, -20°C - 70°C						
1.54400	CTX290CT-ND	2.35	2.05	1.80	880.08	CB3-3C-1M5440
1.84320	CTX291CT-ND	2.35	2.05	1.80	880.08	CB3-3C-1M8432
3.68640	CTX260CT-ND	2.35	2.05	1.80	880.08	CB3-3C-3M6864
4.00000	CTX261CT-ND	2.35	2.05	1.80	880.08	CB3-3C-4M0000
6.17600	CTX262CT-ND	2.35	2.05	1.80	880.08	CB3-3C-6M1760
7.37280	CTX263CT-ND	2.35	2.05	1.80	880.08	CB3-3C-7M3728
8.00000	CTX264CT-ND	2.35	2.05	1.80	880.08	CB3-3C-8M0000
10.00000	CTX265CT-ND	2.35	2.05	1.80	880.08	CB3-3C-10M0000
12.00000	CTX292CT-ND	2.35	2.05	1.80	880.08	CB3-3C-12M0000
12.28800	CTX266CT-ND	2.35	2.05	1.80	880.08	CB3-3C-12M2880
12.35200	CTX267CT-ND	2.99	2.75	1.58	880.08	CB3-3C-12M3520
15.36000	CTX269CT-ND	2.35	2.05	1.80	880.08	CB3-3C-15M3600
16.00000	CTX270CT-ND	2.35	2.05	1.80	880.08	CB3-3C-16M0000
16.38400	CTX271CT-ND	2.99	2.75	1.58	—	CB3-3C-16M3840
18.43200	CTX293CT-ND	2.35	2.05	1.80	880.08	CB3-3C-18M4320
19.44000	CTX272CT-ND	2.99	2.75	1.58	—	CB3-3C-19M4400
20.00000	CTX273CT-ND	2.35	2.05	1.80	880.08	CB3-3C-20M0000
20.48000	CTX274CT-ND	2.35	2.05	1.80	880.08	CB3-3C-20M4800
24.00000	CTX294CT-ND	2.35	2.05	1.80	880.08	CB3-3C-24M0000
24.70400	CTX275CT-ND	2.99	2.75	1.58	880.08	CB3-3C-24M7040
25.00000	CTX276CT-ND	2.35	2.05	1.80	880.08	CB3-3C-25M0000
29.49120	CTX295CT-ND	2.35	2.05	1.80	880.08	CB3-3C-29M4912
30.00000	CTX296CT-ND	2.35	2.05	1.80	880.08	CB3-3C-30M0000
32.00000	CTX277CT-ND	2.35	2.05	1.80	880.08	CB3-3C-32M0000
32.76800	CTX278CT-ND	2.35	2.05	1.80	880.08	CB3-3C-32M7680
33.33300	CTX279CT-ND	2.35	2.05	1.80	880.08	CB3-3C-33M3330
40.00000	CTX280CT-ND	2.35	2.05	1.80	880.08	CB3-3C-40M0000
44.73600	CTX281CT-ND	2.99	2.75	1.58	880.08	CB3-3C-44M7360
45.00000	CTX297CT-ND	2.35	2.05	1.80	880.08	CB3-3C-45M0000
49.15200	CTX282CT-ND	2.35	2.05	1.80	880.08	CB3-3C-49M1520
50.00000	CTX283CT-ND	2.35	2.05	1.80	880.08	CB3-3C-50M0000
51.84000	CTX284CT-ND	2.99	2.75	1.58	880.08	CB3-3C-51M8400
60.00000	CTX285CT-ND	2.35	2.05	1.80	880.08	CB3-3C-60M0000
64.00000	CTX286CT-ND	2.39	2.07	1.82	891.29	CB3-3C-64M0000
66.66660	CTX287CT-ND	3.03	2.79	1.60	891.29	CB3-3C-66M6666
72.00000	CTX288CT-ND	3.03	2.79	1.60	891.29	CB3-3C-72M0000
80.00000	CTX289CT-ND	2.53	2.20	1.93	943.98	CB3-3C-80M0000
CB3-3I 5.0V, ±50ppm, -40°C - 85°C						
16.00000	CTX304CT-ND	2.35	2.05	1.80	880.08	CB3-3I-16M0000
18.43200	CTX300CT-ND	2.35	2.05	1.80	880.08	CB3-3I-18M4320
20.00000	CTX306CT-ND	2.35	2.05	1.80	880.08	CB3-3I-20M0000
40.00000	CTX314CT-ND	2.35	2.05	1.80	880.08	CB3-3I-40M0000
CB3LV-3C 3.3V, ±50ppm, -20°C - 70°C						
1.54400	CTX290LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-1M5440
1.84320	CTX291LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-1M8432
3.68640	CTX260LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-3M6864
4.00000	CTX261LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-4M0000
6.17600	CTX262LVCT-ND	2.99	2.75	1.58	880.08	CB3LV-3C-6M1760
7.37280	CTX263LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-7M3728
8.00000	CTX264LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-8M0000
10.00000	CTX265LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-10M0000
12.00000	CTX292LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-12M0000
12.28800	CTX266LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-12M2880
12.35200	CTX267LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-12M3520
14.31818	CTX268LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-14M31818
15.36000	CTX269LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-15M3600
16.00000	CTX270LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-16M0000
16.38400	CTX271LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-16M3840
18.43200	CTX293LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-18M4320
19.44000	CTX272LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-19M4400
20.00000	CTX273LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-20M0000
20.48000	CTX274LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-20M4800
24.00000	CTX294LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-24M0000
24.70400	CTX275LVCT-ND	2.99	2.75	1.58	—	CB3LV-3C-24M7040
25.00000	CTX276LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-25M0000
29.49120	CTX295LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-29M4912
30.00000	CTX296LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-30M0000
32.00000	CTX277LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-32M0000

Frequency (MHz)	Digi-Key Part No.	Cut Tape Price Each			T & R Pricing† 1,000	CTS Part No.
		1	10	50		
32.76800	CTX278LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-32M7680
33.33300	CTX279LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-33M3330
40.00000	CTX280LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-40M0000
44.73600	CTX281LVCT-ND	2.99	2.75	1.58	—	CB3LV-3C-44M7360
45.00000	CTX297LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-45M0000
49.15200	CTX282LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-49M1520
50.00000	CTX283LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-50M0000
51.84000	CTX284LVCT-ND	2.99	2.75	1.58	880.08	CB3LV-3C-51M8400
60.00000	CTX285LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3C-60M0000
64.00000	CTX286LVCT-ND	2.39	2.07	1.82	891.29	CB3LV-3C-64M0000
66.66660	CTX287LVCT-ND	2.39	2.07	1.82	891.29	CB3LV-3C-66M6666
72.00000	CTX288LVCT-ND	2.39	2.07	1.82	891.29	CB3LV-3C-72M0000
80.00000	CTX289LVCT-ND	2.53	2.20	1.93	943.98	CB3LV-3C-80M0000
CB3LV-3I 3.3V, ±50ppm, -40°C - 85°C						
1.843200	CTX945LVCT-ND	1.83	1.59	1.38	880.08	CB3LV-3I-1M8432
3.579545	CTX929LVCT-ND	1.75	1.52	1.32	880.08	CB3LV-3I-3M579545
3.686400	CTX946LVCT-ND	2.35	2.05	1.78	880.08	CB3LV-3I-3M6864
4.000000	CTX930LVCT-ND	2.35	2.05	1.78	880.08	CB3LV-3I-4M0000
7.372800	CTX325LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-7M3728
8.000000	CTX301LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-8M0000
8.192000	CTX302LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-8M1920
10.000000	CTX707LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-10M0000
11.059200	CTX931LVCT-ND	1.75	1.52	1.32	653.61	CB3LV-3I-11M0592
12.000000	CTX303LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-12M0000
14.318180	CTX932LVCT-ND	1.75	1.52	1.32	653.61	CB3LV-3I-14M31818
14.745600	CTX933LVCT-ND	2.35	2.05	1.78	880.08	CB3LV-3I-14M7456
16.000000	CTX947LVCT-ND	2.35	2.05	1.78	880.08	CB3LV-3I-16M0000
16.384000	CTX708LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-16M3840
18.432000	CTX305LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-18M4320
19.440000	CTX709LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-19M4400
20.000000	CTX306LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-20M0000
24.000000	CTX307LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-24M0000
24.576000	CTX326LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-24M5760
25.000000	CTX308LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-25M0000
27.000000	CTX710LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-27M0000
30.000000	CTX309LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-30M0000
32.000000	CTX310LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-32M0000
32.768000	CTX311LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-32M7680
33.000000	CTX312LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-33M0000
33.333000	CTX313LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-33M3330
40.000000	CTX314LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-40M0000
44.736000	CTX711LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-44M7360
48.000000	CTX315LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-48M0000
50.000000	CTX327LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-50M0000
60.000000	CTX712LVCT-ND	2.35	2.05	1.80	880.08	CB3LV-3I-60M0000
64.000000	CTX328LVCT-ND	2.39	2.07	1.82	891.29	CB3LV-3I-64M0000
65.536000	CTX713LVCT-ND	2.39	2.07	1.82	891.29	CB3LV-3I-65M5360
66.000000	CTX316LVCT-ND	2.39	2.07	1.82	891.29	CB3LV-3I-66M0000
66.666000	CTX934LVCT-ND	1.99	1.73	1.50	742.18	CB3LV-3I-66M6660
74.250000	CTX714LVCT-ND	2.39	2.07	1.82	891.29	CB3LV-3I-74M2500
74.752800	CTX715LVCT-ND	2.39	2.07	1.82	89	