



Sealed Surface Mount Tact Switches KSC Series — Washable, Totally Sealed (IP67) (Cont.)



Operating Force	Actuator	Termination	Contact Material	Digi-Key Part No.	Cut Tape Price Each			Digi-Key Part No.	Tape and Reel		C&K Part No.
					1	25	100		Qty.	Pricing	
350gF	Soft 3.5mm	J-Lead	Silver	401-1762-1-ND◆	.36	.34	.31	401-1762-2-ND◆	2,000	199.26/M	KSC241JLFS
160gF	Hard 3.5mm	Gullwing	Silver	401-1765-1-ND◆	.36	.33	.31	401-1765-2-ND◆	2,000	197.77/M	KSC321GLFS
160gF	Hard 3.5mm	J-Lead	Silver	401-1766-1-ND◆	.36	.33	.31	401-1766-2-ND◆	2,000	197.77/M	KSC321JLFS
160gF	Hard 3.5mm	Gullwing	Gold	401-1767-1-ND◆	.48	.45	.41	401-1767-2-ND◆	2,000	266.17/M	KSC323GLFG
160gF	Hard 3.5mm	J-Lead	Gold	401-1768-1-ND◆	.48	.45	.41	401-1768-2-ND◆	2,000	266.17/M	KSC323JLFG
300gF	Hard 3.5mm	Gullwing	Silver	401-1769-1-ND◆	.36	.33	.31	401-1769-2-ND◆	2,000	197.77/M	KSC341GLFS
300gF	Hard 3.5mm	J-Lead	Silver	401-1770-1-ND◆	.36	.33	.31	401-1770-2-ND◆	2,000	197.77/M	KSC341JLFS
300gF	Hard 3.5mm	Gullwing	Gold	401-1771-1-ND◆	.48	.45	.41	401-1771-2-ND◆	2,000	266.17/M	KSC343GLFG
300gF	Hard 3.5mm	J-Lead	Gold	401-1772-1-ND◆	.48	.45	.41	401-1772-2-ND◆	2,000	266.17/M	KSC343JLFG
550gF	Hard 3.5mm	Gullwing	Silver	401-1773-1-ND◆	.40	.37	.34	401-1773-2-ND◆	2,000	221.56/M	KSC351GLFS
550gF	Hard 3.5mm	J-Lead	Silver	401-1774-1-ND◆	.40	.37	.34	401-1774-2-ND◆	2,000	221.56/M	KSC351JLFS
120gF	Soft 5.2mm	Gullwing	Silver	CKN10282CT-ND◆	.44	.41	.38	CKN10282TR-ND◆	1,000	242.38	KSC401G 50SH LFS
120gF	Soft 5.2mm	J-Lead	Silver	401-1775-1-ND◆	.44	.41	.38	401-1775-2-ND◆	1,000	242.38	KSC401J 50SH LFS
120gF	Soft 5.2mm	J-Lead	Gold	401-1776-1-ND◆	.71	.66	.61	401-1776-2-ND◆	1,000	395.54	KSC403J 50SH LFG
140gF	Soft 5.2mm	Gullwing	Silver	401-1777-1-ND◆	.44	.41	.37	401-1777-2-ND◆	1,000	240.89	KSC411G 70SH LFS
140gF	Soft 5.2mm	J-Lead	Silver	401-1778-1-ND◆	.44	.41	.37	401-1778-2-ND◆	1,000	240.89	KSC411J 70SH LFS
160gF	Soft 5.2mm	Gullwing	Silver	CKN9198CT-ND◆§	.45	.42	.38	CKN9198TR-ND◆§	1,000	246.84	KSC422G 70SH LFS
160gF	Soft 5.2mm	Gullwing	Silver	401-1779-1-ND◆	.41	.39	.36	401-1779-2-ND◆	1,000	230.48	KSC421G 70SH LFS
160gF	Soft 5.2mm	J-Lead	Silver	401-1780-1-ND◆	.64	.59	.50	401-1780-2-ND◆	1,000	230.48	KSC421J 70SH LFS
160gF	Soft 5.2mm	J-Lead	Silver	CKN9199CT-ND◆§	.45	.42	.38	CKN9199TR-ND◆§	1,000	247.00	KSC422J 70SH LFS
170gF	Soft 5.2mm	Right Angle	Silver	401-1781-ND†◆	.64	.59	.50	—	—	—	KSC421V30ACT2.95LFS
300gF	Soft 5.2mm	Gullwing	Silver	401-1783-1-ND◆	.43	.40	.37	401-1783-2-ND◆	1,000	236.43	KSC441G 70SH LFS
300gF	Soft 5.2mm	J-Lead	Silver	401-1784-1-ND◆	.43	.40	.37	401-1784-2-ND◆	1,000	236.43	KSC441J 70SH LFS
300gF	Soft 5.2mm	J-Lead	Gold	401-1785-1-ND◆	.70	.66	.60	401-1785-2-ND◆	1,000	391.08	KSC443J 70SH LFG
320gF	Soft 5.2mm	J-Lead	Silver	CKN9197CT-ND◆§	.45	.42	.38	CKN9197TR-ND◆§	1,000	247.00	KSC442J 70SH LFS
320gF	Soft 5.2mm	Gullwing	Silver	CKN9196CT-ND◆§	.45	.43	.39	—	—	—	KSC442G 70SH LFS
160gF	Rocker 5.6mm	Gullwing	Silver	401-1907-1-ND◆‡	.45	.42	.39	401-1907-2-ND◆‡	1,000	249.81	KSC521G ROHS
160gF	Hard 7.7mm	Gullwing	Silver	401-1786-1-ND◆	.48	.44	.41	401-1786-2-ND◆	750	197.40	KSC621GLFS
160gF	Hard 7.7mm	J-Lead	Silver	401-1748-1-ND◆	.42	.39	.36	401-1748-2-ND◆	750	197.40	KSC621J LFS
300gF	Hard 7.7mm	Gullwing	Silver	401-1787-1-ND◆	.49	.46	.42	401-1787-2-ND◆	750	202.97	KSC641GLFS
300gF	Hard 7.7mm	J-Lead	Silver	401-1788-1-ND◆	.49	.46	.42	401-1788-2-ND◆	750	202.97	KSC641JLFS
KSC4D Sealed Detect Switch for SMT — RoHS Compliant											
200gF	Soft 5.2mm	J-Lead	Silver	CKN9428CT-ND	.69	.64	.59	CKN9428TR-ND	1,000	383.64	KSC4D1J 50SH LFS
200gF	Soft 5.2mm	Gullwing	Silver	CKN9429CT-ND	.69	.64	.59	CKN9429TR-ND	1,000	383.64	KSC4D1G 50SH LFS

◆ RoHS Compliant § Long Life Version ‡ KSC5 Not Sealed



RACON Short-Travel Keyswitches



RACON short-travel keyswitches offer an extremely high switching reliability while needing very little space. They can be arranged as single keys, in rows or key blocks.

Specifications: • Operating Temperature: -40°C - 80°C • Operating Life: 1,000,000 cycles • Maximum Rated Voltage: 42V • Maximum Rated Current: 100mA

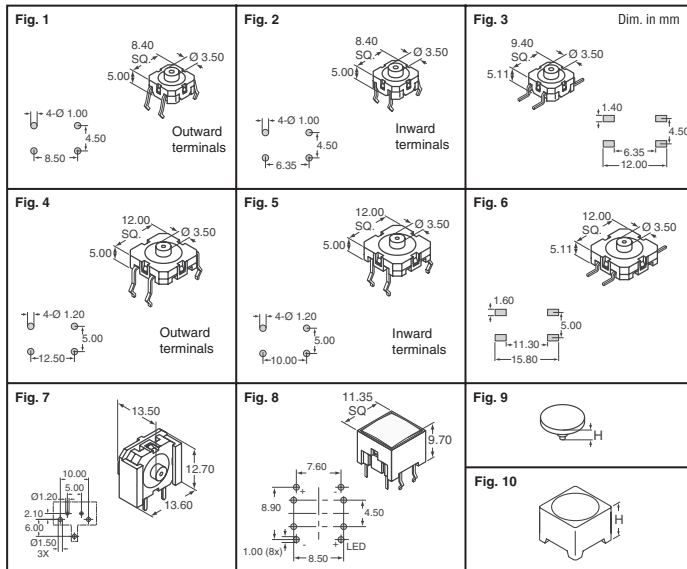


Fig.	Description	Digi-Key Part No.	Price Each			C&K Part No.
			1	25	100	
Switches						
1	RACON 8, 330gF, Outward Terminals	CKN9361-ND	2.45	1.97	1.56	1.14100.5010000
2	RACON 8, 330gF Inward Terminals	CKN9362-ND	2.59	2.08	1.65	1.14100.5020000
3	RACON 8, 330gF, Surface Mount	CKN9363CT-ND†	2.48	2.29	2.10	1.14100.5030000
3	RACON 8, 330gF, Surface Mount	CKN9363TR-ND◇	1373.80/1,000			1.14100.5030000
4	RACON 12, 360gF, Outward Terminals	CKN9364-ND	2.54	2.04	1.61	1.14001.5010000
5	RACON 12, 360gF Inward Terminals	CKN9365-ND	2.54	2.04	1.61	1.14001.5020000
6	RACON 12, 360gf, Surface Mount	CKN9366CT-ND†	2.72	2.52	2.31	1.14001.5030000
6	RACON 12, 360gf, Surface Mount	CKN9366TR-ND◇	1129.73/750			1.14001.5030000
7	RACON 12V, 360gF, PCB Mount	CKN9367-ND	3.63	2.91	2.30	1.14001.5050000
8	RACON 12i, 330gF, Red LED	CKN9368-ND	14.76	11.81	9.35	1.14001.5510000
8	RACON 12i, 330gF, Green LED	CKN9205-ND	14.76	11.81	9.35	1.14001.5520000
8	RACON 12i, 330gF, Yellow LED	CKN9206-ND	14.76	11.81	9.35	1.14001.5530000
Accessories						
9	Plunger, H=6.5mm x 8mm dia.	CKN9369-ND	.44	.36	.28	5.46167.3010209
9	Plunger, H=7mm x 8mm dia.	CKN9207-ND	.44	.36	.28	5.46167.0900209
9	Plunger, H=6.5mm x 11.5mm dia.	CKN9208-ND	.44	.36	.28	5.46167.2270209
9	Plunger, H=7mm x 11.5mm dia.	CKN9370-ND	.44	.36	.28	5.46167.0420209
9	Plunger, H=7mm x 14.5 dia.	CKN9209-ND	.44	.36	.28	5.46168.0420209
9	Plunger, H=9.7mm x 14.5mm dia.	CKN9371-ND	.44	.36	.28	5.46168.0430209
9	Plunger, H=7mm x 19mm dia.	CKN9210-ND	.35	.28	.22	5.46169.0420209
9	Plunger, H=12.5mm x 19mm dia.	CKN9372-ND	.44	.36	.28	5.46169.0440209
10	Plunger, H=7mm x 14mm square	CKN9211-ND	.44	.36	.28	5.46001.0570209
10	Plunger, H=12.5mm x 14mm square	CKN9373-ND	.44	.36	.28	5.46001.0590209

† Cut Tape ◇ Tape and Reel

Digi-Reel® Most SMT cutdown parts are available on a Digi-Reel®. For Digi-Reel part number, change 1-ND to 6-ND or CT-ND to DKR-ND. See Digi-Key® Services on page 2 for additional information.

2204 (EU2011-EN) **Free shipping on orders over €65! All prices in euro and include duties.**