

OMRON Low Signal Relays (Cont.)

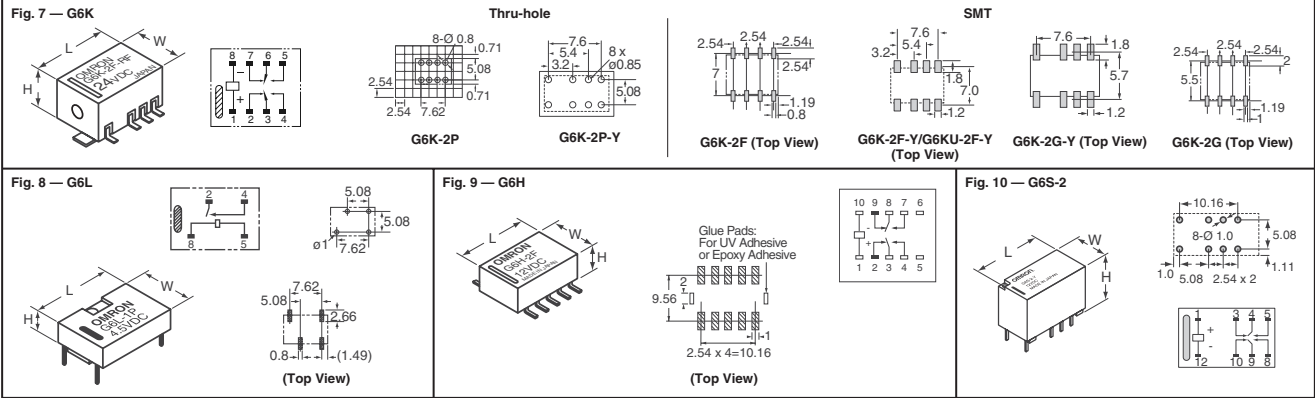


Fig.	Contact Form	Coil		Contact Ratings Resistive (A)		Operating Voltage (% of Rated) Pull/Drop/Max. On/Out/Cont.	Operate/Release Time (msec.)	Dimensions (mm) H x L x W	Digi-Key Part No.	Price Each			Omron Part No.	
		Voltage (VDC)	Resistance (Ω)	24 VDC	115 VAC					1	25	50		
7	DPDT	24	5,220	1	0.3	75/5/200	3/3	5.0 x 10 x 6.5	Z118-ND	2.92	2.64	2.34	G6K-2P-DC24	
	DPDT	3	91	1	0.3	80/10/150	3/3	5.0 x 10 x 6.5	Z2658-ND	2.92	2.64	2.34	G6K-2P-Y-DC3	
	DPDT	4.5	194	1	0.3	75/5/200	3/3	5.0 x 10 x 6.5	Z131-ND	2.92	2.64	2.34	G6K-2P-Y-DC4.5	
	DPDT	5	237	1	0.3	75/5/200	3/3	5.0 x 10 x 6.5	Z132-ND	2.92	2.64	2.34	G6K-2P-Y-DC5	
	DPDT	12	1,407	1	0.3	75/5/200	3/3	5.0 x 10 x 6.5	Z133-ND	2.92	2.64	2.34	G6K-2P-Y-DC12	
	DPDT	24	5,220	1	0.3	75/5/200	3/3	5.0 x 10 x 6.5	Z134-ND	2.92	2.64	2.34	G6K-2P-Y-DC24	
SMT														
6	DPDT	3	62.5	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2526TR-ND0	585.22/400			G6J-2FS-Y-TR-DC3	
	DPDT	4.5	137.9	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2135-ND	2.92	2.64	2.35	G6J-2FS-Y-DC4.5	
	DPDT	4.5	137.9	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2135TR-ND0	600.28/400			G6J-2FS-Y-TR-DC4.5	
	DPDT	5	173.1	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2136-ND	2.92	2.64	2.35	G6J-2FS-Y-DC5	
	DPDT	5	173.1	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2136TR-ND0	585.22/400			G6J-2FS-Y-TR-DC5	
	DPDT	12	976.8	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2137-ND	2.92	2.64	2.35	G6J-2FS-Y-DC12	
	DPDT	12	976.8	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2137TR-ND0	585.22/400			G6J-2FS-Y-TR-DC12	
	DPDT	24	2,600.5	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2138-ND	2.92	2.64	2.35	G6J-2FS-Y-DC24	
	DPDT	24	2,600.5	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2138TR-ND0	585.22/400			G6J-2FS-Y-TR-DC24	
	DPDT	4.5	137.9	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2139-ND	2.92	2.64	2.35	G6J-2FL-Y-DC4.5	
	DPDT	4.5	137.9	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2139TR-ND0	599.48/400			G6J-2FL-Y-TR-DC4.5	
	DPDT	3	62.5	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2933-ND	2.92	2.64	2.35	G6J-2FL-Y-DC3	
	DPDT	5	173.1	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2140-ND	2.92	2.64	2.35	G6J-2FL-Y-DC5	
	DPDT	5	173.1	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2140TR-ND0	585.22/400			G6J-2FL-Y-TR-DC5	
	DPDT	12	976.8	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2141-ND	2.92	2.64	2.35	G6J-2FL-Y-DC12	
	DPDT	12	976.8	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2141TR-ND0	644.00/400			G6J-2FL-Y-TR-DC12	
	DPDT	24	2,600.5	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2142-ND	2.92	2.64	2.35	G6J-2FL-Y-DC24	
	DPDT	24	2,600.5	1	0.3	75/10/150	3/3	10 x 10.6 x 5.7	Z2142TR-ND0	585.22/400			G6J-2FL-Y-TR-DC24	
7	DPDT	3	91	1	0.3	75/5/200	3/3	5.2 x 10 x 6.5	Z2186-ND	2.92	2.64	2.34	G6K-2F-DC3	
	DPDT	4.5	194	1	0.3	75/5/200	3/3	5.2 x 10 x 6.5	Z1111-ND	2.92	2.64	2.34	G6K-2F-DC4.5	
	DPDT	5	237	1	0.3	75/5/200	3/3	5.2 x 10 x 6.5	Z112-ND	2.92	2.64	2.34	G6K-2F-DC5	
	DPDT	12	1,407	1	0.3	75/5/200	3/3	5.2 x 10 x 6.5	Z113-ND	2.92	2.64	2.34	G6K-2F-DC12	
	DPDT	12	1,315	1	0.3	80/10/150	3/3	5.2 x 10 x 6.5	Z113TR-ND0	1315.23/900			G6K-2F-TR-DC12	
	DPDT	24	5,220	1	0.3	75/5/200	3/3	5.2 x 10 x 6.5	Z114-ND	2.92	2.64	2.34	G6K-2F-DC24	
	DPDT	24	5,220	1	0.3	80/10/150	3/3	5.0 x 10 x 6.5	Z114TR-ND0	1578.27/900			G6K-2F-TR-DC24	
	DPDT	3	91	1	0.3	75/5/200	3/3	5.2 x 10 x 6.5	Z2354-ND	2.92	2.64	2.34	G6K-2F-Y-DC3	
	DPDT	4.5	194	1	0.3	75/5/200	3/3	5.2 x 10 x 6.5	Z127-ND	2.92	2.64	2.34	G6K-2F-Y-DC4.5	
	DPDT	5	237	1	0.3	75/5/200	3/3	5.2 x 10 x 6.5	Z128-ND	2.92	2.64	2.34	G6K-2F-Y-DC5	
	DPDT	5	237	1	0.3	80/10/150	3/3	5.2 x 10 x 6.5	Z128TR-ND0	1315.23/900			G6K-2F-Y-TR-DC5	
	DPDT	12	1,407	1	0.3	75/5/200	3/3	5.2 x 10 x 6.5	Z129-ND	2.92	2.64	2.34	G6K-2F-Y-DC12	
	DPDT	12	1,315	1	0.3	80/10/150	3/3	5.2 x 10 x 6.5	Z129TR-ND0	1315.23/900			G6K-2F-Y-TR-DC12	
	DPDT	24	5,220	1	0.3	75/5/200	3/3	5.2 x 10 x 6.5	Z130-ND	2.92	2.64	2.34	G6K-2F-Y-DC24	
	DPDT	24	5,220	1	0.3	80/10/150	3/3	5.2 x 10 x 6.5	Z130TR-ND0	1315.23/900			G6K-2F-Y-TR-DC24	
	DPDT	4.5	194	1	0.3	75/5/200	3/3	5.2 x 10 x 6.5	Z135-ND	2.92	2.64	2.34	G6K-2G-Y-DC4.5	
	DPDT	5	237	1	0.3	80/10/150	3/3	5.2 x 10 x 6.5	Z2867-ND	2.92	2.64	2.34	G6K-2G-DC5	
	DPDT	5	237	1	0.3	75/5/200	3/3	5.2 x 10 x 6.5	Z136-ND	2.92	2.64	2.34	G6K-2G-Y-DC5	
	DPDT	5	237	1	0.3	80/10/150	3/3	5.2 x 10 x 6.5	Z2657TR-ND0	1315.23/900			G6K-2G-TR-DC5	
	DPDT	12	1,407	1	0.3	75/5/200	3/3	5.2 x 10 x 6.5	Z137-ND	2.92	2.64	2.34	G6K-2G-Y-DC12	
	DPDT	24	5,220	1	0.3	75/5/200	3/3	5.2 x 10 x 6.5	Z138-ND	2.92	2.64	2.34	G6K-2G-Y-DC24	
	DPDT	3	91	1	0.3	75/5/150	3/3	5.2 x 10 x 6.5	Z3030-ND	3.08	2.77	2.46	G6KU-2F-Y-DC3	
	8	SPST	3	62.5	1	0.3	75/10/150	5/5	4.0 x 10.6 x 7	Z1230-ND	1.83	1.65	1.47	G6L-1F-DC3
		SPST	4.5	140.4	1	0.3	75/10/150	5/5	4.0 x 10.6 x 7	Z1231-ND	1.83	1.65	1.47	G6L-1F-DC4.5
SPST		5	171.1	1	0.3	75/10/150	5/5	4.0 x 10.6 x 7	Z1232-ND	1.83	1.65	1.47	G6L-1F-DC5	
SPST		12	979.8	1	0.3	75/10/150	5/5	4.0 x 10.6 x 7	Z1233-ND	1.83	1.65	1.47	G6L-1F-DC12	
SPST		24	2,504	1	0.3	75/10/150	5/5	4.0 x 10.6 x 7	Z2040-ND	2.01	1.81	1.61	G6L-1F-DC24	
SPST		3	50	1	0.3	75/10/150	5/5	4.0 x 10.6 x 7	Z1226-ND	1.83	1.65	1.47	G6L-1P-DC3	
SPST		4.5	112.5	1	0.3	75/10/150	5/5	4.0 x 10.6 x 7	Z1227-ND	1.83	1.65	1.47	G6L-1P-DC4.5	
SPST		5	139	1	0.3	75/10/150	5/5	4.0 x 10.6 x 7	Z1228-ND	1.83	1.65	1.47	G6L-1P-DC5	
SPST		12	800	1	0.3	75/10/150	5/5	4.0 x 10.6 x 7	Z1229-ND	1.83	1.65	1.47	G6L-1P-DC12	
SPST		24	2,504	1	0.3	75/10/150	5/5	4.0 x 10.6 x 7	Z2041-ND	1.83	1.65	1.47	G6L-1P-DC24	
9		DPDT	3	64.30	1	0.5	75/10/150	3/2	5.2 x 14.1 x 9	Z2856-ND	3.72	3.35	2.98	G6H-2F-DC3
		DPDT	5	178	1	0.5	75/10/120	3/2	5.2 x 14.1 x 9	Z827-ND	3.50	3.15	2.80	G6H-2F-DC5
	DPDT	12	1,028	1	0.5	75/10/120	3/2	5.2 x 14.1 x 9	Z828-ND	3.50	3.15	2.80	G6H-2F-DC12	
	DPDT	12	1,028	1	0.5	75/10/200	3/2	5.2 x 14.1 x 9	Z2984TR-ND0	1075.79/500			G6H-2F-TR-DC12	

† Sealed case ‡ Meets FCC Part 68 standards ◊ Tape and Reel

(Continued)

Free shipping on orders over €65! All prices in euro and include duties. (EU2011-EN) 2329