

OMRON Low Signal Relays (Cont.)

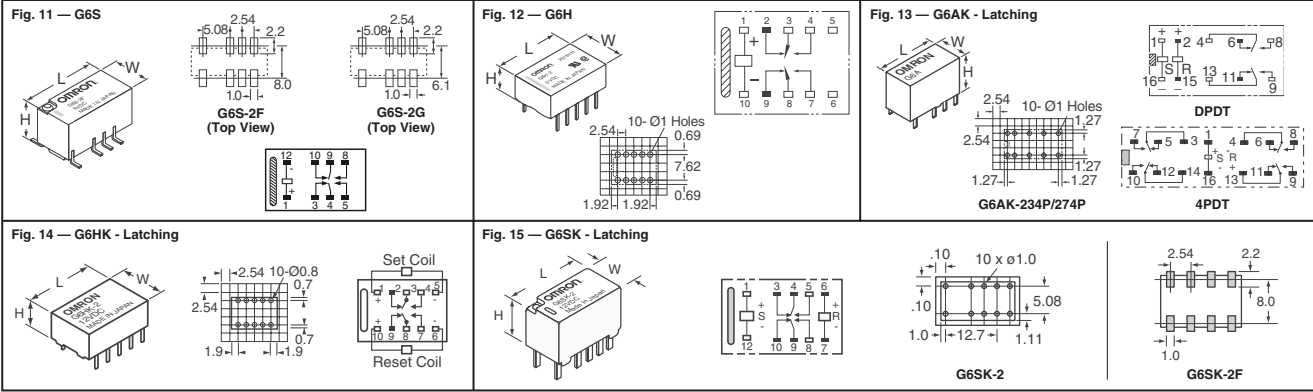


Fig.	Contact Form	Coil		Contact Ratings Resistive (A)		Operating Voltage (% of Rated) Pull/Drop/Max. On/Out/Cont.	Operate/Release Time (msec.)	Dimensions (mm) H x L x W	Digi-Key Part No.	Price Each			Omron Part No.	
		Voltage (VDC)	Resistance (Ω)	24 VDC	115 VAC					1	25	50		
10	DPDT	4.5	145	2	0.5	75/10/200	4/4	9.2 x 14.8 x 7.3	Z2601-ND	2.55	2.30	2.05	G6S-2-DC4.5	
	DPDT	5	178	2	0.5	75/10/200	4/4	9.2 x 14.8 x 7.3	Z2615-ND	2.55	2.30	2.05	G6S-2-DC5 BY OMR	
	DPDT	9	579	2	0.5	75/10/200	4/4	9.2 x 14.8 x 7.3	Z2609-ND	2.55	2.30	2.05	G6S-2-DC9 BY OMR	
	DPDT	12	1,028	2	0.5	75/10/200	4/4	9.2 x 14.8 x 7.3	Z2607-ND	2.55	2.30	2.05	G6S-2-DC12 BY OMR	
	DPDT	24	2,880	2	0.5	75/10/200	4/4	9.2 x 14.8 x 7.3	Z2608-ND	2.87	2.58	2.30	G6S-2-DC24 BY OMR	
11	DPDT	3	64.3	2 @ 30VAC	0.5	75/10/200	4/4	9.2 x 14.8 x 7.3	Z2187-ND	2.61	2.35	2.09	G6S-2F-DC3 BY OMR	
	DPDT	3	64.3	2 @ 30VAC	0.5	75/10/200	4/4	9.2 x 14.8 x 7.3	Z2187TR-ND	533.25/400			G6S-2F-TR-DC3 BY OMR	
	DPDT	4.5	145	2 @ 30VAC	0.5	75/10/200	4/4	9.2 x 14.8 x 7.3	Z2857-ND	2.61	2.35	2.09	G6S-2F-DC4.5	
	DPDT	5	178	2 @ 30VAC	0.5	75/10/200	4/4	9.2 x 14.8 x 7.3	Z888-ND	2.61	2.35	2.09	G6S-2F-DC5 BY OMR	
	DPDT	5	178	2 @ 30VAC	0.5	75/10/200	4/4	9.2 x 14.8 x 7.3	Z888TR-ND	533.25/400			G6S-2F-TR-DC5 BY OMR	
	DPDT	12	1,028	2 @ 30VAC	0.5	75/10/200	4/4	9.2 x 14.8 x 7.3	Z889-ND	2.61	2.35	2.09	G6S-2F-DC12 BY OMR	
	DPDT	12	1,028	2 @ 30VAC	0.5	75/10/200	4/4	9.2 x 14.8 x 7.3	Z889TR-ND	533.25/400			G6S-2F-TR-DC12 BY OMR	
	DPDT	24	2,880	2 @ 30VAC	0.5	75/10/200	4/4	9.2 x 14.8 x 7.3	Z890-ND	2.98	2.69	2.39	G6S-2F-DC24 BY OMR	
	DPDT	3	64.3	2 @ 30VAC	0.5	75/10/200	4/4	9.2 x 14.8 x 7.3	Z3032TR-ND	725.22/400			G6S-2G-TR-DC3 BY OMR	
	DPDT	5	178	2 @ 30VAC	0.5	75/10/200	4/4	9.2 x 14.8 x 7.3	Z891-ND	2.61	2.35	2.09	G6S-2G-DC5 BY OMR	
12	DPDT	12	1,028	2 @ 30VAC	0.5	75/10/200	4/4	9.2 x 14.8 x 7.3	Z892-ND	2.67	2.41	2.15	G6S-2G-DC12 BY OMR	
	DPDT	24	2,880	2 @ 30VAC	0.5	75/10/200	4/4	9.2 x 14.8 x 7.3	Z893-ND	2.98	2.69	2.39	G6S-2G-DC24 BY OMR	
	DPDT	3	64.3	1	0.5	75/10/200	3/2	5.4 x 14.3 x 9.3	Z2540-ND	2.39	2.15	1.92	G6H-2-DC3	
	DPDT	6	257	1	0.5	75/10/200	3/2	5.4 x 14.3 x 9.3	Z2541-ND	2.39	2.15	1.92	G6H-2-DC6	
13	DPDT	9	579	1	0.5	75/10/200	3/2	5.4 x 14.3 x 9.3	Z2542-ND	2.39	2.15	1.92	G6H-2-DC9	
	DPDT	12	1,028	1	0.5	75/10/200	3/2	5.4 x 14.3 x 9.3	Z741-ND	2.39	2.15	1.92	G6H-2-DC12	
	Low Signal Relays — Single and Dual Coil Latching Type													
	6	DPDT	4.5	204.3	1	0.3	75/75/150	3/3	9.0 x 10.3 x 4.8	Z2143-ND	2.99	2.70	2.40	G6JU-2P-Y-DC4.5
DPDT		5	245.5	1	0.3	75/75/150	3/3	9.0 x 10.3 x 4.8	Z2144-ND	2.99	2.70	2.40	G6JU-2P-Y-DC5	
DPDT		12	1,329.2	1	0.3	75/75/150	3/3	9.0 x 10.3 x 4.8	Z2145-ND	2.99	2.70	2.40	G6JU-2P-Y-DC12	
DPDT		24	2,600	1	0.3	75/75/150	3/3	9.0 x 10.3 x 4.8	Z2146-ND	4.11	3.70	3.29	G6JU-2P-Y-DC24	
DPDT		4.5	204.3	1	0.3	75/75/150	3/3	10 x 10.3 x 4.8	Z2147-ND	2.99	2.70	2.40	G6JU-2FL-Y-DC4.5	
DPDT		5	245.5	1	0.3	75/75/150	3/3	10 x 10.3 x 4.8	Z2148-ND	2.99	2.70	2.40	G6JU-2FL-Y-DC5	
DPDT		12	1,329.2	1	0.3	75/75/150	3/3	10 x 10.3 x 4.8	Z2149-ND	2.99	2.70	2.40	G6JU-2FL-Y-DC12	
DPDT		24	2,600	1	0.3	75/75/150	3/3	10 x 10.3 x 4.8	Z2150-ND	4.11	3.70	3.29	G6JU-2FL-Y-DC24	
DPDT		24	4,430	1	0.3	75/75/150	3/3	10 x 10.3 x 4.8	Z1214-ND	3.36	3.03	2.70	G6JU-2FL-DC24	
DPDT		4.5	204.3	1	0.3	75/75/150	3/3	10 x 10.3 x 4.8	Z2151-ND	2.99	2.70	2.40	G6JU-2FS-Y-DC4.5	
14	DPDT	24	2,600	1	0.3	75/75/150	3/3	10 x 10.3 x 4.8	Z2154-ND	4.11	3.70	3.29	G6JU-2FS-Y-DC24	
	DPDT	24	3,672	1	0.3	75/75/150	3/3	10 x 10.3 x 4.8	Z1222-ND	3.36	3.03	2.70	G6JU-2FS-DC24	
	DPDT	5	139	1	0.3	70/70/200	5/5	8.4 x 20.2 x 10.1	Z749-ND	5.33	4.80	4.27	G6AK-234P-ST-US-DC5	
	DPDT	12	800	1	0.3	70/70/200	5/5	8.4 x 20.2 x 10.1	Z750-ND	5.33	4.80	4.27	G6AK-234P-ST-US-DC12	
	DPDT	24	3,200	1	0.3	70/70/200	5/5	8.4 x 20.2 x 10.1	Z751-ND	5.33	4.80	4.27	G6AK-234P-ST-US-DC24	
	DPDT	5	139	1	0.3	70/70/200	5/5	8.4 x 20.2 x 10.1	Z2595-ND	5.33	4.80	4.27	G6AK-274P-ST-US-DC5	
15	DPDT	12	800	1	0.3	70/70/200	5/5	8.4 x 20.2 x 10.1	Z2593-ND	5.33	4.80	4.27	G6AK-274P-ST-US-DC12	
	DPDT	24	3,200	1	0.3	70/70/200	5/5	8.4 x 20.2 x 10.1	Z2594-ND	5.33	4.80	4.27	G6AK-274P-ST-US-DC24	
	4PDT	24	3,200	2	0.5	70/70/150	7/5	8.4 x 35.4 x 10.1	Z2981-ND	9.53	8.58	7.63	G6AK-474P-ST-US-DC24	
	SPDT	5	125	2	0.4	70/70/190	5/5	7.9 x 16 x 9.9	Z833-ND	5.12	4.61	4.10	G6EK-134P-ST-US-DC5	
	SPDT	12	720	2	0.4	70/70/190	5/5	7.9 x 16 x 9.9	Z834-ND	5.12	4.61	4.10	G6EK-134P-ST-US-DC12	
	SPDT	24	2,880	2	0.4	70/70/190	5/5	7.9 x 16 x 9.9	Z835-ND	5.30	4.78	4.25	G6EK-134P-ST-US-DC24	
14	DPDT	3	45	1	0.5	75/75/150	3/2	5.0 x 14 x 9.0	Z2543-ND	2.90	2.61	2.32	G6HK-2-DC3	
	DPDT	6	180	1	0.5	75/75/150	3/2	5.0 x 14 x 9.0	Z2544-ND	2.90	2.61	2.32	G6HK-2-DC6	
	DPDT	9	405	1	0.5	75/75/150	3/2	5.0 x 14 x 9.0	Z2545-ND	2.90	2.61	2.32	G6HK-2-DC9	
	DPDT	12	720	1	0.5	75/75/150	3/2	5.0 x 14 x 9.0	Z966-ND	2.90	2.61	2.32	G6HK-2-DC12	
	DPDT	24	1,920	1	0.5	75/75/150	3/2	5.0 x 14 x 9.0	Z967-ND	3.12	2.81	2.50	G6HK-2-DC24	
15	DPDT	5	125	2	0.5	75/75/170	4/4	9.2 x 14.8 x 7.3	Z2665-ND	2.89	2.61	2.32	G6SK-2-DC5	
	DPDT	12	720	2	0.5	75/75/170	4/4	9.2 x 14.8 x 7.3	Z2663-ND	2.89	2.61	2.32	G6SK-2-DC12	
	DPDT	24	1,920	2	0.5	75/75/140	4/4	9.2 x 14.8 x 7.3	Z2664-ND	3.26	2.94	2.61	G6SK-2-DC24	
	DPDT	5	125	2	0.5	75/75/170	4/4	9.2 x 14.8 x 7.3	Z3021-ND	2.95	2.66	2.36	G6SK-2-H-DC5	
	DPDT	5	125	2	0.5	75/75/170	4/4	9.2 x 14.8 x 7.3	Z2668-ND	2.95	2.66	2.36	G6SK-2F-DC5	
	DPDT	12	720	2	0.5	75/75/170	4/4	9.2 x 14.8 x 7.3	Z2666-ND	2.95	2.66	2.36	G6SK-2F-DC12	
	DPDT	12	720	2	0.5	75/75/170	4/4	9.2 x 14.8 x 7.3	Z2666TR-ND	818.02/400			G6SK-2F-TR-DC12	
	DPDT	24	1,920	2	0.5	75/75/140	4/4	9.2 x 14.8 x 7.3	Z2667-ND	3.32	2.99	2.66	G6SK-2F-DC24	

† Sealed case ‡ Meets FCC Part 68 standards ◊ Tape and Reel

2330 (EU2011-EN) **Free shipping on orders over €65!** All prices in euro and include duties.