

Plage de pression de fonctionnement PSIG	Tension d'alim. (V c.c.)	N° de référence Digi-Key	Prix unitaire		N° de référence Measurement Specialties
			1	10	
500 1000 2500 5000 10000	5	MSP3501P2-ND MSP3102P2-ND MSP3252P2-ND MSP3502P2-ND MSP3103P2-ND	88.14 88.14 88.14 88.14 88.14	73.85 73.85 73.85 73.85 73.85	2000260 2000046 2000223 2000099 2000158
<b>Sortie 1 à 5 V — Fixe - Alimentation à 3 fils de 10 mA maximum NPT 1/4", câble de 2'</b>					
100 250 500 1000 2500	10 - 32	MSP3101P3-ND MSP3251P3-ND MSP3501P3-ND MSP3102P3-ND MSP3252P3-ND	93.04 93.04 93.04 93.04 93.04	77.96 77.96 77.96 77.96 77.96	2000133 2000204 2000262 2000048 2000226
5000 10000	10 - 32	MSP3502P3-ND MSP3103P3-ND	93.04 93.04	77.96 77.96	2000100 2000159
<b>Sortie 1 à 5 V — NPT 1/8", câble de 2' — Conforme à RoHS</b>					
100 250 500 1000	10 - 32	MSP3101P4A1-ND MSP3251P4A1-ND MSP3501P4A1-ND MSP3102P4A1-ND	93.04 93.04 93.04 93.04	77.96 77.96 77.96 77.96	2000132 2000203 2000261 2000047
<b>Sortie 4 à 20 mA — NPT 1/4", alim. régulée à 2 fils, câble de 2'</b>					
100 250 500 1000 2500	10 - 32	MSP3101P4-ND MSP3251P4-ND MSP3501P4-ND MSP3102P4-ND MSP3252P4-ND	92.64 92.64 92.64 92.64 92.64	79.41 79.41 79.41 79.41 79.41	2000137 2000207 2000264 2000050 2000227
5000 10000	10 - 32	MSP3502P4-ND MSP3103P4-ND	92.64 92.64	79.41 79.41	2000101 2000160
<b>Sortie 4 à 20 mA — NPT 1/8", câble de 2'</b>					
100 250 500 1000	10 - 32	MSP3101P5A1-ND MSP3251P5A1-ND MSP3501P5A1-ND MSP3102P5A1-ND	92.64 92.64 92.64 92.64	79.41 79.41 79.41 79.41	2000136 2000206 2000263 2000049
<b>Série MSP-340 — Conforme à RoHS</b>					
<b>Sortie 100 mV — NPT de 1/8", câble de 2'</b>					
100 300 500 1000	5	MSP6892-ND MSP6893-ND MSP6894-ND MSP6895-ND	81.45 81.45 81.45 81.45	68.25 68.25 68.25 68.25	M3421-000006-100PG M3421-000006-300PG M3421-000006-500PG M3421-000006-01KPG
<b>Sortie 0,5 à 4,5 V — NPT de 1/8", câble de 2'</b>					
100 300 500 1000	5	MSP6896-ND MSP6897-ND MSP6898-ND MSP6899-ND	95.19 95.19 95.19 95.19	79.76 79.76 79.76 79.76	M3431-000006-100PG M3431-000006-300PG M3431-000006-500PG M3431-000006-01KPG
<b>Série MSP-400 — Conforme à RoHS</b>					
<b>Sortie 1 à 5 V — Fixe - Alimentation à 3 fils de 10 mA maximum NPT 1/4", câble de 2'</b>					
5000	10 - 32	MSP4502P3-ND	80.04	68.61	2000455
<b>Sortie 4 à 20 mA — NPT 1/4", alim. régulée à 2 fils, câble de 2'</b>					
1000 5000	10 - 32	MSP4102P4-ND MSP4502P4-ND	91.90 91.90	78.78 78.78	2000417 2000457
<b>Série MSP-600 — Conforme à RoHS</b>					
<b>Sortie 0,5 à 4,5 V c.c. — SAE 7/16", connecteur Packard</b>					
25 50 75 100 500 1000	5	MSP602P3-4-ND MSP605P3-4-ND MSP607P3-4-ND MSP6101P3-4-ND MSP6501P3-4-ND MSP6102P3-4-ND	81.52 81.52 81.52 81.52 81.52 81.52	69.88 69.88 69.88 69.88 69.88 69.88	2000964 2000965 2000966 2000967 2000969 2000970
<b>Sortie 1 à 5 V c.c. — NPT 1/4", câble de 2'</b>					
75	10 - 30	MSP6075P4-1-ND	85.97	73.69	2000884
<b>Sortie 4 à 20 mA — NPT 1/4", câble de 2'</b>					
50 75 2500	10 - 30	MSP6050P5-1-ND MSP6075P5-1-ND MSP6252P5-1-ND	100.79 100.79 100.79	86.40 86.40 86.40	2000879 2000885 2000915
<b>Série MSP-610 — Conforme à RoHS</b>					
<b>Sortie 0,5 à 4,5 V — NPT de 1/8", câble de 2'</b>					
300 500	5	MSP6906-ND MSP6907-ND	96.72 96.72	82.90 82.90	M6131-C00006-300PG M6131-C00006-500PG
<b>Sortie 0,5 à 4,5 V — NPT 1/4", câble de 2'</b>					
100 500	5	MSP6903-ND MSP6905-ND	96.72 96.72	82.90 82.90	M6131-C00005-100PG M6131-C00005-500PG
<b>Sortie 1 à 5 V — NPT 1/4", câble de 2'</b>					
300 500	8 - 30	MSP6909-ND MSP6910-ND	100.79 100.79	86.40 86.40	M6141-C00005-300PG M6141-C00005-500PG
<b>Sortie 4 à 20 mA — NPT 1/4", câble de 2'</b>					
100 300 500	10 - 30	MSP6911-ND MSP6912-ND MSP6913-ND	114.88 114.88 114.88	98.47 98.47 98.47	M6181-C00005-100PG M6181-C00005-300PG M6181-C00005-500PG
<b>Série UltraStable 5100 — Conforme à RoHS</b>					
<b>Sortie ratiométrique de 0,5 à 4,5 V — NPT 1/4", pression absolue, câble de 2'</b>					
15PSIA 30PSIA 100PSIA	4.75 - 5.25	223-1000-ND 223-1002-ND 223-1004-ND	148.23 148.23 148.23	127.05 127.05 127.05	U5131-000005-015PA U5131-000005-030PA U5131-000005-100PA

Plage de pression de fonctionnement PSIG	Tension d'alim. (V c.c.)	N° de référence Digi-Key	Prix unitaire		N° de référence Measurement Specialties
			1	10	
<b>Sortie 4 à 20 mA — NPT 1/4", pression absolue, câble de 2'</b>					
15PSIA 30PSIA 100PSIA	9 - 30	223-1007-ND 223-1009-ND 223-1011-ND	179.06 179.06 179.06	151.94 151.94 151.94	U5151-000005-015PA U5151-000005-030PA U5151-000005-100PA
<b>Sortie ratiométrique 0,5 à 4,5 V — NPT 1/4", câble de 2'</b>					
15 30 100 500	4.75 - 5.25	223-1001-ND 223-1003-ND 223-1005-ND 223-1006-ND	148.23 148.23 148.23 148.23	127.05 127.05 127.05 127.05	U5131-000005-015PG U5131-000005-030PG U5131-000005-100PG U5131-000005-500PG
<b>Sortie 4 à 20 mA — NPT 1/4", câble de 2'</b>					
15 30 100 500	9 - 30	223-1008-ND 223-1010-ND 223-1012-ND 223-1013-ND	179.06 179.06 179.06 179.06	151.94 151.94 151.94 151.94	U5151-000005-015PG U5151-000005-030PG U5151-000005-100PG U5151-000005-500PG
<b>Série M5100 — Conforme à RoHS</b>					
<b>Sortie ratiométrique 0,5 à 4,5 V — NPT 1/4", câble de 2'</b>					
50 75 100 250 500	4.75 - 5.25	223-1038-ND 223-1041-ND 223-1020-ND 223-1026-ND 223-1032-ND	97.27 97.27 97.27 97.27 97.28	83.38 83.38 83.38 83.38 83.39	M5131-000005-050PG M5131-000005-075PG M5131-000005-100PG M5131-000005-250PG M5131-000005-500PG
1000 2500 5000 10000	4.75 - 5.25	223-1014-ND 223-1029-ND 223-1017-ND 223-1023-ND	97.27 97.27 97.27 97.27	83.38 83.38 83.38 83.38	M5131-000005-01KPG M5131-000005-2K5PG M5131-000005-05KPG M5131-000005-10KPG
<b>Sortie 1 à 5 V — NPT 1/4", câble de 2'</b>					
50 75 100 250 500	8 - 30	223-1039-ND 223-1042-ND 223-1021-ND 223-1027-ND 223-1033-ND	101.90 101.90 101.90 101.90 101.90	87.35 87.35 87.35 87.35 87.35	M5141-000005-050PG M5141-000005-075PG M5141-000005-100PG M5141-000005-250PG M5141-000005-500PG
1000 2500 5000 10000	8 - 30	223-1015-ND 223-1030-ND 223-1018-ND 223-1024-ND	101.90 101.90 101.90 101.90	87.35 87.35 87.35 87.35	M5141-000005-01KPG M5141-000005-2K5PG M5141-000005-05KPG M5141-000005-10KPG
<b>Sortie 4 à 20 mA — NPT 1/4", câble de 2'</b>					
50 75 100 250 500	9 - 30	223-1040-ND 223-1043-ND 223-1022-ND 223-1028-ND 223-1034-ND	106.54 106.54 106.54 106.54 106.54	91.32 91.32 91.32 91.32 91.32	M5151-000005-050PG M5151-000005-075PG M5151-000005-100PG M5151-000005-250PG M5151-000005-500PG
1000 2500 5000 10000	9 - 30	223-1016-ND 223-1031-ND 223-1019-ND 223-1025-ND	106.54 106.54 106.54 106.54	91.32 91.32 91.32 91.32	M5151-000005-01KPG M5151-000005-2K5PG M5151-000005-05KPG M5151-000005-10KPG
<b>Sortie ratiométrique de 0,5 à 4,5 V — Mâle UNF 7/16", joint torique, connecteur Packard</b>					
50 75 100 250 500	4.75 - 5.25	223-1045-ND 223-1046-ND 223-1047-ND 223-1048-ND 223-1049-ND	97.27 97.27 97.27 97.27 97.27	83.38 83.38 83.38 83.38 83.38	M5134-000004-050PG M5134-000004-075PG M5134-000004-100PG M5134-000004-250PG M5134-000004-500PG
1000 2500 5000 7500 10000	4.75 - 5.25	223-1050-ND 223-1051-ND 223-1052-ND 223-1074-ND 223-1053-ND	97.27 97.27 97.27 97.27 97.27	83.38 83.38 83.38 83.38 83.38	M5134-000004-01KPG M5134-000004-2K5PG M5134-000004-05KPG M5134-000004-7K5PG M5134-000004-10KPG
<b>Sortie de 1 à 5 V — Mâle UNF 7/16", joint torique, connecteur Packard</b>					
50 75 100 250 500	8 - 30	223-1055-ND 223-1056-ND 223-1057-ND 223-1058-ND 223-1059-ND	101.90 101.90 101.90 101.90 101.90	87.35 87.35 87.35 87.35 87.35	M5144-000004-050PG M5144-000004-075PG M5144-000004-100PG M5144-000004-250PG M5144-000004-500PG
1000 2500 5000 7500 10000	8 - 30	223-1060-ND 223-1061-ND 223-1062-ND 223-1075-ND 223-1063-ND	101.90 101.90 101.90 101.90 101.90	87.35 87.35 87.35 87.35 87.35	M5144-000004-01KPG M5144-000004-2K5PG M5144-000004-05KPG M5144-000004-7K5PG M5144-000004-10KPG
<b>Sortie de 4 à 20 mA — Mâle UNF 7/16", joint torique, connecteur Packard</b>					
50 75 100 250 500	9 - 30	223-1065-ND 223-1066-ND 223-1067-ND 223-1068-ND 223-1069-ND	106.54 106.54 106.54 106.54 106.54	91.32 91.32 91.32 91.32 91.32	M5154-000004-050PG M5154-000004-075PG M5154-000004-100PG M5154-000004-250PG M5154-000004-500PG
1000 2500 5000 7500 10000	9 - 30	223-1070-ND 223-1071-ND 223-1072-ND 223-1076-ND 223-1073-ND	106.54 106.54 106.54 106.54 106.54	91.32 91.32 91.32 91.32 91.32	M5154-000004-01KPG M5154-000004-2K5PG M5154-000004-05KPG M5154-000004-7K5PG M5154-000004-10KPG


◆ Conforme à RoHS

Faisceaux de câbles

Faisceaux de câbles préfabriqués de la technologie SSI avec la norme de l'industrie Packard™ de connecteurs automobiles.



Description	Longueur (en pouces)	N° de référence Digi-Key	Prix unitaire			N° de référence SSI Technologies
			1	10	25	
Faisceau de câbles Packard	12	734-1163-ND	9.88	8.83	8.28	P2432.3
Faisceau de câbles Packard	36	734-1164-ND	17.70	16.98	15.37	P2435.3
Faisceau de câbles Packard	72	734-1165-ND	22.39	21.55	19.68	14306.3

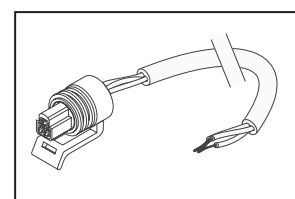

N

Livraison gratuite pour les commandes de plus de 65 € ! Tous les prix sont indiqués en euros.

fr.digikey.com — Téléphone (numéro vert) : 0800-161-113 — Téléphone : +31 (0)53-484-9584 — Télécopieur : +33 (0)38-717-0111

(FR091) 2427