
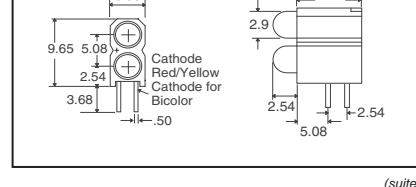
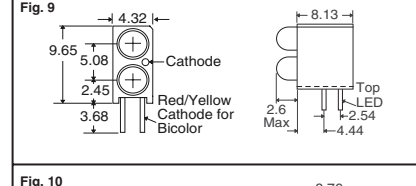
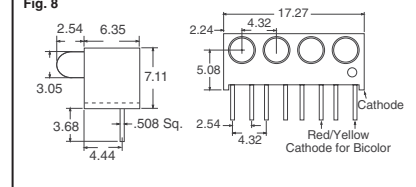
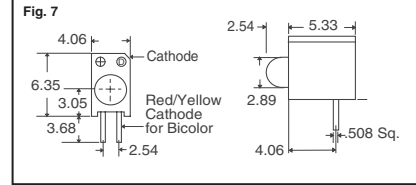
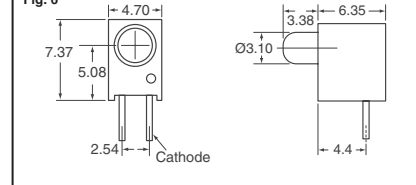
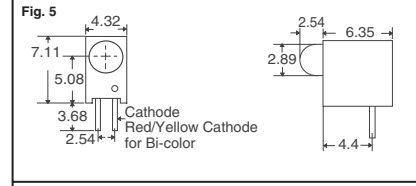
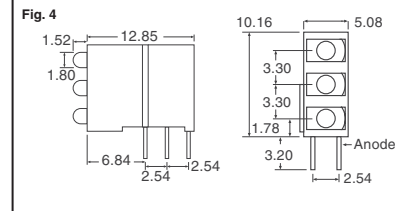
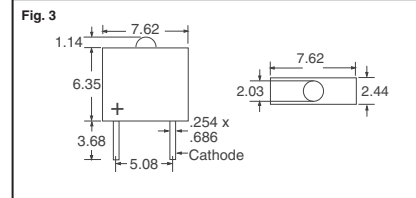
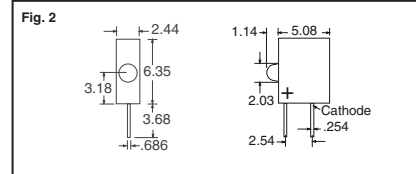


Fig.	Couleur	Longueur d'onde crête (nm)	Io typ. (mcd)	Vf typ. (V)	If typ. (mA)	N° de référence Digi-Key	Prix unitaire			N° de référence Dialight
							1	25	100	
3	Jaune	583	2.0	2.2	20.0	350-1162-ND	1.72	1.34	1.06	555-3401
6	Vert	525	3400	3.5	30.0	350-1522-ND	4.85	3.78	3.06	551-4207
18	Rouge/Vert	660/565	90/40	1.8/2.1	20.0	350-1114-ND	1.86	1.44	1.15	552-0711
Conforme à RoHS										
1	Bleu	470	1010	3.8	30.0	350-1563-ND	1.21	.94	.75	521-9946F
	Blanc	—	1690	3.8	30.0	350-1564-ND	2.41	1.87	1.52	521-9948
2	Rouge	650	1.2	1.6	20.0	350-1711-ND	1.17	.90	.73	555-2001F
	Vert	565	1.0	2.4	20.0	350-1716-ND	1.06	.81	.66	555-2301F
	Jaune	583	2.0	2.2	20.0	350-1718-ND	1.19	.92	.74	555-2401F
	Rouge	650	1.9	5.0	6.0	350-1712-ND	1.21	.93	.75	555-2003F
	Rouge	650	0.9	5.0	3.0	350-1713-ND	1.24	.95	.76	555-2007F
	Rouge	650	0.6	5.0	1.0	350-1715-ND	1.22	.94	.76	555-2009F
	Vert	565	2.5	5.0	4.7	350-1717-ND	1.19	.92	.74	555-2303F
	Jaune	583	2.1	5.0	4.7	350-1719-ND	1.21	.93	.75	555-2403F
3	Rouge	650	0.9	24.0	3.0	350-1714-ND	1.26	.98	.79	555-2008F
	Rouge	650	1.2	1.6	20.0	350-1720-ND	1.22	.94	.76	555-3001F
	Vert	565	1.0	2.4	20.0	350-1725-ND	1.56	1.21	.96	555-3301F
	Jaune	583	2.0	2.2	20.0	350-1727-ND	1.56	1.21	.96	555-3401F
	Rouge	650	1.9	5.0	6.0	350-1721-ND	1.19	.92	.74	555-3003F
	Rouge	650	0.9	5.0	3.0	350-1722-ND	1.43	1.11	.88	555-3007F
	Rouge	650	0.6	5.0	1.0	350-1724-ND	1.51	1.17	.93	555-3009F
	Vert	565	2.5	5.0	4.7	350-1726-ND	1.69	1.31	1.04	555-3303F
	Jaune	583	2.1	5.0	4.7	350-1728-ND	1.69	1.31	1.04	555-3403F
	Rouge	650	0.9	24.0	3.0	350-1723-ND	1.43	1.11	.88	555-3008F
	Rouge	650	1.9	5.0	6.0	350-1802-ND	5.52	4.30	3.48	555-5003F
	4	Rouge	650	1.2	1.6	20.0	350-1803-ND	4.85	3.78	3.06
Vert		565	1.0	2.4	20.0	350-1804-ND	5.73	4.47	3.62	555-5301F
Jaune		583	2.0	2.2	20.0	350-1805-ND	5.73	4.47	3.62	555-5401F
Vert		565	8.7	2.1	20.0	350-1806-ND	2.25	1.74	1.39	570-0100-222F
4	Rouge	635	12.6	2.0	20.0	350-1807-ND	2.25	1.74	1.39	570-0100-111F
	Jaune	585	12.6	2.1	20.0	350-1808-ND	2.25	1.74	1.39	570-0100-333F
	Rouge/Jaune/Vert	635/585/565	12.6/12.6/8.7	2.0/2.1/2.1	20.0	350-1809-ND	2.25	1.74	1.39	570-0100-132F
	Vert	563	16.0	2.1	10.0	350-1810-ND	.69	.52	.43	551-0207F
5	Jaune	585	6.3	2.1	10.0	350-1811-ND	.69	.52	.43	551-0307F
	Rouge	650	10.0	2.0	10.0	350-1812-ND	.69	.52	.43	551-0407F
	Vert	565	8.0	5.0	12.0	350-1813-ND	.98	.75	.61	551-0607F
	Rouge	635	4.0	5.0	10.0	350-1814-ND	.98	.75	.61	551-0507F
	Jaune	583	8.0	5.0	10.0	350-1815-ND	.98	.75	.61	551-0707F
	Bleu ht rend.	428	12.0	3.5	20.0	350-1844-ND	2.41	1.88	1.52	551-0807F
	Rouge	635	1.8	1.8	2.0	350-1816-ND	.84	.65	.52	551-1107F
	Vert	565	1.6	1.8	2.0	350-1817-ND	.84	.65	.52	551-1307F
	Jaune	583	1.6	1.9	2.0	350-1818-ND	.84	.65	.52	551-1207F
	Rouge/Vert	635/565	5.0	2.0	10.0	350-1819-ND	1.19	.92	.73	551-3007F
6	Jaune/Vert	585/565	4.3/6.3	2.1/2.1	10.0	350-1820-ND	.97	.76	.60	551-3107F
	Bleu	470	1000	3.6	30.0	350-1846-ND	4.77	3.72	3.01	551-4007F
7	Blanc	—	1270	3.6	30.0	350-1847-ND	8.62	6.55	5.52	551-4107F
	Vert	525	3400	3.5	30.0	350-1848-ND	4.41	3.43	2.78	551-4207F
	Vert	563	16.0	2.1	10.0	350-1665-ND	.75	.58	.47	551-0209F
	Jaune	585	6.3	2.1	10.0	350-1667-ND	.75	.58	.47	551-0309F
	Rouge	650	10.0	2.0	10.0	350-1669-ND	.75	.58	.47	551-0409F
	Orange	600	6.5	2.2	10.0	350-1682-ND	.84	.65	.52	551-2509F
	Rouge	635	4.0	5.0	10.0	350-1671-ND	1.08	.84	.68	551-0509F
	Vert	565	8.0	5.0	12.0	350-1673-ND	1.08	.84	.68	551-0609F
	Jaune	583	8.0	5.0	10.0	350-1675-ND	1.08	.84	.68	551-0709F
	Bleu ht rend.	428	12.0	3.5	20.0	350-1845-ND	2.41	1.88	1.52	551-0809F
8	Rouge	635	1.8	1.8	2.0	350-1677-ND	.84	.65	.52	551-1109F
	Jaune	583	1.6	1.9	2.0	350-1679-ND	.84	.65	.52	551-1209F
	Vert	565	1.6	1.8	2.0	350-1681-ND	.84	.65	.52	551-1309F
	Rouge/Vert	635/565	5.0	2.0	10.0	350-1684-ND	1.36	1.05	.84	551-3009F
	Jaune/Vert	585/565	4.3/6.3	2.1	20.0	350-1685-ND	1.57	1.21	.97	551-3109F
	Vert	563	16.0	2.1	10.0	350-1664-ND	2.61	2.03	1.65	551-0207-004F
	Jaune	585	6.3	2.1	10.0	350-1666-ND	2.61	2.03	1.65	551-0307-004F
	Rouge	650	10.0	2.0	10.0	350-1668-ND	2.42	1.87	1.49	551-0407-004F
	Rouge	635	4.0	5.0	10.0	350-1670-ND	3.74	2.91	2.36	551-0507-004F
	Vert	565	8.0	5.0	12.0	350-1672-ND	3.29	2.56	2.07	551-0607-004F
8	Jaune	583	8.0	5.0	10.0	350-1674-ND	3.74	2.91	2.36	551-0707-004F
	Rouge	635	1.8	1.8	2.0	350-1676-ND	2.69	2.10	1.70	551-1107-004F
	Jaune	583	1.6	1.9	2.0	350-1678-ND	3.39	2.64	2.14	551-1207-004F
	Vert	565	1.6	1.8	2.0	350-1680-ND	3.39	2.64	2.14	551-1307-004F
	Rouge/Vert	635/565	5.0	2.0	10.0	350-1683-ND	5.74	4.37	3.68	551-3007-004F
	Rouge	650	10.0	2.0	10.0	350-1821-ND	1.36	1.05	.84	553-0111F
9	Vert	563	16.0	2.1	10.0	350-1825-ND	1.20	.93	.74	553-0122F

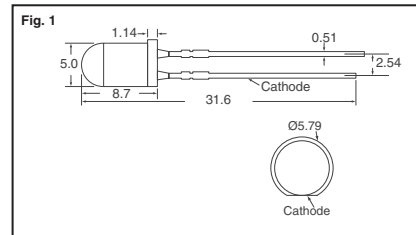

(suite)

Livraison gratuite pour les commandes de plus de 65 € ! Tous les prix sont indiqués en euros.

fr.digikey.com — Téléphone (numéro vert) : 0800-161-113 — Téléphone : +31 (0)53-484-9584 — Télécopieur : +33 (0)38-717-0111

(FR091) 2503

