

Fig.	Couleur émise	Longueur d'onde de crête (nm)	Dimensions de chiffre en pouces (mm)	Nb de chiffres	Tension directe (Typ.) (V)	Courant direct (mA)	Iv mcd (min.) (Typ.)	N° de référence Digi-Key	Prix unitaire			N° de référence Rohm	
									1	25	100		
1	Rouge	626	.31 (8.0)	1	2.05	25	36 90	511-1517-ND	2.47	1.36	1.21	LA-301AB	
	Rouge	626	.31 (8.0)	1	2.05	25	36 90	511-1518-ND	2.47	1.36	1.21	LA-301AL	
	Orange	610	.31 (8.0)	1	2.05	25	36 90	511-1519-ND	2.71	1.49	1.29	LA-301EB	
	Orange	610	.31 (8.0)	1	2.05	25	36 90	511-1520-ND	2.71	1.49	1.29	LA-301EL	
	Vert	563	.31 (8.0)	1	2.1	20	3.6 10	511-1563-ND	1.93	1.09	.97	LA-301MB	
	Vert	563	.31 (8.0)	1	2.1	20	3.6 10	511-1564-ND	1.93	1.09	.97	LA-301ML	
	Rouge	650	.31 (8.0)	1	2.0	15	3.6 10	511-1565-ND	1.43	.71	.62	LA-301VB	
	Rouge	650	.31 (8.0)	1	2.0	15	3.6 10	511-1566-ND	1.93	1.09	.97	LA-301VL	
	Jaune	589	.31 (8.0)	1	2.05	25	36 90	511-1567-ND	2.71	1.49	1.29	LA-301XB	
	Jaune	589	.31 (8.0)	1	2.05	25	36 90	511-1521-ND	2.71	1.49	1.29	LA-301XL	
	2	Rouge	626	.40 (10.16)	1	2.05	25	36 90	511-1522-ND	2.37	1.30	1.16	LA-401AD
		Rouge	626	.40 (10.16)	1	2.05	25	36 90	511-1523-ND	2.37	1.30	1.16	LA-401AN
Bleu		470	.40 (10.16)	1	3.6	10	14 56	511-1524-ND	8.68	5.61	5.16	LA-401BD	
Bleu		470	.40 (10.16)	1	3.6	10	14 56	511-1525-ND	8.68	5.61	5.16	LA-401BN	
Orange		610	.40 (10.16)	1	2.05	25	36 90	511-1526-ND	2.92	1.81	1.59	LA-401ED	
Orange		610	.40 (10.16)	1	2.05	25	36 90	511-1527-ND	2.92	1.81	1.59	LA-401EN	
Vert		563	.40 (10.16)	1	2.1	20	5.6 16	511-1528-ND	2.37	1.30	1.16	LA-401MD	
Vert		563	.40 (10.16)	1	2.1	20	5.6 16	511-1529-ND	2.37	1.30	1.16	LA-401MN	
Rouge		650	.40 (10.16)	1	2.0	15	5.6 16	511-1530-ND	2.37	1.30	1.16	LA-401VD	
Rouge		650	.40 (10.16)	1	2.0	15	5.6 16	511-1531-ND	2.37	1.30	1.16	LA-401VN	
Jaune		589	.40 (10.16)	1	2.05	25	36 90	511-1532-ND	2.92	1.81	1.59	LA-401XD	
Jaune		589	.40 (10.16)	1	2.05	25	36 90	511-1533-ND	2.92	1.81	1.59	LA-401XN	
3		Rouge	626	.57 (14.6)	1	2.05	25	36 90	511-1534-ND	2.54	1.57	1.39	LA-601AB
		Rouge	626	.57 (14.6)	1	2.05	25	36 90	511-1535-ND	2.54	1.57	1.39	LA-601AL
		Bleu	470	.57 (14.6)	1	3.6	10	14 56	511-1536-ND	8.56	5.53	5.09	LA-601BB
		Bleu	470	.57 (14.6)	1	3.6	10	14 56	511-1537-ND	9.88	7.13	6.35	LA-601BL
		Orange	610	.57 (14.6)	1	2.05	25	36 90	511-1538-ND	3.06	1.84	1.66	LA-601EB
		Orange	610	.57 (14.6)	1	2.05	25	36 90	511-1539-ND	3.06	1.84	1.66	LA-601EL
	Vert	563	.57 (14.6)	1	2.1	20	9 22	511-1540-ND	2.20	1.24	1.08	LA-601MB	
	Vert	563	.57 (14.6)	1	2.1	20	9 22	511-1541-ND	2.20	1.24	1.08	LA-601ML	
	Rouge	650	.57 (14.6)	1	2.0	20	5.6 14	511-1542-ND	2.20	1.24	1.08	LA-601VB	
	Rouge	650	.57 (14.6)	1	2.0	20	5.6 14	511-1543-ND	2.20	1.24	1.08	LA-601VL	
	Jaune	589	.57 (14.6)	1	2.05	25	36 90	511-1544-ND	2.92	1.81	1.59	LA-601XL	
	Jaune	589	.57 (14.6)	1	2.05	25	36 90	511-1571-ND	2.92	1.81	1.59	LA-601XB	
4	Vert	563	.30 (7.62)	2	2.1	20	2.2 6.3	511-1545-ND	3.77	2.27	2.05	LB-302MF	
	Vert	563	.30 (7.62)	2	2.1	20	2.2 6.3	511-1546-ND	6.54	4.41	3.89	LB-302MP	
	Rouge	650	.30 (7.62)	2	2.0	15	2.2 6.3	511-1547-ND	4.56	2.66	2.44	LB-302VF	
	Rouge	650	.30 (7.62)	2	2.0	15	2.2 6.3	511-1548-ND	5.38	3.11	2.78	LB-302VP	
5	Orange	610	.40 (10.16)	2	2.0	15	3.6 10	511-1549-ND	3.51	2.11	1.91	LB-402DN	
	Orange	610	.40 (10.16)	2	2.0	15	3.6 10	511-1550-ND	3.51	2.11	1.91	LB-402DD	
	Vert	563	.40 (10.16)	2	2.1	20	9.0 25	511-1551-ND	6.02	3.48	3.12	LB-402MD	
	Vert	563	.40 (10.16)	2	2.1	20	9.0 25	511-1552-ND	6.02	3.48	3.12	LB-402MN	
	Rouge	650	.40 (10.16)	2	2.0	15	5.6 16	511-1553-ND	6.02	3.48	3.12	LB-402VD	
	Rouge	650	.40 (10.16)	2	2.0	15	5.6 16	511-1554-ND	6.02	3.48	3.12	LB-402VN	
6	Rouge	626	.56 (14.3)	2	2.05	25	36 90	511-1555-ND	5.18	2.99	2.68	LB-602AA2	
	Rouge	626	.56 (14.3)	2	2.05	25	36 90	511-1556-ND	5.18	2.99	2.68	LB-602AK2	
	Bleu	470	.56 (14.3)	2	3.6	10	14 56	511-1557-ND	14.13	10.01	9.07	LB-602BA2	
	Bleu	470	.56 (14.3)	2	3.6	10	14 56	511-1558-ND	14.13	10.01	9.07	LB-602BK2	
	Vert	563	.56 (14.3)	2	2.1	20	9 25	511-1559-ND	3.63	2.18	1.97	LB-602MA2	
	Vert	563	.56 (14.3)	2	2.1	20	9 25	511-1560-ND	3.63	2.18	1.97	LB-602MK2	
7	Rouge	650	.56 (14.3)	2	2.0	20	5.6 16	511-1561-ND	3.77	2.27	2.05	LB-602VA2	
	Rouge	650	.56 (14.3)	2	2.0	20	5.6 16	511-1562-ND	3.63	2.18	1.97	LB-602VK2	
	Vert	563	.31 (8.0)	1	2.1	20	3.6 10	511-1568-1-ND†	2.63	1.63	1.43	LF-301MA	
	Vert	563	.31 (8.0)	1	2.1	20	3.6 10	511-1568-2-ND▲	2.63	1.63	1.43	LF-301MA	
	Rouge	650	.31 (8.0)	1	2.0	15	3.6 10	511-1569-1-ND†	2.63	1.63	1.43	LF-301VA	
	Rouge	650	.31 (8.0)	1	2.0	15	3.6 10	511-1569-2-ND▲	2.63	1.63	1.43	LF-301VA	
	Rouge	650	.31 (8.0)	1	2.0	15	3.6 10	511-1570-1-ND†	2.63	1.63	1.43	LF-301VK	
Rouge	650	.31 (8.0)	1	2.0	15	3.6 10	511-1570-2-ND▲	2.63	1.63	1.43	LF-301VK		

† Bande coupée ▲ Bande et bobine

DEL d'affichage à matrice de points

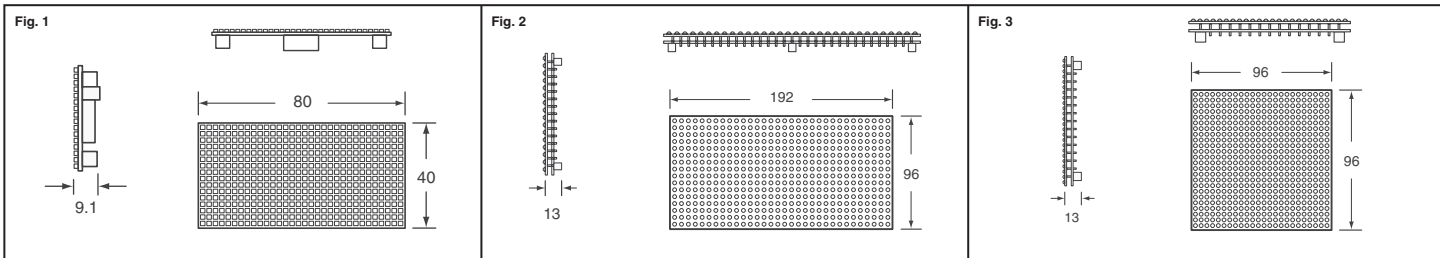


Fig	Matrice	Couleur émise	Lentille	Longueur d'onde (nm)	Tension directe (Typ.) (V)	Sortie (candelas)	Angle de visualisation	N° de référence Digi-Key	Prix unitaire			N° de référence Rohm
									1	25	100	
1	16x32	Rouge/Vert	Dôme	630/570	5	100/200	160°	511-1572-ND	250.92	207.79	196.03	LUM-512CMU300
2	16x32	Rouge/Vert	Dôme	624/571	5	250/200	140°	511-1574-ND	144.65	120.54	111.78	LPM-5123MU350
3	24x24	Rouge/Vert	Dôme	624/571	5	300/300	140°	511-1575-ND	144.65	120.54	111.78	LPM-5763MU301



Livraison gratuite pour les commandes de plus de 65 € ! Tous les prix sont indiqués en euros.