


**Serie CSM-7, SMD, a profilo ribassato**

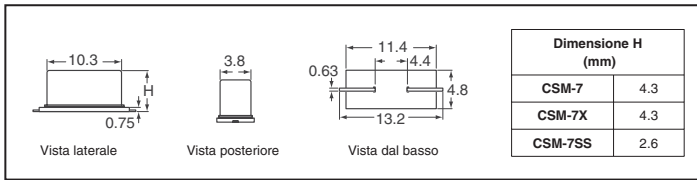

Frequenza (MHz)	Cap. carico	N. di articolo Digi-Key	Prezzo unitario su nastro pre-tagliato			Prezzi Nastrati in bobina† 1.000	N. di articolo ECS
			1	10	100		
<b>CSM-7X-EN a intervallo di temperatura industriale: -40° ~ 85° C — A norma RoHS</b>							
3.579545	18pF	XC1677CT-ND	.46	.42	.34	276.28	ECS-35-18-5PXEN-TR
3.686400	18pF	XC1678CT-ND	.46	.42	.34	276.28	ECS-36-18-5PXEN-TR
4.000000	18pF	XC1679CT-ND	.46	.42	.34	276.28	ECS-40-18-5PXEN-TR
4.096000	18pF	XC1680CT-ND	.46	.42	.34	276.28	ECS-41-18-5PXEN-TR
4.194304	18pF	XC1681CT-ND	.46	.42	.34	276.28	ECS-42-18-5PXEN-TR
4.915200	18pF	XC1682CT-ND	.46	.42	.34	276.28	ECS-49-18-5PXEN-TR
5.000000	18pF	XC1683CT-ND	.46	.42	.34	276.28	ECS-50-18-5PXEN-TR
5.068800	18pF	XC1684CT-ND	.46	.42	.34	276.28	ECS-51-18-5PXEN-TR
6.000000	18pF	XC1685CT-ND	.46	.42	.34	276.28	ECS-60-18-5PXEN-TR
6.144000	18pF	XC1686CT-ND	.46	.42	.34	276.28	ECS-61-18-5PXEN-TR
7.372800	18pF	XC1687CT-ND	.46	.42	.34	276.28	ECS-73-18-5PXEN-TR
7.680000	18pF	XC1688CT-ND	.46	.42	.34	276.28	ECS-76.8-18-5PXEN-TR
9.830400	18pF	XC1689CT-ND	.46	.42	.34	276.28	ECS-98.3-18-5PXEN-TR
11.000000	18pF	XC1690CT-ND	.46	.42	.34	276.28	ECS-110-18-5PXEN-TR
11.059200	18pF	XC1691CT-ND	.46	.42	.34	276.28	ECS-110.5-18-5PXEN-TR
12.288000	18pF	XC1692CT-ND	.46	.42	.34	276.28	ECS-122.8-18-5PXEN-TR
13.516800	18pF	XC1706CT-ND	.46	.42	.34	276.28	ECS-135-18-5PXEN-TR
14.318180	18pF	XC1693CT-ND	.46	.42	.34	276.28	ECS-143-18-5PXEN-TR
14.745600	18pF	XC1694CT-ND	.46	.42	.34	276.28	ECS-147.4-18-5PXEN-TR
16.000000	18pF	XC1695CT-ND	.46	.42	.34	276.28	ECS-160-18-5PXEN-TR
16.000312	18pF	XC1696CT-ND	.46	.42	.34	276.28	ECS-160.003-18-5PXEN-TR
16.257000	18pF	XC1697CT-ND	.46	.42	.34	276.28	ECS-162.57-18-5PXEN-TR
16.384000	18pF	XC1698CT-ND	.46	.42	.34	276.28	ECS-163-18-5PXEN-TR
19.660800	18pF	XC1699CT-ND	.46	.42	.34	276.28	ECS-196.6-18-5PXEN-TR
20.000000	18pF	XC1700CT-ND	.46	.42	.34	276.28	ECS-200-18-5PXEN-TR
22.118400	18pF	XC1701CT-ND	.46	.42	.34	276.28	ECS-221-18-5PXEN-TR
24.000000	18pF	XC1702CT-ND	.46	.42	.34	276.28	ECS-240-18-5PXEN-TR
24.576000	18pF	XC1703CT-ND	.46	.42	.34	276.28	ECS-245.7-18-5PXEN-TR
25.175000	18pF	XC1704CT-ND	.46	.42	.34	276.28	ECS-251.75-18-5PXEN-TR
28.636360	18pF	XC1705CT-ND	.46	.42	.34	276.28	ECS-286.3-18-5PXEN-TR
<b>CSM-7-DN a intervallo di temperature industriali: -40° C ~ 85° C — A norma RoHS</b>							
3.579545	17pF	XC730CT-ND	.84	.71	.57	421.62	ECS-35-17-5PDN-TR
3.686400	20pF	XC731CT-ND	.84	.71	.57	421.62	ECS-36-20-5PDN-TR
4.000000	20pF	XC732CT-ND	.84	.71	.57	421.62	ECS-40-20-5PDN-TR
6.000000	32pF	XC733CT-ND	.84	.71	.57	421.62	ECS-60-32-5PDN-TR
7.372800	20pF	XC734CT-ND	.84	.71	.57	421.62	ECS-73-20-5PDN-TR
8.000000	18pF	XC735CT-ND	.84	.71	.57	421.62	ECS-80-18-5PDN-TR
12.000000	20pF	XC736CT-ND	.84	.71	.57	421.62	ECS-120-20-5PDN-TR
14.318180	20pF	XC737CT-ND	.84	.71	.57	421.62	ECS-143-20-5PDN-TR
16.000000	20pF	XC738CT-ND	.84	.71	.57	421.62	ECS-160-20-5PDN-TR
18.432000	20pF	XC739CT-ND	.84	.71	.57	421.62	ECS-184-20-5PDN-TR
19.660800	20pF	XC740CT-ND	.84	.71	.57	421.62	ECS-196-20-5PDN-TR
20.000000	20pF	XC741CT-ND	.84	.71	.57	421.62	ECS-200-20-5PDN-TR
24.000000	20pF	XC742CT-ND	.84	.71	.57	421.62	ECS-240-20-5PDN-TR
<b>CSM-7X-DN a intervallo di temperature industriali: -40° C ~ 85° C — A norma RoHS</b>							
3.579545	17pF	XC1292CT-ND	.84	.71	.57	422.02	ECS-35-17-5PXDN-TR
3.686400	20pF	XC1293CT-ND	.84	.71	.57	422.02	ECS-36-20-5PXDN-TR
4.000000	20pF	XC1294CT-ND	.84	.71	.57	422.02	ECS-40-20-5PXDN-TR
6.000000	32pF	XC1295CT-ND	.84	.71	.57	422.02	ECS-60-32-5PXDN-TR
7.372800	20pF	XC1296CT-ND	.84	.71	.57	422.02	ECS-73-20-5PXDN-TR
8.000000	18pF	XC1297CT-ND	.84	.71	.57	422.02	ECS-80-18-5PXDN-TR
12.000000	20pF	XC1298CT-ND	.84	.71	.57	422.02	ECS-120-20-5PXDN-TR
16.000000	20pF	XC1299CT-ND	.84	.71	.57	422.02	ECS-160-20-5PXDN-TR
18.432000	20pF	XC1300CT-ND	.84	.71	.57	422.02	ECS-184-20-5PXDN-TR
19.660800	20pF	XC1301CT-ND	.84	.71	.57	422.02	ECS-196-20-5PXDN-TR
20.000000	20pF	XC1302CT-ND	.84	.71	.57	422.02	ECS-200-20-5PXDN-TR
24.000000	20pF	XC1303CT-ND	.84	.71	.57	422.02	ECS-240-20-5PXDN-TR
<b>CSM-7X-DU a intervallo di temperature industriali: -55° C ~ 125° C — A norma RoHS</b>							
3.579545	18pF	XC1522CT-ND	.94	.85	.71	468.47	ECS-35-18-5PXDU-TR
3.686400	20pF	XC1523CT-ND	.94	.85	.71	468.47	ECS-36-20-5PXDU-TR
4.000000	20pF	XC1524CT-ND	.94	.85	.71	468.47	ECS-40-20-5PXDU-TR
6.000000	20pF	XC1525CT-ND	.94	.85	.71	468.47	ECS-60-20-5PXDU-TR
8.000000	20pF	XC1526CT-ND	.94	.85	.71	468.47	ECS-80-20-5PXDU-TR
9.830400	20pF	XC1527CT-ND	.94	.85	.71	468.47	ECS-98.3-20-5PXDU-TR
10.000000	20pF	XC1528CT-ND	.94	.85	.71	468.47	ECS-100-20-5PXDU-TR
11.059200	20pF	XC1529CT-ND	.94	.85	.71	468.47	ECS-110.5-20-5PXDU-TR
12.000000	18pF	XC1530CT-ND	.94	.85	.71	468.47	ECS-120-18-5PXDU-TR
12.000000	32pF	XC1531CT-ND	.94	.85	.71	468.47	ECS-120-32-5PXDU-TR
12.288000	20pF	XC1532CT-ND	.94	.85	.71	468.47	ECS-122.8-20-5PXDU-TR
14.318180	20pF	XC1533CT-ND	.94	.85	.71	468.47	ECS-143-20-5PXDU-TR
14.745600	20pF	XC1534CT-ND	.94	.85	.71	468.47	ECS-147.4-20-5PXDU-TR
16.000000	20pF	XC1535CT-ND	.94	.85	.71	468.47	ECS-160-20-5PXDU-TR
18.432000	20pF	XC1536CT-ND	.94	.85	.71	468.47	ECS-184-20-5PXDU-TR
20.000000	20pF	XC1537CT-ND	.94	.85	.71	468.47	ECS-200-20-5PXDU-TR
24.000000	20pF	XC1538CT-ND	.94	.85	.71	468.47	ECS-240-20-5PXDU-TR
24.576000	20pF	XC1539CT-ND	.94	.85	.71	468.47	ECS-245.7-20-5PXDU-TR
25.000000	20pF	XC1540CT-ND	.94	.85	.71	468.47	ECS-250-20-5PXDU-F-TR
27.000000	20pF	XC1541CT-ND	.94	.85	.71	468.47	ECS-270-20-5PXDU-F-TR
<b>CSM-7, -10° C ~ 70° C</b>							
3.579545	SERIE	XC663CT-ND	.58	.49	.39	324.32	ECS-35-S-5P-TR
3.579545	17pF	XC560CT-ND	.58	.49	.39	324.32	ECS-35-17-5P-TR

Frequenza (MHz)	Cap. carico	N. di articolo Digi-Key	Prezzo unitario su nastro pre-tagliato			Prezzi Nastrati in bobina† 1.000	N. di articolo ECS
			1	10	100		
3.686400	SERIE	XC561CT-ND	.58	.49	.39	324.32	ECS-36-S-5P-TR
3.686400	20pF	XC562CT-ND	.58	.49	.39	324.32	ECS-36-20-5P-TR
4.000000	SERIE	XC563CT-ND	.58	.49	.39	324.32	ECS-40-S-5P-TR
4.000000	20pF	XC564CT-ND	.58	.49	.39	324.32	ECS-40-20-5P-TR
4.032000	SERIE	XC665CT-ND	.58	.49	.39	324.32	ECS-40.3-S-5P-TR
4.032000	20pF	XC664CT-ND	.58	.49	.39	324.32	ECS-40.3-20-5P-TR
4.096000	20pF	XC666CT-ND	.58	.49	.39	324.32	ECS-41-20-5P-TR
4.194304	12pF	XC667CT-ND	.58	.49	.39	324.32	ECS-42-12-5P-TR
4.194304	16pF	XC668CT-ND	.58	.49	.39	324.32	ECS-42-16-5P-TR
4.433618	20pF	XC669CT-ND	.58	.49	.39	324.32	ECS-44-20-5P-TR
4.915200	SERIE	XC565CT-ND	.58	.49	.39	324.32	ECS-49-S-5P-TR
4.915200	20pF	XC566CT-ND	.58	.49	.39	324.32	ECS-49-20-5P-TR
5.000000	SERIE	XC670CT-ND	.58	.49	.39	324.32	ECS-50-S-5P-TR
5.000000	20pF	XC671CT-ND	.58	.49	.39	324.32	ECS-50-20-5P-TR
5.068800	SERIE	XC672CT-ND	.58	.49	.39	324.32	ECS-51-S-5P-TR
5.068800	20pF	XC673CT-ND	.58	.49	.39	324.32	ECS-51-20-5P-TR
5.185000	SERIE	XC674CT-ND	.58	.49	.39	324.32	ECS-52-S-5P-TR
5.185000	32pF	XC675CT-ND	.58	.49	.39	324.32	ECS-52-32-5P-TR
5.990400	SERIE	XC676CT-ND	.58	.49	.39	324.32	ECS-59-S-5P-TR
5.990400	20pF	XC677CT-ND	.58	.49	.39	324.32	ECS-59.9-20-5P-TR
6.000000	SERIE	XC678CT-ND	.58	.49	.39	324.32	ECS-60-S-5P-TR
6.000000	32pF	XC679CT-ND	.58	.49	.39	324.32	ECS-60-32-5P-TR
6.144000	32pF	XC567CT-ND	.58	.49	.39	324.32	ECS-61-32-5P-TR
7.372800	SERIE	XC568CT-ND	.58	.49	.39	324.32	ECS-73-S-5P-TR
7.372800	20pF	XC680CT-ND	.58	.49	.39	324.32	ECS-73-20-5P-TR
8.000000	SERIE	XC569CT-ND	.58	.49	.39	324.32	ECS-80-S-5P-TR
8.000000	18pF	XC681CT-ND	.58	.49	.39	324.32	ECS-80-18-5P-TR
8.000000	32pF	XC682CT-ND	.58	.49	.39	324.32	ECS-80-32-5P-TR
9.216000	SERIE	XC683CT-ND	.58	.49	.39	324.32	ECS-92-1-S-5P-TR
9.216000	20pF	XC684CT-ND	.58	.49	.39	324.32	ECS-92-1-20-5P-TR
9.830400	SERIE	XC570CT-ND	.58	.49	.39	324.32	ECS-98.3-S-5P-TR
9.830400	20pF	XC571CT-ND	.58	.49	.39	324.32	ECS-98.3-20-5P-TR
10.000000	SERIE	XC572CT-ND	.58	.49	.39	324.32	ECS-100-S-5P-TR
10.000000	18pF	XC716CT-ND	.58	.49	.39	324.32	ECS-100-18-5P-TR
11.000000	SERIE	XC685CT-ND	.58	.49	.39	324.32	ECS-110-S-5P-TR
11.059200	SERIE	XC573CT-ND	.58	.49	.39	324.32	ECS-110.5-S-5P-TR
11.059200	20						