


CSM-7 系列 SMD 小尺寸

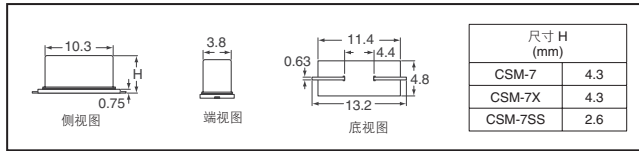

频率 (MHz)	负载电容	Digi-Key 零件编号	1	10	100	带卷† 价格 1,000	ECS 零件编号
CSM-7-DN 工业温度范围, -40°C - 85°C							
3.579545	17pF	XC730CT-ND	1.62	1.36	1.09	810.81	ECS-35-17-5PDN-TR
3.686400	20pF	XC731CT-ND	1.62	1.36	1.09	810.81	ECS-36-20-5PDN-TR
4.000000	20pF	XC732CT-ND	1.62	1.36	1.09	810.81	ECS-40-20-5PDN-TR
6.000000	32pF	XC733CT-ND	1.62	1.36	1.09	810.81	ECS-60-32-5PDN-TR
7.372800	20pF	XC734CT-ND	1.62	1.36	1.09	810.81	ECS-73-20-5PDN-TR
8.000000	18pF	XC735CT-ND	1.62	1.36	1.09	810.81	ECS-80-18-5PDN-TR
12.000000	20pF	XC736CT-ND	1.62	1.36	1.09	810.81	ECS-120-20-5PDN-TR
14.318180	20pF	XC737CT-ND	1.62	1.36	1.09	810.81	ECS-143-20-5PDN-TR
16.000000	20pF	XC738CT-ND	1.62	1.36	1.09	810.81	ECS-160-20-5PDN-TR
18.432000	20pF	XC739CT-ND	1.62	1.36	1.09	810.81	ECS-184-20-5PDN-TR
19.660800	20pF	XC740CT-ND	1.62	1.36	1.09	810.81	ECS-196-20-5PDN-TR
20.000000	20pF	XC741CT-ND	1.62	1.36	1.09	810.81	ECS-200-20-5PDN-TR
24.000000	20pF	XC742CT-ND	1.62	1.36	1.09	810.81	ECS-240-20-5PDN-TR
CSM-7X-DN 工业温度范围, -40°C - 85°C - 符合 RoHS 规范要求							
3.579545	17pF	XC1292CT-ND	1.62	1.36	1.09	811.58	ECS-35-17-5PXDN-TR
3.686400	20pF	XC1293CT-ND	1.62	1.36	1.09	811.58	ECS-36-20-5PXDN-TR
4.000000	20pF	XC1294CT-ND	1.62	1.36	1.09	811.58	ECS-40-20-5PXDN-TR
6.000000	32pF	XC1295CT-ND	1.62	1.36	1.09	811.58	ECS-60-32-5PXDN-TR
7.372800	20pF	XC1296CT-ND	1.62	1.36	1.09	811.58	ECS-73-20-5PXDN-TR
8.000000	18pF	XC1297CT-ND	1.62	1.36	1.09	811.58	ECS-80-18-5PXDN-TR
12.000000	20pF	XC1298CT-ND	1.62	1.36	1.09	811.58	ECS-120-20-5PXDN-TR
16.000000	20pF	XC1299CT-ND	1.62	1.36	1.09	811.58	ECS-160-20-5PXDN-TR
18.432000	20pF	XC1300CT-ND	1.62	1.36	1.09	811.58	ECS-184-20-5PXDN-TR
19.660800	20pF	XC1301CT-ND	1.62	1.36	1.09	811.58	ECS-196-20-5PXDN-TR
20.000000	20pF	XC1302CT-ND	1.62	1.36	1.09	811.58	ECS-200-20-5PXDN-TR
24.000000	20pF	XC1303CT-ND	1.62	1.36	1.09	811.58	ECS-240-20-5PXDN-TR
CSM-7X-DU 自动温度, -55°C - 125°C - 符合 RoHS 规范要求							
3.579545	18pF	XC1522CT-ND	1.80	1.63	1.36	900.90	ECS-35-18-5PXDU-TR
3.686400	20pF	XC1523CT-ND	1.80	1.63	1.36	900.90	ECS-36-20-5PXDU-TR
4.000000	20pF	XC1524CT-ND	1.80	1.63	1.36	900.90	ECS-40-20-5PXDU-TR
6.000000	20pF	XC1525CT-ND	1.80	1.63	1.36	900.90	ECS-60-20-5PXDU-TR
8.000000	20pF	XC1526CT-ND	1.80	1.63	1.36	900.90	ECS-80-20-5PXDU-TR
9.830400	20pF	XC1527CT-ND	1.80	1.63	1.36	900.90	ECS-98.3-20-5PXDU-TR
10.000000	20pF	XC1528CT-ND	1.80	1.63	1.36	900.90	ECS-100-20-5PXDU-TR
11.059200	20pF	XC1529CT-ND	1.80	1.63	1.36	900.90	ECS-110.5-20-5PXDU-TR
12.000000	18pF	XC1530CT-ND	1.80	1.63	1.36	900.90	ECS-120-18-5PXDU-TR
12.000000	32pF	XC1531CT-ND	1.80	1.63	1.36	900.90	ECS-120-32-5PXDU-TR
12.288000	20pF	XC1532CT-ND	1.80	1.63	1.36	900.90	ECS-122.8-20-5PXDU-TR
14.318180	20pF	XC1533CT-ND	1.80	1.63	1.36	900.90	ECS-143-20-5PXDU-TR
14.745600	20pF	XC1534CT-ND	1.80	1.63	1.36	900.90	ECS-147.4-20-5PXDU-TR
16.000000	20pF	XC1535CT-ND	1.80	1.63	1.36	900.90	ECS-160-20-5PXDU-TR
18.432000	20pF	XC1536CT-ND	1.80	1.63	1.36	900.90	ECS-184-20-5PXDU-TR
20.000000	20pF	XC1537CT-ND	1.80	1.63	1.36	900.90	ECS-200-20-5PXDU-TR
24.000000	20pF	XC1538CT-ND	1.80	1.63	1.36	900.90	ECS-240-20-5PXDU-TR
24.576000	20pF	XC1539CT-ND	1.80	1.63	1.36	900.90	ECS-245.7-20-5PXDU-TR
25.000000	20pF	XC1540CT-ND	1.80	1.63	1.36	900.90	ECS-250-20-5PXDU-F-TR
27.000000	20pF	XC1541CT-ND	1.80	1.63	1.36	900.90	ECS-270-20-5PXDU-F-TR
CSM-7, -10°C - 70°C							
3.579545	系列	XC663CT-ND	1.12	.94	.75	623.70	ECS-35-S-5P-TR
3.579545	17pF	XC560CT-ND	1.12	.94	.75	623.70	ECS-35-17-S-5P-TR
3.686400	系列	XC561CT-ND	1.12	.94	.75	623.70	ECS-36-S-5P-TR
3.686400	20pF	XC562CT-ND	1.12	.94	.75	623.70	ECS-36-20-S-5P-TR
4.000000	系列	XC563CT-ND	1.12	.94	.75	623.70	ECS-40-S-5P-TR
4.000000	20pF	XC564CT-ND	1.12	.94	.75	623.70	ECS-40-20-S-5P-TR
4.032000	系列	XC665CT-ND	1.12	.94	.75	623.70	ECS-40.3-S-5P-TR
4.032000	20pF	XC664CT-ND	1.12	.94	.75	623.70	ECS-40.3-20-S-5P-TR
4.096000	20pF	XC666CT-ND	1.12	.94	.75	623.70	ECS-41-20-S-5P-TR
4.194304	12pF	XC667CT-ND	1.12	.94	.75	623.70	ECS-42-12-S-5P-TR
4.194304	16pF	XC668CT-ND	1.12	.94	.75	623.70	ECS-42-16-S-5P-TR
4.433618	20pF	XC669CT-ND	1.12	.94	.75	623.70	ECS-44-20-S-5P-TR
4.915200	系列	XC565CT-ND	1.12	.94	.75	623.70	ECS-49-S-5P-TR
4.915200	20pF	XC566CT-ND	1.12	.94	.75	623.70	ECS-49-20-S-5P-TR
5.000000	系列	XC670CT-ND	1.12	.94	.75	623.70	ECS-50-S-5P-TR
5.000000	20pF	XC671CT-ND	1.12	.94	.75	623.70	ECS-50-20-S-5P-TR
5.068800	系列	XC672CT-ND	1.12	.94	.75	623.70	ECS-51-S-5P-TR
5.068800	20pF	XC673CT-ND	1.12	.94	.75	623.70	ECS-51-20-S-5P-TR
5.185000	系列	XC674CT-ND	1.12	.94	.75	623.70	ECS-52-S-5P-TR
5.185000	32pF	XC675CT-ND	1.12	.94	.75	623.70	ECS-52-32-S-5P-TR

频率 (MHz)	负载电容	Digi-Key 零件编号	1	10	100	带卷† 价格 1,000	ECS 零件编号
5.990400	系列	XC676CT-ND	1.12	.94	.75	623.70	ECS-59-S-5P-TR
5.990400	20pF	XC677CT-ND	1.12	.94	.75	623.70	ECS-59.9-20-S-5P-TR
6.000000	系列	XC678CT-ND	1.12	.94	.75	623.70	ECS-60-S-5P-TR
6.000000	32pF	XC679CT-ND	1.12	.94	.75	623.70	ECS-60-32-S-5P-TR
6.144000	32pF	XC567CT-ND	1.12	.94	.75	623.70	ECS-61-32-S-5P-TR
7.372800	系列	XC568CT-ND	1.12	.94	.75	623.70	ECS-73-S-5P-TR
7.372800	20pF	XC680CT-ND	1.12	.94	.75	623.70	ECS-73-20-S-5P-TR
8.000000	系列	XC569CT-ND	1.12	.94	.75	623.70	ECS-80-S-5P-TR
8.000000	18pF	XC681CT-ND	1.12	.94	.75	623.70	ECS-80-18-S-5P-TR
8.000000	32pF	XC682CT-ND	1.12	.94	.75	623.70	ECS-80-32-S-5P-TR
9.216000	系列	XC683CT-ND	1.12	.94	.75	623.70	ECS-92.1-S-5P-TR
9.216000	20pF	XC684CT-ND	1.12	.94	.75	623.70	ECS-92.1-20-S-5P-TR
9.830400	系列	XC570CT-ND	1.12	.94	.75	623.70	ECS-98.3-S-5P-TR
9.830400	20pF	XC571CT-ND	1.12	.94	.75	623.70	ECS-98.3-20-S-5P-TR
10.000000	系列	XC572CT-ND	1.12	.94	.75	623.70	ECS-100-S-5P-TR
10.000000	18pF	XC716CT-ND	1.12	.94	.75	623.70	ECS-100-18-S-5P-TR
11.000000	系列	XC685CT-ND	1.12	.94	.75	623.70	ECS-110-S-5P-TR
11.059200	系列	XC573CT-ND	1.12	.94	.75	623.70	ECS-110.5-S-5P-TR
11.059200	20pF	XC574CT-ND	1.12	.94	.75	623.70	ECS-110.5-20-S-5P-TR
11.059200	32pF	XC686CT-ND	1.12	.94	.75	623.70	ECS-110.5-32-S-5P-TR
12.000000	系列	XC575CT-ND	1.12	.94	.75	623.70	ECS-120-S-5P-TR
12.000000	18pF	XC717CT-ND	1.12	.94	.75	623.70	ECS-120-18-S-5P-TR
12.000000	32pF	XC687CT-ND	1.12	.94	.75	623.70	ECS-120-32-S-5P-TR
12.000393	18pF	XC688CT-ND	1.12	.94	.75	623.70	ECS-120.003-18-S-5P-TR
12.288000	系列	XC689CT-ND	1.12	.94	.75	623.70	ECS-122.8-S-5P-TR
12.288000	20pF	XC690CT-ND	1.12	.94	.75	623.70	ECS-122.8-20-S-5P-TR
14.318180	系列	XC576CT-ND	1.12	.94	.75	623.70	ECS-143-S-5P-TR
14.318180	20pF	XC718CT-ND	1.12	.94	.75	623.70	ECS-143-20-S-5P-TR
14.745600	系列	XC691CT-ND	1.12	.94	.75	623.70	ECS-147.4-S-5P-TR
14.745600	20pF	XC692CT-ND	1.12	.94	.75	623.70	ECS-147.4-20-S-5P-TR
15.000000	系列	XC693CT-ND	1.12	.94	.75	623.70	ECS-150-S-5P-TR
16.000000	系列	XC577CT-ND	1.12	.94	.75	623.70	ECS-160-S-5P-TR
16.000000	20pF	XC694CT-ND	1.12	.94	.75	623.70	ECS-160-20-S-5P-TR
16.000312	18pF	XC695CT-ND	1.12	.94	.75	623.70	ECS-160.003-18-S-5P-TR
16.257000	系列	XC697CT-ND	1.12	.94	.75	623.70	ECS-162.5-S-5P-TR
16.257000	20pF	XC696CT-ND	1.12	.94	.75	623.70	ECS-162.5-20-S-5P-TR
18.000000	系列	XC698CT-ND	1.12	.94	.75	623.70	ECS-180-S-5P-TR
18.432000	系列	XC578CT-ND	1.12	.94	.75	623.70	ECS-184-S-5P-TR
18.432000	18pF	XC699CT-ND	1.12	.94	.75	623.70	ECS-184-18-S-5P-TR
18.432000	20pF	XC700CT-ND	1.12	.94	.75	623.70	ECS-184-20-S-5P-TR
19.660800	系列	XC579CT-ND	1.12	.94	.75	623.70	ECS-196.5-S-5P-TR
19.660800	20pF	XC701CT-ND	1.12	.94	.75	623.70	ECS-196.6-20-S-5P-TR
20.000000	系列	XC580CT-ND	1.12	.94	.75	623.70	ECS-200-S-5P-TR
20.000000	16pF	XC719CT-ND	1.12	.94	.75	623.70	ECS-200-16-S-5P-TR
20.000000	20pF	XC581CT-ND	1.12	.94	.75	623.70	ECS-200-20-S-5P-TR
20.480000	20pF	XC743CT-ND	1.12	.94	.75	623.70	ECS-204.8-20-S-5P-TR
24.000000	16pF	XC583CT-ND	1.12	.94	.75	623.70	ECS-240-16-S-5P-TR
24.000000							