



WE-FI 系列 - 带引线螺旋管线路扼流圈




特点:

- 存储容量高 • 低损耗的铁粉芯 • 低磁泄漏场

应用:

- 在变压器和电源中的应用 • 适用于干扰频率高达 10MHz • 极其适合于过滤对干扰抗

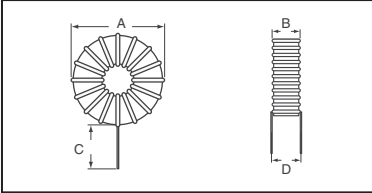

电感 (μH)	最大 DCR 值 (Ω)	额定电流 (A)	尺寸 - mm				Digi-Key 零件编号	单价			Würth 零件编号
			A	B	C	D		1	25	100	
10.0	0.020	2.00	10.5	5.5	15.0	5.0	732-1416-ND	4.13	3.45	3.06	7447054
12.0	0.030	1.00	10.0	5.0	15.0	4.0	732-1417-ND	4.13	3.45	3.06	7447053
22.0	0.015	5.00	19.0	10.5	15.0	8.0	732-1418-ND	4.68	3.91	3.46	7447017
29.0	0.015	5.00	18.5	9.7	15.0	8.0	732-1419-ND	4.68	3.91	3.46	7447016
35.0	0.025	3.00	18.5	8.5	15.0	8.0	732-1420-ND	4.68	3.91	3.46	7447015
43.0	0.060	1.00	13.0	6.5	15.0	4.5	732-1421-ND	4.20	3.51	3.11	7447034
68.0	0.100	0.80	12.0	5.5	15.0	4.5	732-1422-ND	—	—	—	7447041
68.0	0.055	2.00	14.0	7.0	15.0	6.0	732-1423-ND	4.20	3.51	3.11	7447033
100.0	0.070	2.00	15.5	8.0	15.0	7.0	732-1424-ND	4.20	3.51	3.11	7447021
100.0	0.035	5.00	25.0	11.0	15.0	8.0	732-1425-ND	5.10	4.25	3.77	7447070
150.0	0.130	1.00	16.0	8.0	20.0	7.0	732-1426-ND	4.20	3.51	3.11	7447028
150.0	0.045	5.00	27.5	13.0	15.0	11.5	732-1427-ND	6.07	5.06	4.48	7447076
220.0	0.220	0.80	14.0	7.5	15.0	6.0	732-1428-ND	4.20	3.51	3.11	7447036
220.0	0.160	1.00	15.8	7.5	15.0	7.0	732-1429-ND	4.20	3.51	3.11	7447020
300.0	0.130	2.00	21.0	11.0	25.0	9.0	732-1430-ND	5.10	4.25	3.77	7447060
360.0	0.400	0.40	13.5	6.0	15.0	5.0	732-1431-ND	—	—	—	7447037
470.0	0.225	1.00	18.5	9.5	15.0	9.0	732-1432-ND	4.20	3.51	3.11	7447010
470.0	0.110	3.00	25.0	12.0	25.0	11.0	732-1433-ND	5.10	4.25	3.77	7447071
860.0	0.150	3.00	28.5	15.0	25.0	14.0	732-1434-ND	6.07	5.06	4.48	7447075

WE-CMB 系列 - 电流补偿扼流圈




特点:

- 您可以使用此产品抑制不对称干扰, 即使在低频范围内也可实现 • 采用低电容绕线技术, 可抑制宽带干扰 • 极其紧凑的设计 • 小尺寸中最佳的电流特性

应用:

- 功率电子产品 • 电源线输入输出滤波器 • 用于不稳定接地设备的滤波 • 电机中的无线电干扰抑制

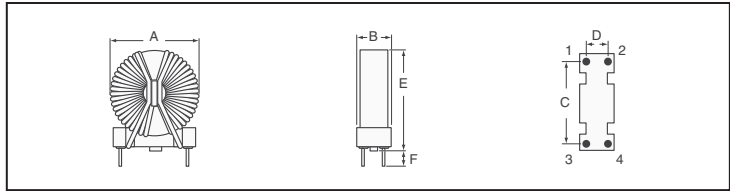

电感 (mH)	最大 DCR 值 (mΩ)	额定电流 (A)	尺寸 - mm						Digi-Key 零件编号	单价			Würth 零件编号
			A	B	C	D	E	F		1	25	100	
XS 型													
1.0	45	2.0							732-1435-ND	6.88	5.75	5.09	744821201
4.0	140	1.5	15.0	7.5	10.0	4.5	18.0	2.5	732-1436-ND	6.88	5.75	5.09	744821240
10.0	350	0.7							732-1437-ND	6.88	5.75	5.09	744821110
20.0	1000	0.5							732-1438-ND	6.88	5.75	5.09	744821120
14	15	4.0							732-1459-ND	6.88	5.75	5.09	744841414
30	26	3.0	16.0	7.5	10.0	4.5	17.5	—	732-1460-ND	6.88	5.75	5.09	744841330
47	40	2.0							732-1461-ND	6.88	5.75	5.09	744841247
100	80	1.5							732-1462-ND	6.88	5.75	5.09	744841210
S 型													
1.0	35	3.0							732-1439-ND	8.27	6.89	6.11	744822301
2.2	70	2.0							732-1440-ND	8.27	6.89	6.11	744822222
3.3	120	1.5	17.5	13.0	7.7	5.0	22.0	3.0	732-1441-ND	8.27	6.89	6.11	744822233
10.0	360	1.0							732-1442-ND	8.27	6.89	6.11	744822110
20.0	540	0.5							732-1443-ND	8.27	6.89	6.11	744822120
M 型													
1.0	10	6.0							732-1444-ND	10.33	8.62	7.63	744823601
2.2	30	4.0							732-1445-ND	10.33	8.62	7.63	744823422
3.3	60	2.5	23.0	17.0	7.5	10.7	28.0	3.0	732-1446-ND	10.33	8.62	7.63	744823333
10.0	125	2.0							732-1447-ND	10.33	8.62	7.63	744823210
20.0	270	1.5							732-1448-ND	10.33	8.62	7.63	744823220
L 型													
1.0	7	10.0							732-1449-ND	11.70	9.76	8.65	744824101
2.2	20	6.0							732-1450-ND	11.70	9.76	8.65	744824622
3.3	35	4.0	27.5	18.5	10.0	12.0	33.0	5.0	732-1451-ND	11.70	9.76	8.65	744824433
10.0	105	3.0							732-1452-ND	11.70	9.76	8.65	744824310
20.0	220	2.0							732-1453-ND	11.70	9.76	8.65	744824220
XL 型													
1.0	9	12.0							732-1454-ND	19.28	16.08	14.24	7448251201
2.2	14	8.0							732-1455-ND	19.28	16.08	14.24	7448258022
3.3	25	6.0	30.0	21.0	25.0	15.0	35.0	5.0	732-1463-ND	19.28	16.08	14.24	7448256033
10.0	55	5.0							732-1457-ND	19.28	16.08	14.24	744825510
20.0	160	3.0							732-1458-ND	19.28	16.08	14.24	744825320

WE-CNSW 系列 - SMD 共模噪音抑制器




特点:

- 高频率下的高共模抑制 • 工作温度: -40°C ~ 125°C • 推荐的焊接方法: 回流

应用:

- USB 2.0 • 火线/IEEE 1394 • LVDS • 高速数据线 • 共模滤波器

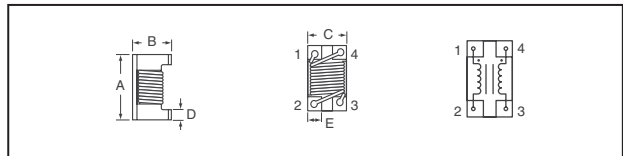

100MHz 时的阻抗 (Ω)	最大 DCR 值 (Ω)	额定电流 (A)	尺寸 - mm					Digi-Key 零件编号			带卷价格 2,000	Würth 零件编号			
			A	B	C	D	E	1	25	100					
0805 型															
67	0.25	0.4							732-1464-1-ND	1.72	1.44	1.22	732-1464-2-ND	574.42/M	744231061
120	0.30	0.37							732-1465-1-ND	1.72	1.44	1.22	732-1465-2-ND	574.42/M	744231121
180	0.35	0.33	2.0	1.2	1.2	0.45	0.4		732-1466-1-ND	1.72	1.44	1.22	732-1466-2-ND	574.42/M	744231181
260	0.40	0.3							732-1467-1-ND	1.72	1.44	1.22	732-1467-2-ND	574.42/M	744231261
370	0.45	0.28							732-1468-1-ND	1.72	1.44	1.22	732-1468-2-ND	574.42/M	744231371
1206 Bauform 型															
90	0.30	0.37							732-1469-1-ND	2.66	2.22	1.89	732-1469-2-ND	885.50/M	744232090
160	0.40	0.34							732-1470-1-ND	2.66	2.22	1.89	732-1470-2-ND	885.50/M	744232161
260	0.50	0.31	3.2	1.9	1.6	0.6	0.6		732-1471-1-ND	2.66	2.22	1.89	732-1471-2-ND	885.50/M	744232261
600	0.80	0.26							732-1472-1-ND	2.66	2.22	1.89	732-1472-2-ND	885.50/M	744232601
1000	1.00	0.23							732-1473-1-ND	2.66	2.22	1.89	732-1473-2-ND	885.50/M	744232102
2200	1.20	0.2							732-1474-1-ND	2.66	2.22	1.89	732-1474-2-ND	885.50/M	744232222

若订单金额超过S\$135, 可提供免费送货! 全部产品均以新加坡元计价。

www.digikey.sg — 免费电话: 800-1011-692 — 电话: (852) 3104 0500 — 传真: (852) 3104 0686 (SG092-10) 1705