

Fig.	Length Feet (Meters)	Lines	Description	Digi-Key Part No.	1	Price Each 10	25	Assmann Part No.
11	6.56 (2) 9.84 (3)	9	2x D-Sub 9-Pin Male to Female	AE1379-ND AE9871-ND	6.17 7.72	5.43 6.79	4.87 6.09	AK131-2-R AK178-3-R
	6.56 (2) 9.84 (3)	9	2x D-Sub 9-Pin Female to Female	AE9872-ND AE9873-ND	7.66 8.05	6.73 7.08	6.04 6.35	AK152-2-R AK182-3-R
VGA Monitor Extension Cable - IBM PS/2 — RoHS Compliant								
12	6.56 (2)	—	2x HD D-Sub 15-Pin Male to Female	AE1380-ND	8.51	7.49	6.71	AK322-2-R
VGA Monitor Cable - IBM PS/2 — RoHS Compliant								
—	6.56 (2)	—	2x HD D-Sub 15 Pin Male to Male	AE10183-ND	6.47	5.69	5.10	AK532-2-R
Molded VGA to 5 x BNC, Monitor Cable — RoHS Compliant								
—	6.56 (2)	—	HD D-Sub 15-Pin Male to 5 x BNC Male	AE1381-ND	25.31	22.25	19.95	AK553-2-R
Molded Premium VGA Monitor Extension Cable — RoHS Compliant								
13	5.90 (1.8)	—	HD D-Sub 15-Pin Male to HD D-Sub 15-Pin Female	AE9874-ND	13.83	12.16	10.90	AK3220-1.8-R
IBM PC-XT/AT Keyboard Extension								
14	6.56 (2) 16.40 (5)	5	5-Pin Standard DIN Male to Female	AE1023-ND AE10261-ND◆	4.29 12.84	3.77 11.29	3.38 10.12	AK306-2 AK307-5-R
	Molded PS/2 Keyboard Extension — RoHS Compliant							
15	6.56 (2) 16.40 (5)	6	6-Pin MiniDIN Male to Female, Spiral	AE10177-ND AE10262-ND	7.79 14.09	6.85 12.39	6.14 11.11	AK323-2-R AK528-5-R
	6.56 (2)	6	MiniDIN 6-Pin Male to MiniDIN 6-Pin Female, Straight	AE9875-ND	4.13	3.63	3.25	AK323G-2-R
PS/2 Keyboard Cable - Straight — RoHS Compliant								
17	6.56 (2)	6	MiniDIN 6-Pin Male to MiniDIN 6-Pin Male, Molded	AE9876-ND	4.59	4.04	3.62	AK678-2-R
PC Modem (AT Adapter Cable) — RoHS Compliant								
18	.82 (.25) 6.56 (2)	9	D-Sub 9-Pin Female to D-Sub 25-Pin Male D-Sub 9-Pin Female to D-Sub 25-Pin Male	AE1382-ND AE9877-ND	3.86 6.07	3.40 5.34	3.05 4.79	AK128-.25-R AK125-2-R
	Modem Cables — RoHS Compliant							
18	9.84 (3)	9	D-Sub 9-Pin Female to D-Sub 25-Pin Male D-Sub 9-Pin Female to D-Sub 25-Pin Female	AE9878-ND	8.15	7.17	6.43	AK149-3-R
				AE1383-ND	8.12	7.14	6.40	AK124-3-R
Null Modem, Cross-Cables — RoHS Compliant								
19	9.84 (3)	9	D-Sub 9-Pin Female to D-Sub 9-Pin Female D-Sub 9-Pin Male to D-Sub 9-Pin Female	AE9879-ND	8.35	7.34	6.58	AK143-3-R
				AE9880-ND	8.05	7.08	6.35	AK142-3-R
Null Modem, Serial Cables								
20	9.84 (3)	25	D-Sub 25-Pin Female to D-Sub 25-Pin Female	AE1035-ND	4.39	3.86	3.46	AK144-3
			D-Sub 25-Pin Female to D-Sub 25-Pin Female	AE1384-ND◆	7.56	6.65	5.96	AK144-3-R
			D-Sub 25-Pin Male to D-Sub 25-Pin Male	AE1385-ND◆	10.56	9.28	8.32	AK250-3-R
			D-Sub 25-Pin Female to D-Sub 25-Pin Female	AE1037-ND	4.39	3.86	3.46	AK251-3
			D-Sub 25-Pin Female to D-Sub 25-Pin Female	AE1386-ND◆	7.59	6.67	5.98	AK251-3-R
PS/2 Keyboard Adapters								
21	—	—	1 x MiniDIN, 6-Pin Female to 1 x DIN 5-Pin Male	AE1046-ND	3.93	3.46	3.10	AB961
			1 x MiniDIN, 6-Pin Female to 1 x DIN 5-Pin Male	AE1387-ND◆	4.03	3.54	3.18	AB961-R
			1 x MiniDIN, 6-Pin Male to DIN 5-Pin Female	AE1047-ND	3.04	2.67	2.40	AB440
			1 x MiniDIN, 6-Pin Male to DIN 5-Pin Female	AE1388-ND◆	4.09	3.60	3.23	AB440-R
D-Sub Adapters — RoHS Compliant								
22	—	—	9-Pin Male to 25-Pin Male	AE1389-ND	5.02	4.41	3.96	AB913-R
			9-Pin Female to 25-Pin Male	AE9881-ND	4.49	3.95	3.54	AB914-R
			9-Pin Male to 25-Pin Female	AE9882-ND	3.96	3.48	3.12	AB914-F-R
PS/2 Mouse Adapters								
23	—	—	1 x MiniDIN, 6-Pin Female to 1 x D-Sub 9-Pin Female	AE1156-ND	2.05	1.80	1.62	AB406
			1 x MiniDIN, 6-Pin Female to 1 x D-Sub 25-Pin Female	AE1056-ND	7.26	6.38	5.72	AB441
PS/2 Mouse-Cable Adapters								
24	.5 (.15)	—	1 x MiniDIN, 6-Pin Female to 1 x D-Sub 9-Pin Male	AE1154-ND	2.05	1.80	1.62	AB401K
			1 x MiniDIN, 6-Pin Male to 1 x D-Sub 9-Pin Female	AE1393-ND◆	3.20	2.82	2.53	AB450K-R
			1 x MiniDIN, 6-Pin Male to 1 x D-Sub 9-Pin Male	AE1155-ND	2.05	1.80	1.62	AB405K
			1 x MiniDIN, 6-Pin Female to 1 x D-Sub 9-Pin Female	AE1157-ND	2.05	1.80	1.62	AB406K
Jumper Box — RoHS Compliant								
25	—	—	1 x Male, 1 x Female, 25-Pin, Plastic	AE10180-ND	13.30	11.69	10.48	AB972-R
			1 x Male, 1 x Female, 25-Pin, Metalized	AE10182-ND	11.22	9.86	8.84	AB973-R

◆ RoHS Compliant

(Continued)

More Product Available Online: www.digikey.com

Toll-Free: 1-800-344-4539 • Phone 218-681-6674 • Fax: 218-681-3380

A

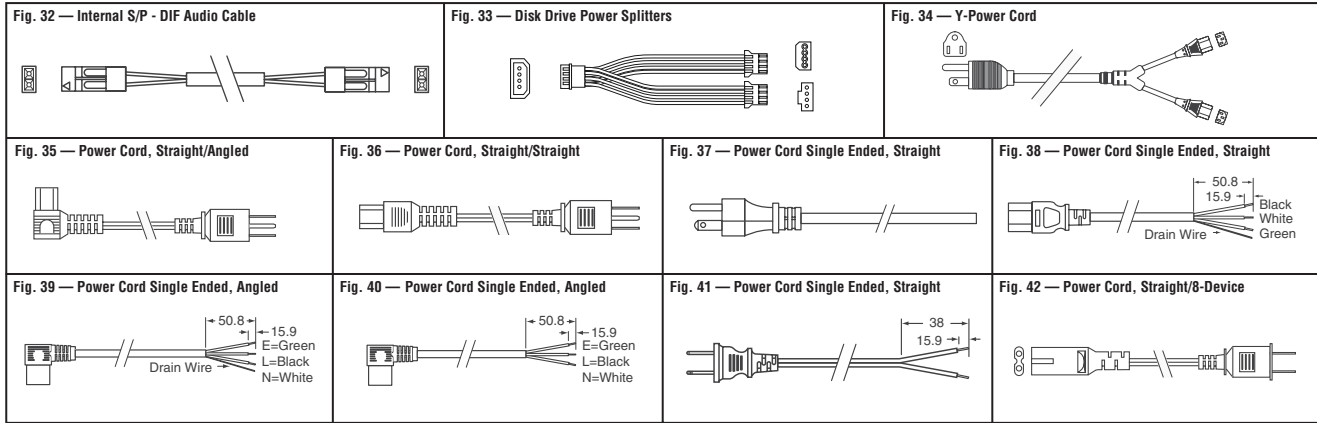


Fig.	Length Feet (Meters)	Lines	Description	Digi-Key Part No.	1	Price Each 10	25	Assmann Part No.			
Wiring Box											
26	—	—	1 x Male, 1 x Female, 25-Pin, Metallized	AE1041-ND	14.62	12.85	11.52	AB947			
D-Sub/RS 232 Adapters — RoHS Compliant											
27	—	—	D-Sub 9-Pin Male to D-Sub 25-Pin Male	AE10291-ND	5.94	5.22	4.68	AB467-R			
			D-Sub 9-Pin Male to D-Sub 25-Pin Female	AE10292-ND	5.18	4.56	4.09	AB468-R			
			D-Sub 9-Pin Female to D-Sub 25-Pin Female	AE10293-ND	5.18	4.56	4.09	AB469-R			
			D-Sub 9-Pin Female to D-Sub 25-Pin Male	AE10294-ND	4.82	4.24	3.80	AB470-R			
Gender Changers — RoHS Compliant											
28	—	—	D-Sub 9 Position Male to Male	AE10295-ND	4.09	3.60	3.23	AB410-R			
			D-Sub 9 Position Female to Female	AE10296-ND	4.09	3.60	3.23	AB411-R			
			D-Sub 15 Position Male to Male	AE10297-ND	4.09	3.60	3.23	AB412-R			
			D-Sub 15 Position Female to Female	AE10298-ND	4.26	3.75	3.36	AB413-R			
			D-Sub 25 Position Male to Male	AE10299-ND	4.26	3.75	3.36	AB414-R			
			D-Sub 25 Position Female to Female	AE10300-ND	4.46	3.92	3.51	AB415-R			
			D-Sub HD 15 Position Male to Male	AE10301-ND	5.18	4.56	4.09	AB418-R			
			D-Sub HD 15 Position Female to Female	AE10302-ND	5.18	4.56	4.09	AB420-R			
D-Sub/RJ Adapters (Beige) — RoHS Compliant											
29	—	—	9 Position Male RJ12 Jack	AE10307-ND	5.38	4.73	4.24	AT-23064-R			
			9 Position Female RJ12 Jack	AE10308-ND	5.38	4.73	4.24	AT-23065-R			
			9 Position Male RJ45 Jack	AE10309-ND	5.38	4.73	4.24	AT-23066-R			
			9 Position Female RJ45 Jack	AE10310-ND	5.38	4.73	4.24	AT-23067-R			
			25 Position Male RJ12 Jack	AE10303-ND	5.74	5.05	4.53	AT-23052-R			
			25 Position Female RJ12 Jack	AE10304-ND	5.74	5.05	4.53	AT-23053-R			
			25 Position Male RJ45 Jack	AE10305-ND	5.74	5.05	4.53	AT-23054-R			
			25 Position Female RJ45 Jack	AE10306-ND	5.74	5.05	4.53	AT-23055-R			
			Power Splitter Cables								
			30	1.64 (0.5)	—	Audio CD-ROM 4 Position 3 Wire	AE1396-ND	1.65	1.45	1.30	AK2525-R
31	1.64 (0.5)	—	Audio CD-ROM 4 Position 3 Wire	AE1397-ND	1.85	1.63	1.46	AK2524-R			
32	1.64 (0.5)	—	Internal Cable 2-Pin Housing/Housing	AE9884-ND	2.31	2.03	1.82	AK2526DVD-R			
33	.66 (.2)	4	Power Cable for 2 - 5 1/4" Drives	AE9885-ND	2.28	2.01	1.80	AK319-2-R			
			Power Cable for 2 - 3 1/2" Drives	AE1398-ND	2.61	2.30	2.06	AK520-2-R			
			Power Cable for 3 1/2" and 5 1/4" Drives	AE1029-ND	1.98	1.74	1.56	AK521-2			
			Power Cable for 3 1/2" and 5 1/4" Drives	AE1399-ND	2.61	2.30	2.06	AK521-2-R			
Y-Power Cord — RoHS Compliant											
34	6.56 (2)	—	1 x Power Plug to 2 x Straight Connector, 10A, 125V	AE9886-ND	19.07	16.77	15.03	AK500/Y-U-R			
Power Cords											
35	6.56 (2)	—	Power Plug, Straight to IEC Connector, Angled, 10A, 125V	AE9887-ND	8.84	7.78	6.97	AK500/U-1-R			
36	6.56 (2)	—	Power Plug, Straight to IEC Connector, Straight, 10A, 125V	AE9888-ND	8.91	7.83	7.02	AK500/U-2-R			
37	6.56 (2)	—	Cord SVT 18AWG 3 Cond Shielded	AE9889-ND	8.51	7.49	6.71	AK500-OE-5-2-R			
	9.84 (3)		Cord SVT 18AWG 3 Cond Shielded	AE9890-ND	11.81	10.39	9.31	AK500-OE-5-3-R			
	6.56 (2)		Cord SJT 18AWG 3 Cond Shielded	AE9891-ND	8.78	7.72	6.92	AK500-OE-6-2-R			
	9.84 (3)		Cord SJT 18AWG 3 Cond Shielded	AE9892-ND	12.34	10.85	9.73	AK500-OE-6-3-R			
	6.56 (2)		Cord SVT 18AWG 3 Cond Shielded	AE9893-ND	8.35	7.34	6.58	AK500-OE-7-2-R			
38	6.56 (2)	—	Cord SJT 18AWG 3 Cond Shielded	AE9895-ND	8.81	7.75	6.95	AK500-OE-9-2-R			
	9.84 (3)		Cord SJT 18AWG 3 Cond Shielded	AE1339-ND	6.27	5.51	4.94	AK500-OE-9-3			
	9.84 (3)		Cord SJT 18AWG 3 Cond Shielded	AE9896-ND	13.99	12.30	11.03	AK500-OE-9-3-R			
39	6.56 (2)	—	Cord SJT 18AWG 3 Cond Shielded	AE1331-ND	4.55	4.01	3.59	AK500-RA-5-2			
	6.56 (2)		Cord SJT 18AWG 3 Cond Shielded	AE9897-ND	8.75	7.69	6.89	AK500-RA-5-2-R			
40	6.56 (2)	—	Cord SVT 18AWG 3 Cond	AE1333-ND	5.64	4.96	4.45	AK500-RA-6-2			
	6.56 (2)		Cord SVT 18AWG 3 Cond	AE9899-ND	6.86	6.04	5.41	AK500-RA-6-2-R			
	6.56 (2)		Cord SJT 18AWG 3 Cond	AE9900-ND	7.82	6.88	6.17	AK500-RA-7-2-R			
	9.84 (3)		Cord SJT 18AWG 3 Cond	AE1335-ND	6.11	5.38	4.82	AK500-RA-7-3			
41	6 (1.83)	—	Cord SPT-1 18AWG 2 Cond	AE9902-ND	5.54	4.88	4.37	AK500-OE-12-6F-R			
	8.99 (2.74)		Cord SPT-1 18AWG 2 Cond	AE9903-ND	7.85	6.91	6.19	AK500-OE-12-9F-R			
	6 (1.83)		Cord SPT-2 18AWG 2 Cond	AE9904-ND	5.74	5.05	4.53	AK500-OE-13-6F-R			
	8 (2.44)		Cord SPT-2 18AWG 2 Cond	AE1348-ND	3.23	2.84	2.55	AK500-OE-13-8F			
42	6.56 (2)	—	Power Plug, Straight to Figure 8 Device Connector, Straight	AE1123-ND	2.92	2.57	2.30	AK500/U-3			
	6.56 (2)		Power Plug, Straight to Figure 8 Device Connector, Straight	AE9906-ND	7.00	6.15	5.52	AK500/U-3-R			
Power Cord Extension											
43	6.56 (2)	—	IEC Plug, Straight to IEC Socket, Straight, 10A, 125V	AE9854-ND	11.02	9.69	8.69	AK500/U-4-R			
	3.28 (1)		Cord SJT 18AWG 3 Cond Shielded	AE1336-ND	3.56	3.13	2.81	AK500-JC-5-1			
	3.28 (1)		Cord SJT 18AWG 3 Cond Shielded	AE9908-ND	10.56	9.28	8.32	AK500-JC-5-1-R			

◆ RoHS Compliant

(Continued)

More Product Available Online: www.digikey.com

Toll-Free: 1-800-344-4539 • Phone 218-681-6674 • Fax: 218-681-3380