


HP = Half Pitch

A

Fig.	Length Meters	Lines	Description	Digi-Key Part No.	Price Each			Assmann Part No.
					1	10	25	
FAST SCSI 2 to SCSI 2 Cable, Shielded, UL 2919 — RoHS Compliant								
1	0.90 2.0	50	HP D-sub 50, HP D-sub, Male Clip to HP D-sub 50, HP D-sub, Male, Clip	AE1428-ND AE1429-ND	27.42 29.67	24.10 26.98	21.61 24.28	AK579/F-1-R AK579/F-2-R
SCSI-2 Series, Round Cable								
2	0.91	50	HP D-sub 50 Male to Centronic 50 Male, A Cable	AE1069-ND	16.60	14.59	13.08	AK-Y1202
SCSI-3 Series, Round Cable								
3	0.91	68	HP D-sub 68 Male X 2, A Cable	AE1430-ND	28.30	25.73	23.16	AK-Y1301-R
4	0.91	50	HP D-sub 68 Male to Centronic 50 Male, A Cable	AE1071-ND	18.94	16.65	14.93	AK-Y1302
SCSI-3 Series, Flat Cable								
5	0.45	68	635mm HP D-sub 68 Male X 2, P Cable	AE1489-ND	17.46	15.35	13.76	AK-Y2301-R
6	1.6	68	635mm HP D-sub 68 Female X 2 to 635mm HP D-sub 68 Male X 8	AE1079-ND	42.17	38.92	36.20	AK-Y2310
Hard Drive Cable for 2 x IDE / AT Bus Hard Drives — RoHS Compliant								
7	0.5	40	(3) 40 Pin Socket Connectors	AE10263-ND	4.19	3.69	3.31	AK5430-5-R
Ultra ATA Flat Cable — RoHS Compliant								
8	0.46	40	Ultra ATA HDD 100Mbps	AE10184-ND	5.54	4.88	4.37	AK-ATA-100-R
Serial ATA Cables — RoHS Compliant								
9	0.3	7	Serial ATA Cable	AE10077-ND	3.17	2.79	2.50	AK-SATA-030-R
	0.5			AE10079-ND	3.43	3.02	2.71	AK-SATA-050-R
	0.75			AE10081-ND	3.66	3.22	2.89	AK-SATA-075-R
	1.0			AE10083-ND	4.16	3.66	3.28	AK-SATA-100-R
	0.3			AE10078-ND	3.53	3.11	2.79	AK-SATA-030DL-R
10	0.5	7	Serial ATA Cable Right Angle	AE10080-ND	3.04	2.67	2.40	AK-SATA-050DL-R
	0.75			AE10082-ND	3.66	3.22	2.89	AK-SATA-075DL-R
	1.0			AE10084-ND	5.87	5.17	4.63	AK-SATA-SP-050-R
11	0.75	7	Serial ATA Cable 4-Pos. Power Connector	AE10085-ND	6.24	5.49	4.92	AK-SATA-SP-075-R
	1.0			AE10086-ND	6.57	5.78	5.18	AK-SATA-SP-100-R
12	0.15	4	Power Supply Cable 15-Pos. - 4-Pos.	AE10087-ND	2.97	2.61	2.34	AK-SATA-PC-015-R
13A	0.5	7	Conn Slotbracket 1-SATA Port	AE10088-ND	6.57	5.78	5.18	AK-SATA-SB1-R
13B	0.5	7	Conn Slotbracket 2-SATA Ports	AE10089-ND	11.85	10.42	9.34	AK-SATA-SB2-R
HDMI / DVI Cables and Adapters — RoHS Compliant								
14	2.0	—	HDMI-A Male to HDMI-A Male Cable	AE10256-ND	22.41	19.70	17.66	AK627-2-R
	3.0			AE10257-ND	25.55	23.23	20.91	AK627-3-R
	5.0			AE10246-ND	30.76	28.38	26.40	AK627-5-R
15	2.0	—	HDMI-A Male to DVI-D Cable	AE10258-ND	21.65	19.03	17.06	AK639-2-R
	3.0			AE10259-ND	23.54	21.40	19.26	AK639-3-R
	5.0			AE10260-ND	29.78	27.48	25.56	AK639-5-R
	—			AE10249-ND	16.47	14.48	12.98	AB556-R
	—			AE10250-ND	16.47	14.48	12.98	AB557-R
—	—	—	HDMI-A Female to DVI-D 24+1, Female Adapter	AE10254-ND	18.12	15.93	14.28	AB566-R
	—			AE10255-ND	16.47	14.48	12.98	AB567-R
	—			AE10251-ND	16.47	14.48	12.98	AB560-R
	—			AE10252-ND	18.12	15.93	14.28	AB561-R
	—			AE10253-ND	16.47	14.48	12.98	AB562-R
IEEE 1394 Cable Double Shielded								
16	1.8	6	6-Pin Male to 6-Pin Male	AE1432-ND	15.08	13.26	11.89	AK-1394-18-R
	3.0			AE1433-ND	18.68	16.42	14.72	AK-1394-30-R
	5.0			AE1434-ND	23.04	21.27	19.78	AK-1394-50-R
17	1.8	5	6-Pin Male to 4-Pin Male	AE1435-ND	13.96	12.27	11.00	AK-1394-184-R
	3.0			AE1436-ND	13.34	12.13	10.92	AK-1394-304-R
	5.0			AE1437-ND	21.04	19.42	18.06	AK-1394-504-R
18	1.8	4	4-Pin Male to 4-Pin Male	AE1127-ND	23.38	21.25	19.13	AK-1394-1844
	3.0			AE1438-ND	11.94	10.85	9.77	AK-1394-1844-R
	5.0			AE1133-ND	29.03	26.79	24.92	AK-1394-5044
IEEE 1394 and USB Connectors								
19	—	—	IEEE 1394 Recept Horizontal SMT	AE7348-ND	2.00	1.76	1.58	A-IE-S-SMT
20	—	—	IEEE 1394 Recept Horizontal PCB	AE9920-ND	2.84	2.50	2.24	A-IE-S-SMT-R
21	—	—	IEEE 1394 Recept Vertical PCB	AE9921-ND	2.71	2.38	2.14	A-IE-S-DIP-R
22	—	4	USB 4P Recept Thru-hole, Type A	AE9922-ND	2.71	2.38	2.14	A-IE-E-DIP-R
23	—	4	USB 4P Recept Thru-hole, Type B	AE9923-ND	83	73	65	AU-Y1005-R
24	—	4	USB 4P Recept Dual Port, Type A	AE9924-ND	1.09	96	86	AU-Y1006-R
24	—	4	USB 4P Recept Dual Port, Type B	AE9925-ND	96	85	76	AU-Y1007-R
24	—	4	USB 4P Recept Dual Port, Type A	AE9926-ND	1.65	1.45	1.30	AU-Y1008-R
USB Plugs and Hoods — RoHS Compliant								
25	—	—	USB A-Male, Solder Version Hood for USB A Male Hood for USB B Male USB B-Male, Solder Version	AE10091-ND	43	38	34	A-USBPA-R
	—			AE10090-ND	40	35	32	A-USBPA-HOOD-R
	—			AE1441-ND	40	35	32	A-USBPB-HOOD-R
	—			AE10178-ND	43	38	34	A-USBPB-R
USB Cables								
26	1.0	4	Cable Mini USB 4-Pin Male	AE1442-ND	4.59	4.04	3.62	AK670M-1-R
	2.0			AE1443-ND	5.64	4.96	4.45	AK670M-2-R
	5.0			AE1283-ND	4.36	3.83	3.44	AK670M-5
	1.0			AE1444-ND	5.18	4.56	4.09	AK670M/2-1-R
27	2.0	4	Cable Mini USB 2.0, 4-Pin Male	AE1445-ND	6.24	5.49	4.92	AK670M/2-2-R
	3.0			AE1446-ND	7.66	6.73	6.04	AK670M/2-3-R
	5.0			AE1447-ND	10.79	9.49	8.51	AK670M/2-5-R
	1.0			AE1448-ND	5.97	5.25	4.71	AK672M-1-R
	2.0			AE9927-ND	6.47	5.69	5.10	AK672M-2-R
28	3.0	4	Cable Mini USB 5-Pin Male	AE9928-ND	6.60	5.80	5.20	AK672M-3-R
	5.0			AE1449-ND	9.37	8.24	7.39	AK672M-5-R
	1.0			AE1450-ND	3.42	2.44	2.32	AK672M/2-1-R
	2.0			AE9929-ND	4.93	3.52	3.35	AK672M/2-2-R
	3.0			AE1451-ND	5.99	4.28	4.07	AK672M/2-3-R
	5.0			AE1452-ND	9.17	8.07	7.23	AK672M/2-5-R
29	1.0	4	Cable Mini USB, 5-Pin Female to 5-Pin Male	AE10311-ND	5.48	4.82	4.32	AK669M-1-R
	2.0			AE10312-ND	6.07	5.34	4.79	AK669M-2-R
30	2.0	4	Cable USB A Male, Open End	AE9855-ND	3.47	2.48	2.36	AK670-OE-R
	5.0			AE9930-ND	6.34	5.57	5.00	AK670-2-R
	1.0			AE1453-ND	11.52	10.13	9.08	AK670-5-R
	3.0			AE1454-ND	4.72	4.15	3.72	AK670/2-1-R
	5.0			AE1455-ND	8.09	7.11	6.37	AK670/2-3-R
	5.0			AE1456-ND	11.65	10.24	9.18	AK670/2-5-R

◆ RoHS Compliant

(Continued)

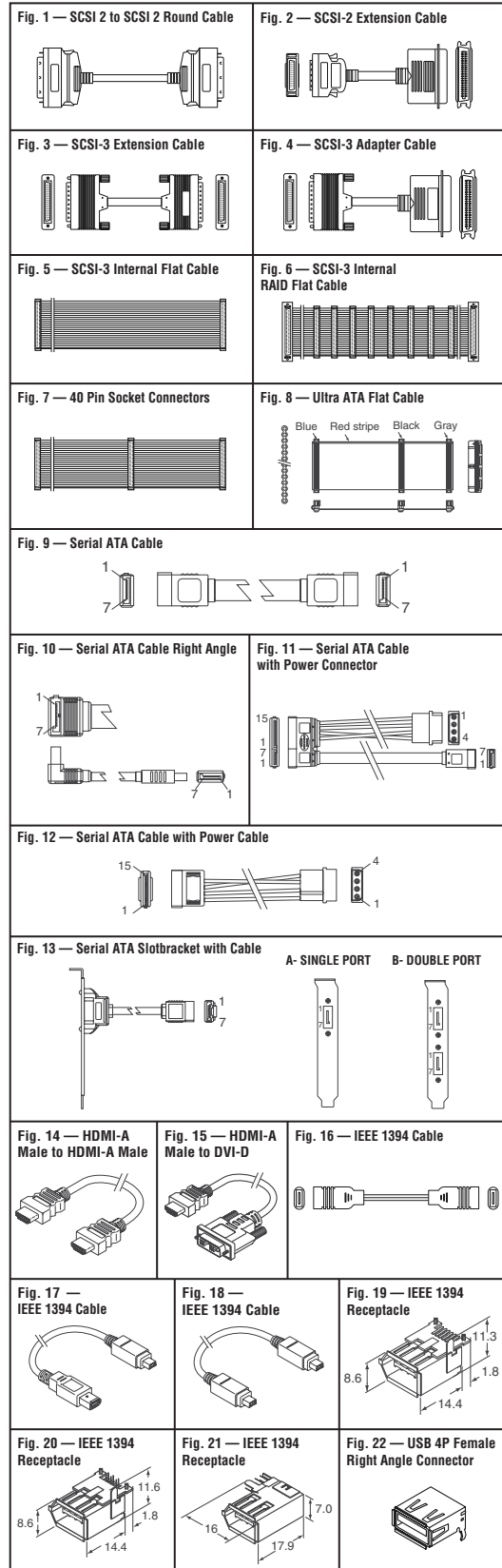

More Product Available Online: www.digkey.com

Toll-Free: 1-800-344-4539 • Phone 218-681-6674 • Fax: 218-681-3380